

Fig.	Description	Dim. - Inch			Digi-Key Part No.	Price Each			NorComp Part No.
		A	B	C		1	10	100	
Slide Lock Posts for Ethernet Hood (980, 981 and 994 Series)									
1	9-Pin, D-Sub or Ethernet	—	—	—	160-099SL-ND	1.77	1.53	1.04	160-009-002-031
	9-Pin, D-Sub or Ethernet	—	—	—	160-099SLA-ND	1.78	1.54	1.05	160-009-002R031
	15-Pin, D-Sub or Ethernet	—	—	—	T2040A-ND	1.42	1.22	83	160-015-003R031
	25-Pin, D-Sub or Ethernet	—	—	—	160-25SLA-ND	2.12	1.83	1.25	160-025-004R031
2	2 Connectors Required	—	—	—	T2042A-ND	.74	.64	.44	160-000-005R031
Dust Cover									
3	Female, 9-Position D-Sub	—	—	—	909DCA-ND	.57	.49	.34	160-000-209R000
	Female, 15-Position D-Sub	—	—	—	915DCA-ND	.86	.75	.51	160-000-215R000
	Female, 25-Position D-Sub	—	—	—	925DCA-ND	.55	.48	.33	160-000-225R000
	Female, 37-Position D-Sub	—	—	—	160-37FA-ND	.71	.61	.42	160-000-237R000
	Female, 50-Position D-Sub	—	—	—	160-50F-ND	.75	.65	.45	160-000-250-000
	Female, 50-Position D-Sub	—	—	—	160-50FA-ND	.80	.69	.47	160-000-250R000
3	Male, 9-Position D-Sub	—	—	—	160-09MA-ND	.58	.51	.35	160-000-109R000
	Male, 15-Position D-Sub	—	—	—	160-15MA-ND	.58	.51	.35	160-000-115R000
	Male, 25-Position D-Sub	—	—	—	160-25M-ND	.55	.48	.33	160-000-125-000
	Male, 25-Position D-Sub	—	—	—	160-25MA-ND	.61	.53	.37	160-000-125R000
	Male, 37-Position D-Sub	—	—	—	160-37MA-ND	.71	.61	.42	160-000-137R000
	Male, 50-Position D-Sub	—	—	—	160-50MA-ND	.80	.69	.47	160-000-150R000
Shielded Dust Cover									
3	Female, 9-Position D-Sub	—	—	—	160-209F-ND	3.13	2.70	1.84	160-020-209-000
	Female, 9-Position D-Sub	—	—	—	160-209FA-ND	3.66	3.16	2.15	160-020-209R000
	Female, 15-Position D-Sub	—	—	—	160-215F-ND	3.28	2.83	1.93	160-020-215-000
	Female, 15-Position D-Sub	—	—	—	160-215FA-ND	3.81	3.29	2.24	160-020-215R000
	Female, 25-Position D-Sub	—	—	—	160-225F-ND	3.54	3.05	2.08	160-020-225-000
	Female, 25-Position D-Sub	—	—	—	160-225FA-ND	4.12	3.55	2.42	160-020-225R000
3	Male, 9-Position D-Sub	—	—	—	160-209M-ND	2.87	2.48	1.69	160-020-109-000
	Male, 9-Position D-Sub	—	—	—	160-209MA-ND	3.04	2.63	1.79	160-020-109R000
	Male, 15-Position D-Sub	—	—	—	160-215M-ND	3.50	3.02	2.06	160-020-115R000
	Male, 25-Position D-Sub	—	—	—	160-225M-ND	3.22	2.78	1.89	160-020-125-000
	Male, 25-Position D-Sub	—	—	—	160-225MA-ND	3.75	3.24	2.20	160-020-125R000
	Cover Flange — RoHS Compliant								
4	Female, 9-Position D-Sub	1.209	.984	.642	CF09S-ND	2.54	1.72	1.33	CF09S
	Female, 15-Position D-Sub	1.535	1.312	.969	CF15S-ND	2.69	1.77	1.43	CF15S
	Female, 25-Position D-Sub	2.083	1.852	1.512	CF25S-ND	2.73	1.85	1.50	CF25S
	Female, 37-Position D-Sub	2.728	2.500	2.157	CF37S-ND	3.24	2.16	1.77	CF37S
	Female, 50-Position D-Sub	2.626	2.406	2.059	CF50S-ND	3.54	2.44	1.99	CF50S
	Male, 9-Position D-Sub	1.205	.984	.669	CF09P-ND	2.54	1.72	1.33	CF09P
Male, 15-Position D-Sub	1.535	1.312	.996	CF15P-ND	2.69	1.77	1.43	CF15P	

Fig.	Description	Dim. - Inch			Digi-Key Part No.	Price Each			NorComp Part No.		
		A	B	C		1	10	100			
5	Male, 25-Position D-Sub	2.079	1.852	1.535	CF25P-ND	2.73	1.85	1.50	CF25P		
	Male, 37-Position D-Sub	2.724	2.500	2.181	CF37P-ND	3.24	2.16	1.77	CF37P		
	Male, 50-Position D-Sub	2.626	2.406	2.079	CF50P-ND	3.54	2.44	1.99	CF50P		
Silicon Sealing Flange — RoHS Compliant											
6	9-Position	1.299	.984	.717	SF09-ND	1.04	.68	.49	SF09		
	15-Position	1.614	1.311	1.039	SF15-ND	1.25	.80	.58	SF15		
	25-Position	2.165	1.850	1.583	SF25-ND	1.33	.82	.62	SF25		
37-Position	2.835	2.500	2.228	SF37-ND	1.48	.96	.70	SF37			
4-40 Female Coupling Nut — RoHS Compliant											
7	Brass Finish, Yellow Chromate Plated	—	—	—	160-106YCA-ND	.38	.22	.14	160-000-006R042		
	Brass Finish, Nickel Plated	—	—	—	160-06YCA-ND	.19	.16	.11	160-000-006R032		
4-40 Male Screwlock with Slip-On Retainer — RoHS Compliant											
8	Steel Finish, Nickel Plated	—	—	—	160-01MYCA-ND	1.20	1.04	.71	160-000-001R031		
4-40 Male Screwlock with Clip-On Retainer (2 screws, 2 clips) — RoHS Compliant											
9	Screw - Steel, Nickel Plated, Clip - Stainless Steel	—	—	—	160-02MA-ND	.86	.75	.51	160-000-002R031		
Plastic Clips for Retaining Connectors to PC .062" Board											
10	Nylon	—	—	—	163-01P-ND	25	.15	.11	163-001-000-000		
4-40 Female Screwlock Assembly — RoHS Compliant											
11	Steel Finish, Nickel Plated	.187	.312	—	160-10FA-ND	.74	.64	.44	160-000-010R031		
		.187	.625	—	160-11FA-ND	.98	.85	.58	160-000-011R031		
		.250	.156	—	160-12FA-ND	.80	.69	.47	160-000-012R031		
		.197	.197	—	160-13FA-ND	.71	.61	.42	160-000-013R031		
		.197	.236	—	160-14FA-ND	.68	.59	.40	160-000-014R031		
		.197	.323	—	160-15FA-ND	.68	.59	.40	160-000-015R031		
11	Steel Finish, Nickel Plated	.197	.433	—	160-16FA-ND	.80	.69	.47	160-000-016R031		
		.197	.520	—	160-17FA-ND	.68	.59	.40	160-000-017R031		
		.197	.669	—	160-18FA-ND	.96	.83	.56	160-000-018R031		
		4-40 Female Screwlock — RoHS Compliant									
		11	Steel Finish, Nickel Plated	.187	.312	—	SFS04401NR-ND	.45	.26	.17	SFS04401NR
				.197	.197	—	SFS04404NR-ND	.45	.26	.17	SFS04404NR
4-40 Thumbscrew — Steel Finish, Nickel Plated — RoHS Compliant											
12	For 977/ 978/ 979 Series Backshells	1.75	.625	—	160-02TSA-ND	25	.22	.15	160-000-050R031		
M2.6 Thumbscrew — Steel Finish, Nickel Plated — RoHS Compliant											
12	For 970/ 972 Series Backshells	1.811	.360	—	160-03TSA-ND	.74	.64	.44	160-000-060R031		
Tool											
—	Insertion/Removal Tool	—	—	—	T2020-ND	9.07	—	—	180-901-170-000		

♦ RoHS Compliant † Hex Nuts and Washers NOT Included

Parallel Interface Connectors (Centronics Type)

Material: • Insulator: Glass filled thermoplastic, UL 94V-0 rated • Shell: Steel, Nickel plated • Contacts: Copper alloy, 10µ gold over 30µ nickel

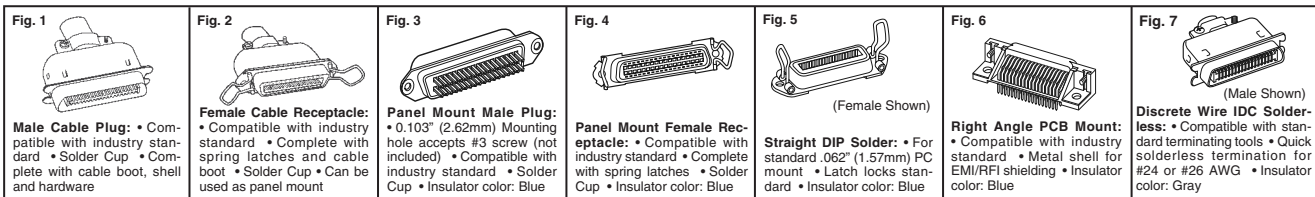


Fig.	No. of Contacts	Type	Digi-Key Part No.	Price Each			NorComp Part No.
				1	10	100	
1	14	Male	T1501A-ND	3.94	3.40	2.31	110-014-103L001
	36		T1503A-ND	4.00	3.45	2.35	110-036-103L001
	50		T1504A-ND	7.08	6.11	4.16	110-050-103L001
2	14	Female	T1507A-ND	4.45	3.84	2.62	110-014-203L001
	36		T1509A-ND	5.05	4.36	2.97	110-036-203L001
	50		T1510A-ND	7.80	6.72	4.57	110-050-203L001
3	14	Male	1014M-ND	2.51	2.16	1.47	111-014-103-001
	14		1014MA-ND	2.72	2.35	1.60	111-014-103L001
	24		1024M-ND	2.69	2.33	1.58	111-024-103-001
	24		1024MA-ND	2.92	2.52	1.72	111-024-103L001
	36		1036M-ND	2.61	2.26	1.54	111-036-103-001
	36		1036MA-ND	2.83	2.44	1.66	111-036-103L001
4	14	Female	1014F-ND	4.26	3.70	2.52	111-014-203L001
	14		1014FA-ND	2.86	2.47	1.68	111-014-203L001
	24		1024F-ND	4.26	3.68	2.50	111-024-203-001
	24		1024FA-ND	4.70	4.06	2.76	111-024-203L001
	36		1036F-ND	3.39	2.93	1.99	111-036-203L001
	50		1050F-ND	5.36	4.62	3.14	111-050-203L001
5	14	Male	1014PMA-ND	3.38	2.92	1.99	111-014-113L001
	24		1024PM-ND	4.52	3.90	2.66	111-024-113-001
	24		1024PMA-ND	5.14	4.44	3.02	111-024-113L001
36	1036PM-ND	4.88	4.21	2.86	111-036-113-001		

Fig.	No. of Contacts	Type	Digi-Key Part No.	Price Each			NorComp Part No.
				1	10	100	
5	36	Male	1036PMA-ND	5.55	4.79	3.26	111-036-113L001
	50		1050PMA-ND	6.21	5.35	3.64	111-050-113L001
	14		1014PFA-ND	3.13	2.70	1.84	111-014-213L001
	24		1024PF-ND	2.97	2.57	1.75	111-024-213-001
	24		1024PFA-ND	3.38	2.92	1.99	111-024-213L001
	36		1036PFA-ND	4.98	4.30	2.92	111-036-213L001
6	14	Male	1050PFA-ND	7.72	6.66	4.53	111-050-213L001
	14		1014RM-ND	3.18	2.74	1.87	112-014-113-001
	14		1014RMA-ND	5.33	3.90	3.18	112-014-113R001
	24		1024RM-ND	3.58	3.09	2.10	112-024-113-001
	24		1024RMA-ND	4.92	3.50	2.87	112-024-113R001
	36		1036RMA-ND	6.04	5.21	3.55	112-036-113R001
6	14	Female	1050RM-ND	6.39	5.51	3.75	112-050-113-001
	14		1050RMA-ND	7.26	6.27	4.26	112-050-113R001
	14		1014RF-ND	3.69	3.19	2.17	112-014-213-001
	14		1014RFA-ND	5.43	3.98	3.24	112-014-213R001
	24		1024RFA-ND	5.09	3.70	2.96	112-024-213R001
	36		1036RFA-ND	5.30	4.58	3.11	112-036-213R001
7	50	Male	1050RF-ND	6.68	5.76	3.92	112-050-213-001
	50		1050RFA-ND	7.60	6.56	4.46	112-050-213R001
	36		1036CM-ND	10.18	8.78	5.97	110-036-193-001

♦ RoHS Compliant

More Product Available Online: www.digkey.com

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380