

A

Series	Fig.	Description	Pos. - Contacts	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each		Stewart Part No.
				A	B	C		1	25	
65	7	Jack, 1pc Shield with Stops	10-8	.670 (17.02)	.640 (16.26)	.670 (17.02)	380-1027-ND	2.27	2.13	SS-650810S-A-FLS
		Jack, 1pc Shield without Stops	10-8	.670 (17.02)	.640 (16.26)	.670 (17.02)	380-1028-ND	2.27	2.13	SS-650810S-A-NF
		Jack, Unshielded without Stops	10-10	.650 (16.51)	.615 (15.62)	.644 (16.36)	380-1029-ND	1.70	1.59	SS-651010-A-NF
		Jack, Unshielded with Stops	10-10	.650 (16.51)	.615 (15.62)	.644 (16.36)	380-1113-ND	1.15	1.08	SS65100-030F
66	8	Jack, Unshielded, 2 Port without Stops	6-6	.815 (20.70)	.848 (21.54)	.503 (12.78)	380-1031-ND	3.71	3.48	SS-666602-NF
		Jack, Unshielded, 4 Port without Stops	6-6	.815 (20.70)	1.744 (44.30)	.503 (12.78)	380-1032-ND	4.93	4.62	SS-666604-NF
		Jack, Unshielded, 6 Port without Stops	6-6	.815 (20.70)	2.640 (67.06)	.503 (12.78)	380-1033-ND	11.17	10.47	SS-666606-NF
		Jack, Shielded, 4 Port without Stops	8-8	.865 (21.97)	2.100 (53.34)	.545 (13.84)	380-1035-ND	6.50	6.09	SS-668804S-A-PG4-AC
		Jack, Unshielded, 4 Port without Stops	8-8	.815 (20.70)	4.300 (109.22)	.523 (13.28)	380-1034-ND	3.20	3.00	SS-668804-NF
		Jack, Shielded, 8 Port without Stops	8-8	.865 (21.97)	4.300 (109.22)	.545 (13.84)	380-1036-ND	11.23	10.53	SS-668808S-A-PG4-AC
		Jack, Unshielded, with Stops	6-6	.725 (18.42)	.526 (13.34)	.505 (12.83)	380-1037-ND	2.88	2.70	SS6666F-FLS-C40
		Jack, Unshielded without Stops	6-4	.712 (18.08)	.525 (13.33)	.453 (11.51)	380-1042-ND	1.54	1.44	SS-7046-NF
70	5	Jack, Unshielded without Stops	6-6	.712 (18.08)	.525 (13.33)	.453 (11.51)	380-1043-ND	1.63	1.53	SS-7066-NF
		Jack, Unshielded without Stops	10-8	.712 (18.08)	.600 (15.24)	.453 (11.51)	380-1038-ND	1.09	1.02	SS-700810-NF
		Jack, 1pc Shield without Stops, Alternate Style Shield Ground Tail	10-8	.738 (18.74)	.626 (15.90)	.475 (12.06)	380-1039-ND	2.43	2.28	SS-700810S-A-PG4-1-BA
		Jack, 1pc Shield without Stops	10-8	.738 (18.74)	.626 (15.90)	.475 (12.06)	380-1040-ND	2.43	2.28	SS-700810S-A-PG4-BA
71	5	Jack, Unshielded without Stops	8-8	.815 (20.70)	.605 (15.36)	.505 (12.82)	380-1046-ND	1.02	.96	SS-7188-NF
		Jack, 1pc Shield without Stops, Without Panel Stop Flanges	8-8	.815 (20.70)	.605 (15.36)	.505 (12.82)	380-1047-ND	1.98	1.86	SS-7188S-A-NF
		Jack, 1pc Shield without Stops, Alternate Style Shield Ground Tail	8-8	.850 (21.59)	.635 (16.13)	.550 (13.97)	380-1048-ND	1.98	1.86	SS-7188S-A-PG4-1-BA
		Jack, 1pc Shield without Stops, Standard Shield Ground Tail	8-8	.850 (21.59)	.635 (16.13)	.550 (13.97)	380-1049-ND	1.98	1.86	SS-7188S-A-PG4-BA
	7	Jack, Unshielded without Stops	8-8	.650 (16.51)	.615 (15.62)	.644 (16.36)	380-1050-ND	.93	.87	SS-7188V-A-NF
		Jack, Standard Shield without Stops	8-8	.670 (17.02)	.640 (16.26)	.670 (17.02)	380-1051-ND	2.62	2.46	SS-7188V-A-NF
		Jack, 1pc Shield, 2 Port without Stops	8-8	.815 (20.70)	1.205 (30.61)	.523 (13.28)	380-1044-ND	7.97	7.47	SS-718802S-A-NF
		Jack, 1pc Shield, 4 Port	8-8	.815 (20.70)	2.305 (58.55)	.523 (13.28)	380-1045-ND	9.44	8.85	SS-718804S-A-PG4-AC
73	11	Jack, Shielded, 12 Port without Stops	8-8	1.103 (28.02)	3.429 (87.10)	1.004 (25.50)	380-1052-ND	16.80	15.75	SS-73100-046
		Jack, Shielded, 16 Port without Stops	8-8	1.103 (28.02)	4.529 (115.04)	1.004 (25.50)	380-1053-ND	24.00	22.50	SS-73100-047
80	12	Jack, Unshielded, Cable Ready	10-8	1.300 (33.02)	.750 (19.05)	.780 (19.81)	380-1078-ND	6.24	5.85	SS-800810S8-SP50-040-250
82	12	Jack, CAT-5e, Unshielded, Cable Ready	8-8	1.073 (27.25)	.619 (15.72)	.654 (16.61)	380-1100-ND	5.28	4.95	SS-82000-002
		Jack, CAT-5e, Shielded, Cable Ready	8-8	1.51 (38.35)	.690 (17.53)	.680 (17.27)	380-1101-ND	9.02	8.46	SS-82100-001
<b>ARJ45™ Category 7a — RoHS Compliant</b>										
77	13	Jack, CAT-7a, Shielded	8-8	.860 (21.84)	.600 (15.24)	.530 (13.46)	380-1125-ND	12.13	11.37	SS-77100-004

\* Note: Pins without electrical connections may be omitted. ♦ RoHS Compliant


Modular Connector Plugs



Series	Fig.	Description	Pos. - Contacts	Crimp Tool with Die	Die only	Dimensions - Inch (mm)				Digi-Key Part No.	Price Each		Stewart Part No.
						A	B	C	D		1	25	
<b>Unshielded Plugs (any die works with all crimp tools used for unshielded plugs)</b>													
30	15	Plug, Handset	4-4	380-1055-ND	380-1059-ND	.525 (13.33)	.300 (7.62)	.260 (6.60)	.485 (12.32)	380-1002-ND	.22	.21	940-SP-3044
		Plug	6-2	380-1056-ND	380-1060-ND	.525 (13.33)	.380 (9.65)	.260 (6.60)	.534 (13.57)	380-1001-ND	.19	.18	940-SP-3026
		Plug	6-4	380-1056-ND	380-1060-ND	.525 (13.33)	.380 (9.65)	.260 (6.60)	.534 (13.57)	380-1003-ND	.22	.21	940-SP-3046
		Plug	6-6	380-1056-ND	380-1060-ND	.525 (13.33)	.260 (6.60)	.260 (6.60)	.534 (13.57)	380-1004-ND	.26	.24	940-SP-3066
		Plug, .038" (.965mm) OD Cable	8-8	380-1057-ND	380-1061-ND	.885 (22.48)	.460 (11.68)	.312 (7.92)	.622 (15.80)	380-1005-ND	.38	.36	940-SP-3088R
		Plug, .040" (1.02mm) OD Cable	8-8	380-1057-ND	380-1061-ND	.885 (22.48)	.460 (11.68)	.312 (7.92)	.622 (15.80)	380-1006-ND	.42	.39	940-SP-3088R-A133
		Plug	10-10	380-1058-ND	380-1062-ND	.885 (22.48)	.460 (11.68)	.312 (7.92)	.622 (15.80)	380-1000-ND	.58	.54	940-SP-301010R
		Plug, CAT-5e	8-8	380-1057-ND	380-1061-ND	.884 (22.46)	.460 (11.68)	.312 (7.92)	.622 (15.80)	380-1008-ND	.48	.45	943-SP-3088R2-A264
		Plug, CAT-5e	8-8	380-1057-ND	380-1061-ND	.885 (22.48)	.460 (11.68)	.312 (7.92)	.622 (15.80)	380-1098-ND	.42	.39	SS-37000-002
		39	15	Plug, CAT-6, Anti-Snag	8-8	380-1134-ND	380-1131-ND	1.47 (37.34)	.460 (11.68)	.312 (7.92)	380-1092-ND	1.12	1.05
<b>Shielded and Specialty Plugs (require special crimp tools and die)</b>													
36	15	Plug	8-8	380-1133-ND	380-1135-ND	1.046 (26.57)	.460 (11.68)	.360 (9.14)	—	380-1007-ND	1.09	1.02	940-SP-360808-A108
37	15	Plug, CAT-5e	8-8	380-1133-ND	380-1135-ND	.884 (22.46)	.460 (11.68)	.360 (9.14)	—	380-1009-ND	1.34	1.26	943-SP-370808SM2A264
		Plug, CAT-5e	8-8	380-1057-ND	380-1061-ND	.897 (22.78)	.460 (11.68)	.321 (8.15)	—	380-1099-ND	1.02	.96	SS-37200-028
		Plug, CAT-6a	8-8	380-1133-ND	380-1130-ND	.884 (22.46)	.460 (11.68)	.312 (7.92)	.622 (15.80)	380-1014-ND	2.08	1.95	SS-39100-002
39	15	Plug, CAT-6	8-8	380-1132-ND	—	1.67 (42.4)	.540 (13.71)	.312 (7.92)	—	380-1093-ND	1.70	1.59	SS-39200-011

‡ Crimp tool only, Die must be purchased separately

Crimp Tools and Die Sets

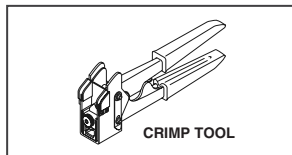


Positions	Digi-Key Part No.	Price Each	Stewart Part No.
<b>Crimp Tool with Die Set</b>			
4	380-1055-ND	93.00	2990001-01
6	380-1056-ND	93.00	2990002-01
8	380-1057-ND	93.00	2990003-01
8	380-1134-ND	124.00	2990009-01
10	380-1058-ND	93.00	2990007-01
8	380-1132-ND	287.50	2980075-01
8	380-1133-ND	230.00	2940231-01

Positions	Digi-Key Part No.	Price Each	Stewart Part No.
<b>Die Set Modular</b>			
4	380-1059-ND	28.50	2990004-01
6	380-1060-ND	28.50	2990005-01
8	380-1061-ND	28.50	2990006-01
8	380-1131-ND	28.50	2990010-01
10	380-1062-ND	28.50	2990008-01
8	380-1129-ND	210.00	295029-01
8	380-1130-ND	210.00	295014-01
8	380-1135-ND	274.00	2906253-01

‡ Crimp tool only, Die must be purchased separately

 CAT5e and CAT6 Jumpers



Available Through Digi-Key®

**Enhanced CAT-5 Cords:** Enhanced patch cords built using high performance Stewart 37 Series plugs optimized for consistent, reliable performance in high speed networking applications.


**CAT-6 Cords:** Patch cords built using high performance Stewart 39 Series plugs which are designed and manufactured to meet or exceed the current EIA/TIA CAT-6 specs.

Description Ft. (Meter)	Digi-Key Part No.	Price Each
<b>Cat-5 — Enhanced</b>		
15' (4.572)	380-1072-ND	6.42
<b>Cat-6</b>		
15' (4.572)	380-1071-ND	9.98
25' (7.62)	380-1075-ND	26.72

Modular Components

Fig.	Description	Digi-Key Part No.	1	50
1	DB9S to RJ45 Jack (8-8)	046-0001-ND	4.13	37.13 165.00
2	DB9P to RJ45 Jack (8-8)	046-0002-ND	4.13	37.13 165.00
1	DB9S to RJ12 Jack (6-6)	046-0003-ND	4.13	37.13 165.00
2	DB9P to RJ12 Jack (6-6)	046-0004-ND	4.13	37.13 165.00
1	DB15S to RJ45 (8-8)	046-0005-ND	4.63	41.63 185.00
2	DB15P to RJ45 (8-8)	046-0004-ND	4.63	41.63 185.00
1	DB25S to RJ12 (6-6)	046-0009-ND	4.38	39.38 175.00
2	DB25P to RJ12 (6-6)	046-0008-ND	4.38	39.38 175.00
1	DB25S to RJ45 (8-8)	046-0011-ND	4.38	39.38 175.00
2	DB25P to RJ45 (8-8)	046-0010-ND	4.38	39.38 175.00
1	DB15S to RJ12 (6-6)	046-0017-ND	4.63	41.63 185.00
2	DB15P to RJ12 (6-6)	046-0016-ND	4.63	41.63 185.00
3	BNC RJ12 Converter (6-6)	048-0000-ND	16.58	149.18 653.00
4	4 Wire TEE Adapter 1M-2F	048-0050-ND	2.75	24.75 110.00
4	6 Wire TEE Adapter 1M-2F	048-0051-ND	4.05	36.45 162.00
5	6-6 Modular Coupling (crossed) #1 to #6	048-0056-ND	2.28	20.48 91.00
	6-6 Modular Coupling (straight) #1 to #1	048-0103-ND	2.28	20.48 91.00
6	6 Wire Wall Plate (6-6)	048-0061-ND	2.70	24.30 108.00
	8 Wire Wall Plate (8-8)	048-0062-ND	3.35	30.15 134.00

\* User Configurable ♦ RoHS Compliant

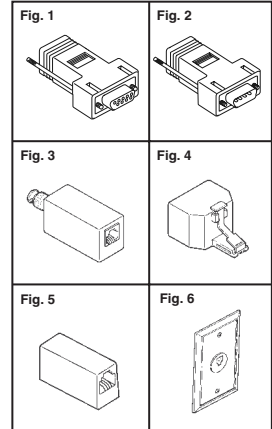

More Product Available Online: [www.digkey.com](http://www.digkey.com)