




## BNC Connectors and Reversed Polarized Connectors

A

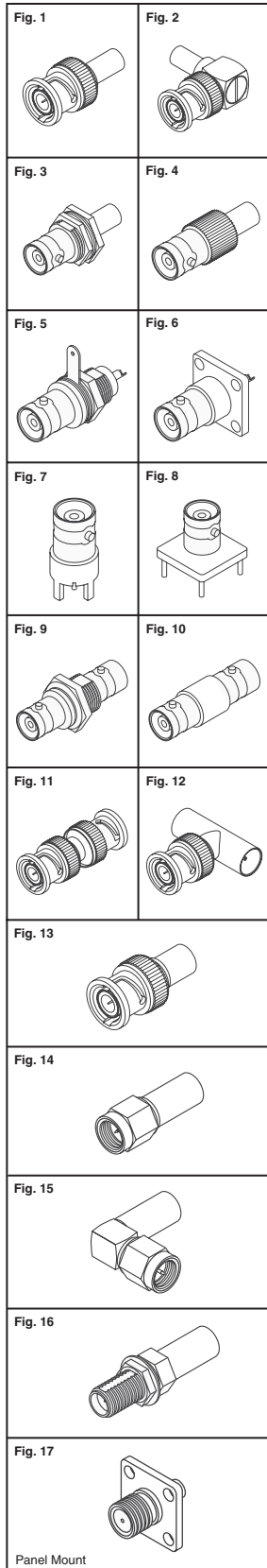


| Fig.                               | Description                                 | Cable Group<br>RG/U                       | Center<br>Contact | Body<br>Plating | Cable Attachment<br>Outer / Inner | Digi-Key<br>Part No. | Price Each  |      |      | Amphenol<br>Part No. |          |
|------------------------------------|---|---|-------------------|-----------------|-----------------------------------|----------------------|-------------|------|------|----------------------|----------|
|                                    |   |   |                   |                 |                                   |                      | 1           | 50   | 100  |                      |          |
| 1                                  | Plug, Straight                              | 58, 58A, 58C, 141, 303, LMR195™, B7806A   | Gold              | Nickel          | Crimp Crimp                       | ACX1000-ND           | 2.11        | 1.32 | 1.17 | 112116               |          |
|                                    | Plug, Straight                              | 58, 58A, 58C, 141, 303, LMR195, B7806A    | Gold              | Nickel          | Crimp Crimp                       | ACX1001-ND*          | 3.32        | 2.08 | 1.84 | 112116RP             |          |
|                                    | Plug, Straight                              | RG 55, 142A, 223, 400                     | Gold              | Nickel          | Crimp Crimp                       | ACX1002-ND           | 2.09        | 1.31 | 1.16 | 112514               |          |
|                                    | Plug, Straight                              | LMR200™, B7807A                           | Gold              | Nickel          | Crimp Crimp                       | ACX1003-ND           | 2.48        | 1.55 | 1.37 | 112597               |          |
|                                    | Plug, Straight                              | RG 59, 62, 140, 210                       | Gold              | Nickel          | Crimp Crimp                       | ACX1004-ND           | 2.12        | 1.32 | 1.17 | 112119               |          |
|                                    | Plug, Straight                              | RG 59, U-20AWG                            | Gold              | Nickel          | Crimp Crimp                       | ACX1005-ND           | 2.08        | 1.30 | 1.15 | 112507               |          |
|                                    | Plug, Straight                              | 174, 188A, 316, B7805A, LMR100            | Gold              | Nickel          | Crimp Crimp                       | ACX1006-ND           | 2.68        | 1.67 | 1.48 | 112132               |          |
|                                    | Plug, Straight                              | 174, 188A, 316, B7805A, LMR100            | Gold              | Nickel          | Crimp Crimp                       | ACX1007-ND*          | 3.35        | 2.09 | 1.86 | 112132RP             |          |
|                                    | Plug, Straight                              | 316, U Double Braided                     | Gold              | Nickel          | Crimp Crimp                       | ACX1008-ND           | 2.68        | 1.67 | 1.48 | 112512               |          |
|                                    | Plug, Straight                              | RG 179, 187, B9221                        | Gold              | Nickel          | Crimp Crimp                       | ACX1009-ND           | 2.68        | 1.67 | 1.48 | 112133               |          |
|                                    | Plug, Straight                              | 179, U Double Braided                     | Gold              | Nickel          | Crimp Crimp                       | ACX1010-ND           | 2.70        | 1.69 | 1.50 | 112644               |          |
|                                    | Plug, Straight                              | RG 178, 196                               | Gold              | Nickel          | Crimp Crimp                       | ACX1011-ND           | 3.04        | 1.90 | 1.68 | 112516               |          |
| 2                                  | Plug, Straight                              | RG 8, 8A, 213, 393                        | Gold              | Nickel          | Crimp Crimp                       | ACX1012-ND           | 6.57        | 4.11 | 3.64 | 112562               |          |
|                                    | Plug, Straight                              | RG 214                                    | Gold              | Nickel          | Crimp Crimp                       | ACX1013-ND           | 6.57        | 4.11 | 3.64 | 112589               |          |
|                                    | Plug, Straight                              | RG 8X, LMR240™, B7808A                    | Gold              | Nickel          | Crimp Crimp                       | ACX1014-ND           | 2.21        | 1.39 | 1.23 | 112533               |          |
|                                    | Plug, Straight                              | RG 8X, LMR240™, B7808A                    | Gold              | Nickel          | Crimp Crimp                       | ACX1015-ND*          | 3.32        | 2.08 | 1.84 | 112533RP             |          |
|                                    | Plug, Straight                              | B9913, LMR400™, B7810A, B8214             | Gold              | Nickel          | Crimp Crimp                       | ACX1016-ND           | 6.57        | 4.11 | 3.64 | 112563               |          |
|                                    | Plug, Straight                              | B9913, LMR400, B7810A, B8214              | Gold              | Nickel          | Crimp Crimp                       | ACX1017-ND*          | 6.85        | 4.28 | 3.79 | 112563RP             |          |
|                                    | Plug, Straight                              | RG 6, 143, 212                            | Gold              | Nickel          | Crimp Crimp                       | ACX1018-ND           | 2.18        | 1.37 | 1.21 | 112508               |          |
|                                    | Plug, Straight                              | RG B1694A, B9248                          | Gold              | Nickel          | Crimp Crimp                       | ACX1019-ND           | 2.19        | 1.37 | 1.21 | 112565               |          |
|                                    | Plug, Straight                              | RG 6 Plenum, B1695A                       | Gold              | Nickel          | Crimp Crimp                       | ACX1020-ND           | 2.23        | 1.39 | 1.23 | 112519               |          |
|                                    | Plug, Straight                              | .141 Semi-Rigid, 402, U                   | Gold              | Gold            | Solder Solder                     | ACX1021-ND           | 3.07        | 1.92 | 1.70 | 112551               |          |
|                                    | Plug, Straight                              | .085 Semi-Rigid, 405, U                   | Gold              | Gold            | Solder Solder                     | ACX1022-ND           | 3.07        | 1.92 | 1.70 | 112552               |          |
|                                    | Plug, Straight                              | .250 Semi-Rigid                           | Gold              | Gold            | Solder Solder                     | ACX1023-ND           | 2.76        | 1.73 | 1.53 | 112710               |          |
| 3                                  | Plug, Right Angle                           | 58, 58A, 58C, 141, 303, LMR195, B7806A    | Gold              | Nickel          | Crimp Solder                      | ACX1024-ND           | 4.62        | 2.89 | 2.56 | 112162               |          |
|                                    | Plug, Right Angle                           | 55, 142A, 223, 400                        | Gold              | Nickel          | Crimp Solder                      | ACX1025-ND           | 5.66        | 3.54 | 3.13 | 112526               |          |
|                                    | Plug, Right Angle                           | RG 8, 8A, 213, 393                        | Gold              | Nickel          | Crimp Solder                      | ACX1026-ND           | 6.84        | 4.28 | 3.79 | 112594               |          |
|                                    | Plug, Right Angle                           | B9913, LMR400, B7810A, B8214              | Gold              | Nickel          | Crimp Solder                      | ACX1027-ND           | 6.84        | 4.28 | 3.79 | 112596               |          |
|                                    | Plug, Right Angle                           | RG 174, 188A, 316                         | Gold              | Nickel          | Crimp Solder                      | ACX1028-ND           | 5.04        | 3.15 | 2.79 | 112178               |          |
|                                    | Plug, Right Angle                           | RG 179, 187A                              | Gold              | Nickel          | Crimp Solder                      | ACX1029-ND           | 4.99        | 3.12 | 2.76 | 112179               |          |
|                                    | Bulkhead Jack                               | 58, 58A, 58C, 141, 303, LMR195, B7806A    | Gold              | Nickel          | Crimp Crimp                       | ACX1030-ND           | 4.42        | 2.76 | 2.45 | 112202               |          |
|                                    | Bulkhead Jack                               | RG 58, 58A, 58C, 141, 303, LMR195, B7806A | Gold              | Nickel          | Crimp Crimp                       | ACX1031-ND*          | 3.88        | 2.43 | 2.15 | 112202RP             |          |
|                                    | Bulkhead Jack                               | 55, 142A, 223, 400                        | Gold              | Nickel          | Crimp Crimp                       | ACX1032-ND           | 4.38        | 2.74 | 2.43 | 112505               |          |
|                                    | Bulkhead Jack                               | RG 174, 188A, 316, B7805A, LMR100         | Gold              | Nickel          | Crimp Crimp                       | ACX1033-ND           | 4.38        | 2.74 | 2.43 | 112234               |          |
|                                    | Bulkhead Jack                               | 316, U Double Braided                     | Gold              | Nickel          | Crimp Crimp                       | ACX1034-ND           | 4.38        | 2.74 | 2.43 | 112517               |          |
|                                    | Bulkhead Jack                               | RG 179, 187A, B9221                       | Gold              | Nickel          | Crimp Crimp                       | ACX1035-ND           | 4.38        | 2.74 | 2.43 | 112235               |          |
| 4                                  | Bulkhead Jack                               | RG 178B, 196A                             | Gold              | Nickel          | Crimp Crimp                       | ACX1036-ND           | 7.11        | 4.44 | 3.94 | 112522               |          |
|                                    | Bulkhead Jack                               | .141 Semi-Rigid, 402, U                   | Gold              | Nickel          | Solder Solder                     | ACX1037-ND           | 4.56        | 2.85 | 2.53 | 112581               |          |
|                                    | Bulkhead Jack                               | .085 Semi-Rigid, 405, U                   | Gold              | Nickel          | Solder Solder                     | ACX1038-ND           | 4.56        | 2.85 | 2.53 | 112580               |          |
|                                    | Jack, Straight                              | RG 58, 58A, 58C, 141, 303, LMR195, B7806A | Gold              | Nickel          | Crimp Crimp                       | ACX1039-ND           | 2.70        | 1.69 | 1.50 | 112144               |          |
|                                    | Jack, Straight                              | 58, 58A, 58C, 141, 303, LMR195, B7806A    | Gold              | Nickel          | Crimp Crimp                       | ACX1040-ND*          | 2.70        | 1.69 | 1.50 | 112144RP             |          |
|                                    | Jack, Straight                              | RG 55, 142, 223, 400                      | Gold              | Nickel          | Crimp Crimp                       | ACX1041-ND           | 2.70        | 1.69 | 1.50 | 112513               |          |
|                                    | Jack, Straight                              | RG 59, 62, 140, 210                       | Gold              | Nickel          | Crimp Crimp                       | ACX1042-ND           | 2.68        | 1.67 | 1.48 | 112147               |          |
|                                    | Jack, Straight                              | RG 59, U-20AWG                            | Gold              | Nickel          | Crimp Crimp                       | ACX1043-ND           | 2.70        | 1.69 | 1.50 | 112649               |          |
|                                    | Jack, Straight                              | RG 174, 188A, 316, B7805A, LMR100         | Gold              | Nickel          | Crimp Crimp                       | ACX1044-ND           | 2.80        | 1.75 | 1.55 | 112160               |          |
|                                    | Jack, Straight                              | RG 179, 187, B9221                        | Gold              | Nickel          | Crimp Crimp                       | ACX1045-ND           | 2.80        | 1.75 | 1.55 | 112161               |          |
|                                    | Bulkhead Receptacle, 50Ω                    | —   | Gold              | Nickel          | —                                 | —                    | ACX1046-ND  | 2.34 | 1.46 | 1.30                 | 112424   |
|                                    | Bulkhead Receptacle                         | —   | Gold              | Nickel          | —                                 | —                    | ACX1047-ND* | 7.53 | 4.90 | 4.42                 | 112424RP |
| Bulkhead Receptacle, Isolated, 50Ω | —   | Gold                                      | Nickel            | —               | —                                 | ACX1048-ND           | 3.94        | 2.46 | 2.18 | 112431               |          |
| 5                                  | Panel Receptacle                            | —   | Gold              | Nickel          | —                                 | —                    | ACX1049-ND  | 4.30 | 2.69 | 2.38                 | 112290   |
|                                    | PCB Receptacle, 4-Legs                      | —   | Gold              | Nickel          | —                                 | —                    | ACX1050-ND  | 2.31 | 1.44 | 1.28                 | 112538   |
|                                    | PCB Receptacle, 4-Legs, Short Body          | —   | Gold              | Nickel          | —                                 | —                    | ACX1051-ND  | 2.77 | 1.73 | 1.53                 | 112404   |
|                                    | PCB Receptacle Jack, 3-Legs                 | —   | Gold              | Nickel          | —                                 | —                    | ACX1052-ND  | 4.81 | 3.01 | 2.67                 | 112483   |
|                                    | PCB Receptacle Jack, 50Ω, Vertical          | —   | Gold              | Nickel          | —                                 | —                    | ACX1053-ND  | 3.68 | 2.30 | 2.04                 | 112536   |
|                                    | Adapter, Bulkhead, Jack-Jack, 50Ω           | —   | Gold              | Nickel          | —                                 | —                    | ACX1054-ND  | 3.98 | 2.49 | 2.21                 | 112437   |
|                                    | Adapter, Bulkhead, Jack-Jack, 75Ω           | —   | Gold              | Nickel          | —                                 | —                    | ACX1055-ND  | 3.98 | 2.49 | 2.21                 | 112438   |
|                                    | Adapter, Bulkhead, Jack-Jack, Isolated, 50Ω | —   | Gold              | Nickel          | —                                 | —                    | ACX1056-ND  | 5.60 | 3.50 | 3.10                 | 112439   |
|                                    | Adapter, Bulkhead, Jack-Jack, Isolated, 75Ω | —   | Gold              | Nickel          | —                                 | —                    | ACX1057-ND  | 5.60 | 3.50 | 3.10                 | 112440   |
|                                    | Adapter, Bulkhead, Jack-Jack, Isolated, 50Ω | —   | Gold              | Nickel          | —                                 | —                    | ACX1058-ND  | 4.38 | 2.74 | 2.43                 | 112443   |
|                                    | Adapter, Bulkhead, Jack-Jack, Isolated, 75Ω | —   | Gold              | Nickel          | —                                 | —                    | ACX1059-ND  | 4.38 | 2.74 | 2.43                 | 112444   |
|                                    | Adapter, Jack-Jack, 50Ω                     | —   | Gold              | Nickel          | —                                 | —                    | ACX1060-ND  | 2.80 | 1.75 | 1.55                 | 112445   |
| Adapter, Jack-Jack, 75Ω            | —   | Gold                                      | Nickel            | —               | —                                 | ACX1061-ND           | 2.80        | 1.75 | 1.55 | 112446               |          |
| 6                                  | Adapter, Plug-Plug, 50Ω                     | —   | Gold              | Nickel          | —                                 | —                    | ACX1062-ND  | 4.67 | 2.92 | 2.58                 | 112447   |
|                                    | Adapter, Plug-Plug, 75Ω                     | —   | Gold              | Nickel          | —                                 | —                    | ACX1063-ND  | 4.67 | 2.92 | 2.58                 | 112448   |
|                                    | T Adapter, Jack-Plug-Jack, 50Ω              | —   | Gold              | Nickel          | —                                 | —                    | ACX1064-ND  | 2.94 | 1.84 | 1.63                 | 112461   |
|                                    | T Adapter, Jack-Plug-Jack, 75Ω              | —   | Gold              | Nickel          | —                                 | —                    | ACX1065-ND  | 3.29 | 2.06 | 1.82                 | 112462   |
|                                    | Terminator Plug, 50Ω                        | —   | Gold              | Nickel          | —                                 | —                    | ACX1066-ND  | 2.80 | 1.75 | 1.55                 | 202103   |
|                                    | Terminator Plug, 75Ω                        | —   | Gold              | Nickel          | —                                 | —                    | ACX1067-ND  | 2.80 | 1.75 | 1.55                 | 202105   |
|                                    | Shorting Plug                               | —   | Gold              | Nickel          | —                                 | —                    | ACX1069-ND  | 3.67 | 2.30 | 2.03                 | 202114   |
|                                    | Male Cap with Chain (For Receptacles)       | —   | —                 | Nickel          | —                                 | —                    | ACX1068-ND  | 2.68 | 1.67 | 1.48                 | 202100   |

\* Reverse Polarity

## SMA and Reverse Polarized SMA Connectors

| Fig. | Description                     | Cable Group<br>RG/U                        | Center<br>Contact | Body<br>Plating | Cable Attachment<br>Outer / Inner | Digi-Key<br>Part No. | Price Each |      |      | Amphenol<br>Part No. |
|------|---------------------------------|--|-------------------|-----------------|-----------------------------------|----------------------|------------|------|------|----------------------|
|      |                                 |  |                   |                 |                                   |                      | 1          | 50   | 100  |                      |
| 15   | Direct Solder Plug              | .141 Semi-Rigid, 402, U                    | —                 | Gold            | Solder Solder                     | ACX1175-ND           | 2.06       | 1.29 | 1.14 | 132100               |
|      | Semi-Rigid Plug                 | .141 Semi-Rigid, 402, U                    | —                 | Gold            | Solder Solder                     | ACX1176-ND           | 3.77       | 2.36 | 2.09 | 132102               |
|      | Semi-Rigid Plug                 | .085 Semi-Rigid, 405, U                    | —                 | Gold            | Solder Solder                     | ACX1177-ND           | 3.77       | 2.36 | 2.09 | 132101               |
|      | Semi-Rigid Plug                 | .085 Semi-Rigid, 405, U                    | —                 | Gold            | Solder Solder                     | ACX1178-ND*          | 4.60       | 2.88 | 2.55 | 132101RP             |
|      | Semi-Rigid Plug                 | .250 Semi-Rigid                            | —                 | Gold            | Solder Solder                     | ACX1179-ND           | 6.05       | 3.78 | 3.35 | 132296               |
| 14   | Plug, Straight                  | RG 58, 58A, 58C, 141, 303, LMR195™, B7806A | Gold              | Gold            | Crimp Solder                      | ACX1192-ND           | 4.37       | 2.73 | 2.42 | 132113               |
|      | Plug, Straight                  | 58, 58A, 58C, 141, 303, LMR195, B7806A     | Gold              | Gold            | Crimp Solder                      | ACX1193-ND*          | 5.48       | 3.42 | 3.03 | 132113RP             |
|      | Plug, Straight                  | RG 55, 142A, 223, 400                      | Gold              | Gold            | Crimp Solder                      | ACX1194-ND           | 4.38       | 2.74 | 2.43 | 132195               |
|      | Plug, Straight                  | 55, 142A, 223, 400                         | Gold              | Gold            | Crimp Solder                      | ACX1195-ND*          | 5.01       | 3.13 | 2.77 | 132195RP             |
|      | Plug, Straight                  | LMR200™, B7807A                            | Gold              | Gold            | Crimp Solder                      | ACX1196-ND           | 4.52       | 2.82 | 2.50 | 132234               |
|      | Plug, Straight                  | LMR200, B7807A                             | Gold              | Gold            | Crimp Solder                      | ACX1197-ND*          | 5.45       | 3.40 | 3.02 | 132234RP             |
|      | Plug, Straight                  | RG 8X, LMR240™, B7808A                     | Gold              | Gold            | Crimp Solder                      | ACX1198-ND           | 7.22       | 4.51 | 4.00 | 132231               |
|      | Plug, Straight                  | RG 8X, LMR240, B7808A                      | Gold              | Gold            | Crimp Solder                      | ACX1199-ND*          | 8.69       | 5.43 | 4.82 | 132231RP             |
|      | Plug, Straight                  | B9913, LMR400™, B7810A, B8214              | Gold              | Gold            | Crimp Solder                      | ACX1200-ND           | 8.23       | 5.15 | 4.56 | 132298               |
|      | Plug, Straight                  | B9913, LMR400, B7810A, B8214               | Gold              | Gold            | Crimp Solder                      | ACX1201-ND*          | 9.59       | 5.99 | 5.31 | 132298RP             |
|      | Plug, Straight                  | RG 174, 188A, 316, B7805A, LMR100          | Gold              | Gold            | Crimp Solder                      | ACX1202-ND           | 4.37       | 2.73 | 2.42 | 132114               |
|      | Plug, Straight                  | 174, 188A, 316, B7805A, LMR100             | Gold              | Gold            | Crimp Solder                      | ACX1203-ND*          | 6.84       | 4.27 | 3.79 | 132114RP             |
| 15   | Plug, Straight                  | 316, U Double Braided                      | Gold              | Gold            | Crimp Solder                      | ACX1204-ND           | 4.29       | 2.68 | 2.38 | 132178               |
|      | Plug, Straight                  | 316, U Double Braided                      | Gold              | Gold            | Crimp Solder                      | ACX1205-ND*          | 5.94       | 3.71 | 3.29 | 132178RP             |
|      | Plug, Straight                  | RG 178B, 196A                              | Gold              | Gold            | Crimp Solder                      | ACX1206-ND           | 6.74       | 4.21 | 3.73 | 132193               |
|      | Right Angle, Direct Solder Plug | .141 Semi-Rigid, 402, U                    | Gold              | Gold            | Solder Solder                     | ACX1180-ND           | 6.90       | 4.31 | 3.82 | 132112               |
|      | Right Angle, Direct Solder Plug | .085 Semi-Rigid, 405, U                    | Gold              | Gold            | Solder Solder                     | ACX1181-ND           | 6.90       | 4.31 | 3.82 | 132111               |
|      | Right Angle, Crimp Plug         | RG 58, 58A, 58C, 141, 303, LMR195, B7806A  | Gold              | Gold            | Crimp Solder                      | ACX1207-ND           | 7.92       | 4.95 | 4.38 | 132122               |
|      | Right Angle, Crimp Plug         | 58, 58A, 58C, 141, 303, LMR195, B7806A     | Gold              | Gold            | Crimp Solder                      | ACX1208-ND*          | 7.48       | 4.67 | 4.14 | 132122RP             |
|      | Right Angle, Crimp Plug         | RG 55, 142, 223, 400                       | Gold              | Gold            | Crimp Solder                      | ACX1209-ND           | 7.90       | 4.94 | 4.38 | 132194               |
|      | Right Angle, Crimp Plug         | LMR200, B7807A                             | Gold              | Gold            | Crimp Solder                      | ACX1210-ND           | 7.39       | 4.62 | 4.09 |                      |

A

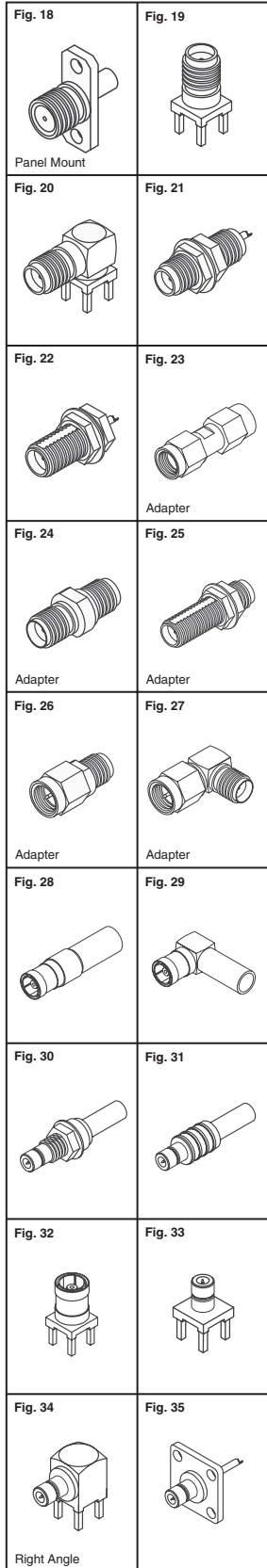

SMA and Reverse Polarized SMA Connectors (Cont.)

| Fig. | Description  | Cable Group<br>RG/U  | Center<br>Contact | Body<br>Plating | Cable Attachment<br>Outer / Inner | Digi-Key<br>Part No.      | Price Each     |              |              | Amphenol<br>Part No.  |
|------|--|--|-------------------|-----------------|-----------------------------------|---------------------------|----------------|--------------|--------------|-----------------------|
|      |  |  |                   |                 |                                   |                           | 1              | 50           | 100          |                       |
| 15   | Right Angle, Crimp Plug  | LMR200™, B7807A  | Gold              | Gold            | Crimp Crimp                       | ACX1211-ND*               | 7.19           | 4.50         | 3.98         | 132235RP              |
|      | Right Angle, Crimp Plug  | RG 8X, LMR240™, B7808A   | Gold              | Gold            | Crimp Crimp                       | ACX1212-ND                | 10.40          | 6.50         | 5.76         | 132239                |
|      | Right Angle, Crimp Plug  | B9913, LMR400™, B7810A, B8214  | Gold              | Gold            | Crimp Crimp                       | ACX1213-ND                | 8.23           | 5.14         | 4.56         | 132299                |
|      | Right Angle, Crimp Plug  | RG 174, 188A, 316, B7805A, LMR100                                      | Gold              | Gold            | Crimp Crimp                       | ACX1214-ND                | 7.92           | 4.95         | 4.38         | 132123                |
|      | Right Angle, Crimp Plug  | RG 174, 188A, 316, B7805A, LMR100                                      | Gold              | Gold            | Crimp Crimp                       | ACX1215-ND*               | 7.48           | 4.67         | 4.14         | 132123RP              |
|      | Right Angle, Crimp Plug<br>Right Angle, Crimp Plug                       | 316 Double Braided<br>RG 178B, 196A                                    | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1216-ND<br>ACX1217-ND  | 7.92<br>7.35   | 4.95<br>4.59 | 4.38<br>4.07 | 132182<br>132173      |
| 16   | Bulkhead, Crimp Jack   | 58, 58A, 58C, 141, 303, LMR195™, B7806A                                | Gold              | Gold            | Crimp Crimp                       | ACX1218-ND                | 6.15           | 3.84         | 3.41         | 132118                |
|      | Bulkhead, Crimp Jack   | RG 174, 188A, 316, B7805A, LMR100                                      | Gold              | Gold            | Crimp Crimp                       | ACX1219-ND*               | 6.01           | 3.76         | 3.33         | 132118RP              |
|      | Bulkhead, Crimp Jack   | RG 55, 142, 223, 400   | Gold              | Gold            | Crimp Crimp                       | ACX1220-ND                | 6.09           | 3.81         | 3.37         | 132191                |
|      | Bulkhead, Crimp Jack   | RG 55, 142, 223, 400   | Gold              | Gold            | Crimp Crimp                       | ACX1221-ND*               | 6.01           | 3.76         | 3.33         | 132191RP              |
|      | Bulkhead, Crimp Jack   | RG 8X, LMR240, B7808A  | Gold              | Gold            | Crimp Crimp                       | ACX1222-ND                | 6.16           | 3.85         | 3.41         | 132241                |
|      | Bulkhead, Crimp Jack<br>Bulkhead, Crimp Jack                             | RG 174, 188A, 316, B7805A, LMR100<br>RG 174, 188A, 316, B7805A, LMR100 | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1223-ND<br>ACX1224-ND  | 5.71<br>5.71   | 3.57<br>3.57 | 3.16<br>3.16 | 132119RP<br>132119RP  |
| 17   | Straight, Crimp Jack†  | RG 58, 58A, 58C, 141, 303, LMR195, B7806A                              | Gold              | Gold            | Crimp Crimp                       | ACX1225-ND*               | 5.91           | 3.69         | 3.27         | 132116                |
|      | Straight, Crimp Jack†  | 58, 58A, 58C, 141, 303, LMR195, B7806A                                 | Gold              | Gold            | Crimp Crimp                       | ACX1226-ND*               | 4.79           | 3.00         | 2.66         | 132116RP              |
|      | Straight, Crimp Jack†  | RG 174, 188A, 316, B7805A, LMR100                                      | Gold              | Gold            | Crimp Crimp                       | ACX1227-ND                | 5.84           | 3.65         | 3.24         | 132117                |
|      | Straight, Crimp Jack†  | 174, 188A, 316, B7805A, LMR100   | Gold              | Gold            | Crimp Crimp                       | ACX1228-ND*               | 4.79           | 3.00         | 2.66         | 132117RP              |
|      | Straight, Crimp Jack†  | 316, U Double Braided  | Gold              | Gold            | Crimp Crimp                       | ACX1229-ND                | 4.86           | 3.04         | 2.69         | 132198                |
|      | Direct Solder, Bulkhead Jack<br>Direct Solder, Bulkhead Jack             | .141 Semi-Rigid, 402, U<br>.085 Semi-Rigid, 405, U                     | Gold<br>Gold      | Gold<br>Gold    | Solder Solder<br>Solder Solder    | ACX1182-ND<br>ACX1183-ND  | 7.06<br>7.06   | 4.41<br>4.41 | 3.91<br>3.91 | 132106<br>132105      |
| 18   | Direct Solder, Bulkhead Jack   | .250 Semi-Rigid  | Gold              | Gold            | Solder Solder                     | ACX1184-ND                | 9.59           | 5.99         | 5.31         | 132346                |
|      | Semi-Rigid, Panel Jack, 4-Hole<br>Semi-Rigid, Panel Jack, 4-Hole         | .085 Semi-Rigid, 405, U<br>.141 Semi-Rigid, 402, U                     | Gold<br>Gold      | Gold<br>Gold    | Solder Solder<br>Solder Solder    | ACX1185-ND<br>ACX1186-ND  | 6.94<br>6.94   | 4.34<br>4.34 | 3.84<br>3.84 | 132107<br>132108      |
|      | Panel Jack   | .085 Semi-Rigid, 405, U  | Gold              | Gold            | Solder Solder                     | ACX1187-ND*               | 5.25           | 3.29         | 2.97         | 132108RP              |
|      | Receptacle, 4-Hole Flange, PTFE  | —  | Gold              | Gold            | —                                 | ACX1238-ND                | 7.60           | 4.75         | 4.21         | 132146                |
|      | Receptacle, 2-Hole Flange, PTFE  | —  | Gold              | Gold            | —                                 | ACX1239-ND                | 7.92           | 4.95         | 4.38         | 132147                |
|      | Semi-Rigid, Jack, 2-Hole Flange<br>Semi-Rigid, Jack, 2-Hole Flange       | .085 Semi-Rigid, 405, U<br>.085 Semi-Rigid, 405, U                     | Gold<br>Gold      | Gold<br>Gold    | Solder Solder<br>Solder Solder    | ACX1188-ND<br>ACX1189-ND* | 6.94<br>5.03   | 4.34<br>3.15 | 3.84<br>2.85 | 132109<br>132109RP    |
| 19   | Direct Solder, Jack, 2-Hole Flange<br>Direct Solder, Jack, 2-Hole Flange | .141 Semi-Rigid, 402, U<br>.141 Semi-Rigid, 402, U                     | Gold<br>Gold      | Gold<br>Gold    | Solder Solder<br>Solder Solder    | ACX1190-ND<br>ACX1191-ND* | 6.48<br>5.96   | 4.05<br>3.73 | 3.59<br>3.37 | 132110<br>132110RP    |
|      | PCB, Jack (Extended Legs)<br>PCB, Jack (Extended Legs)                   | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1230-ND<br>ACX1231-ND* | 5.12<br>4.11   | 3.20<br>2.57 | 2.83<br>2.28 | 132134<br>132134RP    |
|      | Right Angle, PCB, Jack<br>Right Angle, PCB, Jack                         | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1232-ND<br>ACX1233-ND* | 8.64<br>8.04   | 5.40<br>5.03 | 4.79<br>4.45 | 132136<br>132136RP    |
|      | Right Angle, Bulkhead, PCB, Jack<br>Right Angle, Bulkhead, PCB, Jack     | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1234-ND<br>ACX1235-ND* | 11.70<br>10.20 | 7.31<br>6.37 | 6.48<br>5.65 | 132203<br>132203RP    |
|      | Bulkhead, Receptacle, Front Mount<br>Bulkhead, Receptacle, Rear Mount    | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1236-ND<br>ACX1237-ND  | 6.39<br>5.91   | 4.00<br>3.70 | 3.54<br>3.28 | 132137<br>132139      |
|      | Plug to Plug<br>Plug to R-P Plug   | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1240-ND<br>ACX1241-ND* | 7.02<br>12.79  | 4.39<br>7.99 | 3.89<br>7.08 | 132168<br>132168RP    |
| 20   | Jack to Jack<br>Jack to R-P Jack   | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1242-ND<br>ACX1243-ND* | 5.72<br>5.11   | 3.58<br>3.20 | 3.17<br>2.83 | 132169<br>132169RP    |
|      | Bulkhead, Jack to Jack<br>Bulkhead, Jack to R-P Jack                     | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1244-ND<br>ACX1245-ND* | 8.77<br>12.67  | 5.48<br>7.92 | 4.86<br>4.01 | 132170<br>132170RP    |
|      | Plug to Jack<br>R-P Jack to Plug   | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1246-ND<br>ACX1247-ND* | 7.10<br>6.39   | 4.44<br>3.00 | 3.93<br>3.54 | 132171<br>132171RP    |
|      | Jack to R-P Plug<br>Plug to Jack, Right Angle                            | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1248-ND*<br>ACX1249-ND | 6.39<br>10.32  | 4.00<br>6.45 | 3.54<br>5.72 | 132171RP-10<br>132172 |
|      | Plug Cap (Less Chain)<br>Terminator Plug, 50Ω                            | —<br>—   | —<br>Gold         | —<br>Gold       | —<br>—                            | ACX1250-ND<br>ACX1251-ND  | 1.97<br>3.20   | 1.23<br>2.00 | 1.09<br>1.77 | 202112<br>132360      |
|      | Terminator Jack, 50Ω   | —  | Gold              | Gold            | —                                 | ACX1252-ND                | 5.37           | 3.36         | 2.97         | 132361                |

\* Reverse Polarity † Nut and Washer not included


SMB and MINI 75 Ohm SMB Connectors

| Fig. | Description  | Cable Group<br>RG/U  | Center<br>Contact | Body<br>Plating | Cable Attachment<br>Outer / Inner | Digi-Key<br>Part No.     | Price Each     |                |                | Amphenol<br>Part No. |
|------|--|--|-------------------|-----------------|-----------------------------------|--------------------------|----------------|----------------|----------------|----------------------|
|      |  |  |                   |                 |                                   |                          | 1              | 50             | 100            |                      |
| 28   | Plug, Straight   | RG 58, 58A, 58C, 141, 303, LMR195™, B7806A                   | Gold              | Gold            | Crimp Crimp                       | ACX1278-ND               | 6.05           | 3.78           | 3.35           | 142255               |
|      | Plug, Straight   | RG 55, 142, 223, 400   | Gold              | Gold            | Crimp Crimp                       | ACX1279-ND               | 6.75           | 4.22           | 3.74           | 142220               |
|      | Plug, Straight   | RG 174, 188A, 316, B7805A, LMR100                            | Gold              | Gold            | Crimp Crimp                       | ACX1280-ND               | 6.46           | 4.04           | 3.58           | 142186               |
|      | Plug, Straight, Mini 75Ω   | 179, 187,  | Gold              | Gold            | Crimp Crimp                       | ACX1281-ND               | 6.14           | 3.84           | 3.40           | 142186-75            |
|      | Plug, Straight   | 316, U Double Braided  | Gold              | Gold            | Crimp Crimp                       | ACX1282-ND               | 6.52           | 4.08           | 3.61           | 142187               |
|      | Plug, Straight, Mini 75Ω<br>Plug, Straight                           | 179, U Double Braided<br>RG 178, 196                         | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1283-ND<br>ACX1284-ND | 6.08<br>6.52   | 3.80<br>4.08   | 3.37<br>3.61   | 142187-75<br>142229  |
| 29   | Direct Solder Plug<br>Direct Solder Plug, Mini 75Ω                   | .085 Semi-Rigid, 405, U<br>.085 Semi-Rigid, 405, U           | Gold<br>Gold      | Gold<br>Gold    | Solder Solder<br>Solder Solder    | ACX1285-ND<br>ACX1286-ND | 6.05<br>5.14   | 3.78<br>3.22   | 3.35<br>2.91   | 142212<br>142212-75  |
|      | Plug, Straight, Mini 75Ω   | AT&T735A, B735A1   | Gold              | Gold            | Crimp Crimp                       | ACX1287-ND               | 6.51           | 4.07           | 3.61           | 142222-75            |
|      | Right Angle, Crimp Plug<br>Right Angle, Crimp Plug                   | 58, 58A, 58C, 141, 303, LMR195, B7806A<br>55, 142A, 223, 400 | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1288-ND<br>ACX1289-ND | 7.86<br>18.27  | 4.91<br>11.42  | 4.36<br>10.21  | 142206<br>142322     |
|      | Right Angle, Crimp Plug<br>Right Angle, Crimp Plug, Mini 75Ω         | RG 174, 188A, 316, B7805A, LMR100<br>179, 187, B9221         | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1290-ND<br>ACX1291-ND | 5.76<br>6.97   | 3.60<br>4.35   | 3.17<br>3.86   | 142194<br>142194-75  |
|      | Right Angle, Crimp Plug<br>Right Angle, Crimp Plug                   | 316, U Double Braided<br>179, U Double Braided               | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1292-ND<br>ACX1293-ND | 7.92<br>7.03   | 4.95<br>4.40   | 4.38<br>3.89   | 142176<br>142176-75  |
|      | Right Angle, Crimp Plug<br>Right Angle, Crimp Plug                   | RG 178, 196<br>RG 178, 196                                   | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1294-ND<br>ACX1295-ND | 8.30<br>7.19   | 5.18<br>4.50   | 4.59<br>3.98   | 142195<br>142214     |
| 30   | Right Angle, Direct Solder, Plug<br>Right Angle, Direct Solder, Plug | .085 Semi-Rigid, 405, U<br>.141 Semi-Rigid, 402, U           | Gold<br>Gold      | Gold<br>Gold    | Solder Solder<br>Solder Solder    | ACX1296-ND<br>ACX1296-ND | 19.19<br>19.19 | 11.99<br>11.99 | 10.73<br>10.73 | 142329<br>142329     |
|      | Right Angle, Crimp Plug, Mini 75Ω                                    | AT&T735A, B735A1   | Gold              | Gold            | Crimp Crimp                       | ACX1297-ND               | 7.16           | 4.48           | 3.97           | 142221-75            |
|      | Bulkhead, Crimp Jack<br>Bulkhead, Crimp Jack, Mini 75Ω               | RG 174, 188A, 316, B7805A, LMR100<br>179, 187, B9221         | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1298-ND<br>ACX1299-ND | 4.75<br>4.79   | 2.97<br>3.00   | 2.63<br>2.66   | 142191<br>142191-75  |
|      | Bulkhead, Crimp Jack<br>Bulkhead, Crimp Jack, Mini 75Ω               | 316, U Double Braided<br>179, U Double Braided               | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1300-ND<br>ACX1301-ND | 4.79<br>4.57   | 3.00<br>2.85   | 2.66<br>2.55   | 142192<br>142192-75  |
|      | Bulkhead, Crimp Jack<br>Bulkhead, Direct Solder Jack                 | RG 178B, 196A<br>.085 Semi-Rigid, 405, U                     | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Solder Solder      | ACX1302-ND<br>ACX1303-ND | 4.79<br>12.67  | 3.00<br>7.92   | 2.66<br>2.01   | 142231<br>142301     |
|      | Bulkhead, Receptacle Jack  | 174, 188A, 316, B7805A, LMR100                               | Gold              | Gold            | —                                 | ACX1309-ND               | 3.65           | 2.28           | 2.02           | 142154               |
| 31   | Straight Jack<br>Straight Jack, Mini 75Ω                             | 174, 188A, 316, B7805A, LMR100<br>179, 187, B9221            | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1304-ND<br>ACX1305-ND | 4.14<br>4.18   | 2.59<br>2.61   | 2.29<br>2.32   | 142189<br>142189-75  |
|      | Straight Jack<br>Straight Jack, Mini 75Ω                             | 316, U Double Braided<br>179, U Double Braided               | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>Crimp Crimp        | ACX1306-ND<br>ACX1307-ND | 3.93<br>4.18   | 2.46<br>2.61   | 2.18<br>2.32   | 142190<br>142190-75  |
|      | Straight Jack<br>Straight Jack                                       | 178B, 196A<br>—  | Gold<br>Gold      | Gold<br>Gold    | Crimp Crimp<br>—                  | ACX1308-ND<br>ACX1310-ND | 5.99<br>5.72   | 3.74<br>3.58   | 3.32<br>3.17   | 142241<br>142134     |
|      | PCB Straight Plug<br>PCB Straight Plug, Mini 75Ω                     | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1311-ND<br>ACX1312-ND | 5.75<br>2.93   | 3.60<br>1.83   | 3.19<br>1.63   | 142134-75<br>142138  |
|      | PCB Jack<br>PCB Jack, Mini 75Ω                                       | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1313-ND<br>ACX1314-ND | 3.08<br>5.21   | 1.93<br>3.26   | 1.71<br>2.89   | 142138-75<br>142210  |
|      | PCB Bulkhead Receptacle<br>PCB Bulkhead Receptacle, Mini 75Ω         | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1315-ND<br>ACX1316-ND | 5.17<br>5.24   | 3.23<br>3.27   | 2.86<br>2.90   | 142210-75<br>142146  |
| 34   | PCB, Jack<br>PCB, Jack, Mini 75Ω                                     | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1317-ND<br>ACX1318-ND | 5.71<br>7.35   | 3.57<br>4.59   | 3.16<br>4.07   | 142146-75<br>142184  |
|      | PCB, Bulkhead, Jack<br>PCB, Bulkhead, Jack, Mini 75Ω                 | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1319-ND<br>ACX1320-ND | 7.38<br>4.48   | 4.61<br>2.80   | 4.09<br>2.53   | 142184-75<br>142162  |
|      | Panel Receptacle, 4-Hole Flange<br>Panel Receptacle, 2-Hole Flange   | —<br>—   | Gold<br>Gold      | Gold<br>Gold    | —<br>—                            | ACX1321-ND<br>ACX1321-ND | 4.48<br>5.29   | 2.80<br>3.30   | 2.53<br>2.93   | 142162<br>142166     |

More Product Available Online: [www.digkey.com](http://www.digkey.com)

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

A

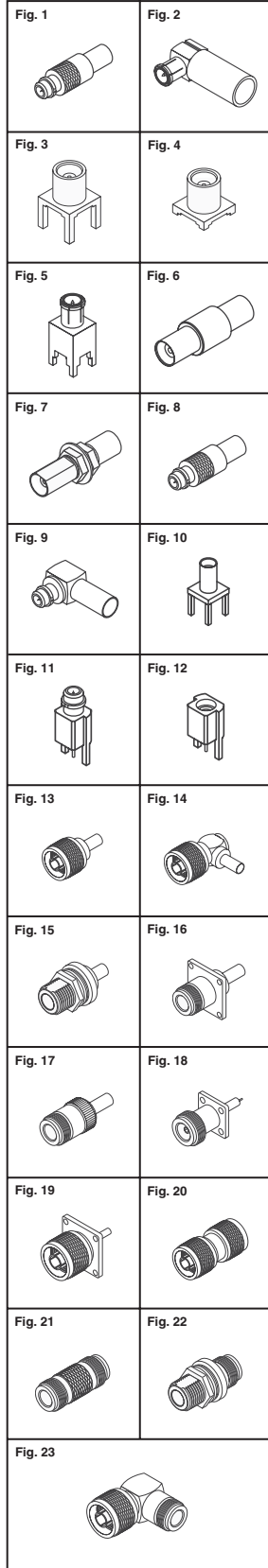

## MCCX Connectors

| Fig. | Description                      | Cable Group<br>RG/U                        | Center<br>Contact | Body<br>Plating | Cable Attachment<br>Outer / Inner | Digi-Key<br>Part No. | Price Each |      |      | Amphenol<br>Part No. |
|------|----------------------------------|--|-------------------|-----------------|-----------------------------------|----------------------|------------|------|------|----------------------|
|      |                                  |  |                   |                 |                                   |                      | 1          | 50   | 100  |                      |
| 1    | Plug, Straight                   | RG 58, 58A, 58C, 141, 303, LMR195™, B7806A | Gold              | Gold            | Crimp Crimp                       | ACX1253-ND           | 4.99       | 3.12 | 2.79 | 252180               |
|      | Plug, Straight                   | RG 174, 188A, 316, B7805A, LMR100          | Gold              | Gold            | Crimp Crimp                       | ACX1254-ND           | 4.86       | 3.04 | 2.72 | 252103               |
|      | Plug, Straight                   | 316, U Double Braided                      | Gold              | Gold            | Crimp Crimp                       | ACX1255-ND           | 5.34       | 3.34 | 2.99 | 252121               |
|      | Direct Solder Plug, Straight     | RG 178, 196<br>.085 Semi-Rigid, 405, U     | Gold              | Gold            | Solder Solder                     | ACX1256-ND           | 7.32       | 4.58 | 4.09 | 252127               |
| 2    | Plug, Right Angle                | 58, 58A, 58C, 141, 303, LMR195, B7806A     | Gold              | Gold            | Crimp Crimp                       | ACX1258-ND           | 7.21       | 4.51 | 4.03 | 252115               |
|      | Plug, Right Angle                | 174, 188A, 316, B7805A, LMR100             | Gold              | Gold            | Crimp Crimp                       | ACX1259-ND           | 6.43       | 4.02 | 3.60 | 252102               |
|      | Plug, Right Angle                | 316, U Double Braided                      | Gold              | Gold            | Crimp Crimp                       | ACX1260-ND           | 6.43       | 4.02 | 3.60 | 252119               |
|      | Plug, Right Angle                | .085 Semi-Rigid, 405, U                    | Gold              | Gold            | Solder Solder                     | ACX1261-ND           | 6.15       | 3.84 | 3.44 | 252109               |
| 3    | P.C.B. Receptacle Jack           | —  | Gold              | Gold            | —                                 | ACX1262-ND           | 5.53       | 3.45 | 3.09 | 252105               |
| 4    | P.C.B. Receptacle, Surface Mount | —  | Gold              | Gold            | —                                 | ACX1263-ND           | 5.29       | 3.31 | 2.96 | 252117               |
| 5    | P.C.B. Receptacle Plug           | —  | Gold              | Gold            | —                                 | ACX1264-ND           | 5.98       | 3.74 | 3.34 | 252153               |
| 6    | Jack to Jack Adapter             | —  | Gold              | Gold            | —                                 | ACX1265-ND           | 14.77      | 9.23 | 8.26 | 252169               |
| 7    | Bulkhead, Jack to Jack Adapter   | —  | Gold              | Gold            | —                                 | ACX1266-ND           | 7.89       | 4.93 | 4.41 | 252171               |

## MMCX Connectors

| Fig. | Description                  | Cable Group<br>RG/U               | Center<br>Contact | Body<br>Plating | Cable Attachment<br>Outer / Inner | Digi-Key<br>Part No. | Price Each |      |      | Amphenol<br>Part No. |
|------|------------------------------|-----------------------------------|-------------------|-----------------|-----------------------------------|----------------------|------------|------|------|----------------------|
|      |                              |                                   |                   |                 |                                   |                      | 1          | 50   | 100  |                      |
| 8    | Semi-Rigid Plug              | .085 Semi-Rigid, 405, U           | Gold              | Gold            | Solder Solder                     | ACX1267-ND           | 4.32       | 2.70 | 2.42 | 262112               |
|      | Plug, Straight               | RG 174, 188A, 316, B7805A, LMR100 | Gold              | Gold            | Crimp Crimp                       | ACX1268-ND           | 3.99       | 2.50 | 2.23 | 262101               |
|      | Plug, Straight               | 316, U Double Braided             | Gold              | Gold            | Crimp Crimp                       | ACX1269-ND           | 3.99       | 2.50 | 2.23 | 262110               |
|      | Plug, Straight               | RG 178B, 196A                     | Gold              | Gold            | Crimp Crimp                       | ACX1270-ND           | 3.99       | 2.50 | 2.23 | 262100               |
| 9    | Right Angle, Semi-Rigid Plug | .085 Semi-Rigid, 405, U           | Gold              | Gold            | Solder Solder                     | ACX1271-ND           | 5.96       | 3.73 | 3.33 | 262113               |
|      | Right Angle, Plug            | RG 174, 188A, 316, B7805A, LMR100 | Gold              | Gold            | Crimp Crimp                       | ACX1272-ND           | 5.10       | 3.19 | 2.85 | 262103               |
|      | Right Angle, Plug            | 316, U Double Braided             | Gold              | Gold            | Crimp Crimp                       | ACX1273-ND           | 5.10       | 3.19 | 2.85 | 262111               |
|      | Right Angle, Plug            | RG 178B, 196A                     | Gold              | Gold            | Crimp Crimp                       | ACX1274-ND           | 5.10       | 3.19 | 2.85 | 262102               |
| 10   | P.C.B. Jack                  | —                                 | Gold              | Gold            | —                                 | ACX1275-ND           | 6.52       | 4.08 | 3.65 | 262104               |
| 11   | Edgecard Mount Plug          | —                                 | Gold              | Gold            | —                                 | ACX1276-ND           | 5.10       | 3.19 | 2.85 | 262106               |
| 12   | Edgecard, Jack               | —                                 | Gold              | Gold            | —                                 | ACX1277-ND           | 4.59       | 2.87 | 2.56 | 262107               |

## N and Reverse Polarized N Connectors

| Fig.            | Description                      | Cable Group<br>RG/U                        | Center<br>Contact | Body<br>Plating | Cable Attachment<br>Outer / Inner | Digi-Key<br>Part No. | Price Each |      |        | Amphenol<br>Part No. |
|-----------------|----------------------------------|--|-------------------|-----------------|-----------------------------------|----------------------|------------|------|--------|----------------------|
|                 |                                  |  |                   |                 |                                   |                      | 1          | 50   | 100    |                      |
| 11              | Plug, Straight                   | RG 58, 58A, 58C, 141, 303, LMR195™, B7806A | Gold              | Nexcote         | Crimp Crimp                       | ACX1118-ND           | 5.43       | 3.40 | 3.01   | 172100               |
|                 | Plug, Straight                   | RG 58, 58A, 58C, 141, 303, LMR195, B7806A  | Gold              | Nexcote         | Crimp Crimp                       | ACX1119-ND*          | 6.35       | 3.97 | 3.52   | 172100RP             |
|                 | Plug, Straight                   | RG 55, 142, 223, 400                       | Gold              | Nexcote         | Crimp Crimp                       | ACX1120-ND           | 5.41       | 3.38 | 3.00   | 172142               |
|                 | Plug, Straight                   | LMR200™, B7807A                            | Gold              | Nexcote         | Crimp Crimp                       | ACX1121-ND           | 5.18       | 3.24 | 2.87   | 172214               |
| 13              | Plug, Straight                   | LMR200, B7807A                             | Gold              | Nexcote         | Crimp Crimp                       | ACX1122-ND*          | 5.36       | 3.35 | 3.03   | 172214RP             |
|                 | Plug, Straight                   | RG 174, 188A, 316, B7805A, LMR100          | Gold              | Nexcote         | Crimp Crimp                       | ACX1123-ND           | 7.26       | 4.54 | 4.02   | 172128               |
|                 | Plug, Straight                   | RG 316, U Double Braided                   | Gold              | Nexcote         | Crimp Crimp                       | ACX1124-ND           | 7.80       | 4.87 | 4.32   | 172171               |
|                 | Plug, Straight                   | RG 8, 8A, 213, 393                         | Gold              | Nexcote         | Crimp Crimp                       | ACX1125-ND           | 5.88       | 3.67 | 3.25   | 172102               |
| 13              | Plug, Straight                   | RG 214                                     | Gold              | Nexcote         | Crimp Crimp                       | ACX1126-ND           | 5.83       | 3.64 | 3.23   | 172166               |
|                 | Plug, Straight                   | RG 8X, LMR240™, B7808A                     | Gold              | Nexcote         | Crimp Crimp                       | ACX1127-ND           | 5.88       | 3.67 | 3.25   | 172135               |
|                 | Plug, Straight                   | RG 8X, LMR240, B7808A                      | Gold              | Nexcote         | Crimp Crimp                       | ACX1128-ND*          | 6.29       | 3.93 | 3.48   | 172135RP             |
|                 | Plug, Straight                   | B9913, LMR400™, B7810A, B8214              | Gold              | Nexcote         | Crimp Crimp                       | ACX1129-ND           | 6.04       | 3.78 | 3.35   | 172102H243           |
| 13              | Plug, Straight                   | B9913, LMR400, B7810A, B8214               | Gold              | Nexcote         | Crimp Crimp                       | ACX1130-ND*          | 6.80       | 4.25 | 3.77   | 172102H243RP         |
|                 | Plug, Straight                   | LMR600™                                    | Gold              | Nexcote         | Crimp Crimp                       | ACX1131-ND           | 13.19      | 8.25 | 7.31   | 172206               |
|                 | Direct Solder Plug               | .141 Semi-Rigid, 402, U                    | Gold              | Nexcote         | Solder Solder                     | ACX1132-ND           | 6.58       | 4.12 | 3.65   | 172133               |
|                 | Direct Solder Plug               | .085 Semi-Rigid, 405, U                    | Gold              | Nexcote         | Solder Solder                     | ACX1133-ND           | 6.78       | 4.24 | 3.75   | 172211               |
| 14              | Direct Solder Plug               | .250 Semi-Rigid                            | Gold              | Nexcote         | Solder Solder                     | ACX1134-ND           | 6.80       | 4.25 | 3.77   | 172139               |
|                 | Right Angle, Plug                | RG 58, 58A, 58C, 141, 303, LMR195, B7806A  | Gold              | Nexcote         | Crimp Crimp                       | ACX1135-ND           | 9.69       | 6.06 | 5.48   | 172177               |
|                 | Right Angle, Plug                | RG 55, 142, 223, 400                       | Gold              | Nexcote         | Crimp Crimp                       | ACX1136-ND           | 10.93      | 6.83 | 6.05   | 172178               |
|                 | Right Angle, Plug                | RG 174, 188A, 316, B7805A, LMR100          | Gold              | Nexcote         | Crimp Crimp                       | ACX1137-ND           | 11.38      | 7.11 | 6.30   | 172180               |
| 14              | Right Angle, Plug                | RG 8, 8A, 213, 393, B9913, M4400           | Gold              | Nexcote         | Crimp Crimp                       | ACX1138-ND           | 12.77      | 7.98 | 7.08   | 172176               |
|                 | Right Angle, Plug                | RG 214                                     | Gold              | Nexcote         | Crimp Crimp                       | ACX1139-ND           | 11.83      | 7.39 | 6.55   | 172167               |
|                 | Bulkhead, Jack                   | RG 58, 58A, 58C, 141, 303, LMR195, B7806A  | Gold              | Nexcote         | Crimp Crimp                       | ACX1140-ND           | 8.26       | 5.16 | 4.57   | 172106               |
|                 | Bulkhead, Jack                   | RG 58, 58A, 58C, 141, 303, LMR195, B7806A  | Gold              | Nexcote         | Crimp Crimp                       | ACX1141-ND*          | 7.79       | 4.87 | 4.36   | 172106RP             |
| 15              | Bulkhead, Jack                   | RG 55, 142, 223, 400                       | Gold              | Nexcote         | Crimp Crimp                       | ACX1142-ND           | 7.69       | 4.81 | 4.26   | 172132               |
|                 | Bulkhead, Jack                   | RG 174, 188A, 316, B7805A, LMR100          | Gold              | Nexcote         | Crimp Crimp                       | ACX1143-ND           | 8.21       | 5.13 | 4.55   | 172129               |
|                 | Bulkhead, Jack                   | RG 174, 188A, 316, B7805A, LMR100          | Gold              | Nexcote         | Crimp Crimp                       | ACX1144-ND*          | 7.74       | 4.83 | 4.28   | 172129RP             |
|                 | Bulkhead, Jack                   | RG 316, U Double Braided                   | Gold              | Nexcote         | Crimp Crimp                       | ACX1145-ND           | 8.21       | 5.13 | 4.55   | 172165               |
| 15              | Bulkhead, Jack                   | RG 8X, LMR240, B7808A                      | Gold              | Nexcote         | Crimp Crimp                       | ACX1146-ND           | 7.76       | 4.85 | 4.30   | 172149               |
|                 | Bulkhead, Jack                   | .141 Semi-Rigid, 402, U                    | Gold              | Nexcote         | Solder Solder                     | ACX1147-ND           | 9.50       | 5.94 | 5.26   | 172137               |
|                 | Bulkhead, Direct Solder Jack     | .085 Semi-Rigid, 405, U                    | Gold              | Nexcote         | Solder Solder                     | ACX1148-ND           | 9.42       | 5.89 | 5.22   | 172138               |
|                 | Bulkhead, Direct Solder Jack     | .250 Semi-Rigid                            | Gold              | Nexcote         | Solder Solder                     | ACX1149-ND           | 9.59       | 5.99 | 5.31   | 172153               |
| 16              | Panel Jack                       | RG 58, 58A, 58C, 141, 303, LMR195, B7806A  | Gold              | Nexcote         | Crimp Crimp                       | ACX1150-ND           | 8.30       | 5.18 | 4.59   | 172208               |
|                 | Panel Jack                       | RG 55, 142A, 223, 400                      | Gold              | Nexcote         | Crimp Crimp                       | ACX1151-ND           | 10.39      | 6.50 | 5.76   | 172175               |
|                 | Panel Jack                       | RG 174, 188A, 316, B7805A, LMR100          | Gold              | Nexcote         | Crimp Crimp                       | ACX1152-ND           | 9.53       | 5.95 | 5.28   | 172173               |
|                 | Panel Direct Solder Jack         | .141 Semi-Rigid, 402, U                    | Gold              | Nexcote         | Solder Solder                     | ACX1153-ND           | 9.78       | 6.11 | 5.42   | 172170               |
| 17              | Panel Direct Solder Jack         | .085 Semi-Rigid, 405, U                    | Gold              | Nexcote         | Solder Solder                     | ACX1154-ND           | 9.75       | 6.10 | 5.40   | 172169               |
|                 | Jack, Straight                   | RG 58, 58A, 58C, 141, 303, LMR195, B7806A  | Gold              | Nexcote         | Crimp Crimp                       | ACX1155-ND           | 5.31       | 3.32 | 2.94   | 172103               |
|                 | Jack, Straight                   | RG 58, 58A, 58C, 141, 303, LMR195, B7806A  | Gold              | Nexcote         | Crimp Crimp                       | ACX1156-ND*          | 5.08       | 3.17 | 2.81   | 172103RP             |
|                 | Jack, Straight, 50Ω, Cap. Con.   | RG 55, 142, 223, 400                       | Gold              | Nexcote         | Crimp Crimp                       | ACX1157-ND           | 5.31       | 3.32 | 2.94   | 172147               |
| 17              | Jack, Straight                   | LMR200, B7807A                             | Gold              | Nexcote         | Crimp Crimp                       | ACX1158-ND           | 7.85       | 4.91 | 4.35   | 172216               |
|                 | Jack, Straight                   | RG 174, 188A, 316, B7805A, LMR100          | Gold              | Nexcote         | Crimp Crimp                       | ACX1159-ND           | 7.48       | 4.67 | 4.14   | 172204               |
|                 | Jack, Straight                   | RG 8X, LMR240, B7808A                      | Gold              | Nexcote         | Crimp Crimp                       | ACX1160-ND           | 5.18       | 3.24 | 2.87   | 172148               |
|                 | Jack, Straight                   | B9913, LMR400, B7810A, B8214               | Gold              | Nexcote         | Crimp Crimp                       | ACX1161-ND           | 5.43       | 3.40 | 3.01   | 172203               |
| 17              | Jack, Straight                   | B9913, LMR400, B7810A, B8214               | Gold              | Nexcote         | Crimp Crimp                       | ACX1162-ND*          | 5.20       | 3.25 | 2.88   | 172203RP             |
|                 | Solder Jack                      | .141 Semi-Rigid, 402, U                    | Gold              | Nexcote         | Solder Solder                     | ACX1163-ND           | 5.48       | 3.43 | 3.04   | 172238               |
|                 | Solder Jack                      | .085 Semi-Rigid, 405, U                    | Gold              | Nexcote         | Solder Solder                     | ACX1164-ND           | 5.38       | 3.36 | 2.98   | 172237               |
|                 | Panel Receptacle Jack, Ext. Tef. | —  | Gold              | Nexcote         | —                                 | ACX1165-ND           | 5.88       | 3.68 | 3.26   | 172117               |
| 18              | Panel Receptacle Jack            | —  | Gold              | Nexcote         | —                                 | ACX1167-ND           | 6.52       | 4.08 | 3.61   | 172119               |
|                 | Panel Receptacle Plug            | —  | Gold              | Nexcote         | —                                 | ACX1166-ND           | 8.39       | 5.24 | 4.65   | 172118               |
|                 | Plug to Plug Adapter             | —  | Gold              | Nexcote         | —                                 | ACX1168-ND           | 8.82       | 5.51 | 4.89   | 172122               |
|                 | Jack to Jack Adapter             | —  | Gold              | Nexcote         | —                                 | ACX1169-ND           | 6.30       | 3.94 | 3.49   | 172123               |
| 19              | Bulkhead, Jack to Jack Adapter   | —  | Gold              | Nexcote         | —                                 | ACX1170-ND           | 8.06       | 5.03 | 4.46   | 172124               |
|                 | Jack to Plug Adapter             | —  | Gold              | Nexcote         | —                                 | ACX1171-ND           | 12.56      | 7.85 | 6.96   | 172126               |
|                 | Plug Cap with Chain              | —  | —                 | Nexcote         | —                                 | ACX1172-ND           | 2.68       | 1.67 | 1.48   | 202102               |
|                 | Terminator Plug with Chain       | —  | Gold              | Nexcote         | —                                 | ACX1173-ND           | 8.32       | 5.20 | 4.61   | 202109-10            |
| Terminator Jack | —                                | Gold                                       | Nexcote           | —               | ACX1174-ND                        | 5.75                 | 3.59       | 3.18 | 202110 |                      |

\* Reverse Polarity


More Product Available Online: [www.digkey.com](http://www.digkey.com)

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380



## TNC and Reverse Polarized TNC Connectors


**A**

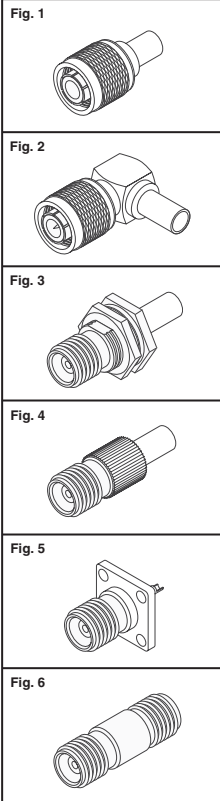

| Fig.                      | Description                      | Cable Group<br>RG/U                                     | Center<br>Contact | Body<br>Plating | Cable Attachment<br>Outer / Inner | Digi-Key<br>Part No. | 1     | Price Each<br>50 | 100    | Amphenol<br>Part No. |
|---------------------------|----------------------------------|---|-------------------|-----------------|-----------------------------------|----------------------|-------|------------------|--------|----------------------|
| Fig. 1                    | Plug, Straight-Captive Contact   | RG 58, 58A, 58C, 141, 303, LMR195 <sup>™</sup> , B7806A | Gold              | Nickel          | Crimp Crimp                       | ACX1070-ND           | 2.09  | 1.31             | 1.16   | 122108               |
|                           | Plug, Straight                   | 58, 58A, 58C, 141, 303, LMR195, B7806A                  | Gold              | Nickel          | Crimp Crimp                       | ACX1071-ND*          | 2.85  | 1.78             | 1.58   | 122108RP             |
|                           | Plug, Straight                   | RG 55, 142A, 223, 400                                   | Gold              | Nickel          | Crimp Crimp                       | ACX1072-ND           | 2.09  | 1.31             | 1.16   | 122372               |
|                           | Plug, Straight                   | 55, 142A, 223, 400<br>LMR200 <sup>™</sup> , B7807A      | Gold              | Nickel          | Crimp Crimp                       | ACX1073-ND*          | 4.16  | 2.60             | 2.30   | 122372RP             |
| Fig. 2                    | Plug, Straight                   | RG 59, 62, 140, 210                                     | Gold              | Nickel          | Crimp Crimp                       | ACX1075-ND           | 2.09  | 1.31             | 1.16   | 122111               |
|                           | Plug, Straight, 75Ω              | 59, U-20AWG   | Gold              | Nickel          | Crimp Crimp                       | ACX1076-ND           | 2.11  | 1.32             | 1.17   | 122426               |
|                           | Plug, Straight                   | RG 8, 8A, 213, 393                                      | Gold              | Nickel          | Crimp Crimp                       | ACX1077-ND           | 6.57  | 4.11             | 3.64   | 122394               |
|                           | Plug, Straight                   | RG 214  | Gold              | Nickel          | Crimp Crimp                       | ACX1078-ND           | 7.10  | 4.44             | 3.93   | 122398               |
|                           | Plug, Straight                   | RG 8X, LMR240 <sup>™</sup> , B7808A                     | Gold              | Nickel          | Crimp Crimp                       | ACX1079-ND           | 4.40  | 1.50             | 1.33   | 122408               |
|                           | Plug, Straight                   | RG 8X, LMR240, B7808A                                   | Gold              | Nickel          | Crimp Crimp                       | ACX1080-ND*          | 4.31  | 2.69             | 2.39   | 122408RP             |
|                           | Plug, Straight                   | B9913, LMR400 <sup>™</sup> , B7810A, B8214              | Gold              | Nickel          | Crimp Crimp                       | ACX1081-ND           | 7.35  | 4.59             | 4.07   | 122393               |
|                           | Plug, Straight                   | B9913, LMR400, B7810A, B8214                            | Gold              | Nickel          | Crimp Crimp                       | ACX1082-ND*          | 7.28  | 4.55             | 4.03   | 122393RP             |
|                           | Plug, Straight                   | RG 174, 188A, 316, B7805A, LMR100                       | Gold              | Nickel          | Crimp Crimp                       | ACX1083-ND           | 2.68  | 1.67             | 1.48   | 122116               |
|                           | Plug, Straight                   | 174, 188A, 316, B7805A, LMR100                          | Gold              | Nickel          | Crimp Crimp                       | ACX1085-ND*          | 3.52  | 2.07             | 1.84   | 122116RP             |
| Fig. 3                    | Plug, Straight                   | 316, U Double Braided                                   | Gold              | Nickel          | Crimp Crimp                       | ACX1084-ND           | 2.70  | 1.69             | 1.50   | 122375               |
|                           | Direct Solder Plug               | .085 Semi-Rigid, 405, U                                 | Gold              | Gold            | Solder Solder                     | ACX1086-ND           | 16.01 | 10.01            | 8.87   | 122387               |
|                           | Direct Solder Plug               | .141 Semi-Rigid, 402, U                                 | Gold              | Gold            | Solder Solder                     | ACX1087-ND           | 4.09  | 2.56             | 2.27   | 122386               |
|                           | Direct Solder Plug               | .085 Semi-Rigid, 405, U                                 | Gold              | Gold            | Solder Solder                     | ACX1088-ND*          | 4.84  | 3.02             | 2.68   | 122386RP             |
| Fig. 4                    | Right Angle Plug                 | 58, 58A, 58C, 141, 303, LMR195, B7806A                  | Gold              | Nickel          | Crimp Solder                      | ACX1090-ND           | 4.59  | 2.87             | 2.54   | 122140               |
|                           | Right Angle Plug                 | 58, 58A, 58C, 141, 303, LMR195, B7806A                  | Gold              | Nickel          | Crimp Solder                      | ACX1091-ND*          | 4.79  | 3.00             | 2.66   | 122140RP             |
|                           | Right Angle Plug                 | RG 55, 142A, 223, 400                                   | Gold              | Nickel          | Crimp Solder                      | ACX1092-ND           | 4.79  | 3.00             | 2.66   | 122430               |
|                           | Right Angle Plug                 | RG 8X, LMR240 <sup>™</sup> , B7808A                     | Gold              | Nickel          | Crimp Solder                      | ACX1093-ND           | 7.24  | 4.53             | 4.01   | 122414               |
|                           | Right Angle Plug                 | B9913, LMR400, B7810A, B8214                            | Gold              | Nickel          | Crimp Solder                      | ACX1094-ND           | 6.85  | 4.28             | 3.79   | 122416               |
|                           | Right Angle Plug                 | 174, 188A, 316, B7805A, LMR100                          | Gold              | Nickel          | Crimp Solder                      | ACX1095-ND           | 4.99  | 3.12             | 2.76   | 122418               |
|                           | Bulkhead Jack                    | RG 58, 58A, 58C, 141, 303, LMR195, B7806A               | Gold              | Nickel          | Crimp Crimp                       | ACX1096-ND           | 4.38  | 2.74             | 2.43   | 122160               |
|                           | Bulkhead Jack                    | RG 58, 58A, 58C, 141, 303, LMR195, B7806A               | Gold              | Nickel          | Crimp Crimp                       | ACX1097-ND*          | 5.24  | 3.27             | 2.90   | 122160RP             |
|                           | Bulkhead Jack                    | 174, 188A, 316, B7805A, LMR100                          | Gold              | Nickel          | Crimp Crimp                       | ACX1098-ND           | 4.38  | 2.74             | 2.43   | 122192               |
|                           | Bulkhead Jack                    | 316, U Double Braided                                   | Gold              | Nickel          | Crimp Crimp                       | ACX1099-ND           | 4.26  | 2.66             | 2.36   | 122248               |
| Fig. 5                    | Bulkhead Jack                    | RG 178B, 196A   | Gold              | Nickel          | Crimp Crimp                       | ACX1101-ND*          | 6.14  | 3.84             | 3.40   | 122370RP             |
|                           | Bulkhead, Direct Solder, Jack    | .141 Semi-Rigid, 402, U                                 | Gold              | Gold            | Solder Solder                     | ACX1102-ND           | 4.56  | 2.85             | 2.53   | 122401               |
|                           | Bulkhead, Solder Jack            | .085 Semi-Rigid, 405, U                                 | Gold              | Gold            | Solder Solder                     | ACX1103-ND           | 4.79  | 3.00             | 2.66   | 122400               |
|                           | Jack, Straight                   | RG 58, 58A, 58C, 141, 303, LMR195, B7806A               | Gold              | Nickel          | Crimp Crimp                       | ACX1104-ND           | 2.68  | 1.67             | 1.48   | 122122               |
| Fig. 6                    | Jack, Straight                   | 58, 58A, 58C, 141, 303, LMR195, B7806A                  | Gold              | Nickel          | Crimp Crimp                       | ACX1105-ND*          | 3.20  | 2.00             | 1.77   | 122122RP             |
|                           | Jack, Straight                   | RG 55, 142A, 223, 400                                   | Gold              | Nickel          | Crimp Crimp                       | ACX1106-ND           | 2.08  | 1.30             | 1.15   | 122373               |
|                           | Jack, Straight                   | RG 8X, LMR240, B7808A                                   | Gold              | Nickel          | Crimp Crimp                       | ACX1107-ND           | 5.43  | 3.39             | 3.01   | 122409               |
|                           | Jack, Straight                   | RG 8X, LMR240, B7808A                                   | Gold              | Nickel          | Crimp Crimp                       | ACX1108-ND*          | 3.20  | 2.00             | 1.77   | 122409RP             |
|                           | Jack, Straight                   | RG 8, 8A, 213, 393                                      | Gold              | Nickel          | Crimp Crimp                       | ACX1109-ND           | 5.93  | 3.71             | 3.29   | 122482               |
|                           | Jack, Straight                   | B9913, LMR400, B7810A, B8214                            | Gold              | Nickel          | Crimp Crimp                       | ACX1110-ND           | 6.11  | 3.82             | 3.38   | 122392               |
|                           | Jack, Straight                   | B9913, LMR400, B7810A, B8214                            | Gold              | Nickel          | Crimp Crimp                       | ACX1111-ND*          | 5.48  | 3.42             | 3.03   | 122392RP             |
|                           | Bulkhead, Receptacle, Solder Pot | ---   | Gold              | Nickel          | ---                               | ACX1112-ND           | 2.51  | 1.44             | 1.28   | 122332               |
|                           | Panel Receptacle, Solder Pot     | ---   | Gold              | Nickel          | ---                               | ACX1113-ND           | 4.26  | 2.66             | 2.36   | 122248               |
|                           | Jack to Jack Adapter, 50Ω        | ---   | Gold              | Nickel          | ---                               | ACX1114-ND           | 2.83  | 1.77             | 1.57   | 122348               |
| Plug to Plug Adapter, 50Ω | ---                              | Gold  | Nickel            | ---             | ACX1115-ND                        | 4.67                 | 2.92  | 2.58             | 122350 |                      |
| Plug Cap with Chain       | ---                              | ---   | Nickel            | ---             | ACX1116-ND                        | 2.68                 | 1.67  | 1.48             | 202101 |                      |
| Plug Termination, 50Ω     | ---                              | ---   | ---               | ---             | ACX1117-ND                        | 3.02                 | 1.89  | 1.67             | 202117 |                      |

\* Reverse Polarity

## Between Series Adapters

 

| Description                    | Center Contact | Body Plating | Digi-Key Part No. | 1     | Price Each 50 | 100   | Amphenol Part No. |
|--------------------------------|----------------|--------------|-------------------|-------|---------------|-------|-------------------|
| SMA Plug to BNC Jack           | Gold           | Nickel       | ACX1322-ND        | 6.22  | 3.88          | 3.51  | 242102            |
| SMA Jack to BNC Plug           | Gold           | Gold         | ACX1323-ND        | 12.06 | 7.54          | 6.81  | 242103            |
| SMA Plug to BNC Plug           | Gold           | Nickel       | ACX1324-ND        | 18.10 | 11.31         | 10.22 | 242104            |
| SMA Jack to BNC Jack           | Gold           | Nickel       | ACX1325-ND        | 10.86 | 6.79          | 6.13  | 242123            |
| SMA Jack to BNC Bulkhead Jack  | Gold           | Nickel       | ACX1326-ND        | 18.10 | 11.31         | 10.22 | 242181            |
| TNC Jack to SMA Plug           | Gold           | Nickel       | ACX1327-ND        | 12.07 | 7.54          | 6.81  | 242124            |
| SMA Jack to TNC Plug           | Gold           | Nickel       | ACX1328-ND        | 9.05  | 5.66          | 5.11  | 242105            |
| SMA Jack to TNC R/P Plug       | Gold           | Gold         | ACX1329-ND*       | 18.10 | 11.31         | 10.22 | 242105RP          |
| SMA Plug to TNC Plug           | Gold           | Nickel       | ACX1330-ND        | 18.10 | 11.31         | 10.22 | 242106            |
| SMA Jack to TNC Jack           | Gold           | Nickel       | ACX1331-ND        | 18.10 | 11.31         | 10.22 | 242107            |
| SMA Jack to TNC R/P Jack       | Gold           | Gold         | ACX1332-ND*       | 18.10 | 11.31         | 10.22 | 242107RP          |
| SMA Jack to TNC Bulkhead Jack  | Gold           | Nickel       | ACX1333-ND        | 18.10 | 11.31         | 10.22 | 242178            |
| SMA Plug to SMB Jack           | Gold           | Gold         | ACX1334-ND        | 18.10 | 11.31         | 10.22 | 242144            |
| SMA Jack to SMB Plug           | Gold           | Gold         | ACX1335-ND        | 18.10 | 11.31         | 10.22 | 242145            |
| SMA Plug to SMB Plug           | Gold           | Gold         | ACX1336-ND        | 18.10 | 11.31         | 10.22 | 242146            |
| SMA Jack to SMB Jack           | Gold           | Gold         | ACX1337-ND        | 18.10 | 11.31         | 10.22 | 242147            |
| SMA Bulkhead Jack to SMB Jack  | Gold           | Gold         | ACX1338-ND        | 18.10 | 11.31         | 10.22 | 242182            |
| SMA Plug to N Jack             | Gold           | Nickel       | ACX1339-ND        | 12.07 | 7.54          | 6.81  | 242112            |
| SMA R/P Plug to N Jack         | Gold           | Nickel       | ACX1340-ND*       | 12.07 | 7.54          | 6.81  | 242112RP          |
| SMA Jack to N Plug             | Gold           | Nickel       | ACX1341-ND        | 9.66  | 6.03          | 5.45  | 242113            |
| SMA R/P Jack to N Plug         | Gold           | Nickel       | ACX1342-ND*       | 18.10 | 11.31         | 10.22 | 242133RP          |
| SMA Plug to N Plug             | Gold           | Nickel       | ACX1343-ND        | 12.07 | 7.54          | 6.81  | 242114            |
| SMA Jack to N Jack             | Gold           | Nickel       | ACX1344-ND        | 12.07 | 7.54          | 6.81  | 242115            |
| SMA Jack to N Bulkhead Jack    | Gold           | Nickel       | ACX1345-ND        | 10.92 | 6.83          | 6.17  | 242125            |
| SMA Jack to N Panel Jack       | Gold           | Nickel       | ACX1346-ND        | 12.07 | 7.54          | 6.81  | 242163            |
| SMA Plug to MCX Jack           | Gold           | Gold         | ACX1347-ND        | 18.10 | 11.31         | 10.22 | 242126            |
| SMA Jack to MCX Plug           | Gold           | Gold         | ACX1348-ND        | 15.09 | 9.43          | 8.52  | 242127            |
| SMA Plug to MCX Plug           | Gold           | Gold         | ACX1349-ND        | 20.46 | 12.79         | 11.55 | 242128            |
| SMA Jack to MCX Jack           | Gold           | Gold         | ACX1350-ND        | 18.10 | 11.31         | 10.22 | 242129            |
| SMA Plug to MMCX Jack          | Gold           | Gold         | ACX1351-ND        | 18.10 | 11.31         | 10.22 | 242140            |
| SMA Jack to MMCX Plug          | Gold           | Gold         | ACX1352-ND        | 18.10 | 11.31         | 10.22 | 242141            |
| SMA Plug to MMCX Plug          | Gold           | Gold         | ACX1353-ND        | 18.10 | 11.31         | 10.22 | 242142            |
| SMA Jack to MMCX Jack          | Gold           | Gold         | ACX1354-ND        | 18.10 | 11.31         | 10.22 | 242143            |
| SMA Jack to MMCX Bulkhead Plug | Gold           | Gold         | ACX1355-ND        | 18.10 | 11.31         | 10.22 | 242193            |
| N Plug to BNC Jack             | Gold           | Nickel       | ACX1356-ND        | 18.10 | 11.31         | 10.22 | 242121            |
| N Jack to BNC Plug             | Gold           | Nickel       | ACX1357-ND        | 18.10 | 11.31         | 10.22 | 242101            |
| N Jack to BNC Jack             | Gold           | Nickel       | ACX1358-ND        | 18.10 | 11.31         | 10.22 | 242100            |
| N Plug to BNC Plug             | Gold           | Nickel       | ACX1359-ND        | 18.10 | 11.31         | 10.22 | 242122            |
| N Jack to BNC Bulkhead Jack    | Gold           | Nickel       | ACX1360-ND        | 30.17 | 18.86         | 17.03 | 242162            |
| N Plug to TNC Jack             | Gold           | Nickel       | ACX1361-ND        | 18.10 | 11.31         | 10.22 | 242130            |

| Description                  | Center Contact | Body Plating | Digi-Key Part No. | 1     | Price Each 50 | 100   | Amphenol Part No. |
|------------------------------|----------------|--------------|-------------------|-------|---------------|-------|-------------------|
| N Plug to TNC R/P Jack       | Gold           | Nickel       | ACX1362-ND*       | 18.10 | 11.31         | 10.22 | 242130RP          |
| N Jack to TNC Plug           | Gold           | Nickel       | ACX1363-ND        | 12.07 | 7.54          | 6.81  | 242131            |
| N Jack to TNC R/P Plug       | Gold           | Nickel       | ACX1364-ND*       | 18.10 | 11.31         | 10.22 | 242131RP          |
| N Jack to TNC Jack           | Gold           | Nickel       | ACX1365-ND        | 18.10 | 11.31         | 10.22 | 242132            |
| N Jack to TNC R/P Jack       | Gold           | Nickel       | ACX1366-ND*       | 18.10 | 11.31         | 10.22 | 242132RP          |
| N Plug to TNC Plug           | Gold           | Nickel       | ACX1367-ND        | 18.10 | 11.31         | 10.22 | 242133            |
| N Plug to TNC R/P Plug       | Gold           | Nickel       | ACX1368-ND*       | 18.10 | 11.31         | 10.22 | 242133RP          |
| N Plug to F Jack, Waterproof | Gold           | Nickel       | ACX1369-ND        | 12.07 | 7.54          | 6.81  | 242156            |
| N Plug to 7/16 Jack          | Silver         | Nexcote      | ACX1370-ND        | 60.34 | 37.72         | 34.07 | 242135            |
| N Jack to 7/16 Plug          | Silver         | Nexcote      | ACX1371-ND        | 60.34 | 37.72         | 34.07 | 242136            |
| N Jack to 7/16 Jack          | Silver         | Nexcote      | ACX1372-ND        | 60.34 | 37.72         | 34.07 | 242137            |
| N Plug to 7/16 Plug          | Silver         | Nexcote      | ACX1373-ND        | 60.34 | 37.72         | 34.07 | 242138            |
| N Bulkhead Jack to 7/16 Jack | Silver         | Nexcote      | ACX1374-ND        | 63.33 | 39.58         | 35.07 | 272183            |
| N Jack to SMB Jack Panel     | Gold           | Nickel       | ACX1375-ND        | 24.19 | 15.12         | 13.65 | 242198            |
| N Bulkhead Jack to SMB Jack  | Gold           | Nickel       | ACX1376-ND        | 18.10 | 11.31         | 10.22 | 242183            |
| BNC Plug to TNC Jack         | Gold           | Nickel       | ACX1377-ND        | 18.10 | 11.31         | 10.22 | 242148            |
| BNC Jack to TNC Plug         | Gold           | Nickel       | ACX1378-ND        | 7.25  | 4.53          | 4.09  | 242149            |
| BNC Plug to TNC Jack         | Gold           | Nickel       | ACX1379-ND        | 18.10 | 11.31         | 10.22 | 242150            |
| BNC Plug to TNC Plug         | Gold           | Nickel       | ACX1380-ND        | 18.10 | 11.31         | 10.22 | 242151            |
| BNC Plug to F Jack           | Gold           | Nickel       | ACX1381-ND        | 18.10 | 11.31         | 10.22 | 242154            |
| BNC Jack to F Plug           | Gold           | Nickel       | ACX1382-ND        | 18.10 | 11.31         | 10.22 | 242159            |
| BNC Jack to F Jack           | Gold           | Nickel       | ACX1383-ND        | 18.10 | 11.31         | 10.22 | 242161            |
| BNC Plug to F Plug           | Gold           | Nickel       | ACX1384-ND        | 12.07 | 7.54          | 6.81  | 242180            |
| BNC Plug to SMB Jack         | Gold           | Nickel       | ACX1385-ND        | 18.10 | 11.31         | 10.22 | 242184            |
| BNC Jack to SMB Plug         | Gold           | Nickel       | ACX1386-ND        | 12.07 | 7.5           |       |                   |