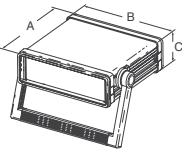
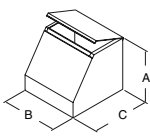
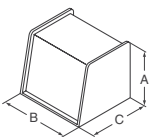
 
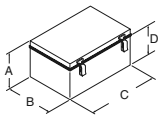
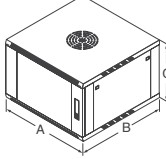
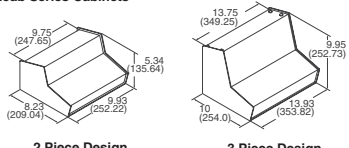


<p><b>Fig. 15 — Aluminum Instrument Case</b></p> <ul style="list-style-type: none"> <li>• Aluminum body with plastic front and rear bezels</li> <li>• Removable front and rear panels</li> <li>• Adjustable locking aluminum/plastic handle</li> <li>• Extruded internal grooves for horizontal mounting of circuit board, chassis or panel</li> </ul> 	<p><b>Fig. 16 — Sloping Panel Cabinets</b></p> <ul style="list-style-type: none"> <li>• Steel</li> <li>• Removable front panel</li> <li>• Hinged top opens completely for access to components mounted on chassis</li> </ul> 	<p><b>Fig. 17 — Slope Enclosure</b></p> 	<p><b>Fig. 18 — Mini Boxes</b></p> <ul style="list-style-type: none"> <li>• .04" aluminum alloy</li> <li>• Two sections slip together and may be joined by either built-in snap lock or sheet metal screws (included)</li> </ul> 
<p><b>Fig. 19 — Gasketed Enclosures</b></p> <p>Meets NEMA 1, 2, 4, 4X, 12 and 13 Ratings.</p> <p>Indoor Version: • ABS/PC blended plastic with UL94-5VB flammability rating</p> <p>• Clear doors polycarbonate with UL94V-0 flammability rating</p> <p>• Suggested service temperature -40°C - 70°C</p> 	<p><b>Fig. 20 — VisionCab Cabinets</b></p> <ul style="list-style-type: none"> <li>• Versatile steel cabinet</li> <li>• EIA spacing</li> <li>• Supplied with see-thru removable front door with clear acrylic window</li> <li>• Equipped with 110VAC, 105CFM exhaust fan for cooling</li> </ul> 	<p><b>Fig. 21 — Small Compucab Series Cabinets</b></p> <ul style="list-style-type: none"> <li>• Dual-slope keyboard styling</li> <li>• Base and side .09" aluminum; back panel and cover .05" aluminum</li> <li>• Rubber feet included</li> </ul>  <p><b>2 Piece Design</b>      <b>3 Piece Design</b></p>	

Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each			Bud Ind. Part No.
	A	B	C		1	5	10	
Natural	1.62 (41.15)	2.12 (53.85)	4.00 (101.6)	377-1089-ND	5.70	—	4.75	CU-3002-A
	2.25 (57.15)	2.25 (57.15)	4.00 (101.6)	377-1090-ND	6.10	—	5.05	CU-3003-A
	2.25 (57.15)	2.25 (57.15)	5.00 (127)	377-1091-ND	7.30	—	6.10	CU-3004-A
	3.00 (76.2)	4.00 (101.6)	5.00 (127)	377-1092-ND	9.20	—	7.65	CU-3005-A
	2.12 (53.85)	3.00 (76.2)	5.25 (133.35)	377-1093-ND	7.40	—	6.10	CU-3006-A
	4.00 (101.6)	5.00 (127)	6.00 (152.4)	377-1094-ND	13.20	—	11.05	CU-3007-A
	3.00 (76.2)	5.00 (127)	7.00 (177.8)	377-1095-ND	11.90	—	9.95	CU-3008-A
	3.50 (88.9)	6.00 (152.4)	8.00 (203.2)	377-1096-ND	15.50	—	12.95	CU-3009-A
	3.50 (88.9)	6.00 (152.4)	10.00 (254)	377-1097-ND	19.60	—	16.35	CU-3010-A
	4.00 (101.6)	7.00 (177.8)	12.00 (304.8)	377-1098-ND	27.30	—	22.80	CU-3011-A

\* Single knockout only — centered

**UL/NEMA/IEC Gasketed Enclosures**

Color	Dimensions - Inch (mm)				Digi-Key Part No.	Price Each			Bud Ind. Part No.
	A	B	C	D		1	5	15	
<b>Fig. 19 — NBA Series - Stainless Steel Hinges</b>									
7.09 (180.09)	11.80 (299.72)	7.85 (199.39)	5.90 (149.86)	377-1138-ND†	67.30	56.07	50.45	NBA-10144	
7.09 (180.09)	15.75 (400.05)	11.80 (299.72)	5.90 (149.86)	377-1139-ND†	99.20	82.67	74.43	NBA-10148	
5.97 (151.64)	11.80 (299.72)	7.85 (199.39)	4.80 (121.92)	377-1140-ND§	63.90	53.25	47.96	NBA-10162	
<b>Fig. 19 — NBB Series - Plastic Hinges</b>									
3.57 (90.68)	5.90 (149.86)	5.90 (149.86)	2.75 (69.85)	377-1141-ND†	20.20	16.85	15.15	NBB-10240	
5.50 (141.35)	11.28 (286.512)	7.47 (189.79)	4.33 (109.98)	377-1142-ND†	44.00	36.65	32.98	NBB-10243	
7.04 (178.82)	13.00 (330.2)	13.00 (330.2)	5.86 (148.84)	377-1143-ND†	60.80	50.67	45.63	NBB-10245	
6.30 (160.02)	15.68 (398.27)	11.73 (297.94)	5.11 (129.79)	377-1144-ND†	58.40	48.65	43.80	NBB-10247	
3.57 (90.68)	5.90 (149.86)	5.90 (149.86)	2.75 (69.85)	377-1245-ND§	23.20	19.32	17.38	NBB-10260	
3.57 (90.68)	5.90 (149.86)	5.90 (149.86)	2.75 (69.85)	377-1246-ND†	23.40	19.52	17.58	NBB-15240	
<b>Fig. 19 — NBD Series - Non-Metallic Phillips Drive Fasteners</b>									
5.03 (127.76)	7.48 (189.99)	11.02 (279.91)	3.85 (97.79)	377-1145-ND†	44.70	37.25	33.53	NBD-10442	
<b>Fig. 19 — NBE Series - Plastic Hinges / Aluminum Swing-out Panel</b>									
5.50 (141.35)	7.47 (189.79)	11.28 (286.512)	4.33 (109.98)	377-1146-ND§	82.70	69.06	62.13	NBE-10563	
6.30 (160.02)	11.73 (297.94)	15.68 (398.27)	5.11 (129.79)	377-1147-ND§	108.30	90.45	81.41	NBE-10567	
7.85 (199.39)	14.64 (371.86)	19.17 (486.92)	6.67 (169.42)	377-1148-ND§	163.90	136.87	123.17	NBE-10573	

† Solid doors § Clear doors

**VisionCab Cabinets**

Color	Dimensions - Inch (mm)			Panel Space Height - In. (mm)	Digi-Key Part No.	Price Each		Bud Ind. Part No.
	A	B	C			1	10	
<b>Fig. 20 — Black</b>								
23.62 (599.95)	23.62 (599.95)	15.29 (388.37)	10.50 (266.70)	377-1581-ND	293.40	220.05	VC-9930	
23.62 (599.95)	23.62 (599.95)	20.54 (521.72)	15.75 (400.05)	377-1582-ND	337.80	253.35	VC-9931	
23.62 (599.95)	23.62 (599.95)	25.79 (655.07)	21.00 (533.40)	377-1583-ND	404.50	303.36	VC-9932	
23.62 (599.95)	23.62 (599.95)	31.04 (788.42)	26.25 (666.75)	377-1584-ND	488.90	366.66	VC-9933	
23.62 (599.95)	23.62 (599.95)	36.29 (921.77)	31.50 (800.10)	377-1585-ND	546.70	410.00	VC-9934	

**Small Cabinets**

Description	Digi-Key Part No.	1	5	15	Bud Ind. Part No.
<b>Fig. 21 — Compucab Series - Small Metal Enclosures</b>					
2 Piece Design	377-1296-ND	83.00	69.30	62.35	SC-13100
3 Piece Design	377-1297-ND	161.60	134.90	121.41	SC-13101

Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each			Bud Ind. Part No.
	A	B	C		1	5	10	
<b>Fig. 22 — Champion Series Cabinets</b>								
Black	6.00 (152.4)	12.00 (304.8)	10.00 (254)	377-1210-ND	89.30	—	74.52	CS-11212-BT
	8.00 (203.2)	9.00 (228.6)	8.00 (203.2)	377-1211-ND	87.00	—	72.58	CS-11214-BT
	8.00 (203.2)	12.00 (304.8)	10.00 (254)	377-1212-ND	97.80	—	81.62	CS-11216-BT

Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each			Bud Ind. Part No.
	A	B	C		1	5	10	
<b>Fig. 23 — Portacab Cabinets</b>								
Gray	8.00 (203.2)	6.12 (155.45)	8.00 (203.2)	377-1315-ND	107.70	89.85	—	WA-1540
	9.00 (228.6)	8.12 (206.25)	12.00 (304.8)	377-1316-ND	148.70	124.15	—	WA-1541
	8.00 (203.2)	10.12 (257.05)	8.00 (203.2)	377-1317-ND	126.50	105.70	—	WA-1542
	11.00 (279.4)	11.12 (282.45)	18.00 (457.2)	377-1318-ND	202.80	169.37	—	WA-1543

Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each			Bud Ind. Part No.
	A	B	C		1	5	10	
<b>Fig. 24 — Converta Boxes</b>								
Natural	2.00 (50.8)	8.00 (203.2)	4.00 (101.6)	377-1221-ND	17.30	—	14.45	CU-482-A
	2.50 (63.5)	9.50 (241.3)	5.00 (127)	377-1222-ND	19.80	—	16.55	CU-592-A
	2.50 (63.5)	12.00 (304.8)	6.00 (152.4)	377-1223-ND	26.00	—	21.75	CU-622-A

Style	Color	Dimensions - Inch (mm)			Digi-Key Part No.	Price Each		Bud Ind. Part No.
		A	B	C		1	10	
<b>Fig. 25 — Plasticases</b>								
1	Gray	1.53 (38.86)	5.08 (129.03)	5.30 (134.62)	377-1149-ND	14.60	12.19	PC-11402
		2.52 (64.01)	8.10 (205.74)	6.32 (160.53)	377-1150-ND	22.40	18.67	PC-11408
		2.56 (65.02)	10.24 (260.10)	7.09 (180.09)	377-1156-ND	32.80	27.35	PC-11482-A
2	Black	4.02 (102.11)	9.72 (246.89)	8.66 (219.96)	377-1155-ND	109.40	91.30	PC-11438
		3.30 (83.82)	6.12 (155.49)	6.32 (160.53)	377-1151-ND	23.10	19.25	PC-11410
		3.30 (83.82)	8.10 (205.74)	6.32 (160.53)	377-1152-ND	26.70	22.31	PC-11412
		4.04 (102.62)	6.12 (155.49)	6.32 (160.53)	377-1153-ND	24.30	20.29	PC-11414
H	Black	4.04 (102.62)	8.10 (205.74)	6.32 (160.53)	377-1154-ND	28.40	23.73	PC-11416
		9.18 (233.17)	5.25 (133.35)	1.68 (42.67)	377-1570-ND	13.30	11.10	PC-11640
		9.18 (233.17)	5.25 (133.35)	2.36 (59.94)	377-1571-ND	13.70	11.45	PC-11645

<b>Fig. 26 — Accessories</b>					
Battery Clip, 1 - 9V Cell	377-1549-ND	1.20	1.00	HH-3449	
Battery Holder, 2-AAA Cells	377-1557-ND	1.70	1.42	HH-3630	
Battery Holder, 4-AAA Cells	377-1558-ND	2.90	2.42	HH-3631	
Battery Holder, 2-AA Cells	377-1559-ND	1.70	1.42	HH-3632	
Battery Holder, 4-AA Cells	377-1560-ND	2.90	2.42	HH-3633	

(Continued)

**More Product Available Online: [www.digkey.com](http://www.digkey.com)**