




Description	Dimensions Width x Length	Digi-Key Part No.	Price Each		3M Part No.
			1	5	
ScotchCode™ Wire Marker Tape Dispensers					
ScotchCode SDR Wire Marker Tape Dispenser with 0-9 Wire Marker Tapes	—	STD-0-9-ND	39.74	—	STD-0-9
ScotchCode SDR Wire Marker Tape Dispenser with 10 Colored Wire Marker Tapes	—	STD-C-ND	39.74	—	STD-C
ScotchCode SDR Wire Marker Tape Dispenser (no tape included)	—	STD-ND	13.06	—	STD
ScotchCode™ Wire Marker Tape Refills					
"0" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-0-ND	2.84	—	SDR-0
"1" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-1-ND	2.84	—	SDR-1
"2" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-2-ND	2.84	—	SDR-2
"3" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-3-ND	2.84	—	SDR-3
"4" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-4-ND	2.84	—	SDR-4
"5" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-5-ND	2.84	—	SDR-5
"6" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-6-ND	2.84	—	SDR-6
"7" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-7-ND	2.84	—	SDR-7
"8" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-8-ND	2.84	—	SDR-8
"9" ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive, White with Black #s	0.215" x 96"	SDR-9-ND	2.84	—	SDR-9
Black ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-BK-ND	2.84	—	SDR-BK
Brown ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-BN-ND	2.84	—	SDR-BN
Red ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-RD-ND	2.84	—	SDR-RD
Orange ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-OR-ND	2.84	—	SDR-OR
Yellow ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-YL-ND	2.84	—	SDR-YL
Green ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-GN-ND	2.84	—	SDR-GN
Blue ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-BL-ND	2.84	—	SDR-BL
Violet ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-VL-ND	2.84	—	SDR-VL
Gray ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-GY-ND	2.84	—	SDR-GY
White ScotchCode SDR Wire Marker Tape, 3-mil, Pressure-Sensitive Adhesive	0.215" x 96"	SDR-WH-ND	2.84	—	SDR-WH
Specialty Tape					
Sound Damping Tape, Aluminum, 10-mil, Pressure-Sensitive VEP Acrylic Adhesive	2" x 36 yds.	3M5608-ND	93.36	80.02	2552-2"X36YD
Linerless Rubber Splicing Tape, 30-mil, Self-Bonding, Black Ethylene Rubber	3/4" x 30'	3M130C-ND	16.06	—	130C (3/4"X30')
Self-Fusing Electrical Tape, 12-mil, Blue/Gray Silicone Rubber, Easy Tear - Easy Strip Liner	1" x 30'	3M70-ND	48.54	42.48/10	70 (1"X30')
Reflective Tape, 2-mil, Low Emissivity, Silver Metallic Polyester, Pressure-Sensitive Acrylic Adhesive	1" x 72 yds.	3M5629-ND	85.70	73.46	8437-1"X72YD
Chemical and Solvent Resistant Tape, 2.7-mil, Cream Polyester Film, Rubber Adhesive	1" x 72 yds.	3M85401-ND	15.41	—	854 (1")
Chemical and Solvent Resistant Tape, 2.7-mil, Cream Polyester Film, Rubber Adhesive	2" x 72 yds.	3M85402-ND	30.82	—	854 (2")
Electrically Conductive Transfer Tape, 2-mil, Pressure-Sensitive Conductive Adhesive	1/2" x 36 yds.	3M970312-ND	62.39	—	9703 (1/2")
Safety/Marking Tape					
Black Marking Tape, Premium Performance, Conformable, 5.2-mil, Rubber Adhesive	2" x 36 yds.	3M5619-ND	26.04	22.32	471-BLACK-2"X36YD-BULK
Red Marking Tape, Premium Performance, Conformable, 5.2-mil, Rubber Adhesive	2" x 36 yds.	3M5618-ND	26.04	22.32	471-RED-2"X36YD-BULK
Orange Marking Tape, Premium Performance, Conformable, 5.2-mil, Rubber Adhesive	2" x 36 yds.	3M5623-ND	26.04	22.32	471-ORANGE-2"X36YD-BULK
Yellow Marking Tape, Premium Performance, Conformable, 5.2-mil, Rubber Adhesive	2" x 36 yds.	3M5621-ND	26.04	22.32	471-YELLOW-2"X36YD-BULK
Green Marking Tape, Premium Performance, Conformable, 5.2-mil, Rubber Adhesive	2" x 36 yds.	3M5624-ND	26.04	22.32	471-GREEN-2"X36YD-BULK
Blue Marking Tape, Premium Performance, Conformable, 5.2-mil, Rubber Adhesive	2" x 36 yds.	3M5620-ND	26.04	22.32	471-BLUE-2"X36YD-BULK
White Marking Tape, Premium Performance, Conformable, 5.2-mil, Rubber Adhesive	2" x 36 yds.	3M5622-ND	26.04	22.32	471-WHITE-2"X36YD-BULK
Color Coding Tape Assortment, 1 each - Black, Red, Yellow, Green, Blue, White	1" x 36 yds.	3M5634-ND	7.35	6.30	764
Safety Tape, Black and Yellow Diagonal Striped, 5.4-mil, Vinyl backing, Rubber Adhesive	2" x 36 yds.	3M5628-ND	36.61	31.38	5702-2"X36YD

† Recommended for wheel flares or other less demanding applications due to a narrower width.

3M Fastening Systems

Scotchmate™ Hook and Loop Fastening Systems

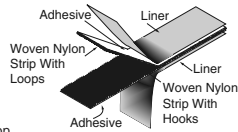

Features: When the two sides of a Scotchmate Hook and Loop Fastener are pressed together, hundreds of tiny stiff hooks mesh with a surface of pliable loops. Simply press together to fasten and pull apart to open and you can do it thousands of times during the life of your product. Depending on the application, select either Plain-backed or Adhesive-backed versions. Plain-backed versions are easily sewn or stapled in place. Adhesive-backed fasteners are available for bonding to bare or painted metal, many plastics including plasticized vinyl, plus wood, glass and more.

Standard Sew-On, Plain-Backed:
 • Tailored appearance for garments • Wash or dry clean • Operating Temperature: Up to 250°F (121°C) continuous

Pressure Sensitive Rubber Adhesive-Backed:
 • General purpose adhesion to most smooth surfaces • Operating Temperature: -20°F ~ 120°F (-29°C ~ 49°C)

Width Inch (mm)	Digi-Key Part No.	Note: X in Part No. = # of yds. Pricing			
		1 yd.	10 yds.	25 yds.	50 yds.
Standard Sew-On, Plain-Backed — Black					
5/8 (15.88)	SJ340158B-X-ND†	1.01	8.07	12.61	15.14
	SJ340258B-X-ND‡	1.01	8.07	12.61	15.14
1 (25.40)	SJ340210B-X-ND‡	1.44	11.51	17.99	21.59
Standard Sew-On, Plain-Backed — White					
5/8 (15.88)	SJ340158W-X-ND†	1.09	8.70	13.60	16.32
	SJ340258W-X-ND‡	.90	7.20	11.25	13.50
1 (25.40)	SJ340110W-X-ND†	1.44	11.51	17.99	21.59
	SJ340210W-X-ND‡	1.44	11.51	17.99	21.59
Pressure Sensitive Rubber Adhesive-Backed					
5/8 (15.88)	SJ352758B-X-ND†	5.04	40.33	63.02	67.05
	SJ352658B-X-ND‡	4.79	38.34	59.90	63.73
1 (25.40)	SJ352710B-X-ND†	5.99	47.94	74.91	79.71
	SJ352610B-X-ND‡	5.99	47.94	74.91	79.71

† Loop ‡ Hook

Scotchmate™ Reclosable Fastener SJ3000 — Thin Back-to-back Hook and Loop

 


Features: 3M™ Scotchmate™ Reclosable Fastener SJ3000 is a thin back-to-back fastener offering closure alternatives to plastic wire, tape, string, rubber bands and other types of closure systems used to secure individual or bundles of items. One side of the thin fastener strip is covered with tiny translucent polypropylene hooks, approximately 1400 per square inch (220/sq. cm). These hooks engage with thousands of soft, pliable, thin polyester loops on the reverse side providing for a limited number of openings and closings (cycles). Simply pull the strips apart to disengage.

- **Material of Construction:** Hook: Translucent Polypropylene; Loop: Polyester
- **Thickness - Unmated:** 0.027", 0.69mm

Width Inch (mm)	Color	Digi-Key Part No.	Note: X in Part No. = # of yds. Pricing			
			1 yd.	10 yds.	25 yds.	50 yds.
1 (25.40)	Red	SJ300010R-X-ND	1.45	9.30	20.66	36.16
		SJ300012R-X-ND	.88	5.69	12.64	22.12
1 (25.40)	Black	SJ300010B-X-ND	1.45	9.30	20.66	36.16
		SJ300012B-X-ND	.87	5.58	12.40	21.69

Rigid Backed Dual Lock



Features: Type 400 Dual Lock Fasteners on a rigid back with recessed mounting hole.

Size (mm)	Hole Size	Digi-Key Part No.	Pricing		
			1	50	100
Round					
20.6 Diameter	4.1mm	SJ3463-ND	.28	11.00	16.50
	4.1mm	SJ3465-ND	.40	16.00	24.00
Square					
38.1 Square	4.2mm	SJ3252-ND	.68	27.00	40.50
	3.6mm	SJ3261-ND	.68	27.00	40.50

(Continued)

More Product Available Online: www.digkey.com