




Thermal Transfer Printer Labels, Cassettes and Accessories

LS6 Thermal Transfer Printer Labels

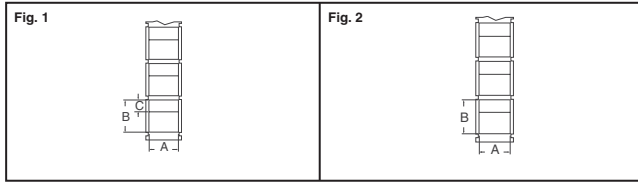

Self-Laminating Wire Markers — Vinyl

Fig.	Label Size A x B x C (In.)	Cable O.D. Range (In.)	For THHN Cable Size	Digi-Key Part No.	Roll Pricing 250	Panduit Part No.
1	1.50 x 1.25 x 0.50	0.16 – 0.24	8 AWG	298-1257-ND	43.37	TWS-3V

Component Labels

Fig.	Label Size A x B (In.)	Material	Color	Digi-Key Part No.	Roll Pricing 250	Panduit Part No.
2	1.00 x 0.75	Vinyl Cloth	White	298-4004-ND	31.89	TC-4C

Printer Accessories


Description	Digi-Key Part No.	Price Each	Panduit Part No.
Replacement Battery Pack	298-1227-ND	110.08	LS6-BP
Replacement AC Adapter/Battery Charger	298-1226-ND	104.65	LS6-ACS

LS7 Thermal Transfer Printer Accessories

Description	Digi-Key Part No.	Price Each	Panduit Part No.
120VAC Adapter	298-1347-ND	54.04	LS7-ACS

Laser Printable Labels

 (Functions with most Desktop Laser Printers)



Laser Self-Laminated Wire Markers — White Polyester (Box)



Label Size A x B (In.)	C Print Area (In.)	Cable O.D. Range (In.)	For THHN Cable Size	Digi-Key Part No.	Roll Qty.	Pricing	Panduit Part No.
1.00 x 1.33	0.50	0.16 – 0.26	8-6 AWG	298-1163-ND	2,500	238.99	LJSL5-Y3-2.5
1.00 x 3.17	0.97	0.31 – 0.70	4-4/0 AWG	298-1164-ND	1,000	196.25	LJSL6-Y3-1
2.00 x 3.17	1.00	0.32 – 0.69	4-4/0 AWG	298-1169-ND	1,000	247.81	LJSL8-Y3-1
0.50 x 1.50	0.50	0.16 – 0.32	8-6 AWG	298-1174-ND	5,000	239.08	LJSL2-Y3-5
2.00 x 1.50	0.50	0.16 – 0.32	8-6 AWG	298-1175-ND	1,000	232.73	LJSL7-Y3-1

Laser Component Labels — Polyester (Box)

Label Size A x B (In.)	Color	Digi-Key Part No.	Roll Qty.	Pricing	Panduit Part No.
1.50 x 0.25	White	298-1165-ND◆	10,000	232.46	PLL-14-Y2-10
1.88 x 0.25	White	298-1166-ND	10,000	288.67	PLL-15-Y2-10
3.00 x 0.38	White	298-1167-ND◆	1,000	94.59	PLL-19-Y2-1
0.80 x 0.20	White	298-1168-ND◆	10,000	199.93	PLL-20-Y2-10
0.38 x 0.38	White	298-1170-ND◆	10,000	153.12	PLL-2-Y2-10
0.50 x 0.44	White	298-1172-ND◆	10,000	223.76	PLL-31-Y2-10
0.65 x 0.20	White	298-1173-ND◆	10,000	169.65	PLL-32-Y2-10
0.80 x 0.25	White	298-1176-ND◆	10,000	199.93	PLL-5-Y2-10
1.00 x 0.38	White	298-1177-ND◆	10,000	276.14	PLL-8-Y2-10
1.00 x 0.50	White	298-1178-ND◆	10,000	334.78	PLL-9-Y2-10

◆ RoHS Compliant

NAKAGAWA MFG. (USA), INC.

Thermal Paper

Quality thermal paper available in 58, 60, 80 and 112mm paper widths.

SPECIFICATIONS:

• Paper core: 12mm • Paper length: 30M • Outer diameter: 55mm • End mark: Red, 50cm from end of roll • Paper weight: 65µm • Print life: Greater than 5 years when stored in a dark location, 25°C or less, 65% R.H. max.

Description	Digi-Key Part No.	Price Each				Nakagawa Part No.
		1	10	100	250	
58mm Thermal Printer Paper	PT1028-ND	2.20	1.76	1.54	1.47	EPT-58
60mm Thermal Printer Paper	PT1029-ND	2.38	1.90	1.67	1.59	EPL-60
80mm Thermal Printer Paper	PT1030-ND	2.88	2.30	2.02	1.93	EPT-80
112mm Thermal Printer Paper	PT1031-ND	3.10	2.48	2.17	2.08	EPL-112


3M Cable Ties

3M Cable Ties secure wire bundles and harness components quickly, without slipping.

The self-locking head, with heavy double teeth on the one piece lock mechanism.

Molded from 6/6 nylon, 3M cable ties are designed to meet a wide range of temperatures from -40°F – 185°F (-40°C – 85°C).

Weather resistant black nylon for indoor and outdoor use and natural nylon for indoor use only.

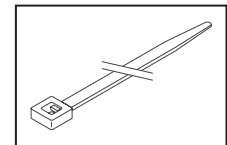

Cable Tie Type	Dimensions – Inch (mm)			Tensile Lb/Kg	Color	Digi-Key Part No.	Bag Qty.	Price Each	3M Part No.	Digi-Key Part No.	Bag Qty.	Price Each	3M Part No.
	Length	Width	Max. Bundle Diameter										
Miniature	4.0 (101.6)	.10 (2.54)	.8 (20.32)	18 (8.16)	Natural	3M101C-ND◆	100	2.84	41931	3M101M-ND◆	1,000	14.90	41932
	4.0 (101.6)	.10 (2.54)	.8 (20.32)	18 (8.16)	Black	3M101BKC-ND◆	100	3.12	41929	3M101BKMN-ND◆	1,000	16.60	41930
	6.0 (152.4)	.10 (2.54)	1.7 (43.18)	18 (8.16)	Natural	3M110C-ND◆	100	4.69	43400	3M110M-ND◆	1,000	27.32	43401
	6.0 (152.4)	.10 (2.54)	1.7 (43.18)	18 (8.16)	Black	3M110BKC-ND◆	100	5.50	43500	3M110BKMN-ND◆	1,000	31.21	43510
	8.0 (203.2)	.10 (2.54)	2.2 (55.88)	18 (8.16)	Natural	3M111C-ND◆	100	5.64	43540	3M111M-ND◆	1,000	32.83	43541
	8.0 (203.2)	.10 (2.54)	2.2 (55.88)	18 (8.16)	Black	3M111BKC-ND◆	100	6.73	43547	—	—	—	—
Inter- mediate	5.7 (144.78)	.14 (3.56)	1.4 (35.56)	40 (18.14)	Natural	3M102C-ND◆	100	5.14	41935	3M102M-ND◆	1,000	29.77	41936
	5.7 (144.78)	.14 (3.56)	1.4 (35.56)	40 (18.14)	Black	3M102BKC-ND◆	100	6.03	41933	3M102BKMN-ND◆	1,000	34.06	41934
Standard	7.5 (190.5)	.18 (4.57)	1.9 (48.26)	50 (22.68)	Natural	3M103C-ND◆	100	6.20	41937	3M103M-ND◆	1,000	36.18	41938
	7.5 (190.5)	.18 (4.57)	1.9 (48.26)	50 (22.68)	Black	3M103BKC-ND◆	100	7.45	41939	3M103BKMN-ND◆	1,000	42.52	41940
	11.3 (287.02)	.18 (4.57)	3.1 (78.74)	50 (22.68)	Natural	3M104C-ND◆	100	11.88	41941	3M106D-ND◆	1,000	73.80	43200
	11.3 (287.02)	.18 (4.57)	3.1 (78.74)	50 (22.68)	Black	3M104BKC-ND◆	100	13.08	41943	3M106BKD-ND◆	1,000	79.92	43201
	14.5 (368.3)	.18 (4.57)	4.1 (104.14)	50 (22.68)	Natural	3M105C-ND◆	100	17.10	41978	3M105D-ND◆	500	71.40	41952
	14.5 (368.3)	.18 (4.57)	4.1 (104.14)	50 (22.68)	Black	3M105BKC-ND◆	100	18.48	41977	3M105BKD-ND◆	500	82.20	41948
Heavy Duty	15.1 (383.54)	.30 (7.62)	4.0 (101.6)	120 (54.43)	Natural	3M107HDC-ND◆	100	30.12	43202	3M105HDD-ND◆	500	148.80	41950
	15.1 (383.54)	.30 (7.62)	4.0 (101.6)	120 (54.43)	Black	3M107HDBKC-ND◆	100	33.42	43203	3M105HDBKDN-ND◆	500	165.00	41946
Extra Heavy Duty	37.1 (942.34)	.34 (8.64)	11 (279.4)	175 (79.38)	Natural	3M109HDL-ND	50	61.71	43206	—	—	—	—
	37.1 (942.34)	.34 (8.64)	11 (279.4)	175 (79.38)	Black	3M109HDBKLN-ND	50	67.86	43207	—	—	—	—
	48 (1219.2)	.35 (8.89)	15 (381)	175 (79.38)	Black	3M114HDBKLN-ND◆	50	111.72	43575	—	—	—	—

◆ RoHS Compliant

More Product Available Online: www.digikey.com

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

(T083) 2225