 


Metal Cable Clamps




Half Clamp		Clamp		218	
D	Dimensions - Inch L W H	Digi-Key Part No.	10	Pricing 100	
Steel Half Clamps					
.125	.437 .500	218 8140K-ND	1.64	11.85	
.187	.437 .500	218 8141K-ND	1.72	12.80	
.250	.437 .500	218 8142K-ND	1.85	13.30	
.312	.500 .500	218 8143K-ND	1.99	14.35	
.375	.531 .625	218 8144K-ND	2.32	16.60	
.437	.562 .625	218 8145K-ND	2.44	17.60	
.500	.625 .625	218 8146K-ND	3.05	21.90	
.562	.687 .625	218 8147K-ND	3.13	22.55	
.625	.750 .625	218 8148K-ND	3.28	23.70	
.687	.812 .625	218 8149K-ND	3.36	24.25	
.750	.812 .625	218 8150K-ND	3.50	25.10	
.812	.875 .625	218 8151K-ND	3.63	26.20	
.875	.937 .750	281 8152K-ND	3.96	28.45	
.937	.968 .750	281 8153K-ND	4.11	29.70	
1.000	1.000 .750	281 8154K-ND	9.00	63.45	
Insulated Steel Half Clamps					
.187	.437 .500	218 8160K-ND	4.44	31.55	
.250	.500 .500	218 8161K-ND	4.39	35.65	
.312	.531 .625	218 8162K-ND	4.97	40.35	
.375	.562 .625	218 8163K-ND	5.20	42.15	
.437	.625 .625	218 8164K-ND	5.87	47.45	
.500	.687 .625	218 8165K-ND	4.31	35.05	
.562	.750 .625	218 8166K-ND	4.46	36.25	
.625	.812 .625	218 8167K-ND	4.57	37.30	
.687	.812 .625	218 8168K-ND	4.74	38.45	
.750	.875 .625	218 8169K-ND	5.16	41.95	
.812	.937 .750	281 8170K-ND	8.17	65.10	
.875	.968 .750	281 8171K-ND	6.75	54.70	
.937	1.000 .750	281 8172K-ND	7.95	64.40	
1.000	1.062 .750	281 8173K-ND	7.48	60.80	
Steel Clamps					
.250	.406 .500	203 8101K-ND	2.03	14.70	
.312	.437 .500	203 8102K-ND	2.11	15.15	
.375	.468 .500	203 8103K-ND	2.19	15.90	
.437	.500 .500	203 8104K-ND	2.28	16.45	
.500	.531 .500	203 8105K-ND	2.40	17.25	
.562	.562 .500	203 8106K-ND	2.52	18.20	
.625	.594 .500	203 8107K-ND	2.61	18.75	
.687	.625 .500	203 8108K-ND	2.69	19.45	
.750	.656 .500	203 8109K-ND	2.77	20.05	
.812	.687 .500	203 8110K-ND	2.86	20.45	
.875	.718 .500	203 8111K-ND	2.96	21.35	
.937	.750 .500	203 8112K-ND	3.06	22.15	
1.000	.781 .500	203 8113K-ND	3.13	22.65	
Insulated Steel Clamps					
.187	.406 .500	203 8121K-ND	3.79	27.25	
.250	.437 .500	203 8122K-ND	3.91	28.25	
.312	.468 .500	203 8123K-ND	4.07	29.45	
.375	.500 .500	203 8124K-ND	4.20	30.25	
.437	.531 .500	203 8125K-ND	4.36	31.65	
.500	.562 .500	203 8126K-ND	4.52	32.60	
.562	.594 .500	203 8127K-ND	4.69	33.95	
.625	.625 .500	203 8128K-ND	4.24	34.80	
.687	.656 .500	203 8129K-ND	4.35	35.80	
.750	.687 .500	203 8130K-ND	4.48	37.05	
.812	.718 .500	203 8131K-ND	4.60	37.80	
.875	.750 .500	203 8132K-ND	4.74	38.95	
.937	.781 .500	203 8133K-ND	4.86	39.80	
1.000	.812 .500	203 8134K-ND	4.99	41.10	

RoHS Compliant

K

Nylon Cable Clamps

 
Ideal for securing, insulating and routing cable wiring, piping, tubing, components and fibre optics. Made of .050" thick nylon 6/6, white.



D	Dimensions - Inch E W H	Digi-Key Part No.	100	Pricing 500 1,000
.125	.325 .375 .140	7620K-ND	5.23	23.25 26.30
.125	.325 .375 .203	7621K-ND	5.23	23.25 26.30
.187	.380 .375 .140	7622K-ND	5.35	23.75 26.60
.187	.380 .375 .203	7623K-ND	5.35	23.75 26.60
.250	.410 .375 .140	7624K-ND	5.44	23.75 27.60
.250	.410 .375 .203	7625K-ND	5.46	23.75 27.60
.312	.445 .375 .140	7626K-ND	5.45	24.50 28.20
.312	.445 .375 .203	7627K-ND	5.45	24.50 28.20
.375	.475 .375 .140	7628K-ND	5.90	25.75 30.30
.375	.475 .375 .203	7629K-ND	5.90	25.75 30.30
.437	.525 .375 .140	7630K-ND	6.29	27.25 31.45
.437	.525 .375 .203	7631K-ND	6.29	27.25 31.45
.500	.550 .375 .140	7632K-ND	6.29	27.75 32.35
.500	.550 .375 .203	7633K-ND	6.29	27.75 32.35
.562	.625 .500 .203	7634K-ND	9.74	43.25 49.55
.625	.660 .500 .203	7635K-ND	10.47	44.50 52.00
.750	.785 .500 .203	7636K-ND	11.63	50.25 59.70
.875	.845 .500 .203	7637K-ND	12.69	54.50 63.60
1.000	.910 .500 .203	7638K-ND	13.01	56.75 66.45
1.125	.970 .500 .203	7639K-ND	18.65	80.50 93.65
1.125	1.060 .500 .203	7640K-ND	19.99	86.75 101.75

RoHS Compliant

Recessed Bumpers

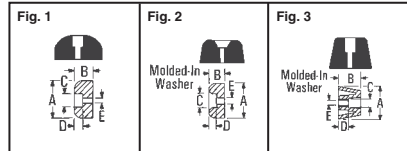


Provides excellent traction and shock absorbing qualities.
Materials:
Fig. 1 and 2: Rubber, BUNA S
Fig. 3: Vinyl

Fig.	A	Dimensions - Inch B C D E	Screw Size	Digi-Key Part No.	10	Pricing 100
1	.500	.250 .250 .125	.125	#4 720K-ND	2.20	15.90
	.625	.312 .250 .187	.125	#4 721K-ND	3.50	25.10
	.718	.437 .250 .218	.125	#4 722K-ND	6.13	50.50
2	.937	.375 .375 .187	.187	#8 723K-ND	5.88	48.55
	.562	.375 .218 .187	.115	#4 727K-ND	5.47	45.00
3	.687	.250 .343 .125	.155	#6 724K-ND	4.52	37.30
	.750	.437 .265 .250	.148	#6 728K-ND	6.16	50.70
	.875	.312 .406 .187	.187	#8 725K-ND	8.34	68.75
	.937	.625 .359 .297	.174	#8 729K-ND	9.11	74.95
	1.062	.437 .468 .234	.200	#10 726K-ND	10.39	85.35

† Gray — all others black

 
Flat Washers



Fibre: Commercial per ASTM D710, Grade CH
Nylon: Grade 6/6 per ASTM D4066

O.D. A	Dimensions - Inch Thick B I.D. C	Digi-Key Part No.	100	Pricing 500 1,000
Nylon Material — #2 Screw Size				
.250	.032 .098	3347K-ND	3.28	14.75 —
Fibre Material — #4 Screw Size				
.250	.032 .120	3116K-ND	3.39	15.50 —
.312	.032 .120	348K-ND	3.41	15.50 —
.375	.032 .120	3117K-ND	3.51	15.50 —
.250	.047 .120	3154K-ND	3.40	15.50 —
.312	.047 .120	3155K-ND	3.40	15.50 —
.375	.047 .120	3156K-ND	3.84	16.50 17.30
.250	.062 .120	3368K-ND	3.40	15.50 —
.312	.062 .120	3196K-ND	3.40	15.50 18.85
.375	.062 .120	3197K-ND	3.51	15.50 17.85
Nylon Material — #4 Screw Size				
.250	.032 .120	3348K-ND	3.28	14.75 —
.312	.032 .120	3359K-ND	3.95	17.00 20.10
.375	.032 .120	3118K-ND	4.18	18.75 21.50
.250	.047 .120	345K-ND	3.95	16.75 —
.312	.047 .120	3157K-ND	3.34	14.75 19.40
.375	.047 .120	3158K-ND	3.34	14.75 21.40
.250	.062 .120	3358K-ND	3.33	14.75 19.40
.312	.062 .120	3198K-ND	3.95	17.00 25.70
.375	.062 .120	3200K-ND	3.96	16.75 24.25
Fibre Material — #6 Screw Size				
.250	.032 .140	3119K-ND	3.39	15.50 —
.312	.032 .140	3120K-ND	3.41	15.50 —
.375	.032 .140	3121K-ND	3.51	15.50 —
.250	.047 .140	3159K-ND	3.40	15.50 —
.312	.047 .140	3160K-ND	3.40	15.50 —
.375	.047 .140	3161K-ND	3.84	16.50 17.30
.250	.062 .140	3369K-ND	3.40	15.50 —
.312	.062 .140	3370K-ND	3.40	15.50 16.50
.375	.062 .140	3201K-ND	3.51	15.50 17.85
Nylon Material — #6 Screw Size				
.250	.032 .140	3122K-ND	3.28	14.75 —
.312	.032 .140	3349K-ND	3.29	14.75 16.00
.375	.032 .140	3123K-ND	4.18	18.75 21.50
.250	.047 .140	3162K-ND	3.28	14.75 15.60
.312	.047 .140	346K-ND	4.17	17.75 19.40
.375	.047 .140	3163K-ND	3.34	14.75 21.40
.250	.062 .140	3360K-ND	3.28	14.75 19.40
.312	.062 .140	3361K-ND	3.95	17.00 25.70
.375	.062 .140	3202K-ND	3.96	16.75 24.25
Fibre Material — #8 Screw Size				
.312	.032 .171	3124K-ND	3.41	15.50 —

 Nylon Shoulder Washers/Bushings



Material: Nylon, Grades 6/6 per ASTM D4066

L	A	Dimensions - Inch B C D	Digi-Key Part No.	100	Pricing 500
#4 Screw Size					
.031	.218	.040 .115 .135	3049K-ND	4.84	20.75
.047	.250	.032 .115 .185	7681K-ND	6.29	27.75
.093	.235	.047 .115 .145	3053K-ND	9.13	39.25
.125	.235	.047 .115 .145	3102K-ND	9.13	39.25
.180	.235	.047 .115 .145	3103K-ND	9.13	39.25
.250	.235	.047 .115 .145	340K-ND	10.29	44.50
#6 Screw Size					
.032	.385	.062 .145 .240	7682K-ND	7.17	30.00
.032	.250	.062 .140 .187	7683K-ND	6.06	26.00
.032	.312	.062 .140 .187	7684K-ND	6.62	28.25
.125	.290	.047 .140 .170	3054K-ND	9.12	39.25
.187	.290	.047 .140 .170	3104K-ND	9.52	41.75
.250	.290	.047 .140 .170	341K-ND	10.29	44.50
.500	.290	.047 .140 .170	3055K-ND	10.46	45.00

More Product Available Online: www.digkey.com