

Weller® Accessories


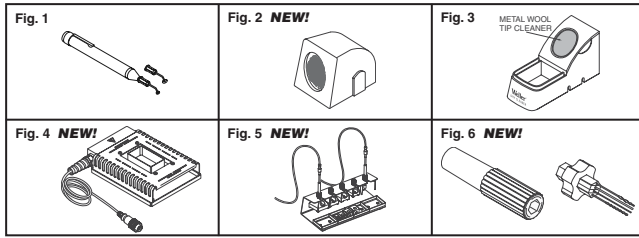


Fig.	Description	Digi-Key Part No.	Price Each	Weller Part No.
1	Vacuum Pick-up Tool	WLSK200-ND	48.80	WLSK200
2	WDH Dry Cleaning System	0051512599-ND NEW!	12.06	0051512599
3	WDC Dry Cleaning System with Wool	0051512499-ND	16.00	0051512499
—	Replacement Wool (2/pack)	0051382499-ND	5.00	0051382499
—	Solder Bath, 80W (for use with WD2 and WD2M Stations)	0052704099-ND NEW!	205.00	0052704099
4	Solder Bath, 150W (for use with WD2 and WD2M Stations)	0052704299-ND NEW!	304.00	0052704299
5	SMT Chip Removal Nozzle Kit	0051515599-ND NEW!	301.50	0051515599
6	Cleanout Tool for Desoldering Pencils	0051350099-ND NEW!	14.70	0051350099
—	Polishing Bar for Soldering Tips	WPB1-ND NEW!	8.05	WPB1
—	Tip Timer for Solder Tip, 1.50z.	0051303199-ND NEW!	8.05	0051303199

Professional Soldering Irons WP25, WP30, WP35 Series Irons

Features: • Fixed temperature units • Ideal for a wide variety of electronic tasks • Interchangeable heater elements - Single handle plus three different heating elements gives the user a trio of irons for different jobs • Quick change knurled collar makes changing heater simple • Lightweight handle with cushioned grip • For additional safety, all irons come with 3-wire power cord • Irons use ST series iron plated tips for long life and greater soldering efficiency • UL Listed

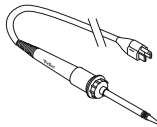

Description	Digi-Key Part No.	Price Each	Weller Part No.
Soldering Iron with ST3 Tip, 25 Watt*	WP25-ND	37.07	WP25
Soldering Iron with ST3 Tip, 30 Watt*	WP30-ND	40.07	WP30
Soldering Iron with ST3 Tip, 35 Watt*	WP35-ND	46.67	WP35
Soldering Iron Stand for WP Series	PH60-ND	23.04	PH60
Knurled Tip Retaining Nut	KN60-ND	3.00	KN60

* Soldering Iron Stand is sold separately.

Soldering Irons

Specifications: • Specifically designed for use at electrostatic free work stations • Non-burnable silicon rubber cord • Lightweight, high impact plastic handle • Blue plastic meets requirements for ESD, Electrostatic Dissipative Materials • Uses Weller EM series tips made of copper with heavy iron, nickel and chromium plating for long life • UL Listed

NOTE: EC1302B and EC1201A work with DEC1001 and EC1002.

<p>EC1302B:</p> <ul style="list-style-type: none"> • Micro-soldering tool • Stainless steel heater element construction • Fine tip iron for light duty applications 	<p>EC1201A:</p> <ul style="list-style-type: none"> • General purpose soldering tool • Stainless steel plug-in heater element construction • General purpose iron for mid-range applications 	<p>PES50:</p> <ul style="list-style-type: none"> • General purpose soldering tool • Stainless steel plug-in heater element construction • General purpose iron for mid-range applications
---	---	---

Description	Digi-Key Part No.	Price Each	Weller Part No.
20W Iron with EPH 101 Tip	EC1302B-ND	115.00	EC1302A
40W Soldering Iron with ETA Tip	EC1201A-ND	115.00	EC1201A
50W Soldering Iron with ETA Tip	PES50-ND	39.77	PES50
Replacement Sponge	TC205-ND	1.04	TC205

Replacement Tips for Irons

Tip Dim. (mm)	Description	Digi-Key Part No.	Price Each	Weller Part No.
PT Series Tips for TC2011 Iron				
1.57	Screwdriver, 700°F (371°C)	PTA7-ND	3.15	PTA7
1.57	Screwdriver, 800°F (427°C)	PTA8-ND	3.15	PTA8
3.18	Screwdriver, 700°F (371°C)	PTC7-ND	3.15	PTC7
3.18	Screwdriver, 800°F (427°C)	PTC8-ND	3.15	PTC8
.79	Conical Flat, 700°F (371°C)	PTF7-ND	3.15	PTF7
.79	Conical Flat, 800°F (427°C)	PTF8-ND	3.15	PTF8
.38	Long Conical, 700°F (371°C)	PTS7-ND	3.15	PTS7
.38	Long Conical, 800°F (427°C)	PTS8-ND	3.15	PTS8
EPH Series Tips for EC1302B Iron				
.38	Micropoint Tip	EPH101-ND	5.10	EPH101
1.57	Screwdriver Tip	EPH106-ND	5.10	EPH106
	Replacement Barrel Nut Assortment for EPH Tip	EC231-ND	8.40	EC231
ET Series Tips for EC1201A				
1.57	Screwdriver Tip	ETA-ND	3.50	ETA
2.36	Screwdriver Tip	ETB-ND	3.50	ETB

Tip Dim. (mm)	Description	Digi-Key Part No.	Price Each	Weller Part No.
.79	Screwdriver Tip	ETH-ND	3.50	ETH
.79	Conical Tip	ETP-ND	3.50	ETP
.40	Single Flat Tip	ETU-ND	3.50	ETU
.80	Long Conical Tip	ETO-ND	3.50	ETO
Tips for Professional Soldering Irons — ST Series Tips for WP25, WP30, WP35 Irons				
1.57	Screwdriver Tip	ST1-ND	3.28	ST1
4.65	Screwdriver Tip	ST4-ND	3.28	ST4
.79	Single Flat Tip	ST5-ND	3.28	ST5
.79	Screwdriver Tip	ST6-ND	3.28	ST6

Flux and Scrub-It® Solvent Dispensers

Flux Dispensers: • Both static safe and standard hold 2 ounces • Avoid spills and waste and place flux precisely where needed • Squeeze bottles dispense one drop of liquid resin, flux, oil solvent through stainless steel needles • Static dissipative models protect static-sensitive components

Scrub-It® Solvent Dispensers: • Squeeze dispenser to distribute solvent through brush • For cleaning printed circuit boards and other connections • No mess, no waste • Available with nylon bristles or horsehair for static-safe applications • Dispenser holds 2 ounces



Description	Digi-Key Part No.	Price Each	Weller Part No.
Flux Dispenser, 0.020" (.51mm) Needle	FD2-ND	2.76	FD2
Scrub-It Bottle, Nylon Bristle	SD74-ND	9.42	SD74
Scrub-It Bottle, Horsehair ESD Safe	SD74H-ND	9.42	SD74H


Hot Air Rework Station and Nozzles

Specifications:

- 650W • Temperature Range: 122°F - 1022°F • Voltage: 120V

Features:

- Compact design maximizes workspace efficiency
- Controlled output maintains set temperature regardless of air flow setting
- Temperature and air flow are controlled independently
- Standby button allows you to power down to low settings when not in use
- Includes a rest support for the hand piece
- Nozzles sold separately

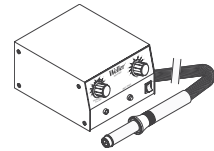


Description	Digi-Key Part No.	Price Each	Weller Part No.
Self-Contained Hot Air Station, 120V	WHA900-ND	549.00	WHA900
Hot Air Nozzle, 44 PIN PLCC	0058736814-ND	66.42	0058736814
Hot Air Nozzle, 84 PIN PLCC	0058736833-ND	83.30	0058736833
Hot Air Nozzle, 20 PIN PLCC	0058736839-ND	63.77	0058736839
Hot Air Nozzle, 68 PIN PLCC	0058736804-ND	66.42	0058736804
Hot Air Nozzle, 14 PIN SOIC-SO8	0058736843-ND	63.77	0058736843
Hot Air Nozzle, 20 PIN SOIC	0058736842-ND	63.77	0058736842
Hot Air Nozzle, SOT23	0058736870-ND	63.77	0058736870

Tools

TB100: • 27 watt continuous heat gun turns into 130 watt soldering gun with a squeeze of the thermo-boost trigger • Includes: Tool, conical and screwdriver soldering tips, scoring tip, rope cutting tip, foam cutting tip, smoothing tip, stand and instructions


WSA350: • Removes flux fumes from the bench top by drawing the smoke through an activated carbon filter • Voltage: 120VAC • Air Consumption: 87-102 CFM • Sound Level: 45-50dB (A) • ESD Safe • UL and cUL Listed • Includes: Bench top smoke absorber and one WSA350F filter

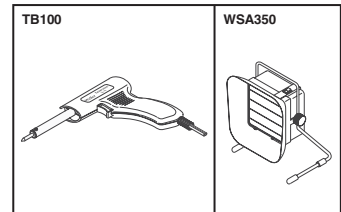

Description	Digi-Key Part No.	Price Each	Weller Part No.
Heat Tool with Thermo-Boost Solder Gun	TB100PK-ND	20.60	TB100PK
Benchtop Smoke Absorber	WSA350-ND	50.00	WSA350
Carbon Replacement Filters (3 pack)	WSA350F-ND	5.25	WSA350F

Weller® portasol® Cordless Soldering Irons and Tips

Features: 75 Watt • Gives the ultimate in portable power and convenience for all soldering jobs • Provides 25 - 75 watts of power • Adjustable temperatures up to 850°F (454.4°C) • Refueled with standard butane refills • Unit lasts for up to an hour of continuous use 125 Watt • Self-igniting portable butane heat tool • Anti-static soldering • "Auto Switch" safety shut-off iron plated tips, and built-in butane filter • Rugged stainless-steel body provides up to 125 watts of power • Adjustable temperature up to 1,076°F (580°C) • Fuel level is clearly visible through a window on the body of the tool **Note:** Butane not included (Butane is not sold by Digi-Key)

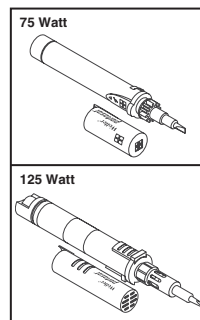

Description	Digi-Key Part No.	Price Each	Weller Part No.
75 Watt			
Cordless Soldering Iron with PPT6 Tip, 2.4mm	P2C-ND	33.99	P2C
Single Flat, Solder Tip, 1.0mm	PPT1-ND	8.31	PPT1
Single Flat, Solder Tip, 2.4mm	PPT2-ND	8.31	PPT2
Double Flat, Solder Tip, 1.0mm	PPT5-ND	8.31	PPT5
Double Flat, Solder Tip, 2.4mm	PPT6-ND	8.31	PPT
125 Watt			
Cordless Soldering Iron	PSI100C-ND	60.06	PSI100C
Single Flat, Solder Tip, 1.0mm	PSI1-ND	10.62	PSI1
Single Flat, Solder Tip, 2.4mm	PSI2-ND	10.62	PSI2
Single Flat, Solder Tip, 3.2mm	PSI3-ND	10.62	PSI3
Single Flat, Solder Tip, 4.8mm	PSI4-ND	10.62	PSI4
Single Chisel, Solder Tip, 1.0mm	PSI5-ND	10.62	PSI5
Double Flat, Solder Tip, 2.4mm	PSI6-ND	10.62	PSI6
Double Flat, Solder Tip, 3.2mm	PSI7-ND	10.62	PSI7
Double Flat, Solder Tip, 4.8mm	PSI8-ND	10.62	PSI8
Hot Blower Tip	PSI9-ND	10.62	PSI9

More Product Available Online: www.digkey.com