

**Test Leads**




**Kit Features:** • Test leads with a right angle banana plug are ideal for use with hand held digital multimeter • Test accessories conveniently store in the four-fold nylon pouch • Compatible with most multimeters that accepts safety style sheath banana plugs • CE Compliant; complies with IEC 1010-2-031 standard for hand held accessories

**Electrical DMM: Model 5673B — Kit Includes (1 red and 1 black of each):** • Modular Probe Set • Extended Fine Point • Extra Large Alligator Clip Set • Medium Alligator Clip Set • Flexible Test Lead Set • Insulated Spade Lug Set **Model 5677B — Kit Includes (1 red and 1 black of each):** • Flexible Test Lead Set • Extra Large Alligator Clip Set • Test Lead Coupler Set • Retractable Tip Set • Spade Lug Adapter Set • IC Test Probe Tip Adapter Set • Minigrabber® Test Clip Set • 0.080 Replacement Probe Tip Set • Replacement Modular Test Probe Set • Minipincer® Test Clip Set • Medium Alligator Clip Set

**SMD Multi-Use Test Kits: Model 72928 — Kit Includes: (1 red and 1 black of each):** • Micro SMD Grabber Test Clips • Mini-alligator clip with 2mm jack • SMD test probe, spring-set tip • Mini SMD Grabber Test Clips • 4mm plug/2mm plug adapter • Bench-top DMM test leads • SMD grabber clip lead • Stacking 2mm patch cords **Model 72935 — Kit Includes:** • 2 DMM Leads with 4mm Plugs • 2 Test Probes with Spring-Loaded Tips • 6 Micro SMD Grabbers • 6 Adapter Leads 0.8mm Female to 0.4mm Jack • 2 Mini SMD Grabbers with 4mm Connectors • 2 Holding Rods

Dimensions in Inches (mm)

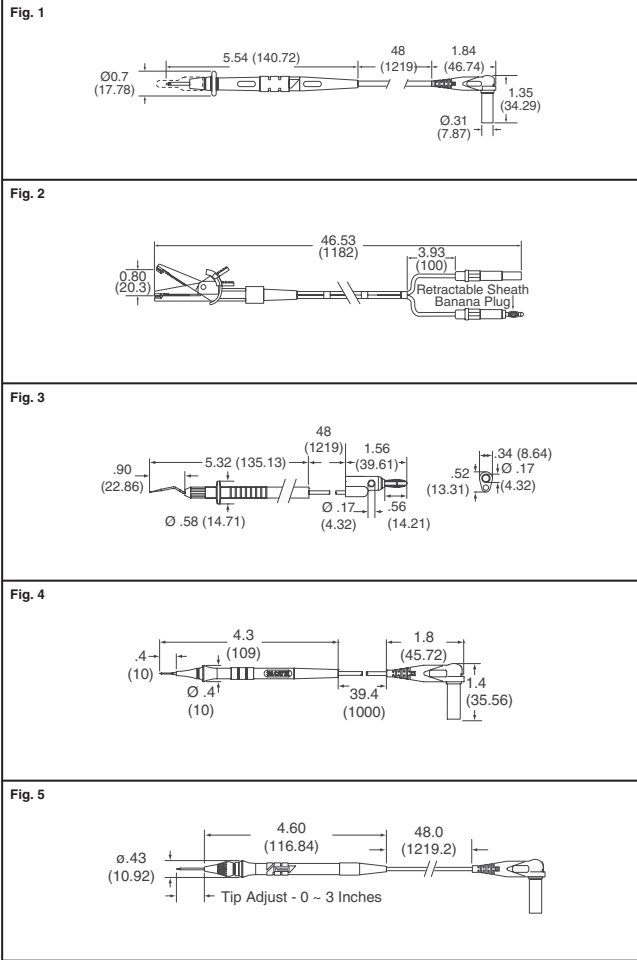

**Oscilloscope Probes**

**Features:** • All Probes meet IEC1010-2-031, 300V, CAT I **Probes Include:** • Retractable Hook Tip • BNC Adapter • IC Adapter • Insulating Tip • Trimmer Tool • 6" (152.40mm) Ground Lead with Alligator Clip

Probe Ratio	System Bandwidth MHz (-3db)	Cable Length Meters	Digi-Key Part No.	Price Each 1	10	Pomona Part No.
1:1 10:1	Up ~ 20 <sup>3</sup> 60	1.2	501-1012-ND	41.12	37.16	6266
1:1 10:1	Up ~ 15 <sup>3</sup> 100	1.2	501-1007-ND	58.88	53.21	4550B
1:1 10:1	Up ~ 20 <sup>3</sup> 200	1.2	501-1008-ND◆	67.40	60.90	5806A
100:1	200	2.0	501-1010-ND◆	108.32	97.88	5827A
10:1	250	1.2	501-1011-ND	62.52	56.49	6069A
10:1	300	1.2	501-1009-ND	114.81	103.74	5812A

◆ RoHS Compliant

**Adapter Kits**



**Universal Adapter Kit (Model 5698) Includes:**

- Type "N" Male and Female • BNC Male and Female • TNC Male and Female
- SMA Male and Female • Coupling Adapter • Double Banana Plug • Double Binding Post



**501-1034-ND ..... \$184.16**

**Maxi Universal Adapter Kit (Model 5748) Includes:**

- Type "N" Male and Female • BNC Male and Female • TNC Male and Female • SMA Male and Female • Coupling Nut
- Double Banana Plug • UHF Male and Female • Mini UHF Male and Female • RCA Phono Male and Female • Type "F" Male and Female • Unidapt Signal Sampler

**501-1035-ND ..... \$297.95**


**7/16 DIN Type "N" Adapter Kit (Model 6254) Includes:**

- Type "N" Male to DIN Male • Type "N" Female to DIN Male • Type "N" Male to DIN Female • Type "N" Female to DIN Female • DIN Female to Female • Right Angle Male to Female

**501-1121-ND ..... \$530.93**

**SMA Adapter Kit (Model 72931) Includes:**

- Right Angle SMA Female to SMA Male • Inline SMA Male to SMA Male
- Inline SMA Female to SMA Female • SMA Male Terminator Plug • SMA Female to BNC Male • SMA Male to BNC Female • SMA Female to BNC Female
- SMA Male to TNC Male • SMA Female to TNC Male • SMA Male to TNC Female • SMA Female to TNC Female • SMA Male to Type "N" Male • SMA Female to Type "N" Male • SMA Male to Type "N" Female • SMA Female to Type "N" Female

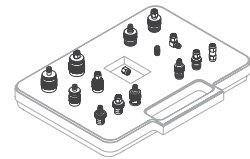

**501-1235-ND ..... \$252.44**


**N Adapter Kit (Model 72932) Includes:**

- Type "N" Male to 50Ω BNC Female • Type "N" Female to 50Ω BNC Male • Inline Type "N" Female to Type "N" Female
- Inline Type "N" Male to Type "N" Male • Right Angle Type "N" Female to Type "N" Male • Type "N" Male to SMA Male
- Type "N" Male to SMA Female • Type "N" Female to SMA Male • Type "N" Female to SMA Female • T Style Type "N" Female to Type "N" Female to Type "N" Female • 50Ω Type "N" Terminator Plug • 75Ω Type "N" Terminator Plug

**501-1236-ND ..... \$309.87**

**Multi-RF Direct Adapter Kit (Model 72934) Includes:**


- BNC Male to Type "N" Female • BNC Female to Type "N" Male • TNC Male to BNC Female • SMA Male to BNC Male • SMA Male to BNC Female • SMA Female to BNC Male • SMA Female to BNC Female
- SMA Male to Type "N" Female • SMA Female to Type "N" Male • SMA Male to Type "N" Female • SMA Male to TNC Male • SMA Male to TNC Female • SMA Female to TNC Male • SMA Female to TNC Female • SMA Male to Type "N" Male • BNC Female to Female • BNC Male to Male • BNC Female to Male to Female TEE • BNC Female to Female to Female TEE • TNC Female to Female Adapter • Type "N" Female to Female • Type "N" Male to Male • SMA Male to Female Right Angle • SMA Male to Male • SMA Female to Female • SMA Termination, 50Ω Male

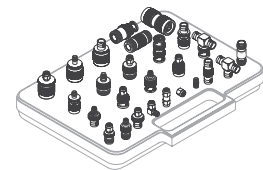

**501-1238-ND ..... \$388.97**

**Broadcast BNC Adapter Kit (Model 72933) Includes:**

- 75Ω BNC Female to Female Adapter • 75Ω BNC Female to Female Adapter • 75Ω BNC Female to Male Adapter • 75Ω BNC Male to Male Adapter • BNC Female to Male to Female Adapter, In-Line, 75Ω • BNC Male to Female to Female, 75Ω • BNC Female to Female to Female, 75Ω • BNC Female to Female to Male, 75Ω • BNC Male to Female to Male, 75Ω • Adapter, BNC Female, Phono Plug • BNC Female to Tini Plug • Adapter, BNC Male, Phono Jack • BNC Female to Microplug • BNC Female to Phono Plug • BNC Male to Phono Jack Adapter • BNC Female to Bantam Plug • BNC Female to .090 Video Plug • BNC to Mini-WECC Adapter • BNC Male Resistor Terminator Plug, 75Ω

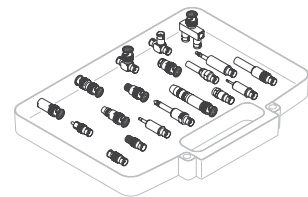

**501-1237-ND ..... \$238.34**

**NEW! Wire Test Leads**



Description	Length (feet)	Color	Digi-Key Part No.	Price Each 1	10	100	Pomona Part No.
Model 6733 with Silicone Insulation	50	Black	501-1281-ND	19.94	18.02	17.18	6733-0
Model 6733 with Silicone Insulation	50	Red	501-1282-ND	19.94	18.02	17.18	6733-2

(Continued)

Fig.	Description	Digi-Key Part No.	Price Each 1	10	Pomona Part No.
1	IEC 1010 Compliant Replacement Test Leads for Sheathed Style DMM's, Includes: One Red and One Black	501-1004-ND	13.86	12.53	5519A
2	Wide Jaw Kelvin Lead Set, Includes: One Red and One Black	501-1102-ND	123.49	111.59	6730
3	SMD Test Probe Set, Includes: One Red and One Black	501-1246-ND	25.45	23.00	6235
4	Precision Electronic Probe with Replaceable Tip Includes: One Red and One Black	501-1248-ND	18.63	16.83	6275
5	Retractable Tip Test Probe Set, Sheathed DMM Plug	501-1249-ND	23.79	21.50	5953A

**Kits**

**Electrical DMM**

—	Electrical DMM Test Lead Kit, Model 5673B	501-1002-ND	56.29	50.87	5673B
—	Deluxe Multi-use DMM Maxi-Test Lead Kit, Model 5677B	501-1000-ND	119.15	107.67	5677B

**SMD Test Kits**

—	SMD Multi-Use Test Kit	501-1223-ND	137.07	123.86	72928
—	SMD High Density Circuit Test Kit	501-1239-ND	186.92	168.90	72935

**More Product Available Online: www.digkey.com**

2270 (T083)

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380