

Fig.	Description	Digi-Key Part No.	Price Each		
			1	10	100
"N" Aluminum Cell Holders					
1	1 Cell	154K-ND	2.10	1.95	1.14
2	2 Cell	155K-ND	3.71	3.46	2.34
3	3 Cell	156K-ND	7.71	7.20	4.65
"AAA" Aluminum Cell Holders					
1	1 Cell	137K-ND	2.37	2.20	1.38
2	2 Cell	138K-ND	3.88	3.62	2.53
3	3 Cell	169K-ND	5.68	5.30	3.42
4	4 Cell	170K-ND	7.77	7.26	4.71
"AAA" Plastic Cell Holders - PC Mount — RoHS Compliant					
5	1 Cell	2466K-ND	1.13	1.00	.81
6	2 Cell	2468K-ND	1.18	1.04	.84
7	3 Cell	2479K-ND	1.38	1.29	1.12
8	4 Cell	2481K-ND	1.52	1.41	1.24
"AAA" Plastic Cell Holders - 6" Wire Leads — RoHS Compliant					
5	1 Cell	2467K-ND	1.13	1.00	.81
6	2 Cell	2469K-ND	1.18	1.04	.84
7	3 Cell	2480K-ND	1.38	1.29	1.12
8	4 Cell	2482K-ND	1.52	1.41	1.24
"AA" Aluminum Cell Holders					
1	1 Cell	139K-ND	1.66	1.55	.90
2	2 Cell	140K-ND	3.10	2.87	1.81
2	2 Cell	146K-ND	3.64	3.33	1.97
3	3 Cell	171K-ND	4.55	4.25	2.74
4	4 Cell	182K-ND	6.46	6.03	4.08
9	2 Cell	189K-ND	2.61	2.42	1.58
10	4 Cell	192K-ND	4.38	4.09	2.61
11	1 Cell	222K-ND	2.08	1.93	1.20
12	2 Cell	2223K-ND	3.30	3.05	2.02
"AA" Plastic Cell Holders - PC Mount — RoHS Compliant					
15	1 Cell	2460K-ND	1.13	1.00	.81
16	2 Cell	2462K-ND	1.18	1.04	.84
17	3 Cell	2464K-ND	1.38	1.29	1.12
18	4 Cell	2477K-ND	1.52	1.41	1.24
"AA" Plastic Cell Holders - 6" Wire Leads — RoHS Compliant					
15	1 Cell	2461K-ND	1.13	1.00	.81
16	2 Cell	2463K-ND	1.18	1.04	.84
17	3 Cell	2465K-ND	1.38	1.29	1.12
18	4 Cell	2478K-ND	1.52	1.41	1.24
"AA" Plastic Cell Holders - with Snap-On Connector — RoHS Compliant					
19	2 Cell	2474K-ND	1.18	1.04	.84
20	3 Cell	2475K-ND	1.38	1.29	1.12
21	4 Cell	2476K-ND	1.52	1.41	1.24
Cell Lithium - Plastic Holders - PC Mount — RoHS Compliant					
22B	1/2 AA	108KK-ND	1.60	1.49	.82
22B	AA	1028K-ND	1.60	1.49	.82
22B	2/3 A	1029K-ND	1.60	1.49	.82
Lithium - Plastic Retaining Cover — RoHS Compliant					
22A	1/2 AA	108CK-ND	.48	.46	.44
22A	AA	1028CK-ND	.71	.63	.51
23	2/3 A	1029CK-ND	.68	.60	.49
"C" Aluminum Cell Holders†					
1	1 Cell	173K-ND	2.03	1.89	1.10
2	2 Cell	174K-ND	3.29	3.04	1.92

Fig.	Description	Digi-Key Part No.	Price Each		
			1	10	100
3	3 Cell	187K-ND	6.87	5.15	4.50
9	2 Cell	185K-ND	2.89	2.67	1.69
10	4 Cell	196K-ND	5.09	4.75	3.32
10	4 Cell	151K-ND	6.26	5.73	3.50
11	1 Cell	2224K-ND	2.13	1.98	1.15
12	2 Cell	2225K-ND	3.53	3.26	2.06
"C" Steel Cell Holders† — RoHS Compliant					
13	1 Cell	2173K-ND	2.80	2.56	1.52
"D" Aluminum Cell Holders†					
1	1 Cell	175K-ND	2.18	2.02	1.24
2	2 Cell	176K-ND	3.84	3.55	2.23
3	3 Cell	190-ND	7.80	7.28	4.72
9	2 Cell	186K-ND	3.29	3.04	1.92
10	4 Cell	200K-ND	6.15	5.74	4.05
11	1 Cell	2226K-ND	2.73	2.53	1.57
12	2 Cell	2227K-ND	3.99	3.73	2.52
"D" Steel Cell Holders† — RoHS Compliant					
14	1 Cell	2175K-ND	3.41	3.12	1.85
12mm Coin Cell Lithium "PC" Holders — RoHS Compliant					
24	1 Cell	500K-ND	1.32	1.16	.74
25	2 Cell	501K-ND	2.08	1.94	1.71
16mm Coin Cell Lithium "PC" Holders — RoHS Compliant					
24	1 Cell	502KE-ND	1.64	1.53	.96
20mm Coin Cell Lithium "PC" Holders — RoHS Compliant					
24	1 Cell	106K-ND	1.64	1.53	.96
24	1 Cell	103K-ND	1.64	1.53	.96
25	2 Cell	1026K-ND	1.80	1.68	1.06
23mm Coin Cell Lithium "PC" Holders — RoHS Compliant					
24	1 Cell	107K-ND	1.64	1.53	.96
24	1 Cell	104K-ND	1.64	1.50	.96
25	2 Cell	1027K-ND	1.80	1.68	1.06
24mm Coin Cell Lithium "PC" Holders — RoHS Compliant					
24	1 Cell	105K-ND	1.64	1.53	.96
24	1 Cell	1025-7K-ND	1.80	1.68	1.06
25	2 Cell	1025K-ND	1.80	1.68	1.06
20mm Coin Cell Holder — RoHS Compliant					
26	1 Cell	1066K-ND	1.64	1.53	.96
Vertical 20mm Coin Cell Holder — RoHS Compliant					
27	1 Cell	1067K-ND	1.83	1.70	1.16
28	1 Cell	1065K-ND	1.83	1.70	1.16
Surface Mount Coin Cell Retainer Contacts — RoHS Compliant					
29	12mm	3000K-ND	.57	.50	.29
29	20mm	3002K-ND	.58	.51	.30
29	23mm	3004K-ND	.59	.52	.31
29	24mm	3006K-ND	.64	.56	.32
Surface Mount Coin Cell Retainer Contacts - Cut Tape — RoHS Compliant					
29	1 Cell, 20mm	3002KCT-ND	.72	.42	.37
29	1 Cell, 24mm	3006KCT-ND	1.09	1.00	.94
Surface Mount Coin Cell Retainer Contacts - Tape & Reel — RoHS Compliant					
29	1 Cell, 20mm	3002KTR-ND	207.01/500		
29	1 Cell, 24mm	3006KTR-ND	276.40/400		
Thru Hole Mount Coin Cell Retainer Contacts — RoHS Compliant					
30	12mm	3001K-ND	.57	.50	.29
30	20mm	3003K-ND	.58	.51	.30

♦ RoHS Compliant † "C" and "D" cell holders are dual clips only ‡ Figs. 36, 38, 48 and 49 sold by the pair (Continued)

More Product Available Online: www.digikey.com

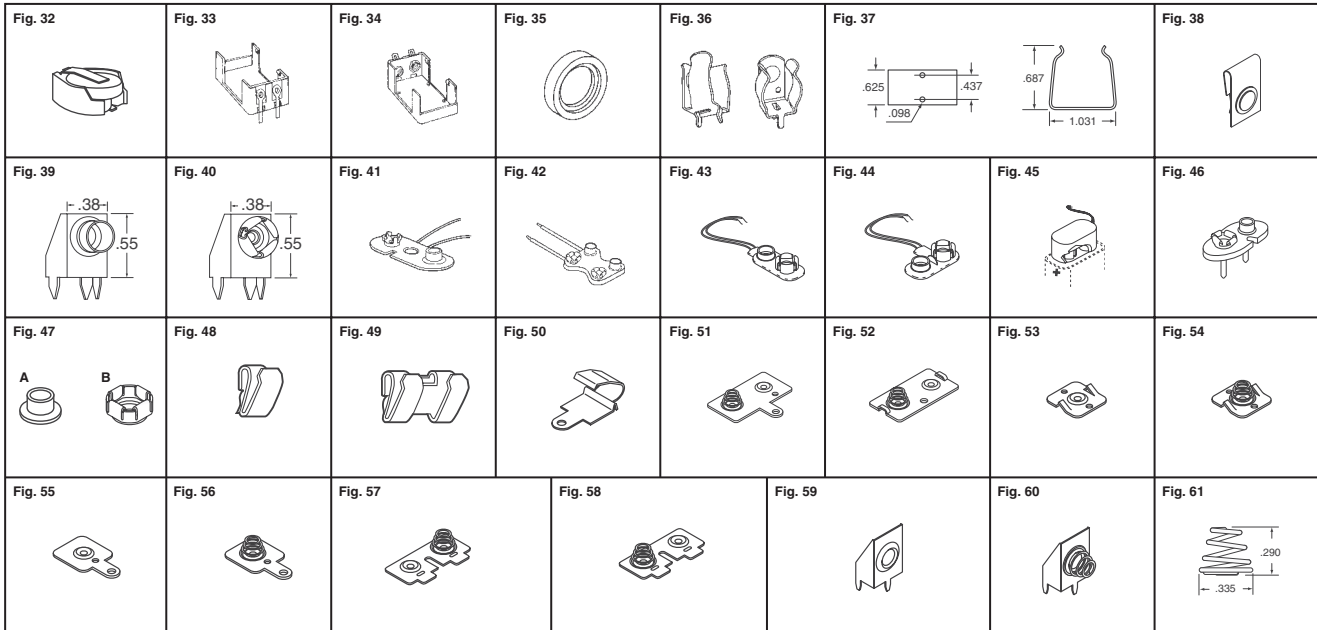


Fig.	Description	Digi-Key Part No.	Price Each		
			1	10	100
30	23mm	3005K-ND	.59	.52	.31
30	23mm	3011K-ND	.62	.55	.32
30	24mm	3007K-ND	.64	.56	.32
30	24mm	3009K-ND	.59	.54	.33
Surface Mount Coin Cell Holder - Bulk — RoHS Compliant					
31	1 Cell, 20mm	1060K-ND	1.64	1.53	.96
32	1 Cell, 20mm	1061K-ND	2.05	1.89	1.29
32	2 Cell, 20mm	1062K-ND	2.05	1.89	1.29
32	1 Cell, 23mm	1071K-ND	2.05	1.89	1.29
Surface Mount Coin Cell Holder - Cut Tape — RoHS Compliant					
29	1 Cell, 12mm	3000KCT-ND	.74	.68	.64
Surface Mount Coin Cell Holder - Tape & Reel — RoHS Compliant					
29	1 Cell, 12mm	3000KTR-ND	319.27/1000		
31	1 Cell, 20mm	1060KTR-ND	493.05/500		
32	1 Cell, 20mm	1061KTR-ND	280.30/200		
32	2 Cell, 20mm	1062KTR-ND	280.30/200		
32	1 Cell, 23mm	1071KTR-ND	280.30/200		
9 Volt Plastic Holders — RoHS Compliant					
33	1 Cell	1294K-ND	1.87	1.74	1.03
34	1 Cell	1295K-ND	1.80	1.68	.99
9 Volt Aluminum Holders — RoHS Compliant					
33	1 Cell	1291K-ND	2.95	2.71	1.60
34	1 Cell	1290K-ND	2.82	2.58	1.53
Insulating Polarizing Washers					
35	Red	59K-ND	—	.12	.08
35	Black	60K-ND	—	.12	.08
“AAA” Snap-In PC Battery Clip — RoHS Compliant					
36	—	82K-ND	.67/2	.32	.17
“AA” Snap-In PC Battery Clip — RoHS Compliant					
36	1 Cell	92K-ND	.67/2	.32	.17
“AAA”, “N” Surface Mount Battery Clip - Cut Tape — RoHS Compliant					
36	1 Cell	55KCT-ND	.66	.38	.34
“AAA”, “N” Surface Mount Battery Clip - Tape & Reel — RoHS Compliant					
36	1 Cell	55KTR-ND	86.81/300		
“9V” Steel Battery Clip — RoHS Compliant					
37	Single	71K-ND	.30	.28	.25
“AAA”, “AAAA”, “N” Snap-IN Battery Contact — RoHS Compliant					
38	—	238K-ND	.36/2	.17	.13
9 Volt “PC” Snap-On Battery (on board battery mount) — RoHS Compliant					
39	Male	593K-ND	.49	.46	.26
40	Female	594K-ND	.55	.49	.31
9 Volt Battery Straps — RoHS Compliant					
41	Single	72K-ND	1.30	1.21	.71
42	Dual	227K-ND	2.86	2.64	1.67
Premium 9 Volt Battery Straps (I-Style) — RoHS Compliant					
43	Single, 4"	2238K-ND	.86	.76	.65
43	Single, 6"	2239K-ND	.88	.78	.66
43	Single, 6.5"	83K-ND	1.89	1.73	1.06
43	Single, 8"	2240K-ND	.90	.79	.68
Premium 9 Volt Battery Straps (T-Style) — RoHS Compliant					
44	Single, 4"	2241K-ND	.91	.80	.69
44	Single, 6"	2242K-ND	.93	.82	.70
44	Single, 8"	2243K-ND	.94	.83	.71

Fig.	Description	Digi-Key Part No.	Price Each		
			1	10	100
Economy 9 Volt Battery Straps (I-Style) — RoHS Compliant					
43	Single, 4"	232K-ND	.47	.44	.31
43	Single, 6"	233K-ND	.48	.45	.32
43	Single, 8"	234K-ND	.49	.46	.33
Economy 9 Volt Battery Straps (T-Style) — RoHS Compliant					
44	Single, 4"	235K-ND	.51	.48	.34
44	Single, 6"	236K-ND	.49	.43	.35
44	Single, 8"	237K-ND	.49	.44	.36
Shielded 9 Volt Battery Straps (I-Style) — RoHS Compliant					
45	Single, 4"	84-4K-ND	.51	.45	.37
45	Single, 6"	84-6K-ND	.53	.47	.38
45	Single, 8"	84-8K-ND	.54	.48	.39
Shielded 9 Volt Battery Straps (T-Style) — RoHS Compliant					
45	Single, 4"	81-4K-ND	.51	.45	.37
45	Single, 6"	81-6K-ND	.53	.47	.38
45	Single, 8"	81-8K-ND	.54	.48	.39
Vertical “9V” PC Snap-On Connector — RoHS Compliant					
46	—	968K-ND	.95	.83	.71
“9V” Battery Snap-Ons — RoHS Compliant					
47A	Stud	261K-ND	.08	.07	.06
47B	Socket	269K-ND	.17	.16	.14
Single “AA” Cell Contacts — RoHS Compliant					
48	—	209K-ND	.52/2	.25	.18
Dual “AA” Cell Contacts — RoHS Compliant					
49	—	210K-ND	.79/2	.37	.26
“A”, “AA”, “9V” Surface Mount Cell Contacts - Cut Tape — RoHS Compliant					
48	—	5231KCT-ND	.67	.62	.58
“A”, “AA”, “9V” Surface Mount Cell Contacts - Tape & Reel — RoHS Compliant					
48	—	5231KTR-ND	76.37/250		
“AAA” Snap-On Contacts — RoHS Compliant					
48	—	204K-ND	.52/2	.25	.18
49	—	202K-ND	.79/2	.37	.26
“A”, “AA”, “9V” Spring Contacts — RoHS Compliant					
50	—	5209K-ND	—	.44	.36
“A”, “AA” Battery Contacts — RoHS Compliant					
51	Dual w/tabs	5211K-ND	—	.36	.26
52	Dual	5212K-ND	—	.44	.31
53	(+) Button	5224K-ND	—	.14	.10
54	(-) Spring	5202K-ND	—	.27	.19
55	(+) Button w/tabs	5223K-ND	—	.14	.10
56	(-) Spring w/tabs	5201K-ND	—	.23	.17
“AAA”, “AAAA”, “N” Battery Contacts — RoHS Compliant					
53	(+) Button	5225K-ND	—	.10	.08
54	(-) Spring	5203K-ND	—	.36	.26
55	(+) Button w/tabs	5226K-ND	—	.14	.10
56	(-) Spring w/tabs	5204K-ND	—	.23	.17
57	Dual Left Side	5214K-ND	—	.32	.23
58	Dual Right Side	5213K-ND	—	.32	.23
“A”, “AA”, “C”, “D” Battery Contacts — RoHS Compliant					
61	Spring	211K-ND	.08	.07	.06
“A” PC Contacts — RoHS Compliant					
59	(+) Button	595K-ND	—	.18	.13
60	(-) Spring	628K-ND	—	.81	.44
“AA”, “AAA”, “N” PC Contacts — RoHS Compliant					
59	(+) Button	637K-ND	—	.17	.12
60	(-) Spring	629K-ND	—	.81	.44

♦ RoHS Compliant † “C” and “D” cell holders are dual clips only ‡ Figs. 36, 38, 48 and 49 sold by the pair