



Rugged Stainless Steel Pressure Transducers
Featuring Microfused Technology (Cont.)

Operating Pressure Range PSIG	Voltage Supply (VDC)	Digi-Key Part No.	Price Each		Measurement Specialties Part No.
			1	10	
500	10 - 32	MSP3501P4A1-ND	109.85	92.04	2000261
1000		MSP3102P4A1-ND	109.85	92.04	2000047
4mA - 20mA Output - 2 Wire Regulated Supply 1/4" NPT, 2 Foot Cable					
100	10 - 32	MSP3101P4-ND	109.38	93.75	2000137
250		MSP3251P4-ND	109.38	93.75	2000207
500		MSP3501P4-ND	109.38	93.75	2000264
1000		MSP3102P4-ND	109.38	93.75	2000050
2500		MSP3252P4-ND	109.38	93.75	2000227
5000		MSP3502P4-ND	109.38	93.75	2000101
10000		MSP3103P4-ND	109.38	93.75	2000160
4mA - 20mA Output - 1/8" NPT, 2 Foot Cable					
100	10 - 32	MSP3101P5A1-ND	109.38	93.75	2000136
250		MSP3251P5A1-ND	109.38	93.75	2000206
500		MSP3501P5A1-ND	109.38	93.75	2000263
1000		MSP3102P5A1-ND	109.38	93.75	2000049
MSP-340 Series - RoHS Compliant					
100mV Output - 1/8" NPT, 2 Foot Cable					
100	5	MSP6892-ND	96.16	80.57	M3421-000006-100PG
300		MSP6893-ND	96.16	80.57	M3421-000006-300PG
500		MSP6894-ND	96.16	80.57	M3421-000006-500PG
1000		MSP6895-ND	96.16	80.57	M3421-000006-01KPG
0.5V - 4.5V Output - 1/8" NPT, 2 Foot Cable					
100	5	MSP6896-ND	112.39	94.17	M3431-000006-100PG
300		MSP6897-ND	112.39	94.17	M3431-000006-300PG
500		MSP6898-ND	112.39	94.17	M3431-000006-500PG
1000		MSP6899-ND	112.39	94.17	M3431-000006-01KPG
MSP-400 Series - RoHS Compliant					
1V - 5V Output - Fixed 3 Wire Supply Current 10mA maximum 1/4" NPT, 2 Foot Cable					
5000	10 - 32	MSP4502P3-ND	94.50	81.00	2000455
4mA - 20mA Output - 2 Wire Regulated Supply 1/4" NPT, 2 Foot Cable					
1000	10 - 32	MSP4102P4-ND	108.50	93.00	2000417
5000		MSP4502P4-ND	108.50	93.00	2000457
MSP-600 Series - RoHS Compliant					
0.5VDC - 4.5VDC Output - 7/16" SAE, Packard Connector					
25	5	MSP6025P3-4-ND	96.25	82.50	2000964
50		MSP6050P3-4-ND	96.25	82.50	2000965
75		MSP6075P3-4-ND	96.25	82.50	2000966
100		MSP6101P3-4-ND	96.25	82.50	2000967
500		MSP6501P3-4-ND	96.25	82.50	2000969
1000		MSP6102P3-4-ND	96.25	82.50	2000970
1VDC - 5VDC Output - 1/4" NPT, 2 Foot Cable					
75	10 - 30	MSP6075P4-1-ND	101.50	87.00	2000884
4mA - 20mA Output - 1/4" NPT, 2 Foot Cable					
50	10 - 30	MSP6050P5-1-ND	119.00	102.00	2000879
75		MSP6075P5-1-ND	119.00	102.00	2000885
2500		MSP6252P5-1-ND	119.00	102.00	2000915
MSP-610 Series - RoHS Compliant					
0.5V - 4.5V Output - 1/8" NPT, 2 Foot Cable					
300	5	MSP6906-ND	114.19	97.88	M6131-C00006-300PG
500		MSP6907-ND	114.19	97.88	M6131-C00006-500PG
0.5V - 4.5V Output - 1/4" NPT, 2 Foot Cable					
100	5	MSP6903-ND	114.19	97.88	M6131-C00005-100PG
500		MSP6905-ND	114.19	97.88	M6131-C00005-500PG
1V - 5V Output - 1/4" NPT, 2 Foot Cable					
100	8 - 30	MSP6908-ND	119.00	102.00	M6141-C00005-100PG
300		MSP6909-ND	119.00	102.00	M6141-C00005-300PG
500		MSP6910-ND	119.00	102.00	M6141-C00005-500PG
4mA - 20mA Output - 1/4" NPT, 2 Foot Cable					
100	10 - 30	MSP6911-ND	135.63	116.25	M6181-C00005-100PG
300		MSP6912-ND	135.63	116.25	M6181-C00005-300PG
500		MSP6913-ND	135.63	116.25	M6181-C00005-500PG
UltraStable 5100 Series - RoHS Compliant					
0.5V - 4.5V Ratiometric Output - 1/4" NPT, Absolute Pressure, 2 Foot Cable					
15PSIA	4.75 - 5.25	223-1000-ND	175.00	150.00	U5131-000005-015PA
30PSIA		223-1002-ND	175.00	150.00	U5131-000005-030PA
100PSIA		223-1004-ND	175.00	150.00	U5131-000005-100PA

Operating Pressure Range PSIG	Voltage Supply (VDC)	Digi-Key Part No.	Price Each		Measurement Specialties Part No.
			1	10	
4mA - 20mA Output - 1/4" NPT, Absolute Pressure, 2 Foot Cable					
15PSIA	9 - 30	223-1007-ND	211.41	179.38	U5151-000005-015PA
30PSIA		223-1009-ND	211.41	179.38	U5151-000005-030PA
100PSIA		223-1011-ND	211.41	179.38	U5151-000005-100PA
0.5V - 4.5V Ratiometric Output - 1/4" NPT, 2 Foot Cable					
15	4.75 - 5.25	223-1001-ND	175.00	150.00	U5131-000005-015PG
30		223-1003-ND	175.00	150.00	U5131-000005-030PG
100		223-1005-ND	175.00	150.00	U5131-000005-100PG
500		223-1006-ND	175.00	150.00	U5131-000005-500PG
4mA - 20mA Output - 1/4" NPT, 2 Foot Cable					
15	9 - 30	223-1008-ND	211.41	179.38	U5151-000005-015PG
30		223-1010-ND	211.41	179.38	U5151-000005-030PG
100		223-1012-ND	211.41	179.38	U5151-000005-100PG
500		223-1013-ND	211.41	179.38	U5151-000005-500PG
M5100 Series - RoHS Compliant					
0.5V - 4.5V Ratiometric Output - 1/4" NPT, 2 Foot Cable					
50	4.75 - 5.25	223-1038-ND	114.84	98.44	M5131-000005-050PG
75		223-1041-ND	114.84	98.44	M5131-000005-075PG
100		223-1020-ND	114.84	98.44	M5131-000005-100PG
250		223-1026-ND	114.84	98.44	M5131-000005-250PG
500		223-1032-ND	114.84	98.44	M5131-000005-500PG
1000	4.75 - 5.25	223-1014-ND	114.84	98.44	M5131-000005-01KPG
2500		223-1029-ND	114.84	98.44	M5131-000005-2K5PG
5000		223-1017-ND	114.84	98.44	M5131-000005-05KPG
10000		223-1023-ND	114.84	98.44	M5131-000005-10KPG
1V - 5V Output - 1/4" NPT, 2 Foot Cable					
50	8 - 30	223-1039-ND	120.31	103.13	M5141-000005-050PG
75		223-1042-ND	120.31	103.13	M5141-000005-075PG
100		223-1021-ND	120.31	103.13	M5141-000005-100PG
250		223-1027-ND	120.31	103.13	M5141-000005-250PG
500		223-1033-ND	120.31	103.13	M5141-000005-500PG
1000	8 - 30	223-1015-ND	120.31	103.13	M5141-000005-01KPG
2500		223-1030-ND	120.31	103.13	M5141-000005-2K5PG
5000		223-1018-ND	120.31	103.13	M5141-000005-05KPG
10000		223-1024-ND	120.31	103.13	M5141-000005-10KPG
4mA - 20mA Output - 1/4" NPT, 2 Foot Cable					
50	9 - 30	223-1040-ND	125.78	107.82	M5151-000005-050PG
75		223-1043-ND	125.78	107.82	M5151-000005-075PG
100		223-1022-ND	125.78	107.82	M5151-000005-100PG
250		223-1028-ND	125.78	107.82	M5151-000005-250PG
500		223-1034-ND	125.78	107.82	M5151-000005-500PG
1000	9 - 30	223-1016-ND	125.78	107.82	M5151-000005-01KPG
2500		223-1031-ND	125.78	107.82	M5151-000005-2K5PG
5000		223-1019-ND	125.78	107.82	M5151-000005-05KPG
10000		223-1025-ND	125.78	107.82	M5151-000005-10KPG
0.5V - 4.5V Ratiometric Output - 7/16" UNF Male, O-Ring, Packard Connector					
50	4.75 - 5.25	223-1045-ND	114.84	98.44	M5134-000004-050PG
75		223-1046-ND	114.84	98.44	M5134-000004-075PG
100		223-1047-ND	114.84	98.44	M5134-000004-100PG
250		223-1048-ND	114.84	98.44	M5134-000004-250PG
500		223-1049-ND	114.84	98.44	M5134-000004-500PG
1000	4.75 - 5.25	223-1050-ND	114.84	98.44	M5134-000004-01KPG
2500		223-1051-ND	114.84	98.44	M5134-000004-2K5PG
5000		223-1052-ND	114.84	98.44	M5134-000004-7K5PG
7500		223-1074-ND	114.84	98.44	M5134-000004-7K5PG
10000	223-1053-ND	114.84	98.44	M5134-000004-10KPG	
1V - 5V Output - 7/16" UNF Male, O-Ring, Packard Connector					
50	8 - 30	223-1055-ND	120.31	103.13	M5144-000004-050PG
75		223-1056-ND	120.31	103.13	M5144-000004-075PG
100		223-1057-ND	120.31	103.13	M5144-000004-100PG
250		223-1058-ND	120.31	103.13	M5144-000004-250PG
500		223-1059-ND	120.31	103.13	M5144-000004-500PG
1000	8 - 30	223-1060-ND	120.31	103.13	M5144-000004-01KPG
2500		223-1061-ND	120.31	103.13	M5144-000004-2K5PG
5000		223-1062-ND	120.31	103.13	M5144-000004-05KPG
7500		223-1075-ND	120.31	103.13	M5144-000004-7K5PG
10000	223-1063-ND	120.31	103.13	M5144-000004-10KPG	
4mA - 20mA Output - 7/16" UNF Male, O-Ring, Packard Connector					
50	9 - 30	223-1065-ND	125.78	107.82	M5154-000004-050PG
75		223-1066-ND	125.78	107.82	M5154-000004-075PG
100		223-1067-ND	125.78	107.82	M5154-000004-100PG
250		223-1068-ND	125.78	107.82	M5154-000004-250PG
500		223-1069-ND	125.78	107.82	M5154-000004-500PG
1000	9 - 30	223-1070-ND	125.78	107.82	M5154-000004-01KPG
2500		223-1071-ND	125.78	107.82	M5154-000004-2K5PG
5000		223-1072-ND	125.78	107.82	M5154-000004-05KPG
7500		223-1076-ND	125.78	107.82	M5154-000004-7K5PG
10000	223-1073-ND	125.78	107.82	M5154-000004-10KPG	

◆ RoHS Compliant




NEW! Cable Harnesses

Pre-made Cable Harnesses from SSI Technology with the industry standard Packard™ Automotive Connector.



Description	Length Inch	Digi-Key Part No.	Price Each		SSI Technologies Part No.
			1	25	
Cable Harness Packard	12	734-1163-ND	11.66	10.43	P2432.3
Cable Harness Packard	36	734-1164-ND	20.90	20.05	P2435.3
Cable Harness Packard	72	734-1165-ND	26.43	25.44	14306.3

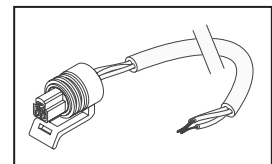

N

More Product Available Online: www.digkey.com

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

(T083) 2443