

ASSMANN Computer Cable Assemblies (Cont.)

A

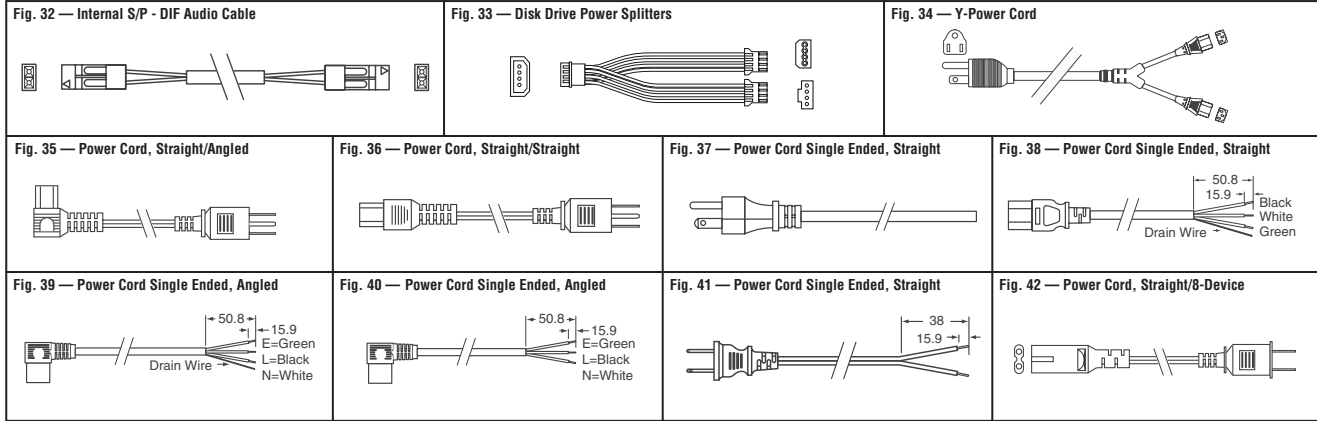


Fig.	Length Feet (Meters)	Lines	Description	Digi-Key Part No.	1	Price Each 10	25	Assmann Part No.			
Wiring Box											
26	—	—	1 x Male, 1 x Female, 25-Pin, Metallized	AE1041-ND	14.62	12.85	11.52	AB947			
D-Sub/RS 232 Adapters — RoHS Compliant											
27	—	—	D-Sub 9-Pin Male to D-Sub 25-Pin Male	AE10291-ND	5.94	5.22	4.68	AB467-R			
			D-Sub 9-Pin Male to D-Sub 25-Pin Female	AE10292-ND	5.18	4.56	4.09	AB468-R			
			D-Sub 9-Pin Female to D-Sub 25-Pin Female	AE10293-ND	5.18	4.56	4.09	AB469-R			
			D-Sub 9-Pin Female to D-Sub 25-Pin Male	AE10294-ND	4.82	4.24	3.80	AB470-R			
Gender Changers — RoHS Compliant											
28	—	—	D-Sub 9 Position Male to Male	AE10295-ND	4.09	3.60	3.23	AB410-R			
			D-Sub 9 Position Female to Female	AE10296-ND	4.09	3.60	3.23	AB411-R			
			D-Sub 15 Position Male to Male	AE10297-ND	4.09	3.60	3.23	AB412-R			
			D-Sub 15 Position Female to Female	AE10298-ND	4.26	3.75	3.36	AB413-R			
			D-Sub 25 Position Male to Male	AE10299-ND	4.26	3.75	3.36	AB414-R			
			D-Sub 25 Position Female to Female	AE10300-ND	4.46	3.92	3.51	AB415-R			
			D-Sub HD 15 Position Male to Male	AE10301-ND	5.18	4.56	4.09	AB418-R			
			D-Sub HD 15 Position Female to Female	AE10302-ND	5.18	4.56	4.09	AB420-R			
D-Sub/RJ Adapters (Beige) — RoHS Compliant											
29	—	—	9 Position Male RJ12 Jack	AE10307-ND	5.38	4.73	4.24	AT-23064-R			
			9 Position Female RJ12 Jack	AE10308-ND	5.38	4.73	4.24	AT-23065-R			
			9 Position Male RJ45 Jack	AE10309-ND	5.38	4.73	4.24	AT-23066-R			
			9 Position Female RJ45 Jack	AE10310-ND	5.38	4.73	4.24	AT-23067-R			
			25 Position Male RJ12 Jack	AE10303-ND	5.74	5.05	4.53	AT-23052-R			
			25 Position Female RJ12 Jack	AE10304-ND	5.74	5.05	4.53	AT-23053-R			
			25 Position Male RJ45 Jack	AE10305-ND	5.74	5.05	4.53	AT-23054-R			
			25 Position Female RJ45 Jack	AE10306-ND	5.74	5.05	4.53	AT-23055-R			
			Power Splitter Cables								
			30	1.64 (0.5)	—	Audio CD-ROM 4 Position 3 Wire	AE1396-ND	1.65	1.45	1.30	AK2525-R
31	1.64 (0.5)	—	Audio CD-ROM 4 Position 3 Wire	AE1397-ND	1.85	1.63	1.46	AK2524-R			
32	1.64 (0.5)	—	Internal Cable 2-Pin Housing/Housing	AE9884-ND	2.31	2.03	1.82	AK2526DVD-R			
33	.66 (.2)	4	Power Cable for 2 - 5 1/4" Drives	AE9885-ND	2.28	2.01	1.80	AK319-2-R			
			Power Cable for 2 - 3 1/2" Drives	AE1398-ND	2.61	2.30	2.06	AK520-2-R			
			Power Cable for 3 1/2" and 5 1/4" Drives	AE1029-ND	1.98	1.74	1.56	AK521-2			
			Power Cable for 3 1/2" and 5 1/4" Drives	AE1399-ND	2.61	2.30	2.06	AK521-2-R			
Y-Power Cord — RoHS Compliant											
34	6.56 (2)	—	1 x Power Plug to 2 x Straight Connector, 10A, 125V	AE9886-ND	19.07	16.77	15.03	AK500/Y-U-R			
Power Cords											
35	6.56 (2)	—	Power Plug, Straight to IEC Connector, Angled, 10A, 125V	AE9887-ND	8.84	7.78	6.97	AK500/U-1-R			
36	6.56 (2)	—	Power Plug, Straight to IEC Connector, Straight, 10A, 125V	AE9888-ND	8.91	7.83	7.02	AK500/U-2-R			
37	6.56 (2)	—	Cord SVT 18AWG 3 Cond Shielded	AE9889-ND	8.51	7.49	6.71	AK500-OE-5-2-R			
	9.84 (3)		Cord SVT 18AWG 3 Cond Shielded	AE9890-ND	11.81	10.39	9.31	AK500-OE-5-3-R			
	6.56 (2)		Cord SJT 18AWG 3 Cond Shielded	AE9891-ND	8.78	7.72	6.92	AK500-OE-6-2-R			
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE9892-ND	12.34	10.85	9.73	AK500-OE-6-3-R			
	6.56 (2)		Cord SVT 18AWG 3 Cond Shielded	AE9893-ND	8.35	7.34	6.58	AK500-OE-7-2-R			
38	6.56 (2)	—	Cord SJT 18AWG 3 Cond Shielded	AE9895-ND	8.81	7.75	6.95	AK500-OE-9-2-R			
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE1339-ND	6.27	5.51	4.94	AK500-OE-9-3			
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE9896-ND	13.99	12.30	11.03	AK500-OE-9-3-R			
39	6.56 (2)	—	Cord SJT 18AWG 3 Cond Shielded	AE1331-ND	4.55	4.01	3.59	AK500-RA-5-2			
	6.56 (2)		Cord SJT 18AWG 3 Cond Shielded	AE9897-ND	8.75	7.69	6.89	AK500-RA-5-2-R			
40	6.56 (2)	—	Cord SVT 18AWG 3 Cond	AE1333-ND	5.64	4.96	4.45	AK500-RA-6-2			
	6.56 (2)		Cord SVT 18AWG 3 Cond	AE9899-ND	6.86	6.04	5.41	AK500-RA-6-2-R			
	6.56 (2)		Cord SJT 18AWG 3 Cond	AE9900-ND	7.82	6.88	6.17	AK500-RA-7-2-R			
	9.84 (3)		Cord SJT 18AWG 3 Cond	AE1335-ND	6.11	5.38	4.82	AK500-RA-7-3			
41	6 (1.83)	—	Cord SPT-1 18AWG 2 Cond	AE9902-ND	5.54	4.88	4.37	AK500-OE-12-6F-R			
	8.99 (2.74)		Cord SPT-1 18AWG 2 Cond	AE9903-ND	7.85	6.91	6.19	AK500-OE-12-9F-R			
	6 (1.83)		Cord SPT-2 18AWG 2 Cond	AE9904-ND	5.74	5.05	4.53	AK500-OE-13-6F-R			
	8 (2.44)		Cord SPT-2 18AWG 2 Cond	AE1348-ND	3.23	2.84	2.55	AK500-OE-13-8F			
42	6.56 (2)	—	Power Plug, Straight to Figure 8 Device Connector, Straight	AE1123-ND	2.92	2.57	2.30	AK500/U-3			
	6.56 (2)		Power Plug, Straight to Figure 8 Device Connector, Straight	AE9906-ND	7.00	6.15	5.52	AK500/U-3-R			
Power Cord Extension											
43	6.56 (2)	—	IEC Plug, Straight to IEC Socket, Straight, 10A, 125V	AE9854-ND	11.02	9.69	8.69	AK500/U-4-R			
	3.28 (1)		Cord SJT 18AWG 3 Cond Shielded	AE1336-ND	3.56	3.13	2.81	AK500-JC-5-1			
	3.28 (1)		Cord SJT 18AWG 3 Cond Shielded	AE9908-ND	10.56	9.28	8.32	AK500-JC-5-1-R			

◆ RoHS Compliant

(Continued)

More Product Available Online: www.digikey.com

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380