


ASSMANN Computer Cable Assemblies (Cont.)

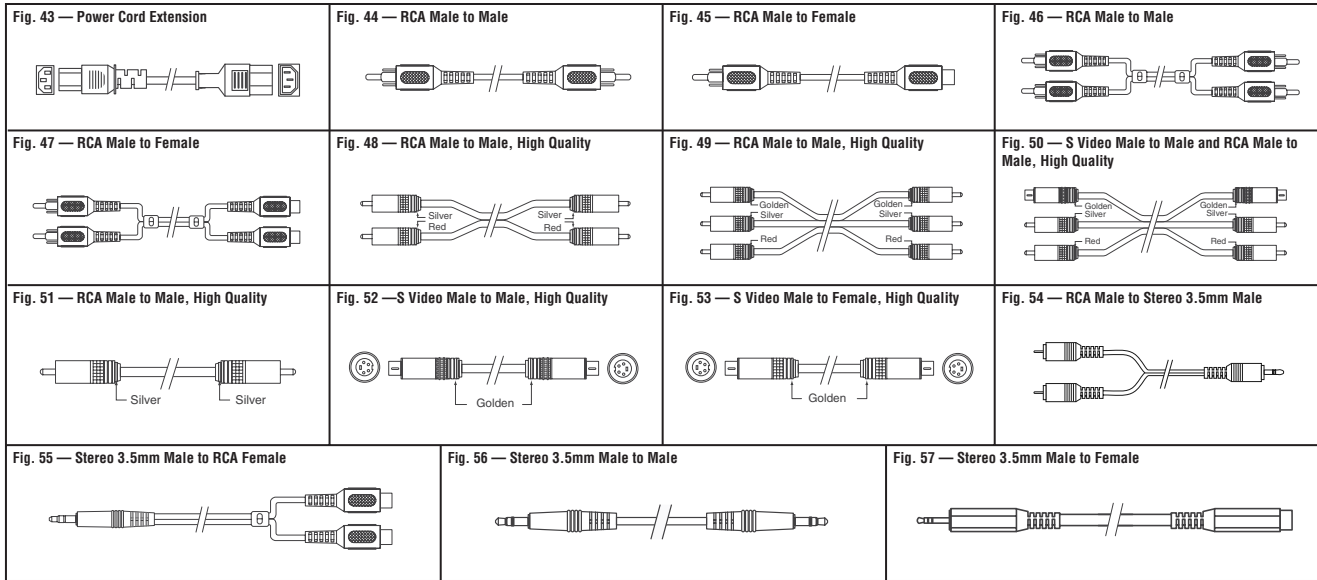

A

Fig.	Length Feet (Meters)	Lines	Description	Digi-Key Part No.	1	Price Each 10	25	Assmann Part No.
43	3.28 (1)	—	Cord SJT 18AWG 3 Cond	AE1337-ND	3.30	2.90	2.60	AK500-JC-6-1
	3.28 (1)		Cord SJT 18AWG 3 Cond	AE9909-ND◆	9.57	8.41	7.54	AK500-JC-6-1-R
	1.64 (.5)		Cord SVT 18AWG 3 Cond Shielded	AE9910-ND◆	4.88	4.30	3.85	AK500-OE-11-5-R
	3.28 (1)		Cord SVT 18AWG 3 Cond Shielded	AE9911-ND◆	8.28	7.28	6.53	AK500-OE-11-1-R
	4.92 (1.5)	—	Cord SVT 18AWG 3 Cond Shielded	AE1342-ND	4.03	3.54	3.18	AK500-OE-11-1.5
	4.92 (1.5)		Cord SVT 18AWG 3 Cond Shielded	AE9912-ND◆	8.38	7.37	6.61	AK500-OE-11-1.5-R
	6.56 (2)		Cord SVT 18AWG 3 Cond	AE9913-ND◆	9.47	8.33	7.47	AK500-OE-11-2-R
	8.20 (2.5)		Cord SVT 18AWG 3 Cond	AE9914-ND◆	9.60	8.44	7.57	AK500-OE-11-2.5-R
Multi-Media Cables								
44	4.92 (1.5)	—	RCA Male to Male	AE1400-ND◆	3.10	2.73	2.45	AK-AV200-R
	6.56 (2)		RCA Male to Male	AE1401-ND◆	3.56	3.14	2.81	AK302-2-R
	8.20 (2.5)		RCA Male to Male	AE1402-ND◆	3.40	2.99	2.68	AK-AV201-R
45	8.20 (2.5)	—	RCA Male to Female	AE1403-ND◆	3.56	3.14	2.81	AK-AV202-R
46	4.92 (1.5)	—	2RCA Male to Male	AE1404-ND◆	4.49	3.95	3.54	AKCHMM-015-R
	6.56 (2)		2RCA Male to Male	AE1405-ND◆	5.41	4.76	4.27	AKCHMM-2-R
	8.20 (2.5)		2RCA Male to Male	AE1406-ND◆	6.30	5.54	4.97	AKCHMM-025-R
	16.40 (5)		2RCA Male to Male	AE1407-ND◆	9.64	8.47	7.60	AKCHMM-050-R
47	4.92 (1.5)	—	2RCA Male to Female (Red and White)	AE1408-ND◆	4.46	3.92	3.51	AKCHMF-015-R
	6.56 (2)		2RCA Male to Female (Red and White)	AE1409-ND◆	4.55	4.01	3.59	AKCHMF-2-R
	6.56 (2)		2RCA Male to Female (Red and Black)	AE1410-ND◆	3.86	3.40	3.05	AK3030-2-R
	8.20 (2.5)		2RCA Male to Female (Red and White)	AE1411-ND◆	5.61	4.93	4.42	AKCHMF-025-R
48	4.92 (1.5)	—	Audio RCA High Quality, Male to Male	AE1412-ND◆	7.69	6.76	6.06	AKCHMF-050-R
	16.40 (5)		Audio RCA High Quality, Male to Male	AE1413-ND◆	20.59	18.10	16.23	AK-AV500-R
49	4.92 (1.5)	—	Audio RCA High Quality, Male to Male	AE1414-ND◆	32.97	28.98	25.98	AK-AV501-R
	4.92 (1.5)		Audio/Video RCA High Quality, Male to Male	AE1353-ND	26.66	23.44	21.01	AK-AV504
	16.40 (5)		Audio/Video RCA High Quality, Male to Male	AE1415-ND◆	32.54	28.60	25.64	AK-AV504-R
50	4.92 (1.5)	—	Audio/Video RCA High Quality, Male to Male	AE1416-ND◆	51.08	44.90	40.25	AK-AV505-R
	16.40 (5)		Audio/Video RCA High Quality, Male to Male	AE1417-ND◆	32.14	28.25	25.33	AK-AV510-R
51	4.92 (1.5)	—	Audio RCA High Quality, Male to Male	AE1418-ND◆	59.90	52.64	47.19	AK-AV511-R
	16.40 (5)		Audio RCA High Quality, Male to Male	AE1419-ND◆	11.45	10.07	9.03	AK-AV502-R
52	4.92 (1.5)	—	Audio RCA High Quality, Male to Male	AE1420-ND◆	15.64	13.75	12.33	AK-AV503-R
	16.40 (5)		Video S-VHS High Quality, Male to Male	AE10074-ND◆	11.95	10.50	9.42	AK-AV506-R
53	4.92 (1.5)	—	Video S-VHS High Quality, Male to Male	AE1422-ND◆	22.74	19.99	17.92	AK-AV507-R
	16.40 (5)		Video S-VHS High Quality, Male to Female	AE9915-ND◆	14.32	12.59	11.29	AK-AV508-R
54	4.92 (1.5)	—	Video S-VHS High Quality, Male to Female	AE1423-ND◆	23.56	20.71	18.57	AK-AV509-R
	16.40 (5)		Video S-VHS High Quality, Male to Female	AE9916-ND◆	4.39	3.86	3.46	AK243-015-R
55	4.92 (1.5)	—	3.5mm Stereo Male to 2RCA Male	AE9917-ND◆	5.15	4.53	4.06	AK243-2-R
	6.56 (2)		3.5mm Stereo Cable, 2 Phono Male	AE1424-ND◆	5.81	5.11	4.58	AK243-025-R
	8.20 (2.5)		3.5mm Stereo Male to 2RCA Male	AE1425-ND◆	8.12	7.14	6.40	AK243-050-R
	16.40 (5)		3.5mm Stereo Male to 2RCA Male	AE1426-ND◆	8.15	7.17	6.43	AK243-10-R
	32.8 (10)		3.5mm Stereo Male to 2RCA Male	AE1427-ND◆	4.49	3.95	3.54	AK244-R
56	6.56 (2)	—	3.5mm Stereo Male to RCA Female	AE9918-ND◆	3.76	3.31	2.97	AK203/MM-R
57	8.20 (2.5)	—	3.5mm Stereo Male to Male	AE9919-ND◆	5.08	4.47	4.01	AK203-2.5-R

◆ RoHS Compliant

More Product Available Online: www.digikey.com

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

(T083) 63