

# ASSMANN SCSI, Serial ATA, USB, CAT5e and CAT6 Computer Cable Assemblies


HP = Half Pitch

A

Fig.	Length Meters	Lines	Description	Digi-Key Part No.	Price Each 1 10 25	Assmann Part No.
<b>FAST SCSI 2 to SCSI 2 Cable, Shielded, UL 2919 — RoHS Compliant</b>						
1	0.90 2.0	50	HP D-sub 50, HP D-sub, Male Clip to HP D-sub 50, HP D-sub, Male, Clip	AE1428-ND AE1429-ND	27.42 24.10 21.61 29.67 26.98 24.28	AK579/F-1-R AK579/F-2-R
<b>SCSI-2 Series, Round Cable</b>						
2	0.91	50	HP D-sub 50 Male to Centronic 50 Male, A Cable	AE1069-ND	16.60 14.59 13.08	AK-Y1202
<b>SCSI-3 Series, Round Cable</b>						
3	0.91	68	HP D-sub 68 Male X 2, A Cable	AE1430-ND	28.30 25.73 23.16	AK-Y1301-R
4	0.91	50	HP D-sub 68 Male to Centronic 50 Male, A Cable	AE1071-ND	18.94 16.65 14.93	AK-Y1302
<b>SCSI-3 Series, Flat Cable</b>						
5	0.45	68	635mm HP D-sub 68 Male X 2, P Cable	AE1489-ND	17.46 15.35 13.76	AK-Y2301-R
6	1.6	68	635mm HP D-sub 68 Female X 2 to 635mm HP D-sub 68 Male X 8	AE1079-ND	42.17 38.92 36.20	AK-Y2310
<b>Hard Drive Cable for 2 x IDE / AT Bus Hard Drives — RoHS Compliant</b>						
7	0.5	40	(3) 40 Pin Socket Connectors	AE10263-ND	4.19 3.69 3.31	AK5430-5-R
<b>Ultra ATA Flat Cable — RoHS Compliant</b>						
8	0.46	40	Ultra ATA HDD 100Mbps	AE10184-ND	5.54 4.88 4.37	AK-ATA-100-R
<b>Serial ATA Cables — RoHS Compliant</b>						
9	0.3 0.5 0.75 1.0	7	Serial ATA Cable	AE10077-ND AE10079-ND AE10081-ND AE10083-ND	3.17 2.79 2.50 3.43 3.02 2.71 3.66 3.22 2.89 4.16 3.66 3.28	AK-SATA-030-R AK-SATA-050-R AK-SATA-075-R AK-SATA-100-R
10	0.3 0.5 0.75	7	Serial ATA Cable Right Angle	AE10078-ND AE10080-ND AE10082-ND	3.53 3.11 2.79 3.04 2.67 2.40 3.66 3.22 2.89	AK-SATA-030DL-R AK-SATA-050DL-R AK-SATA-075DL-R
11	0.5 0.75 1.0	7	Serial ATA Cable 4-Pos. Power Connector	AE10084-ND AE10085-ND AE10086-ND	5.87 5.17 4.63 6.24 5.49 4.92 6.57 5.78 5.18	AK-SATA-SP-050-R AK-SATA-SP-075-R AK-SATA-SP-100-R
12	0.15	4	Power Supply Cable 15-Pos. - 4-Pos.	AE10087-ND	2.97 2.61 2.34	AK-SATA-PC-015-R
13A	0.5	7	Conn Slotbracket 1-SATA Port	AE10088-ND	6.57 5.78 5.18	AK-SATA-SB1-R
13B	0.5	7	Conn Slotbracket 2-SATA Ports	AE10089-ND	11.85 10.42 9.34	AK-SATA-SB2-R
<b>HDMI / DVI Cables and Adapters — RoHS Compliant</b>						
14	2.0 3.0 5.0	—	HDMI-A Male to HDMI-A Male Cable HDMI-A Male to HDMI-A Male Cable HDMI-A Male to HDMI-A Male Cable	AE10256-ND AE10257-ND AE10246-ND	22.41 19.70 17.66 25.55 23.23 20.91 30.76 28.38 26.40	AK627-2-R AK627-3-R AK627-5-R
15	2.0 3.0 5.0	—	HDMI-A Male to DVI-D Cable HDMI-A Male to DVI-D Cable HDMI-A Male to DVI-D Cable	AE10258-ND AE10259-ND AE10260-ND	21.65 19.03 17.06 23.54 21.40 19.26 29.78 27.48 25.56	AK639-2-R AK639-3-R AK639-5-R
—	—	—	HDMI-A Male to DVI-D 24+1, Female Adapter HDMI-A Male to DVI-D 24+1, Male Adapter HDMI-A Female to DVI-D 24+1, Female Adapter HDMI-A Female to DVI-D 24+1, Male Adapter HDMI-A Female to HDMI-A, Female Adapter HDMI-A Male to HDMI-A, Female Adapter HDMI-A Male to HDMI-A, Male Adapter	AE10249-ND AE10250-ND AE10254-ND AE10255-ND AE10251-ND AE10252-ND AE10253-ND	16.47 14.48 12.98 16.47 14.48 12.98 18.12 15.93 14.28 16.47 14.48 12.98 16.47 14.48 12.98 18.12 15.93 14.28 16.47 14.48 12.98	AB556-R AB557-R AB566-R AB567-R AB560-R AB561-R AB562-R
<b>IEEE 1394 Cable Double Shielded</b>						
16	1.8 3.0 5.0	6	6-Pin Male to 6-Pin Male	AE1432-ND AE1433-ND AE1434-ND	15.08 13.26 11.89 18.68 16.42 14.72 23.04 21.27 19.78	AK-1394-18-R AK-1394-30-R AK-1394-50-R
17	1.8 3.0 5.0	4	6-Pin Male to 4-Pin Male	AE1435-ND AE1436-ND AE1437-ND	13.96 12.27 11.00 13.34 12.13 10.92 21.04 19.42 18.06	AK-1394-184-R AK-1394-304-R AK-1394-504-R
18	1.8 3.0 5.0	4	4-Pin Male to 4-Pin Male	AE1127-ND AE1438-ND AE1133-ND	23.38 21.25 19.13 11.94 10.85 9.77 29.03 26.79 24.92	AK-1394-1844 AK-1394-1844-R AK-1394-5044
<b>IEEE 1394 and USB Connectors</b>						
19	—	—	IEEE 1394 Recept Horizontal SMT	AE7348-ND AE9920-ND	2.00 1.76 1.58 2.84 2.50 2.24	A-IE-S-SMT A-IE-S-SMT-R
20	—	—	IEEE 1394 Recept Horizontal PCB	AE9921-ND	2.71 2.38 2.14	A-IE-S-DIP-R
21	—	—	IEEE 1394 Recept Vertical PCB	AE9922-ND	2.71 2.38 2.14	A-IE-E-DIP-R
22	—	4	USB 4P Recept Thru-hole, Type A USB 4P Recept SMT, Type A	AE9923-ND AE9924-ND	83 73 65 1.09 96 86	AU-Y1005-R AU-Y1006-R
23	—	4	USB 4P Recept Thru-hole, Type B	AE9925-ND	96 85 76	AU-Y1007-R
24	—	4	USB 4P Recept Dual Port, Type A	AE9926-ND	1.65 1.45 1.30	AU-Y1008-R
<b>USB Plugs and Hoods — RoHS Compliant</b>						
25	—	—	USB A-Male, Solder Version Hood for USB A Male Hood for USB B Male USB B-Male, Solder Version	AE10091-ND AE10090-ND AE1441-ND AE10178-ND	43 38 34 40 35 32 40 35 32 43 38 34	A-USBPA-R A-USBPA-HOOD-R A-USBPB-HOOD-R A-USBPB-R
<b>USB Cables</b>						
26	1.0 2.0 5.0	4	Cable Mini USB 4-Pin Male	AE1442-ND AE1443-ND AE1283-ND	4.59 4.04 3.62 5.64 4.96 4.45 4.36 3.83 3.44	AK670M-1-R AK670M-2-R AK670M-5
26	1.0 2.0 3.0 5.0	4	Cable Mini USB 2.0, 4-Pin Male	AE1444-ND AE1445-ND AE1446-ND AE1447-ND	5.18 4.56 4.09 6.24 5.49 4.92 7.66 6.73 6.04 10.79 9.49 8.51	AK670M/2-1-R AK670M/2-2-R AK670M/2-3-R AK670M/2-5-R
27	1.0 2.0 3.0 5.0	4	Cable Mini USB 5-Pin Male	AE1448-ND AE9927-ND AE9928-ND AE1449-ND	5.97 5.25 4.71 6.47 5.69 5.10 6.60 5.80 5.20 9.37 8.24 7.39	AK672M-1-R AK672M-2-R AK672M-3-R AK672M-5-R
27	1.0 2.0 3.0 5.0	4	Cable Mini USB 2.0, 5-Pin Male	AE1450-ND AE9929-ND AE1451-ND AE1452-ND	3.42 2.44 2.32 4.93 3.52 3.35 5.99 4.28 4.07 9.17 8.07 7.23	AK672M/2-1-R AK672M/2-2-R AK672M/2-3-R AK672M/2-5-R
28	1.0 2.0	4	Cable Mini USB, 5-Pin Female to 5-Pin Male	AE10311-ND AE10312-ND	5.48 4.82 4.32 6.07 5.34 4.79	AK669M-1-R AK669M-2-R
29	2.0	—	Cable USB A Male, Open End	AE9855-ND	3.47 2.48 2.36	AK670-OE-R
30	2.0 5.0	4	Cable USB A-A Male	AE9930-ND AE1453-ND	6.34 5.57 5.00 11.52 10.13 9.08	AK670-2-R AK670-5-R
30	1.0 3.0 5.0	4	Cable USB 2.0, A-A Male	AE1454-ND AE1455-ND AE1456-ND	4.72 4.15 3.72 8.09 7.11 6.37 11.65 10.24 9.18	AK670/2-1-R AK670/2-3-R AK670/2-5-R

◆ RoHS Compliant

(Continued)

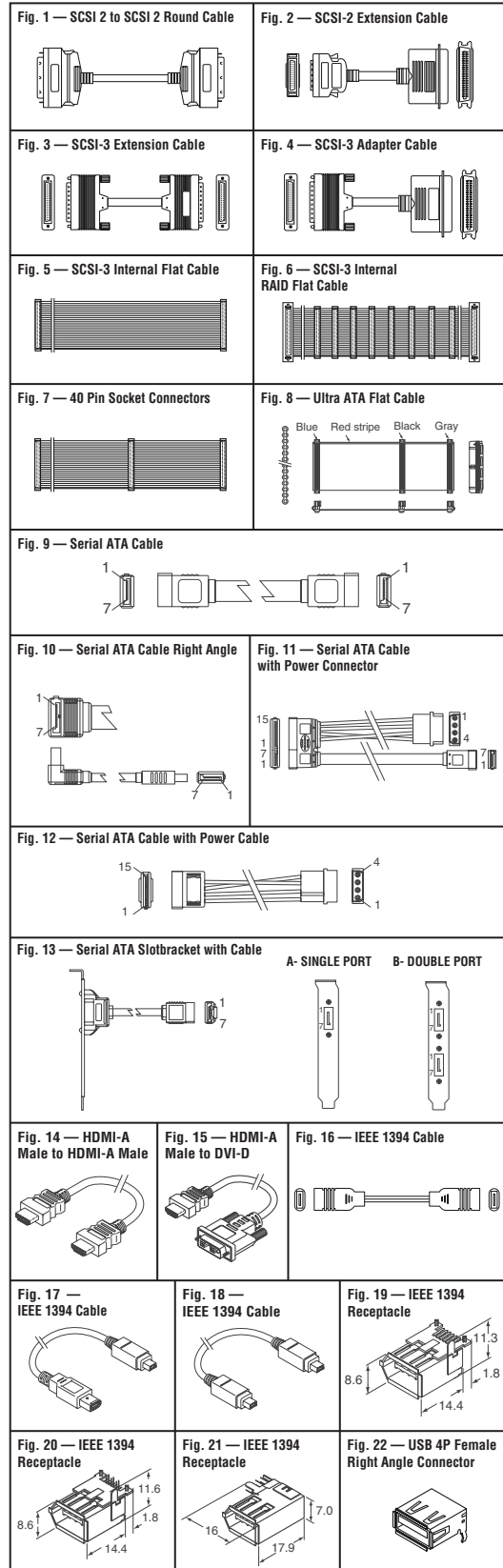

More Product Available Online: [www.digkey.com](http://www.digkey.com)

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380