 


Metal Cable Clamps




Half Clamp		Clamp		218	
D	Dimensions - Inch L W H	Digi-Key Part No.	10	Pricing 100	
Steel Half Clamps					
.125	.437 .500	218	8140K-ND	1.64	16.20
.187	.437 .500	218	8141K-ND	1.72	17.00
.250	.437 .500	218	8142K-ND	1.85	17.90
.312	.500 .500	218	8143K-ND	1.99	19.70
.375	.531 .625	218	8144K-ND	2.32	22.40
.437	.562 .625	218	8145K-ND	2.44	23.95
.500	.625 .625	218	8146K-ND	3.05	29.35
.562	.687 .625	218	8147K-ND	3.13	30.60
.625	.750 .625	218	8148K-ND	3.28	31.30
.687	.812 .625	218	8149K-ND	3.36	32.50
.750	.812 .625	218	8150K-ND	3.50	33.55
.812	.875 .625	218	8151K-ND	3.63	35.00
.875	.937 .750	281	8152K-ND	3.96	38.15
.937	.968 .750	281	8153K-ND	4.11	39.85
1.000	1.000 .750	281	8154K-ND	9.00	40.95
Insulated Steel Half Clamps					
.187	.437 .500	218	8160K-ND	4.44	42.75
.250	.500 .500	218	8161K-ND	5.02	48.25
.312	.531 .625	218	8162K-ND	5.68	54.55
.375	.562 .625	218	8163K-ND	5.95	57.15
.437	.625 .625	218	8164K-ND	6.70	64.35
.500	.687 .625	218	8165K-ND	4.93	47.35
.562	.750 .625	218	8166K-ND	5.10	49.05
.625	.812 .625	218	8167K-ND	5.55	50.40
.687	.812 .625	218	8168K-ND	5.42	51.85
.750	.875 .625	218	8169K-ND	5.90	56.50
.812	.937 .750	281	8170K-ND	8.17	71.55
.875	.968 .750	281	8171K-ND	8.20	74.35
.937	1.000 .750	281	8172K-ND	9.09	87.40
1.000	1.062 .750	281	8173K-ND	8.55	82.25
Steel Clamps					
.250	.406 .500	203	8101K-ND	2.03	19.80
.312	.437 .500	203	8102K-ND	2.11	20.70
.375	.468 .500	203	8103K-ND	2.19	20.95
.437	.500 .500	203	8104K-ND	2.28	21.85
.500	.531 .500	203	8105K-ND	2.40	23.20
.562	.562 .500	203	8106K-ND	2.52	24.55
.625	.594 .500	203	8107K-ND	2.61	25.55
.687	.625 .500	203	8108K-ND	2.69	25.75
.750	.656 .500	203	8109K-ND	2.77	26.65
.812	.687 .500	203	8110K-ND	2.86	28.25
.875	.718 .500	203	8111K-ND	2.96	28.80
.937	.750 .500	203	8112K-ND	3.06	29.35
1.000	.781 .500	203	8113K-ND	3.13	30.60
Insulated Steel Clamps					
.187	.406 .500	203	8121K-ND	3.79	36.45
.250	.437 .500	203	8122K-ND	3.91	37.80
.312	.468 .500	203	8123K-ND	4.07	39.15
.375	.500 .500	203	8124K-ND	4.20	40.75
.437	.531 .500	203	8125K-ND	4.36	42.20
.500	.562 .500	203	8126K-ND	4.52	43.75
.562	.594 .500	203	8127K-ND	4.69	45.55
.625	.625 .500	203	8128K-ND	5.14	46.80
.687	.656 .500	203	8129K-ND	5.28	48.05
.750	.687 .500	203	8130K-ND	5.12	49.30
.812	.718 .500	203	8131K-ND	5.58	50.75
.875	.750 .500	203	8132K-ND	5.75	52.55
.937	.781 .500	203	8133K-ND	5.91	53.80
1.000	.812 .500	203	8134K-ND	6.05	55.15

RoHS Compliant

K

Nylon Cable Clamps

 
Ideal for securing, insulating and routing cable wiring, piping, tubing, components and fibre optics. Made of .050" thick nylon 6/6, white.



D	Dimensions - Inch E W H	Digi-Key Part No.	100	Pricing 500 1,000
.125	.325 .375 .140	7620K-ND	7.45	24.00 29.45
.125	.325 .375 .203	7621K-ND	7.45	24.00 29.45
.187	.380 .375 .140	7622K-ND	7.55	25.75 29.85
.187	.380 .375 .203	7623K-ND	7.55	25.75 29.85
.250	.410 .375 .140	7624K-ND	7.65	25.75 30.70
.250	.410 .375 .203	7625K-ND	7.65	25.75 30.70
.312	.445 .375 .140	7626K-ND	7.75	27.25 32.00
.312	.445 .375 .203	7627K-ND	7.75	27.25 32.00
.375	.475 .375 .140	7628K-ND	8.00	27.25 34.10
.375	.475 .375 .203	7629K-ND	8.00	27.25 34.10
.437	.525 .375 .140	7630K-ND	8.80	29.00 35.50
.437	.525 .375 .203	7631K-ND	8.80	29.00 35.50
.500	.550 .375 .140	7632K-ND	9.10	29.25 36.65
.500	.550 .375 .203	7633K-ND	9.10	29.25 36.65
.562	.625 .500 .203	7634K-ND	13.50	43.75 55.75
.625	.660 .500 .203	7635K-ND	13.85	45.50 58.55
.750	.785 .500 .203	7636K-ND	16.45	52.50 67.20
.875	.845 .500 .203	7637K-ND	17.20	56.50 71.45
1.000	.910 .500 .203	7638K-ND	17.90	60.00 74.40
1.125	.970 .500 .203	7639K-ND	25.55	83.50 105.05
1.25	1.060 .500 .203	7640K-ND	27.10	91.00 114.15

RoHS Compliant

Recessed Bumpers

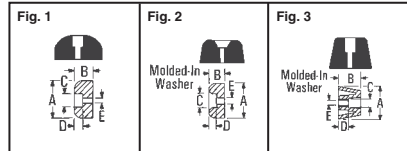


Provides excellent traction and shock absorbing qualities.
Materials:
Fig. 1 and 2: Rubber, BUNA S
Fig. 3: Vinyl

Fig.	A	Dimensions - Inch B C D E	Screw Size	Digi-Key Part No.	10	Pricing 100
1	.500	.250 .250 .125	.125	#4	720K-ND	2.20 20.95
	.625	.312 .250 .187	.125	#4	721K-ND	3.50 33.55
	.718	.437 .250 .218	.125	#4	722K-ND	7.01 67.30
2	.937	.375 .375 .187	.187	#8	723K-ND	6.72 64.35
	.562	.375 .218 .187	.115	#4	727K-ND	6.64 60.30
3	.687	.250 .343 .125	.155	#6	724K-ND	5.49 49.85
	.750	.437 .265 .250	.148	#6	728K-ND	7.04 67.75
	.875	.312 .406 .187	.187	#8	725K-ND	10.13 92.15
	.937	.625 .359 .297	.174	#8	729K-ND	11.06 100.60
	1.062	.437 .468 .234	.200	#10	726K-ND	12.62 114.40

† Gray — all others black

 Flat Washers



Fibre: Commercial per ASTM D710, Grade CH
Nylon: Grade 6/6 per ASTM D4066

O.D. A	Dimensions - Inch Thick B I.D. C	Digi-Key Part No.	100	Pricing 500 1,000
Nylon Material — #2 Screw Size				
.250	.032 .098	3347K-ND	3.28	14.75 —
Fibre Material — #4 Screw Size				
.250	.032 .120	3116K-ND	4.50	15.75 —
.312	.032 .120	348K-ND	4.50	15.75 —
.375	.032 .120	3117K-ND	4.85	16.25 —
.250	.047 .120	3154K-ND	4.50	15.75 —
.312	.047 .120	3155K-ND	4.50	15.75 —
.375	.047 .120	3156K-ND	5.05	17.50 19.20
.250	.062 .120	3368K-ND	4.50	15.75 —
.312	.062 .120	3196K-ND	4.85	16.25 21.35
.375	.062 .120	3197K-ND	4.85	16.25 19.90
Nylon Material — #4 Screw Size				
.250	.032 .120	3348K-ND	4.50	15.75 —
.312	.032 .120	3359K-ND	5.65	17.50 23.05
.375	.032 .120	3118K-ND	5.65	18.75 24.30
.250	.047 .120	345K-ND	5.65	17.50 —
.312	.047 .120	3157K-ND	4.85	16.25 22.30
.375	.047 .120	3158K-ND	4.85	16.25 24.55
.250	.062 .120	3358K-ND	4.50	15.75 21.75
.312	.062 .120	3198K-ND	5.65	18.75 29.45
.375	.062 .120	3200K-ND	5.65	17.50 27.85
Fibre Material — #6 Screw Size				
.250	.032 .140	3119K-ND	4.50	15.75 —
.312	.032 .140	3120K-ND	4.50	15.75 —
.375	.032 .140	3121K-ND	4.85	16.25 —
.250	.047 .140	3159K-ND	4.50	15.75 —
.312	.047 .140	3160K-ND	4.50	15.75 —
.375	.047 .140	3161K-ND	5.05	17.50 19.20
.250	.062 .140	3369K-ND	4.50	15.75 —
.312	.062 .140	3370K-ND	4.50	15.75 18.90
.375	.062 .140	3201K-ND	4.85	16.25 19.90
Nylon Material — #6 Screw Size				
.250	.032 .140	3122K-ND	4.50	15.75 —
.312	.032 .140	3349K-ND	4.50	15.75 18.15
.375	.032 .140	3123K-ND	5.65	18.75 24.30
.250	.047 .140	3162K-ND	4.50	15.75 17.50
.312	.047 .140	346K-ND	6.20	19.75 22.30
.375	.047 .140	3163K-ND	4.85	16.25 24.55
.250	.062 .140	3360K-ND	4.50	15.75 21.75
.312	.062 .140	3361K-ND	5.65	18.75 29.45
.375	.062 .140	3202K-ND	5.65	17.50 27.85
Fibre Material — #8 Screw Size				
.312	.032 .171	3124K-ND	3.41	15.50 —

Nylon Shoulder Washers/Bushings



Material: Nylon, Grades 6/6 per ASTM D4066

L	Dimensions - Inch A B C D	Digi-Key Part No.	100	Pricing 500
#4 Screw Size				
.031	.218 .040 .115 .135	3049K-ND	7.45	24.00
.047	.250 .032 .115 .185	7681K-ND	8.80	29.00
.093	.235 .047 .115 .145	3053K-ND	12.50	43.00
.125	.235 .047 .115 .145	3102K-ND	12.50	41.50
.180	.235 .047 .115 .145	3103K-ND	12.50	41.50
.250	.235 .047 .115 .145	340K-ND	13.50	45.00
#6 Screw Size				
.032	.385 .062 .145 .240	7682K-ND	9.55	32.75
.032	.250 .062 .140 .187	7683K-ND	8.00	27.25
.032	.312 .062 .140 .187	7684K-ND	9.10	29.75
.125	.290 .047 .140 .170	3054K-ND	13.50	43.75
.187	.290 .047 .140 .170	3104K-ND	13.50	43.75
.250	.290 .047 .140 .170	341K-ND	13.50	45.00
.500	.290 .047 .140 .170	3055K-ND	14.50	47.75

More Product Available Online: www.digkey.com