

Weller® Accessories

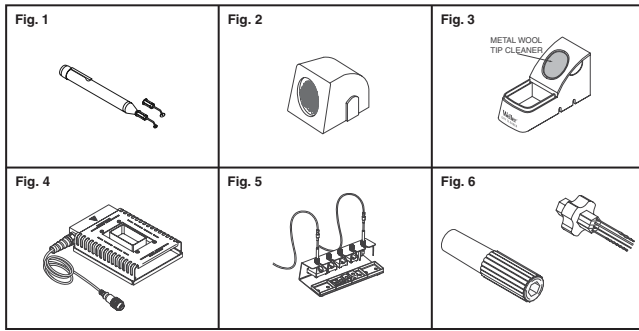



Fig.	Description	Digi-Key Part No.	Price Each	Weller Part No.
1	Vacuum Pick-up Tool	WLSK200-ND	51.24	WLSK200
2	WDH Dry Cleaning System	0051512599-ND	12.60	0051512599
3	WDC Dry Cleaning System with Wool Replacement Wool (2/pack)	0051512499-ND	16.80	0051512499
—	Replacement Wool (2/pack)	0051382499-ND	5.25	0051382499
—	Solder Bath, 80W (for use with WD2 and WD2M Stations)	0052704099-ND	215.25	0052704099
4	Solder Bath, 150W (for use with WD2 and WD2M Stations)	0052704299-ND	319.20	0052704299
5	SMT Chip Removal Nozzle Kit	0051515599-ND	315.00	0051515599
6	Cleanout Tool for Desoldering Pencils	0051350099-ND	15.43	0051350099
—	Polishing Bar for Soldering Tips	WPB1-ND	8.40	WPB1
—	Tip Tinner for Solder Tip, 1.5Oz.	0051303199-ND	8.40	0051303199

Professional Soldering Irons WP25, WP30, WP35 Series Irons

Features:

- Fixed temperature units • Ideal for a wide variety of electronic tasks • Interchangeable heater elements - Single handle plus three different heating elements gives the user a trio of irons for different jobs • Quick change knurled collar makes changing heater simple • Lightweight handle with cushioned grip • For additional safety, all irons come with 3-wire power cord • Irons use ST series iron plated tips for long life and greater soldering efficiency • UL Listed

• Important: Use only Weller tips • ST series tips

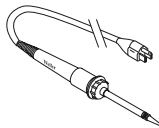

Description	Digi-Key Part No.	Price Each	Weller Part No.
Soldering Iron with ST3 Tip, 25 Watt	WP25-ND	38.92	WP25
Soldering Iron with ST3 Tip, 30 Watt	WP30-ND	42.07	WP30
Soldering Iron with S T3 Tip, 35 Watt	WP35-ND	49.00	WP35
Soldering Iron Stand for WP Series	PH60-ND	24.19	PH60
Knurled Tip Retaining Nut	KN60-ND	3.15	KN60

* Soldering Iron Stand is sold separately.


K Hot Air Rework Station and Nozzles

Specifications:

- 650W • Temperature Range: 122°F - 1022°F • Voltage: 120V

Features:

- Compact design maximizes workspace efficiency • Controlled output maintains set temperature regardless of air flow setting • Temperature and air flow are controlled independently • Standby button allows you to power down to low settings when not in use • Includes a rest support for the hand piece • Nozzles sold separately

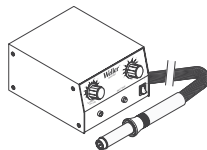

Description	Digi-Key Part No.	Price Each	Weller Part No.
Self-Contained Hot Air Station, 120V	WHA900-ND	576.45	WHA900
Hot Air Nozzle, 44 PIN PLCC	0058736814-ND	69.74	0058736814
Hot Air Nozzle, 84 PIN PLCC	0058736833-ND	87.46	0058736833
Hot Air Nozzle, 20 PIN PLCC	0058736839-ND	66.95	0058736839
Hot Air Nozzle, 68 PIN PLCC	0058736804-ND	69.74	0058736804
Hot Air Nozzle, 14 PIN SOIC-SO8	0058736843-ND	66.95	0058736843
Hot Air Nozzle, 20 PIN SOIC	0058736842-ND	66.95	0058736842
Hot Air Nozzle, SOT23	0058736870-ND	66.95	0058736870

Replacement Tips for Irons


Tip Dim. (mm)	Description	Digi-Key Part No.	Price Each	Weller Part No.
PT Series Tips for TC201T Iron				
1.57	Screwdriver, 700°F (371°C)	PTA7-ND	3.30	PTA7
1.57	Screwdriver, 800°F (427°C)	PTA8-ND	3.30	PTA8
3.18	Screwdriver, 700°F (371°C)	PTC7-ND	3.30	PTC7
3.18	Screwdriver, 800°F (427°C)	PTC8-ND	3.30	PTC8
.79	Conical Flat, 700°F (371°C)	PTF7-ND	3.30	PTF7
.79	Conical Flat, 800°F (427°C)	PTF8-ND	3.30	PTF8
.38	Long Conical, 700°F (371°C)	PTS7-ND	3.30	PTS7
.38	Long Conical, 800°F (427°C)	PTS8-ND	3.30	PTS8
EPH Series Tips for EC1302B Iron				
.38	Micropoint Tip	EPH101-ND	5.35	EPH101
1.57	Screwdriver Tip	EPH106-ND	5.35	EPH106
Replacement Barrel Nut Assortment for EPH Tip		EC231-ND	8.82	EC231
ET Series Tips for EC1201A				
1.57	Screwdriver Tip	ETA-ND	3.67	ETA
2.36	Screwdriver Tip	ETB-ND	3.67	ETB
.79	Screwdriver Tip	ETH-ND	3.67	ETH
.79	Conical Tip	ETP-ND	3.67	ETP
.40	Single Flat Tip	ETU-ND	3.67	ETU
.80	Long Conical Tip	ETO-ND	3.67	ETO
Tips for Professional Soldering Irons — ST Series Tips for WP25, WP30, WP35 Irons				
1.57	Screwdriver Tip	ST1-ND	3.44	ST1
4.65	Screwdriver Tip	ST4-ND	3.44	ST4
.79	Single Flat Tip	ST5-ND	3.44	ST5
.79	Screwdriver Tip	ST6-ND	3.44	ST6

Soldering Irons

Specifications:

- Specifically designed for use at electrostatic free work stations • Non-burnable silicon rubber cord • Lightweight, high impact plastic handle • Blue plastic meets requirements for ESD, Electrostatic Dissipative Materials • Uses Weller EM series tips made of copper with heavy iron, nickel and chromium plating for long life • UL listed

NOTE: EC1302B and EC1201A work with DEC1001 and EC1002.

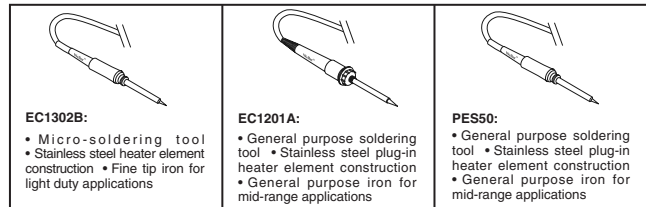

EC1302B:

- Micro-soldering tool • Stainless steel heater element construction • Fine tip iron for light duty applications

EC1201A:

- General purpose soldering tool • Stainless steel plug-in heater element construction • General purpose iron for mid-range applications

PESS0:

- General purpose soldering tool • Stainless steel plug-in heater element construction • General purpose iron for mid-range applications


Description	Digi-Key Part No.	Price Each	Weller Part No.
20W Iron with EPH 101 Tip	EC1302B-ND	123.62	EC1302A
40W Soldering Iron with ETA Tip	EC1201A-ND	123.62	EC1201A
50W Soldering Iron with ETA Tip	PESS0-ND	41.75	PESS0
Replacement Sponge	TC205-ND	1.09	TC205

portasol® Cordless Soldering Irons and Tips

Features:

- 75 Watt • Gives the ultimate in portable power and convenience for all soldering jobs • Provides 25 - 75 watts of power • Adjustable temperatures up to 850°F (454.4°C) • Refueled with standard butane refills • Unit lasts for up to an hour of continuous use

- 125 Watt • Self-igniting portable butane heat tool • Anti-static soldering • "Auto Switch" safety shut-off iron plated tips, and built-in butane filter • Rugged stainless-steel body provides up to 125 watts of power • Adjustable temperature up to 1,076°F (530°C) • Fuel level is clearly visible through a window on the body of the tool • Butane not included (Butane is not sold by Digi-Key)

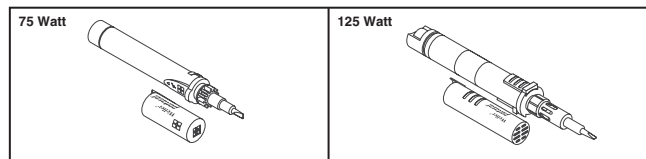

Description	Digi-Key Part No.	Price Each	Weller Part No.
75 Watt			
Cordless Soldering Iron with PPT6 Tip, 2.4mm	P2C-ND	37.38	P2C
Single Flat, Solder Tip, 1.0mm	PPT1-ND	8.72	PPT1
Single Flat, Solder Tip, 2.4mm	PPT2-ND	8.72	PPT2
Double Flat, Solder Tip, 1.0mm	PPT5-ND	8.72	PPT5
Double Flat, Solder Tip, 2.4mm	PPT6-ND	8.72	PPT6
125 Watt			
Cordless Soldering Iron	PSI100C-ND	63.06	PSI100C
Single Flat, Solder Tip, 1.0mm	PSI1-ND	11.15	PSI1
Single Flat, Solder Tip, 2.4mm	PSI2-ND	11.15	PSI2
Single Flat, Solder Tip, 3.2mm	PSI3-ND	11.15	PSI3
Single Flat, Solder Tip, 4.8mm	PSI4-ND	11.15	PSI4
Single Chisel, Solder Tip, 1.0mm	PSI5-ND	11.15	PSI5
Double Flat, Solder Tip, 2.4mm	PSI6-ND	11.15	PSI6
Double Flat, Solder Tip, 3.2mm	PSI7-ND	11.15	PSI7
Double Flat, Solder Tip, 4.8mm	PSI8-ND	11.15	PSI8
Hot Blower Tip	PSI9-ND	11.15	PSI9

More Product Available Online: www.digikey.com