

EZ-HOOK Electronic Test Accessories (Cont.)

Test Leads Tinned copper with flexible PVC insulation.

(Set/10: 1 each of: Brown, Black, Red, Orange, Yellow, Green, Blue, Violet, Gray, White) (Set/2: 1 each of: Black and Red)
 (Set/5R: 1 each of: Red, Blue, White, Purple, Gray) (Set/5B: 1 each of: Black, Brown, Green, Yellow, Orange)

Dimensions in Inches

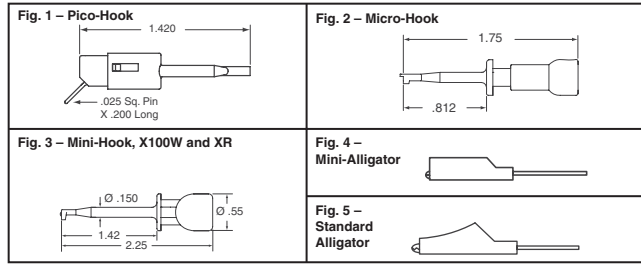


Fig.	Description	AWG	Color	Length (Inches)	Digi-Key Part No.	Price Each	E-Z-Hook Part No.	
Hook Test Leads — RoHS Compliant								
1	E-Z Pico-Hook to Pico-Hook	28 (19 x 40)	Black	12	461-1042-ND	5.40 4.88 4.33	P704-12 BLK	
			Red	12	461-1043-ND	5.40 4.88 4.33	P704-12 RED	
	Pico-Hook to .025" Square Socket	28 (19 x 40)	Set/2	12	461-1165-ND	10.96 9.90 8.78	P703-12 R/B	
			Set/10	12	461-1166-ND	51.96 46.95 41.63	P703-12-S	
1	Pico-Hook to Lead Only	28 (19 x 40)	Set/2	12	461-1167-ND	6.81 6.15 5.46	P713-12 R/B	
			Set/10	12	461-1168-ND	32.37 29.25 25.94	P713-12-S	
	2	Micro-Hook to Micro-Hook	22 (65 x 40)	Black	12	461-1036-ND	4.57 4.13 3.66	204XM-12 BLK
				Red	12	461-1037-ND	4.57 4.13 3.66	204XM-12 RED
Set/10				12	461-1038-ND	44.99 40.65 36.05	204XM-12-S	
Black				24	461-1039-ND	4.57 4.13 3.66	204XM-24 BLK	
2	Micro-Hook to Std. Banana Plug	22 (65 x 40)	Red	24	461-1040-ND	4.57 4.13 3.66	204XM-24 RED	
			Set/10	24	461-1041-ND	44.99 40.65 36.05	204XM-24-S	
			Black	18	461-1044-ND	4.13 3.74 3.32	BXM-18 BLK	
			Red	18	461-1045-ND	4.13 3.74 3.32	BXM-18 RED	
2	Micro-Hook to Std. Banana Plug	22 (65 x 40)	Set/2	18	461-1046-ND	8.27 7.47 6.63	BXM-18 R/B	
			Set/10	18	461-1149-ND	41.17 37.20 32.99	BXM-18-S	
			Black	36	461-1047-ND	4.13 3.74 3.32	BXM-BLK	
			Red	36	461-1048-ND	4.13 3.74 3.32	BXM-RED	
2	Micro-Hook to Std. Banana Plug	22 (65 x 40)	Set/2	36	461-1049-ND	8.27 7.47 6.63	BXM-R/B	
			Set/10	36	461-1150-ND	41.17 37.20 32.99	BXM-S	
			Black	12	461-1030-ND	4.32 3.90 3.46	204-12W BLK	
			Red	12	461-1031-ND	4.32 3.90 3.46	204-12W RED	
2	Mini-Hook to Mini-Hook	22 (65 x 40)	Set/10	12	461-1032-ND	42.50 38.40 34.05	204-12W-S	
			Black	24	461-1033-ND	4.32 3.90 3.46	204-24W BLK	
			Red	24	461-1034-ND	4.32 3.90 3.46	204-24W RED	
			Set/10	24	461-1035-ND	42.50 38.40 34.05	204-24W-S	
2	Mini-Hook to Mini-Hook	22 (65 x 40)	Black	36	461-1147-ND	4.32 3.90 3.46	204-36W BLK	
			Red	36	461-1146-ND	4.32 3.90 3.46	204-36W RED	
			Set/10	36	461-1148-ND	42.83 38.70 34.32	204-36W-S	
			Black	18	461-1050-ND	4.15 3.75 3.33	BX1W-18 BLK	
3	Mini-Hook to Std. Banana Plug	22 (65 x 40)	Red	18	461-1051-ND	4.15 3.75 3.33	BX1W-18 RED	
			Set/2	18	461-1052-ND	8.30 7.50 6.65	BX1W-18 R/B	
			Set/10	18	461-1151-ND	44.82 40.50 35.91	BX1W-18-S	
			Black	36	461-1053-ND	4.15 3.75 3.33	BX1W-BLK	
3	Mini-Hook to Std. Banana Plug	22 (65 x 40)	Red	36	461-1054-ND	4.15 3.75 3.33	BX1W-RED	
			Set/2	36	461-1055-ND	8.30 7.50 6.65	BX1W-R/B	
			Set/10	36	461-1152-ND	44.82 40.50 35.91	BX1W-S	
			Black	18	461-1056-ND	5.59 5.06 4.49	601W-18 BLK	
3	Mini-Hook to Stacking Banana Plug	18 (65 x 36)	Red	18	461-1057-ND	5.59 5.06 4.49	601W-18 RED	
			Set/2	18	461-1058-ND	11.19 10.11 8.97	601W-18 R/B	
			Set/10	18	461-1153-ND	55.61 50.25 44.56	601W-18-S	
			Black	36	461-1059-ND	5.59 5.06 4.49	601W-36 BLK	
3	Mini-Hook to Stacking Banana Plug	18 (65 x 36)	Red	36	461-1060-ND	5.59 5.06 4.49	601W-36 RED	
			Set/2	36	461-1061-ND	11.19 10.11 8.97	601W-36 R/B	
			Set/10	36	461-1154-ND	55.61 50.25 44.56	601W-S	
			Black	18	461-1156-ND	5.74 5.19 4.61	601XR-18 BLK	
3	XR Heavy Duty Mini-Hook to Stacking Banana Plug	18 (65 x 36)	Red	18	461-1155-ND	5.74 5.19 4.61	601XR-18 RED	
			Set/5B	18	461-1157-ND	28.72 25.95 23.01	601XR-18 5B	
			Set/5R	18	461-1158-ND	28.72 25.95 23.01	601XR-18 5R	
			Set/10	18	461-1159-ND	56.77 51.30 45.49	601XR-18-S	
Alligator Clip Test Leads								
4	Mini-Alligator Clip to Mini-Alligator Clip Jumper	22 (65 x 40)	Set/2	12	461-1169-ND	6.87 6.21 5.51	284M-12 R/B	
			Set/10	12	461-1170-ND	34.36 31.05 27.54	284M-12-S	
			Set/2	36	461-1171-ND	6.87 6.21 5.51	284M-36 R/B	
			Set/10	36	461-1172-ND	34.36 31.05 27.54	284M-36-S	
5	Std. Alligator Clip to Stacking Banana Clip	18 (65 x 36)	Set/2	36	461-1173-ND	10.19 9.21 8.17	681 R/B	
			Set/10	36	461-1174-ND	49.80 45.00 39.90	681-S	
			Set/2	12	461-1175-ND	8.60 7.77 6.89	684-12 R/B	
			Set/10	12	461-1176-ND	41.83 37.80 33.52	684-12-S	
5	Std. Alligator Clip to Std. Alligator Jumper	18 (65 x 36)	Set/2	24	461-1177-ND	8.60 7.77 6.89	684-24 R/B	
			Set/10	24	461-1178-ND	41.83 37.80 33.52	684-24-S	
			Set/2	36	461-1179-ND	8.60 7.77 6.89	684-36 R/B	
			Set/10	36	461-1180-ND	41.83 37.80 33.52	684-36-S	
5	Std. Alligator Clip to Std. Alligator Jumper	18 (65 x 36)	Set/2	60	461-1181-ND	10.33 9.33 8.28	684-60 R/B	
			Set/10	60	461-1182-ND	51.46 46.50 41.23	684-60-S	

Patch Cords Tinned copper with flexible PVC insulation.

(Set/10: 1 each of: Brown, Black, Red, Orange, Yellow, Green, Blue, Violet, Gray, White)



Description	AWG	Color	Length (Inches)	Digi-Key Part No.	Price Each	E-Z-Hook Part No.
1 100 250						
Standard Banana Plug to Standard Banana Plug	22 (65 x 40)	Black	18	461-1068-ND	4.57 4.13 3.66	9105-18 BLK
		Red	18	461-1069-ND	4.57 4.13 3.66	9105-18 RED
		Black	36	461-1070-ND	4.57 4.13 3.66	9105-36 BLK
		Red	36	461-1071-ND	4.57 4.13 3.66	9105-36 RED
Stacking Banana Plug with Heavy Wire to Stacking Banana Plug	18 (65 x 36)	Black	8	461-1123-ND	6.44 5.82 5.17	9111-8 BLK
		Red	8	461-1122-ND	6.44 5.82 5.17	9111-8 RED
		Set/10	8	461-1124-ND	63.08 57.00 50.54	9111-8-S
		Black	12	461-1126-ND	6.44 5.82 5.17	9111-12 BLK
		Red	12	461-1125-ND	6.44 5.82 5.17	9111-12 RED
		Set/10	12	461-1127-ND	63.08 57.00 50.54	9111-12-S
		Black	18	461-1072-ND	6.52 5.90 5.23	9111-18 BLK
		Red	18	461-1073-ND	6.52 5.90 5.23	9111-18 RED
		Black	24	461-1129-ND	6.52 5.90 5.23	9111-24 BLK
		Red	24	461-1128-ND	6.52 5.90 5.23	9111-24 RED
		Set/10	24	461-1130-ND	64.57 58.35 51.74	9111-24-S
		.030" Diameter Socket to .030" Diameter Socket	22 (65 x 40)	Black	36	461-1074-ND
Red	36			461-1075-ND	6.61 5.97 5.30	9111-36 RED
Set/10	36			461-1131-ND	64.57 58.35 51.74	9111-36-S
Black	48			461-1133-ND	6.84 6.18 5.48	9111-48 BLK
Red	48			461-1132-ND	6.84 6.18 5.48	9111-48 RED
Set/10	48			461-1134-ND	68.06 61.50 54.53	9111-48-S
Black	60			461-1136-ND	6.84 6.18 5.48	9111-60 BLK
Red	60			461-1135-ND	6.84 6.18 5.48	9111-60 RED
Set/10	60			461-1137-ND	68.06 61.50 54.53	9111-60-S
Black	72			461-1139-ND	7.04 6.36 5.64	9111-72 BLK
Red	72			461-1138-ND	7.04 6.36 5.64	9111-72 RED
Set/10	72			461-1140-ND	69.72 63.00 55.86	9111-72-S
.025" to .025" Square Socket Gold Plated	22 (65 x 40)	Black	12	461-1076-ND	4.20 3.80 3.37	9860-12 BLK
		Red	12	461-1077-ND	4.20 3.80 3.37	9860-12 RED
		Black	24	461-1078-ND	4.20 3.80 3.37	9860-24 BLK
		Red	24	461-1079-ND	4.20 3.80 3.37	9860-24 RED
.025" to .025" Square Socket Gold Plated	22 (65 x 40)	Black	12	461-1094-ND	3.54 3.20 2.84	9110-12 BLK
		Red	12	461-1095-ND	3.54 3.20 2.84	9110-12 RED
		Set/10	12	461-1141-ND	34.53 31.20 27.67	9110-12-S
		Black	24	461-1096-ND	3.54 3.20 2.84	9110-24 BLK
.025" to .025" Square Socket Gold Plated	22 (65 x 40)	Red	24	461-1097-ND	3.54 3.20 2.84	9110-24 RED
		Set/10	24	461-1142-ND	34.53 31.20 27.67	9110-24-S

Flexible Test Lead Wires


Features:
 • PVC Insulated • 100 Feet Length • Temperature: 105°C (200 Series: 60°C UL) • Tinned copper



Description	AWG	Insulation Thickness (Inches)	VV DC	Nom. O.D. (Inches)	Digi-Key Part No.	Price Each	E-Z-Hook Part No.
1 100 250							
200 Series	22 (65 x 40)	.018	1000 (300UL)	.070	461-1114-ND	32.90 29.73 26.37	9504-100FT BLK
					461-1115-ND	32.90 29.73 26.37	9504-100FT RED
500 Series	20 (105 x 40)	.020	1000	.080	461-1116-ND	35.52 32.10 28.47	9505-100FT BLK
					461-1117-ND	35.52 32.10 28.47	9505-100FT RED
600 Series	18 (65 x 36)	.045	5000	.144	461-1118-ND	42.75 38.63 34.25	9506-100FT BLK
					461-1119-ND	42.75 38.63 34.25	9506-100FT RED
700 Series	28 (19 x 40)	.015	600	.047	461-1112-ND	22.91 20.70 18.36	9501-100FT BLK
					461-1113-ND	22.91 20.70 18.36	9501-100FT RED

K

Test Cable Wall Brackets

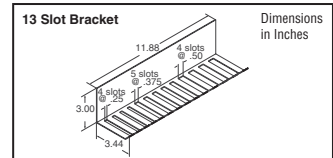

Features:
 • Material: Steel
 • Finish: Blue Powder Coat

Description	Digi-Key Part No.	Price Each	E-Z-Hook Part No.
10 50			
6 Slot Bracket	461-1120-ND	8.42 7.61 6.75	WB6
13 Slot Bracket	461-1121-ND	11.62 10.50 9.31	WB14

(Continued)

More Product Available Online: www.digikey.com

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

(T091) 2327