

**Battery Holders (Cont.)**



Fig.	No. of Cells	Description	Digi-Key Part No.	Price Each		
				1	10	100
<b>Coin Cell Holders — 12.5mm Cell Diameter — RoHS Compliant</b>						
18	1	PC Mount, Solder Legs, 2 - 2.5mm Cell Height	BH501-ND	1.14	.96	.89
19	1	SMT, 1.6 - 2.5mm Cell Height	BK-885-CT-ND†	.45	.38	.30
		SMT, 1.6 - 2.5mm Cell Height	BK-885-TR-ND‡	199.11/800		
<b>Coin Cell Holders — 16mm Cell Diameter — RoHS Compliant</b>						
20	1	PC Mount, Solder Legs, 1.6 - 3.2mm Cell Height	BH600-ND	.83	.76	.63
21	1	SMT, Temperature Range -40°C - 245°C	BH600SM-ND	1.13	1.02	.86
21	1	SMT, Temperature Range -40°C - 245°C, Gold	BH600SM-G-ND	.90	.82	.76
21	1	SMT, High Temperature, 16x5.8mm, Gold	BH600SM-5.8-G-ND	1.00	.90	.83
<b>Coin Cell Holders — 20mm Cell Diameter — RoHS Compliant</b>						
19	1	SMT, 1.6 - 3.2mm Cell Height	BK-883-CT-ND†	.45	.38	.30
		SMT, 1.6 - 3.2mm Cell Height	BK-883-TR-ND‡	134.40/450		
22	2	PC Mount, Solder Legs 2.5 - 3.2mm Cell Height	BH800S-ND	.60	.55	.54
23	1	PC Mount, Solder Legs	BH32T-C-ND	1.04	.79	.66
24	1	Vertical, for BR, CR2032 Battery	BS-5-ND	.74	.67	.56
25	1	Horizontal, for 3V Lithium Battery, CR2032 or BR2032	BS-3-ND	.68	.62	.52
26	1	PC Mount, Press-to-Eject Feature, CR2032 Battery	BS-7-ND	.74	.67	.56
27	1	SMT, Press-to-Eject Feature, CR2032 Battery	BA2032-ND	1.01	.69	.61
28	1	SMT, Press-to-Eject Feature, CR2032 Battery	BA2032SM-ND	1.01	.69	.61
29	1	SMT for 2032, Gold	BU2032SM-HD-GCT-ND†	.90	.75	.60
		SMT for 2032, Gold	BU2032SM-HD-GTR-ND‡	225.60/400		
30	1	SMT, High Grip Holder for 2032, Gold	BU2032SM-JJ-GCT-ND†	.78	.65	.52
		SMT, High Grip Holder for 2032, Gold	BU2032SM-JJ-GTR-ND‡	195.52/400		
31	1	PC Mount for 2032, Gold	BU2032-1-HD-G-ND	.63	.57	.53
<b>Coin Cell Holders — 23mm Cell Diameter — RoHS Compliant</b>						
19	1	SMT, 2 - 3mm Cell Height	BK-884-CT-ND†	.45	.38	.30
22	2	PC Mount, Solder Legs, 2.5mm Cell Height	BH906S-ND	.98	.89	.74
23	1	PC Mount, Solder Legs, 2 - 3.2mm Cell Height	BH908T-C-ND	1.04	.79	.66
<b>Coin Cell Holders — 24-25mm Cell Diameter — RoHS Compliant</b>						
19	1	SMT, 2 - 3mm Cell Height	BK-886-CT-ND†	.45	.38	.30
32	1	PC Mount, Solder Legs, 2 - 3mm Cell Height	BH2430T-C-ND	.95	.86	.75
33	1	PC Mount, Solder Legs, 7.7mm Cell Height	BH1000-G-ND	1.19	1.10	.93
<b>Coin Cell Holders — 30mm Cell Diameter — RoHS Compliant</b>						
34	1	PC Mount, Solder Legs, 3.2mm Cell Height	BH3000-ND	1.19	1.10	.93
<b>9-Volt Cell Holders / Snaps — RoHS Compliant</b>						
35	1	PC Mount, Solder Legs 6" (152.40mm) Wire Leads	BH9V-PC-ND	1.15	1.04	.88
		6" (152.40mm) Battery Snap Cable	BH9V-W-ND	.86	.78	.77
36	1	6" (152.40mm) Battery Snap Cable	BS6I-ND	.30	.27	.25
37	1	6" (152.40mm) Heavy Duty Battery Snap Cable	BS6I-HD-ND	.33	.31	.28
		12" (304.8mm) Heavy Duty Battery Snap Cable	BS12I-HD-24AWG-ND	.33	.30	.28
38	1	6" (152.40mm) I-Style Molded Case Battery Snap Cable	BS6I-MC-ND	.41	.38	.34
		12" (304.8mm) I-Style Molded Case Battery Snap Cable	BS12I-MC-ND	.44	.40	.36
39	1	PC Mount, Printed Circuit Board Type with Contacts	BC9VPC-ND	1.39	1.11	1.00
<b>Printed Circuit Snap-Ons (off board battery mount) — RoHS Compliant</b>						
40	—	9-Volt Female Snap-on	BSPCF-ND	.24	.22	.15
41	—	9-Volt Male Snap-on	BSPCM-ND	.19	.18	.12

◆ RoHS Compliant † Cut Tape ‡ Tape and Reel

**Cigarette Lighter Auto Power**

Specifications: • 21mm (Inside Diameter) • Auto Plugs: (Fuse 3AG Style) • The length of the cord shown in each item is measured from the welding point

Fig.	Description	Digi-Key Part No.	Price Each		
			1	10	100
<b>Auto Power Plug — RoHS Compliant</b>					
42	ABS Fused Auto Plug with LED, Black	APP-001-ND	2.20	1.98	1.95
	ABS Fused Auto Plug with LED, Gray	APP-002-ND	2.20	1.98	1.95
	ABS Fused Auto Plug with No LED, Black	APP-003-ND	2.01	1.81	1.79
43	Auto Locking Plug with LED, Black	AP121-ND	3.63	3.28	2.88
44	Auto Locking Socket, Black (use with AP121-ND)	AS212-ND	2.66	2.40	2.20
<b>Auto Power Assemblies</b>					
45	Cigarette Inline Socket, Plastic	ZA2010-ND◆	1.11	1.00	.99
46	12' (3.66 meters) Coil Cord Assembly with 5A Fused Plug with LED	ZA5070-ND◆	6.31	5.69	5.61
47	12' (3.66 meters) 18AWG Cord Assembly with 10A Fused Plug with LED	ZA5071-ND◆	6.31	5.69	5.61
48	8" (203.2mm) 18AWG Cord Assembly with 10A Fused Plug with LED	ZA5072-ND	6.01	5.42	5.34
49	6' (1.83 meters) 18AWG Cord, 2.1mm x 5.5mm DC Plug with 5A Fused Plug with LED	ZA5073-ND◆	3.74	3.37	3.32
	6' (1.83 meters) 18AWG Cord, 2.5mm x 5.5mm DC Plug with 5A Fused Plug with LED	ZA5073-2.5-ND◆	5.47	4.98	3.50
50	12' (3.66 meters) Cord, 2.1mm x 5.5mm DC Plug, with 5A Fused Plug with LED	ZA5074-ND◆	5.94	5.35	5.27
51	1' (0.30 meters) UL2468 Cord, Lead Acid Clip, with 2A Fused Plug with LED	ZA5076-ND	4.19	3.78	3.72
52	6' (1.83 meters) Cord, 2.1mm x 5.5mm Rt. Angle DC Plug with 3A Fused Plug with LED	ZA5077-ND◆	3.74	3.37	3.32
53	6' (1.83 meters) Cord, Rotary Plug, with Lighted Switch and 5A Fuse	BK-5072-ND◆	7.81	5.35	5.05
54	8" (203.2mm), UL2468 Cord, Lead Acid Clip, 2.1mm x 5.5mm DC Plug	ZA5350-ND◆	2.82	2.54	2.51
	8" (203.2mm), UL2468 Cord, Lead Acid Clip, No Connector	ZA5350-B-ND◆	2.46	2.22	2.19
55	Panel Mount, Power Socket, Insert Lock	ZA2070-ND◆	3.63	3.24	2.93
	Panel Mount, Power Socket, Screw Lock	ZA2060-ND◆	2.81	2.51	2.27
56	Power Plug Splitter, One Male Plug-Two Receptacle Sockets with LED	ZA5018-ND	5.91	5.34	5.25

◆ RoHS Compliant

**"Budget Balancers" Battery Holders**

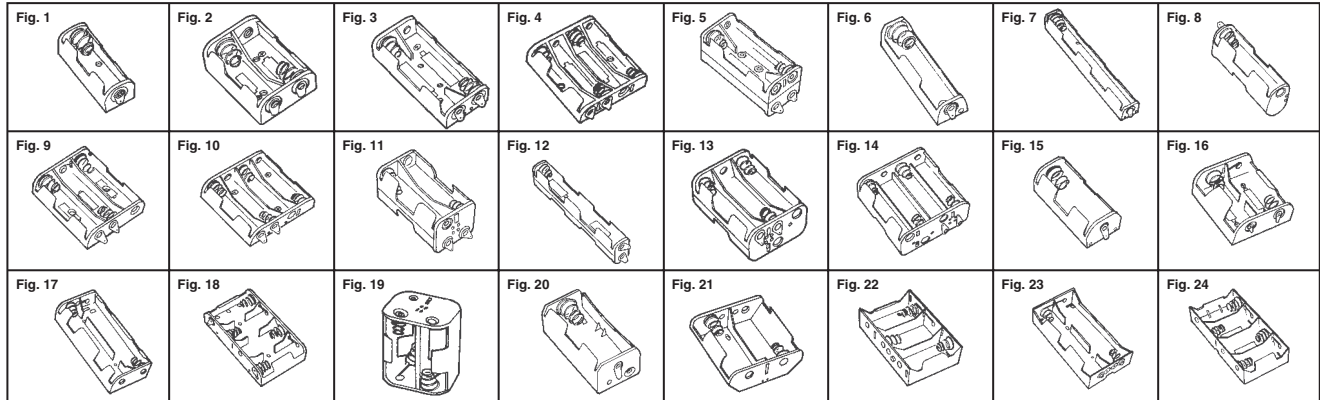


Fig.	No. of Cells	Description	Digi-Key Part No.	Price Each		
				1	10	100
<b>"N" Cell Holders — RoHS Compliant</b>						
1	1	Solder Tabs	BHNL-ND	.55	.50	.46
2	2	Solder Tabs	BH2NL-ND	.59	.54	.50
<b>"AA" Cell Holders</b>						
3	2	Solder Tabs	BC2AAAL-ND◆	.59	.54	.50
4	4	Solder Tabs	BC4AAAL-ND	1.41	1.27	1.18
5	4	Solder Tabs	BH24AAAL-ND	.96	.87	.80
3	2	6" Wire Leads	BC2AAAW-ND†	.67	.60	.56
4	4	6" Wire Leads	BC4AAAW-ND†	1.44	1.30	1.20
5	4	6" Wire Leads	BH24AAAW-ND†	.98	.89	.82
<b>"AA" Cell Holders</b>						
6	1	Solder Tabs	BCAAL-ND◆	.54	.49	.46
7	2	Solder Tabs	BC12AAL-ND◆	.57	.52	.48

Fig.	No. of Cells	Description	Digi-Key Part No.	Price Each		
				1	10	100
8	2	Solder Tabs	BC22AAL-ND◆	.55	.50	.46
9	3	Solder Tabs	BC3AAL-ND◆	.90	.82	.76
10	4	Solder Tabs	BC4AAL-ND◆	.99	.89	.82
11	4	Solder Tabs	BH24AAL-ND◆	.82	.75	.69
12	4	Solder Tabs	BH14AAL-ND◆	.69	.62	.58
13	6	Solder Tabs	BH26AAL-ND◆	1.18	1.06	.98
14	8	Solder Tabs	BH48AAL-ND	1.41	1.27	1.18
8	2	6" Wire Leads	BC2AAW-ND†	.57	.52	.48
9	3	6" Wire Leads	BC3AAW-ND†	.94	.85	.78
10	4	6" Wire Leads	BC4AAW-ND†	.98	.89	.82
11	4	6" Wire Leads	BH24AAW-ND†	.90	.82	.76
12	4	6" Wire Leads	BH14AAW-ND†	.77	.70	.64
13	6	6" Wire Leads	BH26AAW-ND†	1.21	1.10	1.02
14	8	6" Wire Leads	BH48AAW-ND†	1.44	1.30	1.20

Fig.	No. of Cells	Description	Digi-Key Part No.	Price Each		
				1	10	100
<b>"C" Cell Holders — RoHS Compliant</b>						
15	1	Solder Tabs	BHCL-ND	.63	.57	.52
16	2	Solder Tabs	BH2CL-ND	1.21	1.10	1.01
17	4	Solder Tabs	BH24CL-ND	1.35	1.22	1.13
18	4	Solder Tabs	BH4CL-ND	1.58	1.43	1.32
19	4	Solder Tabs	BH24CL-ND	1.70	1.54	1.42
<b>"D" Cell Holders — RoHS Compliant</b>						
20	1	Solder Tabs	BHDL-ND	.71	.65	.60
21	2	Solder Tabs	BH2DL-ND	1.35	1.22	1.13
22	3	Solder Tabs	BH3DL-ND	1.66	1.50	1.38
23	4	Solder Tabs	BH24DL-ND	1.66	1.50	1.38
24	4	Solder Tabs	BH4DL-ND	2.07	1.87	1.73

◆ RoHS Compliant † Stripped-Tinned 3/16" (4.78mm)

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

**More Product Available Online: [www.digikey.com](http://www.digikey.com)**

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

(T091) 2347