

Fig.	Description	Digi-Key Part No.	Price Each		
			1	10	100
<b>"N" Aluminum Cell Holders</b>					
1	1 Cell	154K-ND	2.10	1.95	1.66
2	2 Cell	155K-ND	4.32	4.02	3.52
3	3 Cell	156K-ND	9.00	8.36	7.29
<b>"AAA" Aluminum Cell Holders</b>					
1	1 Cell	137K-ND	2.37	2.20	2.16
2	2 Cell	138K-ND	4.52	4.21	3.92
3	3 Cell	169K-ND	6.62	6.15	5.51
4	4 Cell	170K-ND	9.07	8.42	7.34
<b>"AAA" Plastic Cell Holders - PC Mount — RoHS Compliant</b>					
5	1 Cell	2466K-ND	1.20	1.14	1.09
6	2 Cell	2468K-ND	1.26	1.19	1.14
7	3 Cell	2479K-ND	1.68	1.58	1.52
8	4 Cell	2481K-ND	1.84	1.74	1.67
<b>"AAA" Plastic Cell Holders - 6" Wire Leads — RoHS Compliant</b>					
5	1 Cell	2467K-ND	1.20	1.14	1.09
6	2 Cell	2469K-ND	1.26	1.19	1.14
7	3 Cell	2480K-ND	1.68	1.58	1.52
8	4 Cell	2482K-ND	1.84	1.74	1.67
<b>"AA" Aluminum Cell Holders</b>					
1	1 Cell	139K-ND	1.66	1.55	1.40
2	2 Cell	140K-ND	3.10	2.87	2.65
2	2 Cell	146K-ND	3.64	3.33	3.03
3	3 Cell	171K-ND	5.31	4.94	4.34
4	4 Cell	182K-ND	7.54	7.00	6.17
9	2 Cell	189K-ND	2.81	2.62	2.43
10	4 Cell	192K-ND	5.11	4.75	4.16
11	1 Cell	222K-ND	2.08	1.93	1.81
12	2 Cell	2223K-ND	3.30	3.05	3.03
<b>"AA" Plastic Cell Holders - PC Mount — RoHS Compliant</b>					
15	1 Cell	2460K-ND	1.20	1.14	1.09
16	2 Cell	2462K-ND	1.26	1.19	1.14
17	3 Cell	2464K-ND	1.68	1.58	1.52
18	4 Cell	2477K-ND	1.84	1.74	1.67
<b>"AA" Plastic Cell Holders - 6" Wire Leads — RoHS Compliant</b>					
15	1 Cell	2461K-ND	1.20	1.14	1.09
16	2 Cell	2463K-ND	1.26	1.19	1.14
17	3 Cell	2465K-ND	1.68	1.58	1.52
18	4 Cell	2478K-ND	1.84	1.74	1.67
<b>"AA" Plastic Cell Holders - with Snap-On Connector — RoHS Compliant</b>					
19	2 Cell	2474K-ND	1.26	1.19	1.14
20	3 Cell	2475K-ND	1.68	1.58	1.52
21	4 Cell	2476K-ND	1.84	1.74	1.67
<b>Cell Lithium - Plastic Holders - PC Mount — RoHS Compliant</b>					
22B	1/2 AA	108KK-ND	1.60	1.49	1.32
22B	AA	1028K-ND	1.60	1.49	1.32
22B	2/3 A	1029K-ND	1.60	1.49	1.32
<b>Lithium - Plastic Retaining Cover — RoHS Compliant</b>					
22A	1/2 AA	108CK-ND	.64	.59	.57
22A	AA	1028CK-ND	.76	.72	.69
23	2/3 A	1029CK-ND	.72	.68	.66
<b>"C" Aluminum Cell Holders†</b>					
1	1 Cell	173K-ND	2.03	1.89	1.63
2	2 Cell	174K-ND	3.29	3.04	2.86

Fig.	Description	Digi-Key Part No.	Price Each		
			1	10	100
3	3 Cell	187K-ND	8.01	7.44	6.93
9	2 Cell	185K-ND	2.89	2.67	2.51
10	4 Cell	196K-ND	5.94	5.52	5.15
10	4 Cell	151K-ND	6.26	5.73	5.42
11	1 Cell	2224K-ND	2.13	1.98	1.69
12	2 Cell	2225K-ND	3.53	3.26	3.20
<b>"C" Steel Cell Holders† — RoHS Compliant</b>					
13	1 Cell	2173K-ND	2.80	2.56	2.33
<b>"D" Aluminum Cell Holders†</b>					
1	1 Cell	175K-ND	2.18	2.02	1.84
2	2 Cell	176K-ND	3.84	3.55	3.41
3	3 Cell	190-ND	9.10	8.45	7.47
9	2 Cell	186K-ND	3.29	3.04	2.86
10	4 Cell	200K-ND	7.18	6.67	6.21
11	1 Cell	2226K-ND	2.73	2.53	2.33
12	2 Cell	2227K-ND	4.65	4.32	3.84
<b>"D" Steel Cell Holders† — RoHS Compliant</b>					
14	1 Cell	2175K-ND	3.41	3.12	2.68
<b>12mm Coin Cell Lithium "PC" Holders — RoHS Compliant</b>					
24	1 Cell	500K-ND	1.32	1.16	.95
25	2 Cell	501K-ND	2.08	1.94	1.71
<b>16mm Coin Cell Lithium "PC" Holders — RoHS Compliant</b>					
24	1 Cell	502KE-ND	1.64	1.53	1.34
<b>20mm Coin Cell Lithium "PC" Holders — RoHS Compliant</b>					
24	1 Cell	106K-ND	1.64	1.53	1.34
24	1 Cell	103K-ND	1.64	1.53	1.34
25	2 Cell	1026K-ND	1.80	1.68	1.48
<b>23mm Coin Cell Lithium "PC" Holders — RoHS Compliant</b>					
24	1 Cell	107K-ND	1.64	1.53	1.34
24	1 Cell	104K-ND	1.64	1.50	1.34
25	2 Cell	1027K-ND	1.80	1.68	1.48
<b>24mm Coin Cell Lithium "PC" Holders — RoHS Compliant</b>					
24	1 Cell	105K-ND	1.64	1.53	1.34
24	1 Cell	1025-7K-ND	1.80	1.68	1.48
25	2 Cell	1025K-ND	1.80	1.68	1.48
<b>20mm Coin Cell Holder — RoHS Compliant</b>					
26	1 Cell	1066K-ND	1.64	1.53	1.34
<b>Vertical 20mm Coin Cell Holder — RoHS Compliant</b>					
27	1 Cell	1067K-ND	1.83	1.70	1.49
28	1 Cell	1065K-ND	1.83	1.70	1.49
<b>Surface Mount Coin Cell Retainer Contacts — RoHS Compliant</b>					
29	12mm	3000K-ND	.57	.50	.41
29	20mm	3002K-ND	.58	.51	.42
29	23mm	3004K-ND	.59	.52	.43
29	24mm	3006K-ND	.64	.56	.47
<b>Surface Mount Coin Cell Retainer Contacts - Cut Tape — RoHS Compliant</b>					
29	1 Cell, 20mm	3002KCT-ND	.72	.42	.37
29	1 Cell, 24mm	3006KCT-ND	1.09	1.00	.94
<b>Surface Mount Coin Cell Retainer Contacts - Tape &amp; Reel — RoHS Compliant</b>					
29	1 Cell, 20mm	3002KTR-ND	218.00/500		
29	1 Cell, 24mm	3006KTR-ND	356.00/400		
<b>Thru Hole Mount Coin Cell Retainer Contacts — RoHS Compliant</b>					
30	12mm	3001K-ND	.57	.50	.41
30	20mm	3003K-ND	.58	.51	.42

♦ RoHS Compliant † "C" and "D" cell holders are dual clips only ‡ Figs. 36, 38, 48 and 49 sold by the pair (Continued)

More Product Available Online: [www.digikey.com](http://www.digikey.com)

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

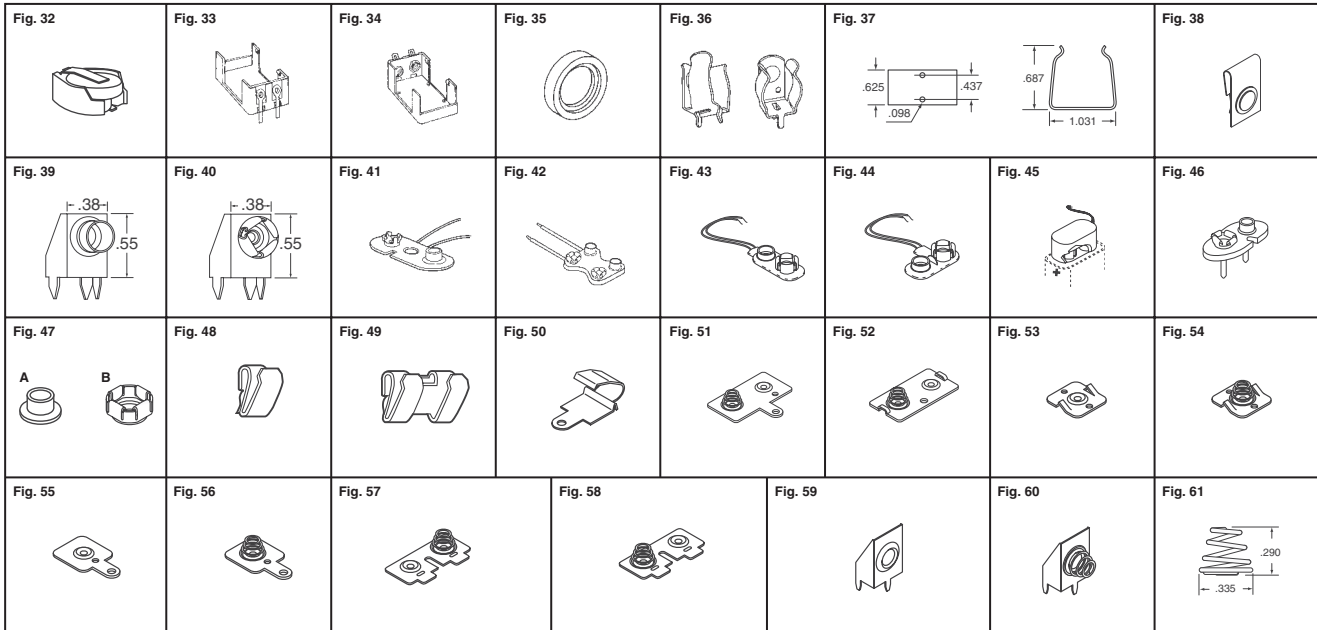


Fig.	Description	Digi-Key Part No.	Price Each		
			1	10	100
30	23mm	3005K-ND	.59	.52	.43
30	23mm	3011K-ND	.62	.55	.32
30	24mm	3007K-ND	.64	.56	.47
30	24mm	3009K-ND	.59	.54	.50
<b>Surface Mount Coin Cell Holder - Bulk — RoHS Compliant</b>					
31	1 Cell, 20mm	1060K-ND	1.64	1.53	1.34
32	1 Cell, 20mm	1061K-ND	2.05	1.89	1.80
32	2 Cell, 20mm	1062K-ND	2.05	1.89	1.80
32	1 Cell, 23mm	1071K-ND	2.05	1.89	1.80
<b>Surface Mount Coin Cell Holder - Cut Tape — RoHS Compliant</b>					
29	1 Cell, 12mm	3000KCT-ND	.74	.68	.64
<b>Surface Mount Coin Cell Holder - Tape &amp; Reel — RoHS Compliant</b>					
29	1 Cell, 12mm	3000KTR-ND	339.60/1000		
31	1 Cell, 20mm	1060KTR-ND	564.75/500		
32	1 Cell, 20mm	1061KTR-ND	422.10/200		
32	2 Cell, 20mm	1062KTR-ND	422.10/200		
32	1 Cell, 23mm	1071KTR-ND	422.10/200		
<b>9 Volt Plastic Holders — RoHS Compliant</b>					
33	1 Cell	1294K-ND	1.87	1.74	1.52
34	1 Cell	1295K-ND	1.80	1.68	1.49
<b>9 Volt Aluminum Holders — RoHS Compliant</b>					
33	1 Cell	1291K-ND	2.95	2.71	2.39
34	1 Cell	1290K-ND	2.82	2.58	2.33
<b>Insulating Polarizing Washers</b>					
35	Red	59K-ND	—	.12	.09
35	Black	60K-ND	—	.12	.09
<b>“AAA” Snap-In PC Battery Clip — RoHS Compliant</b>					
36	—	82K-ND	.67/2	.32	.24
<b>“AA” Snap-In PC Battery Clip — RoHS Compliant</b>					
36	1 Cell	92K-ND	.67/2	.32	.24
<b>“AAA”, “N” Surface Mount Battery Clip - Cut Tape — RoHS Compliant</b>					
36	1 Cell	55KCT-ND	.66	.38	.34
<b>“AAA”, “N” Surface Mount Battery Clip - Tape &amp; Reel — RoHS Compliant</b>					
36	1 Cell	55KTR-ND	161.40/300		
<b>“9V” Steel Battery Clip — RoHS Compliant</b>					
37	Single	71K-ND	.37	.35	.34
<b>“AAA”, “AAAA”, “N” Snap-IN Battery Contact — RoHS Compliant</b>					
38	—	238K-ND	.36/2	.17	.16
<b>9 Volt “PC” Snap-On Battery (on board battery mount) — RoHS Compliant</b>					
39	Male	593K-ND	.49	.46	.35
40	Female	594K-ND	.55	.49	.42
<b>9 Volt Battery Straps — RoHS Compliant</b>					
41	Single	72K-ND	1.30	1.21	1.12
42	Dual	227K-ND	2.86	2.64	2.48
<b>Premium 9 Volt Battery Straps (I-Style) — RoHS Compliant</b>					
43	Single, 4"	2238K-ND	.92	.87	.82
43	Single, 6"	2239K-ND	.94	.89	.84
43	Single, 6.5"	83K-ND	1.89	1.73	1.64
43	Single, 8"	2240K-ND	.96	.90	.86
<b>Premium 9 Volt Battery Straps (T-Style) — RoHS Compliant</b>					
44	Single, 4"	2241K-ND	.96	.91	.87
44	Single, 6"	2242K-ND	.98	.93	.89
44	Single, 8"	2243K-ND	1.00	.95	.90

Fig.	Description	Digi-Key Part No.	Price Each		
			1	10	100
<b>Economy 9 Volt Battery Straps (I-Style) — RoHS Compliant</b>					
43	Single, 4"	232K-ND	.47	.44	.42
43	Single, 6"	233K-ND	.48	.45	.44
43	Single, 8"	234K-ND	.49	.46	.44
<b>Economy 9 Volt Battery Straps (T-Style) — RoHS Compliant</b>					
44	Single, 4"	235K-ND	.51	.48	.46
44	Single, 6"	236K-ND	.52	.49	.47
44	Single, 8"	237K-ND	.53	.50	.48
<b>Shielded 9 Volt Battery Straps (I-Style) — RoHS Compliant</b>					
45	Single, 4"	84-4K-ND	.55	.52	.50
45	Single, 6"	84-6K-ND	.57	.54	.52
45	Single, 8"	84-8K-ND	.58	.55	.52
<b>Shielded 9 Volt Battery Straps (T-Style) — RoHS Compliant</b>					
45	Single, 4"	81-4K-ND	.55	.52	.50
45	Single, 6"	81-6K-ND	.57	.54	.52
45	Single, 8"	81-8K-ND	.58	.55	.52
<b>Vertical “9V” PC Snap-On Connector — RoHS Compliant</b>					
46	—	968K-ND	1.01	.95	.90
<b>“9V” Battery Snap-Ons — RoHS Compliant</b>					
47A	Stud	261K-ND	.11	.10	.09
47B	Socket	269K-ND	.24	.23	.22
<b>Single “AA” Cell Contacts — RoHS Compliant</b>					
48	—	209K-ND	.52/2	.25	.24
<b>Dual “AA” Cell Contacts — RoHS Compliant</b>					
49	—	210K-ND	.79/2	.37	.35
<b>“A”, “AA”, “9V” Surface Mount Cell Contacts - Cut Tape — RoHS Compliant</b>					
48	—	5231KCT-ND	.67	.62	.58
<b>“A”, “AA”, “9V” Surface Mount Cell Contacts - Tape &amp; Reel — RoHS Compliant</b>					
48	—	5231KTR-ND	132.75/250		
<b>“AAA” Snap-On Contacts — RoHS Compliant</b>					
48	—	204K-ND	.52/2	.25	.24
49	—	202K-ND	.79/2	.37	.35
<b>“A”, “AA”, “9V” Spring Contacts — RoHS Compliant</b>					
50	—	5209K-ND	—	.51	.49
<b>“A”, “AA” Battery Contacts — RoHS Compliant</b>					
51	Dual w/tabs	5211K-ND	—	.36	.34
52	Dual	5212K-ND	—	.44	.42
53	(+) Button	5224K-ND	—	.14	.13
54	(-) Spring	5202K-ND	—	.27	.26
55	(+) Button with tabs	5223K-ND	—	.14	.13
56	(-) Spring with tabs	5201K-ND	—	.23	.22
<b>“AAA”, “AAAA”, “N” Battery Contacts — RoHS Compliant</b>					
53	(+) Button	5225K-ND	—	.10	.09
54	(-) Spring	5203K-ND	—	.36	.34
55	(+) Button with tabs	5226K-ND	—	.14	.13
56	(-) Spring with tabs	5204K-ND	—	.23	.22
57	Dual Left Side	5214K-ND	—	.32	.31
58	Dual Right Side	5213K-ND	—	.32	.31
<b>“A”, “AA”, “C”, “D” Battery Contacts — RoHS Compliant</b>					
61	Spring	211K-ND	.11	.10	.09
<b>“A” PC Contacts — RoHS Compliant</b>					
59	(+) Button	595K-ND	—	.18	.17
60	(-) Spring	628K-ND	—	.81	.70
<b>“AA”, “AAA”, “N” PC Contacts — RoHS Compliant</b>					
59	(+) Button	637K-ND	—	.17	.16
60	(-) Spring	629K-ND	—	.81	.70

♦ RoHS Compliant † “C” and “D” cell holders are dual clips only ‡ Figs. 36, 38, 48 and 49 sold by the pair