



## Rugged Stainless Steel Pressure Transducers Featuring Microfused Technology (Cont.)

Operating Pressure Range PSIG	Voltage Supply (VDC)	Digi-Key Part No.	Price Each		Measurement Specialties Part No.
			1	10	
500 1000	10 - 32	MSP3501P5A1-ND◆ MSP3102P5A1-ND	109.38 109.38	93.75 93.75	2000263 2000049
<b>MSP-340 Series — RoHS Compliant</b>					
<b>100mV Output — 1/8" NPT, 2 Foot Cable</b>					
100 300 500 1000	5	MSP6892-ND MSP6893-ND MSP6894-ND MSP6895-ND	96.16 96.16 96.16 96.16	80.57 80.57 80.57 80.57	M3421-000006-100PG M3421-000006-300PG M3421-000006-500PG M3421-000006-01KPG
<b>0.5V - 4.5V Output — 1/8" NPT, 2 Foot Cable</b>					
100 300 500 1000	5	MSP6896-ND MSP6897-ND MSP6898-ND MSP6899-ND	112.39 112.39 112.39 112.39	94.17 94.17 94.17 94.17	M3431-000006-100PG M3431-000006-300PG M3431-000006-500PG M3431-000006-01KPG
<b>MSP-400 Series — RoHS Compliant</b>					
<b>1V - 5V Output — Fixed 3 Wire Supply Current 10mA maximum 1/4" NPT, 2 Foot Cable</b>					
5000	10 - 32	MSP4502P3-ND	94.50	81.00	2000455
<b>4mA - 20mA Output — 2 Wire Regulated Supply 1/4" NPT, 2 Foot Cable</b>					
1000 5000	10 - 32	MSP4102P4-ND MSP4502P4-ND	108.50 108.50	93.00 93.00	2000417 2000457
<b>MSP-600 Series — RoHS Compliant</b>					
<b>0.5VDC - 4.5VDC Output — 7/16" SAE, Packard Connector</b>					
25 50 75 100 500 1000	5	MSP602P3-4-ND MSP605P3-4-ND MSP607P3-4-ND MSP6101P3-4-ND MSP6501P3-4-ND MSP6102P3-4-ND	96.25 96.25 96.25 96.25 96.25 96.25	82.50 82.50 82.50 82.50 82.50 82.50	2000964 2000965 2000966 2000967 2000969 2000970
<b>1VDC - 5VDC Output — 1/4" NPT, 2 Foot Cable</b>					
75	10 - 30	MSP607P4-1-ND	101.50	87.00	2000884
<b>4mA - 20mA Output — 1/4" NPT, 2 Foot Cable</b>					
50 75 2500	10 - 30	MSP605P5-1-ND MSP607P5-1-ND MSP6252P5-1-ND	119.00 119.00 119.00	102.00 102.00 102.00	2000879 2000885 2000915
<b>MSP-610 Series — RoHS Compliant</b>					
<b>0.5V - 4.5V Output — 1/8" NPT, 2 Foot Cable</b>					
300 500	5	MSP6906-ND MSP6907-ND	114.19 114.19	97.88 97.88	M6131-C00006-300PG M6131-C00006-500PG
<b>0.5V - 4.5V Output — 1/4" NPT, 2 Foot Cable</b>					
100 500	5	MSP6903-ND MSP6905-ND	114.19 114.19	97.88 97.88	M6131-C00005-100PG M6131-C00005-500PG
<b>1V - 5V Output — 1/4" NPT, 2 Foot Cable</b>					
300 500	8 - 30	MSP6909-ND MSP6910-ND	119.00 119.00	102.00 102.00	M6141-C00005-300PG M6141-C00005-500PG
<b>4mA - 20mA Output — 1/4" NPT, 2 Foot Cable</b>					
100 300 500	10 - 30	MSP6911-ND MSP6912-ND MSP6913-ND	135.63 135.63 135.63	116.25 116.25 116.25	M6181-C00005-100PG M6181-C00005-300PG M6181-C00005-500PG
<b>UltraStable 5100 Series — RoHS Compliant</b>					
<b>0.5V - 4.5V Ratiometric Output — 1/4" NPT, Absolute Pressure, 2 Foot Cable</b>					
15PSIA 30PSIA 100PSIA	4.75 - 5.25	223-1000-ND 223-1002-ND 223-1004-ND	175.00 175.00 175.00	150.00 150.00 150.00	U5131-000005-015PA U5131-000005-030PA U5131-000005-100PA
<b>4mA - 20mA Output — 1/4" NPT, Absolute Pressure, 2 Foot Cable</b>					
15PSIA 30PSIA 100PSIA	9 - 30	223-1007-ND 223-1009-ND 223-1011-ND	211.41 211.41 211.41	179.38 179.38 179.38	U5151-000005-015PA U5151-000005-030PA U5151-000005-100PA
<b>0.5V - 4.5V Ratiometric Output — 1/4" NPT, 2 Foot Cable</b>					
15 30 100 500	4.75 - 5.25	223-1001-ND 223-1003-ND 223-1005-ND 223-1006-ND	175.00 175.00 175.00 175.00	150.00 150.00 150.00 150.00	U5131-000005-015PG U5131-000005-030PG U5131-000005-100PG U5131-000005-500PG

Operating Pressure Range PSIG	Voltage Supply (VDC)	Digi-Key Part No.	Price Each		Measurement Specialties Part No.
			1	10	
<b>4mA - 20mA Output — 1/4" NPT, 2 Foot Cable</b>					
15 30 100 500	9 - 30	223-1008-ND 223-1010-ND 223-1012-ND 223-1013-ND	211.41 211.41 211.41 211.41	179.38 179.38 179.38 179.38	U5151-000005-015PG U5151-000005-030PG U5151-000005-100PG U5151-000005-500PG
<b>M5100 Series — RoHS Compliant</b>					
<b>0.5V - 4.5V Ratiometric Output — 1/4" NPT, 2 Foot Cable</b>					
50 75 100 250 500	4.75 - 5.25	223-1038-ND 223-1041-ND 223-1020-ND 223-1026-ND 223-1032-ND	114.84 114.84 114.84 114.84 114.85	98.44 98.44 98.44 98.44 98.45	M5131-000005-050PG M5131-000005-075PG M5131-000005-100PG M5131-000005-250PG M5131-000005-500PG
1000 2500 5000 10000	4.75 - 5.25	223-1014-ND 223-1029-ND 223-1017-ND 223-1023-ND	114.84 114.84 114.84 114.84	98.44 98.44 98.44 98.44	M5131-000005-01KPG M5131-000005-2K5PG M5131-000005-05KPG M5131-000005-10KPG
<b>1V - 5V Output — 1/4" NPT, 2 Foot Cable</b>					
50 75 100 250 500	8 - 30	223-1039-ND 223-1042-ND 223-1021-ND 223-1027-ND 223-1033-ND	120.31 120.31 120.31 120.31 120.31	103.13 103.13 103.13 103.13 103.13	M5141-000005-050PG M5141-000005-075PG M5141-000005-100PG M5141-000005-250PG M5141-000005-500PG
1000 2500 5000 10000	8 - 30	223-1015-ND 223-1030-ND 223-1018-ND 223-1024-ND	120.31 120.31 120.31 120.31	103.13 103.13 103.13 103.13	M5141-000005-01KPG M5141-000005-2K5PG M5141-000005-05KPG M5141-000005-10KPG
<b>4mA - 20mA Output — 1/4" NPT, 2 Foot Cable</b>					
50 75 100 250 500	9 - 30	223-1040-ND 223-1043-ND 223-1022-ND 223-1028-ND 223-1034-ND	125.78 125.78 125.78 125.78 125.78	107.82 107.82 107.82 107.82 107.82	M5151-000005-050PG M5151-000005-075PG M5151-000005-100PG M5151-000005-250PG M5151-000005-500PG
1000 2500 5000 10000	9 - 30	223-1016-ND 223-1031-ND 223-1019-ND 223-1025-ND	125.78 125.78 125.78 125.78	107.82 107.82 107.82 107.82	M5151-000005-01KPG M5151-000005-2K5PG M5151-000005-05KPG M5151-000005-10KPG
<b>0.5V - 4.5V Ratiometric Output — 7/16" UNF Male, O-Ring, Packard Connector</b>					
50 75 100 250 500	4.75 - 5.25	223-1045-ND 223-1046-ND 223-1047-ND 223-1048-ND 223-1049-ND	114.84 114.84 114.84 114.84 114.84	98.44 98.44 98.44 98.44 98.44	M5134-000004-050PG M5134-000004-075PG M5134-000004-100PG M5134-000004-250PG M5134-000004-500PG
1000 2500 5000 7500 10000	4.75 - 5.25	223-1050-ND 223-1051-ND 223-1052-ND 223-1074-ND 223-1053-ND	114.84 114.84 114.84 114.84 114.84	98.44 98.44 98.44 98.44 98.44	M5134-000004-01KPG M5134-000004-2K5PG M5134-000004-05KPG M5134-000004-7K5PG M5134-000004-10KPG
<b>1V - 5V Output — 7/16" UNF Male, O-Ring, Packard Connector</b>					
50 75 100 250 500	8 - 30	223-1055-ND 223-1056-ND 223-1057-ND 223-1058-ND 223-1059-ND	120.31 120.31 120.31 120.31 120.31	103.13 103.13 103.13 103.13 103.13	M5144-000004-050PG M5144-000004-075PG M5144-000004-100PG M5144-000004-250PG M5144-000004-500PG
1000 2500 5000 7500 10000	8 - 30	223-1060-ND 223-1061-ND 223-1062-ND 223-1075-ND 223-1063-ND	120.31 120.31 120.31 120.31 120.31	103.13 103.13 103.13 103.13 103.13	M5144-000004-01KPG M5144-000004-2K5PG M5144-000004-05KPG M5144-000004-7K5PG M5144-000004-10KPG
<b>4mA - 20mA Output — 7/16" UNF Male, O-Ring, Packard Connector</b>					
50 75 100 250 500	9 - 30	223-1065-ND 223-1066-ND 223-1067-ND 223-1068-ND 223-1069-ND	125.78 125.78 125.78 125.78 125.78	107.82 107.82 107.82 107.82 107.82	M5154-000004-050PG M5154-000004-075PG M5154-000004-100PG M5154-000004-250PG M5154-000004-500PG
1000 2500 5000 7500 10000	9 - 30	223-1070-ND 223-1071-ND 223-1072-ND 223-1076-ND 223-1073-ND	125.78 125.78 125.78 125.78 125.78	107.82 107.82 107.82 107.82 107.82	M5154-000004-01KPG M5154-000004-2K5PG M5154-000004-05KPG M5154-000004-7K5PG M5154-000004-10KPG

◆ RoHS Compliant




## Cable Harnesses

Pre-made Cable Harnesses from SSI Technology with the industry standard Packard™ Automotive Connector.



Description	Length Inch	Digi-Key Part No.	Price Each			SSI Technologies Part No.
			1	10	25	
Cable Harness Packard	12	734-1163-ND	11.66	10.43	9.78	P2432.3
Cable Harness Packard	36	734-1164-ND	20.90	20.05	18.14	P2435.3
Cable Harness Packard	72	734-1165-ND	26.43	25.44	23.23	14306.3

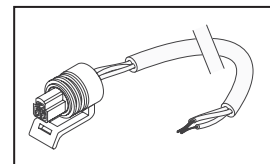

N

More Product Available Online: [www.digkey.com](http://www.digkey.com)

Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

(T091) 2501