





AMP Ribbon Cable Dip Plugs

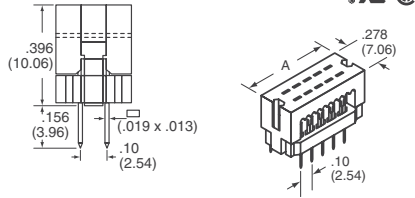

Material and Finish:
 • Plastic Shell: Housing, Cover and Strain Relief — Black thermo-plastic, UL 94V-0 rated • Tin Finish: Contacts — Phosphor bronze
 • Centerline — .100 x .100

No. of Cont.	Contact Finish	Dimension A Inch (mm)	Digi-Key Part No.	Pricing		AMP Part No.
				1	10	
10	Tin	.680 (17.27)	ADM10S-ND	1.79	8.51	2-746610-1
14		.880 (22.35)	ADM14S-ND	2.05	9.73	2-746610-2
16		.980 (24.89)	ADM16S-ND	2.38	11.29	1-746610-4
20		1.180 (29.97)	ADM20S-ND	2.73	12.93	1-746610-5
24		1.380 (35.05)	ADM24S-ND	3.04	14.41	2-746610-3
26	Tin	1.480 (37.59)	ADM26S-ND	3.28	15.57	1-746610-6
30		1.680 (42.67)	ADM30S-ND	3.69	17.52	1-746610-7
34		1.880 (47.75)	ADM34S-ND	3.94	18.69	1-746610-8
40		2.180 (55.37)	ADM40S-ND	4.43	21.03	1-746610-9
44		2.380 (60.45)	ADM44S-ND	5.72	27.12	2-746610-6
50		2.680 (68.07)	ADM50S-ND	5.17	24.53	2-746610-0
60		3.180 (80.77)	ADM60S-ND	4.71	22.36	2-746610-4
64		3.380 (85.85)	ADM64S-ND	6.73	31.94	2-746610-5

AMP Dip Plug Cable Assemblies

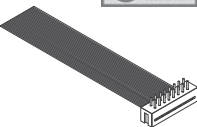

Single Ended — Style 2


* MC = Multi-Color
GR = Gray

No. of Cont.	Conn. Finish	Length Inch (cm)	Ribbon* Cable	Digi-Key Part No.	Pricing	
					1	10
10	Tin	6 (15.24)	MC	A2MXS-1006M-ND	2.25	18.29
		6 (15.24)	GR	A2MXS-1006G-ND	1.94	15.77
		18 (45.72)	MC	A2MXS-1018M-ND	3.15	25.67
		18 (45.72)	GR	A2MXS-1018G-ND	2.22	18.09
		36 (91.44)	MC	A2MXS-1036M-ND	4.51	36.73
36 (91.44)	GR	A2MXS-1036G-ND	2.65	21.57		
14	Tin	6 (15.24)	MC	A2MXS-1406M-ND	2.73	22.24
		6 (15.24)	GR	A2MXS-1406G-ND	2.25	18.34
		18 (45.72)	MC	A2MXS-1418M-ND	4.09	33.30
		18 (45.72)	GR	A2MXS-1418G-ND	2.65	21.59
		36 (91.44)	MC	A2MXS-1436M-ND	6.13	49.89
36 (91.44)	GR	A2MXS-1436G-ND	3.25	26.47		
16	Tin	6 (15.24)	MC	A2MXS-1606M-ND	3.11	25.29
		6 (15.24)	GR	A2MXS-1606G-ND	2.61	21.24
		18 (45.72)	MC	A2MXS-1618M-ND	4.55	37.08
		18 (45.72)	GR	A2MXS-1618G-ND	3.06	24.95
		36 (91.44)	MC	A2MXS-1636M-ND	6.73	54.78
36 (91.44)	GR	A2MXS-1636G-ND	3.75	30.52		
20	Tin	6 (15.24)	MC	A2MXS-2006M-ND	3.63	29.57
		6 (15.24)	GR	A2MXS-2006G-ND	3.05	24.83
		18 (45.72)	MC	A2MXS-2018M-ND	5.44	44.32
		18 (45.72)	GR	A2MXS-2018G-ND	3.69	30.09
		36 (91.44)	MC	A2MXS-2036M-ND	8.16	66.44
36 (91.44)	GR	A2MXS-2036G-ND	4.66	37.98		
24	Tin	6 (15.24)	MC	A2MXS-2406M-ND	4.17	33.95
		6 (15.24)	GR	A2MXS-2406G-ND	3.34	27.21
		18 (45.72)	MC	A2MXS-2418M-ND	6.43	52.39
		18 (45.72)	GR	A2MXS-2418G-ND	3.95	32.15
		36 (91.44)	MC	A2MXS-2436M-ND	9.83	80.04
36 (91.44)	GR	A2MXS-2436G-ND	4.86	39.58		
26	Tin	6 (15.24)	MC	A2MXS-2606M-ND	4.46	36.33
		6 (15.24)	GR	A2MXS-2606G-ND	3.68	29.98
		18 (45.72)	MC	A2MXS-2618M-ND	6.82	55.50
		18 (45.72)	GR	A2MXS-2618G-ND	4.48	36.47
		36 (91.44)	MC	A2MXS-2636M-ND	10.35	84.26
36 (91.44)	GR	A2MXS-2636G-ND	5.67	46.20		
6 (15.24)	GR	A2MXS-3406G-ND	4.37	35.59		
34	Tin	18 (45.72)	MC	A2MXS-3418M-ND	8.56	69.70
		18 (45.72)	GR	A2MXS-3418G-ND	5.23	42.60
		36 (91.44)	MC	A2MXS-3436M-ND	13.18	107.30
		36 (91.44)	GR	A2MXS-3436G-ND	6.52	53.11

No. of Cont.	Conn. Finish	Length Inch (cm)	Ribbon* Cable	Digi-Key Part No.	Pricing	
					1	10
40	Tin	6 (15.24)	MC	A2MXS-4006M-ND	6.24	50.85
		6 (15.24)	GR	A2MXS-4006G-ND	5.03	41.00
		18 (45.72)	MC	A2MXS-4018M-ND	9.87	80.34
		18 (45.72)	GR	A2MXS-4018G-ND	6.24	50.80
		36 (91.44)	MC	A2MXS-4036M-ND	15.30	124.59
36 (91.44)	GR	A2MXS-4036G-ND	8.04	65.50		
50	Tin	6 (15.24)	MC	A2MXS-5006M-ND	7.44	60.55
		6 (15.24)	GR	A2MXS-5006G-ND	5.80	47.27
		18 (45.72)	MC	A2MXS-5018M-ND	11.96	97.42
		18 (45.72)	GR	A2MXS-5018G-ND	7.07	57.57
		36 (91.44)	MC	A2MXS-5036M-ND	18.76	152.73
36 (91.44)	GR	A2MXS-5036G-ND	8.97	73.03		
60	Tin	6 (15.24)	MC	A2MXS-6006M-ND	7.43	60.50
		6 (15.24)	GR	A2MXS-6006G-ND	5.57	45.36
		18 (45.72)	MC	A2MXS-6018M-ND	12.86	104.75
		18 (45.72)	GR	A2MXS-6018G-ND	7.28	59.31
		36 (91.44)	MC	A2MXS-6036M-ND	21.01	171.11
36 (91.44)	GR	A2MXS-6036G-ND	9.85	80.24		
64	Tin	6 (15.24)	MC	A2MXS-6406M-ND	9.45	76.95
		6 (15.24)	GR	A2MXS-6406G-ND	7.59	61.81
		18 (45.72)	MC	A2MXS-6418M-ND	14.88	121.20
		18 (45.72)	GR	A2MXS-6418G-ND	9.30	75.76
		36 (91.44)	MC	A2MXS-6436M-ND	23.03	187.56
36 (91.44)	GR	A2MXS-6436G-ND	11.87	96.69		

Double Ended — Style 6

* MC = Multi-Color
GR = Gray

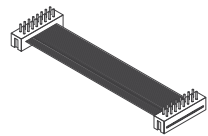

No. of Cont.	Conn. Finish	Length Inch (cm)	Ribbon* Cable	Digi-Key Part No.	Pricing	
					1	10
10	Tin	6 (15.24)	MC	A6MMS-1006M-ND	4.04	32.90
		6 (15.24)	GR	A6MMS-1006G-ND	3.73	30.37
		18 (45.72)	MC	A6MMS-1018M-ND	4.95	40.27
		18 (45.72)	GR	A6MMS-1018G-ND	4.01	32.69
		36 (91.44)	MC	A6MMS-1036M-ND	6.30	51.33
36 (91.44)	GR	A6MMS-1036G-ND	4.44	36.17		
14	Tin	6 (15.24)	MC	A6MMS-1406M-ND	4.78	38.96
		6 (15.24)	GR	A6MMS-1406G-ND	4.30	35.05
		18 (45.72)	MC	A6MMS-1418M-ND	6.14	50.02
		18 (45.72)	GR	A6MMS-1418G-ND	4.70	38.31
		36 (91.44)	MC	A6MMS-1436M-ND	8.18	66.61
36 (91.44)	GR	A6MMS-1436G-ND	5.30	43.19		
16	Tin	6 (15.24)	MC	A6MMS-1606M-ND	5.49	44.67
		6 (15.24)	GR	A6MMS-1606G-ND	4.99	40.63
		18 (45.72)	MC	A6MMS-1618M-ND	6.93	56.47
		18 (45.72)	GR	A6MMS-1618G-ND	5.45	44.34
		36 (91.44)	MC	A6MMS-1636M-ND	9.11	74.17
36 (91.44)	GR	A6MMS-1636G-ND	6.13	49.90		
20	Tin	6 (15.24)	MC	A6MMS-2006M-ND	6.36	51.77
		6 (15.24)	GR	A6MMS-2006G-ND	5.78	47.03
		18 (45.72)	MC	A6MMS-2018M-ND	8.17	66.52
		18 (45.72)	GR	A6MMS-2018G-ND	6.42	52.29
		36 (91.44)	MC	A6MMS-2036M-ND	10.89	88.64
36 (91.44)	GR	A6MMS-2036G-ND	7.39	60.18		
24	Tin	6 (15.24)	MC	A6MMS-2406M-ND	7.21	58.68
		6 (15.24)	GR	A6MMS-2406G-ND	6.38	51.94
		18 (45.72)	MC	A6MMS-2418M-ND	9.47	77.12
		18 (45.72)	GR	A6MMS-2418G-ND	6.99	56.89
		36 (91.44)	MC	A6MMS-2436M-ND	12.87	104.77
36 (91.44)	GR	A6MMS-2436G-ND	7.90	64.31		
26	Tin	6 (15.24)	MC	A6MMS-2606M-ND	7.74	63.06
		6 (15.24)	GR	A6MMS-2606G-ND	6.97	56.72
		18 (45.72)	MC	A6MMS-2618M-ND	10.10	82.24
		18 (45.72)	GR	A6MMS-2618G-ND	7.76	63.21
		36 (91.44)	MC	A6MMS-2636M-ND	13.63	111.00
36 (91.44)	GR	A6MMS-2636G-ND	8.96	72.94		
34	Tin	6 (15.24)	MC	A6MMS-3406M-ND	9.42	76.71
		6 (15.24)	GR	A6MMS-3406G-ND	8.31	67.68
		18 (45.72)	MC	A6MMS-3418M-ND	12.50	101.78
		18 (45.72)	GR	A6MMS-3418G-ND	9.17	74.69
		36 (91.44)	MC	A6MMS-3436M-ND	17.12	139.39
36 (91.44)	GR	A6MMS-3436G-ND	10.46	85.20		
40	Tin	6 (15.24)	MC	A6MMS-4006M-ND	10.68	86.94
		6 (15.24)	GR	A6MMS-4006G-ND	9.47	77.10
		18 (45.72)	MC	A6MMS-4018M-ND	14.30	116.44
		18 (45.72)	GR	A6MMS-4018G-ND	10.67	86.90
		36 (91.44)	MC	A6MMS-4036M-ND	19.73	160.69
36 (91.44)	GR	A6MMS-4036G-ND	12.48	101.59		
50	Tin	6 (15.24)	MC	A6MMS-5006M-ND	12.61	102.66
		6 (15.24)	GR	A6MMS-5006G-ND	10.98	89.38
		18 (45.72)	MC	A6MMS-5018M-ND	17.14	139.53
		18 (45.72)	GR	A6MMS-5018G-ND	12.24	99.69
		36 (91.44)	MC	A6MMS-5036M-ND	23.93	194.84
36 (91.44)	GR	A6MMS-5036G-ND	14.14	115.15		
60	Tin	6 (15.24)	MC	A6MMS-6006M-ND	12.14	98.89
		6 (15.24)	GR	A6MMS-6006G-ND	10.28	83.74
		18 (45.72)	MC	A6MMS-6018M-ND	17.58	143.13
		18 (45.72)	GR	A6MMS-6018G-ND	12.00	97.69
		36 (91.44)	MC	A6MMS-6036M-ND	25.73	209.50
36 (91.44)	GR	A6MMS-6036G-ND	14.57	118.82		
64	Tin	6 (15.24)	MC	A6MMS-6406M-ND	16.18	131.78
		6 (15.24)	GR	A6MMS-6406G-ND	14.32	116.64
		18 (45.72)	MC	A6MMS-6418M-ND	21.62	176.03
		18 (45.72)	GR	A6MMS-6418G-ND	16.04	130.59
		36 (91.44)	MC	A6MMS-6436M-ND	29.77	242.39
36 (91.44)	GR	A6MMS-6436G-ND	18.61	151.52		

No. of Cont.	Conn. Finish	Length Inch (cm)	Ribbon* Cable	Digi-Key Part No.	Pricing	
					1	10
60	Tin	18 (45.72)	MC	A6MMS-6018M-ND	17.58	143.13
		18 (45.72)	GR	A6MMS-6018G-ND	12.00	97.69
		36 (91.44)	MC	A6MMS-6036M-ND	25.73	209.50
		36 (91.44)	GR	A6MMS-6036G-ND	14.57	118.82
64	Tin	6 (15.24)	MC	A6MMS-6406M-ND	16.18	131.78
		6 (15.24)	GR	A6MMS-6406G-ND	14.32	116.64
		18 (45.72)	MC	A6MMS-6418M-ND	21.62	176.03
		18 (45.72)	GR	A6MMS-6418G-ND	16.04	130.59
36 (91.44)	MC					