



Dip Plugs .1" x .1" Assemblies

Single Ended Style 2 (Cont.)




No. of Contacts	Contact Finish	Length Inch (cm)	Rib-on-Cable	Digi-Key Part No.	Price Each 10
14	Tin	6 (15.24)	GR	H2MXS-1406G-ND	2.04 1.55
	Tin	6 (15.24)	MC	H2MXS-1406M-ND	2.46 1.87
	Gold	6 (15.24)	GR	H2MXH-1406G-ND	2.04 1.55
	Gold	6 (15.24)	MC	H2MXH-1406M-ND	2.46 1.87
14	Tin	18 (45.72)	GR	H2MXS-1418G-ND	2.39 1.82
	Tin	18 (45.72)	MC	H2MXS-1418M-ND	3.66 2.78
	Gold	18 (45.72)	GR	H2MXH-1418G-ND	2.39 1.82
	Gold	18 (45.72)	MC	H2MXH-1418M-ND	3.66 2.78
14	Tin	36 (91.44)	GR	H2MXS-1436G-ND	2.92 2.22
	Tin	36 (91.44)	MC	H2MXS-1436M-ND	5.47 4.15
	Gold	36 (91.44)	GR	H2MXH-1436G-ND	2.92 2.22
	Gold	36 (91.44)	MC	H2MXH-1436M-ND	5.47 4.15
16	Tin	6 (15.24)	GR	H2MXS-1606G-ND	2.06 1.57
	Tin	6 (15.24)	MC	H2MXS-1606M-ND	2.50 1.90
	Gold	6 (15.24)	GR	H2MXH-1606G-ND	2.06 1.57
	Gold	6 (15.24)	MC	H2MXH-1606M-ND	2.50 1.90
16	Tin	18 (45.72)	GR	H2MXS-1618G-ND	2.47 1.87
	Tin	18 (45.72)	MC	H2MXS-1618M-ND	3.79 2.87
	Gold	18 (45.72)	GR	H2MXH-1618G-ND	2.47 1.87
	Gold	18 (45.72)	MC	H2MXH-1618M-ND	3.79 2.87
16	Tin	36 (91.44)	GR	H2MXS-1636G-ND	3.07 2.33
	Tin	36 (91.44)	MC	H2MXS-1636M-ND	5.71 4.33
	Gold	36 (91.44)	GR	H2MXH-1636G-ND	3.07 2.33
	Gold	36 (91.44)	MC	H2MXH-1636M-ND	5.71 4.33
20	Tin	6 (15.24)	GR	H2MXS-2006G-ND	2.39 1.82
	Tin	6 (15.24)	MC	H2MXS-2006M-ND	2.91 2.21
	Gold	6 (15.24)	GR	H2MXH-2006G-ND	2.39 1.82
	Gold	6 (15.24)	MC	H2MXH-2006M-ND	2.91 2.21
20	Tin	18 (45.72)	GR	H2MXS-2018G-ND	2.97 2.25
	Tin	18 (45.72)	MC	H2MXS-2018M-ND	4.51 3.43
	Gold	18 (45.72)	GR	H2MXH-2018G-ND	2.97 2.25
	Gold	18 (45.72)	MC	H2MXH-2018M-ND	4.51 3.43
20	Tin	36 (91.44)	GR	H2MXS-2036G-ND	3.82 2.90
	Tin	36 (91.44)	MC	H2MXS-2036M-ND	6.92 5.25
	Gold	36 (91.44)	GR	H2MXH-2036G-ND	3.82 2.90
	Gold	36 (91.44)	MC	H2MXH-2036M-ND	6.92 5.25
24	Tin	6 (15.24)	GR	H2MXS-2406G-ND	3.00 2.28
	Tin	6 (15.24)	MC	H2MXS-2406M-ND	3.73 2.83
	Gold	6 (15.24)	GR	H2MXH-2406G-ND	3.00 2.28
	Gold	6 (15.24)	MC	H2MXH-2406M-ND	3.73 2.83
24	Tin	18 (45.72)	GR	H2MXS-2418G-ND	3.54 2.68
	Tin	18 (45.72)	MC	H2MXS-2418M-ND	5.74 4.35
	Gold	18 (45.72)	GR	H2MXH-2418G-ND	3.54 2.68
	Gold	18 (45.72)	MC	H2MXH-2418M-ND	5.74 4.35
24	Tin	36 (91.44)	GR	H2MXS-2436G-ND	4.34 3.30
	Tin	36 (91.44)	MC	H2MXS-2436M-ND	8.74 6.63
	Gold	36 (91.44)	GR	H2MXH-2436G-ND	4.34 3.30
	Gold	36 (91.44)	MC	H2MXH-2436M-ND	8.74 6.63
26	Tin	6 (15.24)	GR	H2MXS-2606G-ND	2.65 2.01
	Tin	6 (15.24)	MC	H2MXS-2606M-ND	3.34 2.53
	Gold	6 (15.24)	GR	H2MXH-2606G-ND	2.46 1.87
	Gold	6 (15.24)	MC	H2MXH-2606M-ND	3.15 2.39
26	Tin	18 (45.72)	GR	H2MXS-2618G-ND	3.35 2.55
	Tin	18 (45.72)	MC	H2MXS-2618M-ND	5.42 4.11
	Gold	18 (45.72)	GR	H2MXH-2618G-ND	3.17 2.40
	Gold	18 (45.72)	MC	H2MXH-2618M-ND	5.24 3.97
26	Tin	36 (91.44)	GR	H2MXS-2636G-ND	4.41 3.35
	Tin	36 (91.44)	MC	H2MXS-2636M-ND	8.55 6.49
	Gold	36 (91.44)	GR	H2MXH-2636G-ND	4.22 3.21
	Gold	36 (91.44)	MC	H2MXH-2636M-ND	8.36 6.35
30	Tin	6 (15.24)	GR	H2MXS-3006G-ND	3.06 2.32
	Tin	6 (15.24)	MC	H2MXS-3006M-ND	4.09 3.11
	Gold	6 (15.24)	GR	H2MXH-3006G-ND	3.06 2.32
	Gold	6 (15.24)	MC	H2MXH-3006M-ND	4.09 3.11
30	Tin	18 (45.72)	GR	H2MXS-3018G-ND	3.72 2.82
	Tin	18 (45.72)	MC	H2MXS-3018M-ND	6.82 5.17
	Gold	18 (45.72)	GR	H2MXH-3018G-ND	3.72 2.82
	Gold	18 (45.72)	MC	H2MXH-3018M-ND	6.82 5.17
30	Tin	36 (91.44)	GR	H2MXS-3036G-ND	4.71 3.58
	Tin	36 (91.44)	MC	H2MXS-3036M-ND	10.91 8.27
	Gold	36 (91.44)	GR	H2MXH-3036G-ND	4.71 3.58
	Gold	36 (91.44)	MC	H2MXH-3036M-ND	10.91 8.27
34	Tin	6 (15.24)	GR	H2MXS-3406G-ND	3.11 2.36
	Tin	6 (15.24)	MC	H2MXS-3406M-ND	4.09 3.11
	Gold	6 (15.24)	GR	H2MXH-3406G-ND	3.11 2.36
	Gold	6 (15.24)	MC	H2MXH-3406M-ND	4.09 3.11
34	Tin	18 (45.72)	GR	H2MXS-3418G-ND	3.87 2.94
	Tin	18 (45.72)	MC	H2MXS-3418M-ND	6.82 5.17
	Gold	18 (45.72)	GR	H2MXH-3418G-ND	3.87 2.94
	Gold	18 (45.72)	MC	H2MXH-3418M-ND	6.82 5.17
34	Tin	36 (91.44)	GR	H2MXS-3436G-ND	5.01 3.81
	Tin	36 (91.44)	MC	H2MXS-3436M-ND	10.91 8.27
	Gold	36 (91.44)	GR	H2MXH-3436G-ND	5.01 3.81
	Gold	36 (91.44)	MC	H2MXH-3436M-ND	10.91 8.27
40	Tin	6 (15.24)	GR	H2MXS-4006G-ND	4.07 3.09
	Tin	6 (15.24)	MC	H2MXS-4006M-ND	5.14 3.90
	Gold	6 (15.24)	GR	H2MXH-4006G-ND	3.26 2.48
	Gold	6 (15.24)	MC	H2MXH-4006M-ND	4.33 3.29
40	Tin	18 (45.72)	GR	H2MXS-4018G-ND	5.13 3.90
	Tin	18 (45.72)	MC	H2MXS-4018M-ND	8.35 6.33
	Gold	18 (45.72)	GR	H2MXH-4018G-ND	4.33 3.28
	Gold	18 (45.72)	MC	H2MXH-4018M-ND	7.54 5.72
40	Tin	36 (91.44)	GR	H2MXS-4036G-ND	6.73 5.11
	Tin	36 (91.44)	MC	H2MXS-4036M-ND	13.16 9.98
	Gold	36 (91.44)	GR	H2MXH-4036G-ND	5.93 4.50
	Gold	36 (91.44)	MC	H2MXH-4036M-ND	12.35 9.37

No. of Contacts	Contact Finish	Length Inch (cm)	Rib-on-Cable	Digi-Key Part No.	Price Each 10
50	Tin	6 (15.24)	GR	H2MXS-5006G-ND	4.09 3.11
	Tin	6 (15.24)	MC	H2MXS-5006M-ND	5.54 4.20
	Gold	6 (15.24)	GR	H2MXH-5006G-ND	4.09 3.11
	Gold	6 (15.24)	MC	H2MXH-5006M-ND	5.54 4.20
50	Tin	18 (45.72)	GR	H2MXS-5018G-ND	5.22 3.96
	Tin	18 (45.72)	MC	H2MXS-5018M-ND	9.55 7.24
	Gold	18 (45.72)	GR	H2MXH-5018G-ND	5.22 3.96
	Gold	18 (45.72)	MC	H2MXH-5018M-ND	9.55 7.24
50	Tin	36 (91.44)	GR	H2MXS-5036G-ND	6.90 5.23
	Tin	36 (91.44)	MC	H2MXS-5036M-ND	15.57 11.80
	Gold	36 (91.44)	GR	H2MXH-5036G-ND	6.90 5.23
	Gold	36 (91.44)	MC	H2MXH-5036M-ND	15.57 11.80
60	Tin	6 (15.24)	GR	H2MXS-6006G-ND	5.97 4.53
	Tin	6 (15.24)	MC	H2MXS-6006M-ND	7.61 5.78
	Gold	6 (15.24)	GR	H2MXH-6006G-ND	5.97 4.53
	Gold	6 (15.24)	MC	H2MXH-6006M-ND	7.61 5.78
60	Tin	18 (45.72)	GR	H2MXS-6018G-ND	7.48 5.68
	Tin	18 (45.72)	MC	H2MXS-6018M-ND	12.43 9.42
	Gold	18 (45.72)	GR	H2MXH-6018G-ND	7.48 5.68
	Gold	18 (45.72)	MC	H2MXH-6018M-ND	12.43 9.42
60	Tin	36 (91.44)	GR	H2MXS-6036G-ND	9.76 7.40
	Tin	36 (91.44)	MC	H2MXS-6036M-ND	19.65 14.90
	Gold	36 (91.44)	GR	H2MXH-6036G-ND	9.76 7.40
	Gold	36 (91.44)	MC	H2MXH-6036M-ND	19.65 14.90
64	Tin	6 (15.24)	GR	H2MXS-6406G-ND	6.36 4.83
	Tin	6 (15.24)	MC	H2MXS-6406M-ND	8.21 6.23
	Gold	6 (15.24)	GR	H2MXH-6406G-ND	6.36 4.83
	Gold	6 (15.24)	MC	H2MXH-6406M-ND	8.21 6.23
64	Tin	18 (45.72)	GR	H2MXS-6418G-ND	7.79 5.91
	Tin	18 (45.72)	MC	H2MXS-6418M-ND	13.34 10.12
	Gold	18 (45.72)	GR	H2MXH-6418G-ND	7.79 5.91
	Gold	18 (45.72)	MC	H2MXH-6418M-ND	13.34 10.12
64	Tin	36 (91.44)	GR	H2MXS-6436G-ND	9.95 7.54
	Tin	36 (91.44)	MC	H2MXS-6436M-ND	21.04 15.96
	Gold	36 (91.44)	GR	H2MXH-6436G-ND	9.95 7.54
	Gold	36 (91.44)	MC	H2MXH-6436M-ND	21.04 15.96

Double Ended Style 6

*MC=Multi-Color, GR=Gray

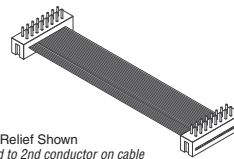

Dip Connector without Strain Relief Shown
Pin #1 on a connector is connected to 2nd conductor on cable

No. of Contacts	Contact Finish	Length Inch (cm)	Rib-on-Cable	Digi-Key Part No.	Price Each 10
10	Tin	6 (15.24)	GR	H6MMS-1006G-ND	3.85 2.92
	Tin	6 (15.24)	MC	H6MMS-1006M-ND	4.12 3.13
	Gold	6 (15.24)	GR	H6MMH-1006G-ND	3.85 2.92
	Gold	6 (15.24)	MC	H6MMH-1006M-ND	4.12 3.13
10	Tin	18 (45.72)	GR	H6MMS-1018G-ND	4.10 3.11
	Tin	18 (45.72)	MC	H6MMS-1018M-ND	4.92 3.74
	Gold	18 (45.72)	GR	H6MMH-1018G-ND	4.10 3.11
	Gold	18 (45.72)	MC	H6MMH-1018M-ND	4.92 3.74
10	Tin	36 (91.44)	GR	H6MMS-1036G-ND	4.48 3.40
	Tin	36 (91.44)	MC	H6MMS-1036M-ND	6.13 4.65
	Gold	36 (91.44)	GR	H6MMH-1036G-ND	4.48 3.40
	Gold	36 (91.44)	MC	H6MMH-1036M-ND	6.13 4.65
14	Tin	6 (15.24)	GR	H6MMS-1406G-ND	3.90 2.96
	Tin	6 (15.24)	MC	H6MMS-1406M-ND	4.32 3.28
	Gold	6 (15.24)	GR	H6MMH-1406G-ND	3.90 2.96
	Gold	6 (15.24)	MC	H6MMH-1406M-ND	4.32 3.28
14	Tin	18 (45.72)	GR	H6MMS-1418G-ND	4.25 3.23
	Tin	18 (45.72)	MC	H6MMS-1418M-ND	5.52 4.19
	Gold	18 (45.72)	GR	H6MMH-1418G-ND	4.25 3.23
	Gold	18 (45.72)	MC	H6MMH-1418M-ND	5.52 4.19
14	Tin	36 (91.44)	GR	H6MMS-1436G-ND	4.78 3.63
	Tin	36 (91.44)	MC	H6MMS-1436M-ND	7.33 5.56
	Gold	36 (91.44)	GR	H6MMH-1436G-ND	4.78 3.63
	Gold	36 (91.44)	MC	H6MMH-1436M-ND	7.33 5.56
16	Tin	6 (15.24)	GR	H6MMS-1606G-ND	3.92 2.98
	Tin	6 (15.24)	MC	H6MMS-1606M-ND	4.36 3.31
	Gold	6 (15.24)	GR	H6MMH-1606G-ND	3.92 2.98
	Gold	6 (15.24)	MC	H6MMH-1606M-ND	4.36 3.31
16	Tin	18 (45.72)	GR	H6MMS-1618G-ND	4.33 3.28
	Tin	18 (45.72)	MC	H6MMS-1618M-ND	5.65 4.28
	Gold	18 (45.72)	GR	H6MMH-1618G-ND	4.33 3.28
	Gold	18 (45.72)	MC	H6MMH-1618M-ND	5.65 4.28
16	Tin	36 (91.44)	GR	H6MMS-1636G-ND	4.93 3.74
	Tin	36 (91.44)	MC	H6MMS-1636M-ND	7.57 5.74
	Gold	36 (91.44)	GR	H6MMH-1636G-ND	4.93 3.74
	Gold	36 (91.44)	MC	H6MMH-1636M-ND	7.57 5.74
20	Tin	6 (15.24)	GR	H6MMS-2006G-ND	4.50 3.42
	Tin	6 (15.24)	MC	H6MMS-2006M-ND	5.02 3.81
	Gold	6 (15.24)	GR	H6MMH-2006G-ND	4.50 3.42
	Gold	6 (15.24)	MC	H6MMH-2006M-ND	5.02 3.81
20	Tin	18 (45.72)	GR	H6MMS-2018G-ND	5.07 3.85
	Tin	18 (45.72)	MC	H6MMS-2018M-ND	6.62 5.02
	Gold	18 (45.72)	GR	H6MMH-2018G-ND	5.07 3.85
	Gold	18 (45.72)	MC	H6MMH-2018M-ND	6.62 5.02
20	Tin	36 (91.44)	GR	H6MMS-2036G-ND	6.93 5.11
	Tin	36 (91.44)	MC	H6MMS-2036M-ND	9.03 6.85
	Gold	36 (91.44)	GR	H6MMH-2036G-ND	5.93 4.50
	Gold	36 (91.44)	MC	H6MMH-2036M-ND	9.03 6.85

No. of Contacts	Contact Finish	Length Inch (cm)	Rib-on-Cable	Digi-Key Part No.	Price Each 10
24	Tin	6 (15.24)	GR	H6MMS-2406G-ND	5.73 4.34
	Tin	6 (15.24)	MC	H6MMS-2406M-ND	6.46 4.90
	Gold	6 (15.24)	GR	H6MMH-2406G-ND	5.73 4.34
	Gold	6 (15.24)	MC	H6MMH-2406M-ND	6.46 4.90