


ASSMANN Computer Cable Assemblies (Cont.)

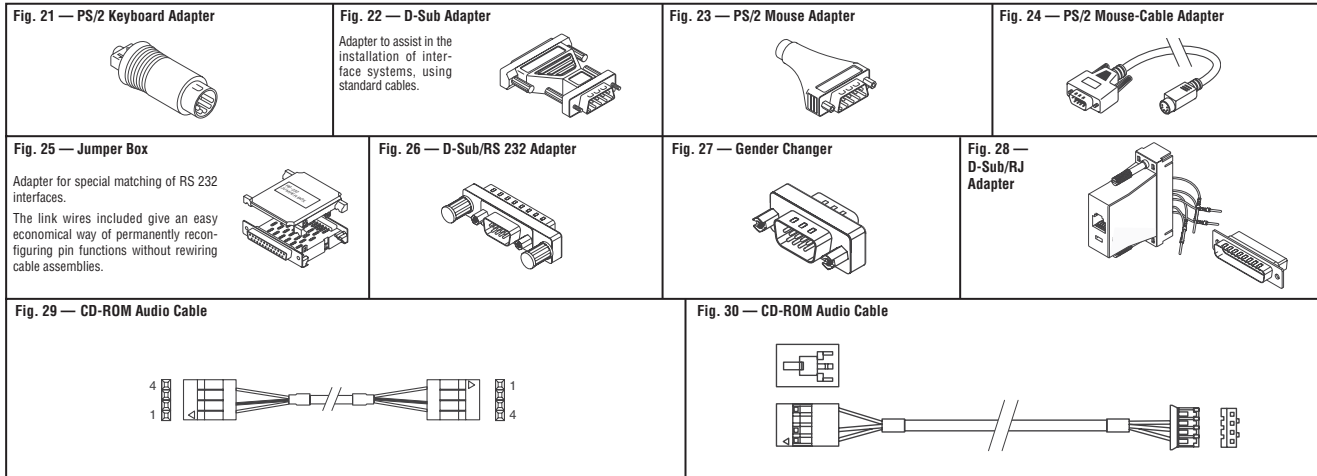

A

Fig.	Length Feet (Meters)	Lines	Description	Digi-Key Part No.	1	Price Each 10	25	Assmann Part No.
11	6.56 (2) 9.84 (3)	9	2x D-Sub 9-Pin Male to Female	AE1379-ND	6.17	5.43	4.87	AK131-2-R
	AE9871-ND			7.72	6.79	6.09	AK178-3-R	
	6.56 (2) 9.84 (3)	9	2x D-Sub 9-Pin Female to Female	AE9872-ND	7.66	6.73	6.04	AK152-2-R
	AE9873-ND			8.05	7.08	6.35	AK182-3-R	
VGA Monitor Extension Cable - IBM PS/2 — RoHS Compliant								
12	6.56 (2)	—	2x HD D-Sub 15-Pin Male to Female	AE1380-ND	8.51	7.49	6.71	AK322-2-R
VGA Monitor Cable - IBM PS/2 — RoHS Compliant								
—	6.56 (2)	—	2x HD D-Sub 15 Pin Male to Male	AE10183-ND	6.47	5.69	5.10	AK532-2-R
Molded VGA to 5 x BNC, Monitor Cable — RoHS Compliant								
—	6.56 (2)	—	HD D-Sub 15-Pin Male to 5 x BNC Male	AE1381-ND	25.31	22.25	19.95	AK553-2-R
Molded Premium VGA Monitor Extension Cable — RoHS Compliant								
13	5.90 (1.8)	—	HD D-Sub 15-Pin Male to HD D-Sub 15-Pin Female	AE9874-ND	13.83	12.16	10.90	AK3220-1.8-R
IBM PC-XT/AT Keyboard Extension								
14	16.40 (5)	5	5-Pin Standard DIN Male to Female	AE10261-ND◆	12.84	11.29	10.12	AK307-5-R
Molded PS/2 Keyboard Extension — RoHS Compliant								
15	6.56 (2) 16.40 (5)	6	6-Pin MiniDIN Male to Female, Spiral	AE10177-ND	7.79	6.85	6.14	AK323-2-R
	AE10262-ND			14.09	12.39	11.11	AK528-5-R	
16	6.56 (2)	6	MiniDIN 6-Pin Male to MiniDIN 6-Pin Female, Straight	AE9875-ND	4.13	3.63	3.25	AK323G-2-R
PS/2 Keyboard Cable - Straight — RoHS Compliant								
17	6.56 (2)	6	MiniDIN 6-Pin Male to MiniDIN 6-Pin Male, Molded	AE9876-ND	4.59	4.04	3.62	AK678-2-R
PC Modem (AT Adapter Cable) — RoHS Compliant								
18	.82 (.25) 6.56 (2)	9	D-Sub 9-Pin Female to D-Sub 25-Pin Male D-Sub 9-Pin Female to D-Sub 25-Pin Male	AE1382-ND	3.86	3.40	3.05	AK128-25-R
	AE9877-ND			6.07	5.34	4.79	AK125-2-R	
Modem Cables — RoHS Compliant								
18	9.84 (3)	9	D-Sub 9-Pin Female to D-Sub 25-Pin Male D-Sub 9-Pin Female to D-Sub 25-Pin Female	AE9878-ND	8.15	7.17	6.43	AK149-3-R
				AE1383-ND	8.12	7.14	6.40	AK124-3-R
Null Modem, Cross-Cables — RoHS Compliant								
19	9.84 (3)	9	D-Sub 9-Pin Female to D-Sub 9-Pin Female D-Sub 9-Pin Male to D-Sub 9-Pin Female	AE9879-ND	8.35	7.34	6.58	AK143-3-R
				AE9880-ND	8.05	7.08	6.35	AK142-3-R
Null Modem, Serial Cables								
20	9.84 (3)	25	D-Sub 25-Pin Female to D-Sub 25-Pin Female D-Sub 25-Pin Female to D-Sub 25-Pin Female D-Sub 25-Pin Male to D-Sub 25-Pin Male D-Sub 25-Pin Female to D-Sub 25-Pin Female	AE1035-ND	4.39	3.86	3.46	AK144-3
				AE1384-ND◆	7.56	6.65	5.96	AK144-3-R
				AE1385-ND◆	10.56	9.28	8.32	AK250-3-R
				AE1386-ND◆	7.59	6.67	5.98	AK251-3-R
PS/2 Keyboard Adapters								
21	—	—	1 x MiniDIN, 6-Pin Female to 1 x DIN 5-Pin Male 1 x MiniDIN, 6-Pin Female to 1 x DIN 5-Pin Male 1 x MiniDIN, 6-Pin Male to DIN 5-Pin Female	AE1046-ND	3.93	3.46	3.10	AB961
				AE1387-ND◆	4.03	3.54	3.18	AB961-R
				AE1047-ND	3.04	2.67	2.40	AB440
D-Sub Adapters — RoHS Compliant								
22	—	—	9-Pin Male to 25-Pin Male 9-Pin Female to 25-Pin Male 9-Pin Male to 25-Pin Female	AE1389-ND	5.02	4.41	3.96	AB913-R
				AE9881-ND	4.49	3.95	3.54	AB914-R
				AE9882-ND	3.96	3.48	3.12	AB914-F-R
PS/2 Mouse Adapters								
23	—	—	1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Female 1 x MiniDIN, 6-Pin Female to 1 x D-Sub 25-Pin Female	AE1156-ND	2.05	1.80	1.62	AB406
				AE1056-ND	7.26	6.38	5.72	AB441
PS/2 Mouse-Cable Adapters								
24	.5 (.15)	—	1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Male 1 x MiniDIN, 6-Pin Male to 1 x D-Sub 9-Pin Female 1 x MiniDIN, 6-Pin Male to 1 x D-Sub 9-Pin Male 1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Female	AE1154-ND	2.05	1.80	1.62	AB401K
				AE1393-ND◆	3.20	2.82	2.53	AB450K-R
				AE1155-ND	2.05	1.80	1.62	AB405K
				AE1157-ND	2.05	1.80	1.62	AB406K
Jumper Box — RoHS Compliant								
25	—	—	1 x Male, 1 x Female, 25-Pin, Plastic 1 x Male, 1 x Female, 25-Pin, Metallized	AE10180-ND	13.30	11.69	10.48	AB972-R
				AE10182-ND	11.22	9.86	8.84	AB973-R

◆ RoHS Compliant

(Continued)

More Product Available Online: www.digikey.com
Toll-Free: 1-800-344-4539 • Phone 218-681-6674 • Fax: 218-681-3380

(T091) 59