




Crystals
ABM3B Series 5.0 x 3.2 SMD Crystals (Cont.)



Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), T & R Pricing (1,000), Abracon Part No. Includes sub-sections for ABM3B-xxx-B2-T Series, ABM3B-xxx-10-D4 Series, and ABM3B-xxx-D-R60-1-W-T Series.

See data sheet for electrical specifications. For Tape and Reel part number, change 1-ND to 2-ND.

 ABM8 Series 3.2 x 2.5 SMD Crystals



Specifications:
ABM8-xxx-B2-T Series: Frequency Stability: ±50ppm, -20°C ~ 70°C • Frequency Tolerance: ±20ppm @ 25°C • Operating Temperature: -20°C ~ 70°C • Load Capacitance: 18.0pF
ABM8-xxx-10-1-U-T Series: Frequency Tolerance: ±10ppm @ 25°C • Frequency Stability: ±10ppm, -10°C ~ 60°C • Operating Temperature: -10°C ~ 60°C • Load Capacitance: 10.0pF

Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), T & R Pricing (1,000), Abracon Part No. Includes sub-sections for ABM8-xxx-B2-T Series, ABM8-xxx-10-1-U-T Series, and ABM8-xxx-10-1-D Series.

For Tape and Reel part number, change 1-ND to 2-ND.

ABM9 Series 4.0 x 2.5 SMD RF Transceiver Crystals


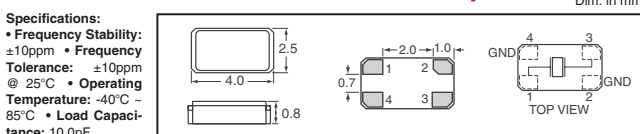


Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), T & R Pricing (1,000), Abracon Part No.

For Tape and Reel part number, change 1-ND to 2-ND.

ABM10 Series 2.5 x 2.0 SMD Crystals

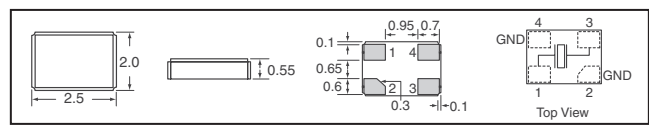


Specifications:
ABM10-xxx-E20-T Series: Frequency Stability: ±20ppm, -20°C ~ 70°C • Frequency Tolerance: ±20ppm
Operating Temperature: -20°C ~ 70°C • Load Capacitance: 10.0pF
ABM10-xxx-8-7A15-T Series: Frequency Stability: ±15ppm, -10°C ~ 60°C • Frequency Tolerance: ±15ppm
Operating Temperature: -10°C ~ 60°C • Load Capacitance: 8.0pF
ABM10-xxx-7A15-T Series: Frequency Stability: ±15ppm, -10°C ~ 60°C • Frequency Tolerance: ±15ppm
Operating Temperature: -10°C ~ 60°C • Load Capacitance: 10.0pF

Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), T & R Pricing (1,000), Abracon Part No. Includes sub-sections for ABM10-xxx-E20-T Series, ABM10-xxx-8-7A15-T Series, and ABM10-xxx-7A15-T Series.

For Tape and Reel part number, change 1-ND to 2-ND.

 ABMM Series 5.0 x 7.0 SMD Crystals




Specifications:
Frequency Stability: ±50ppm, -20°C ~ 70°C • Frequency Tolerance: ±20ppm • Operating Temperature: -20°C ~ 70°C • Load Capacitance: 18.0pF

Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), T & R Pricing (1,000), Abracon Part No.

For Tape and Reel part number, change 1-ND to 2-ND.

 ABMM2 Series 6.0 x 3.6 SMD Crystals



Specifications:
Frequency Stability: ±20ppm, -20°C ~ 70°C • Frequency Tolerance: ±20ppm • Operating Temperature: -20°C ~ 70°C • Load Capacitance: 18.0pF

Table with columns: Frequency (MHz), Digi-Key Part No., Cut Tape Price Each (1, 10, 50), T & R Pricing (1,000), Abracon Part No.

For Tape and Reel part number, change 1-ND to 2-ND.

Digi-Reel Most SMT cutdown parts are available on a Digi-Reel. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key Services on page 2 for additional information.

All prices are in U.S. dollars (www.digikey.com). Toll-Free: 00801-85-4023

1310 (TW092-10) Fax: (852) 3104 0686 — Taiwan dollar available by credit card at www.digikey.tw.