


ASSMANN Computer Cable Assemblies (Cont.)

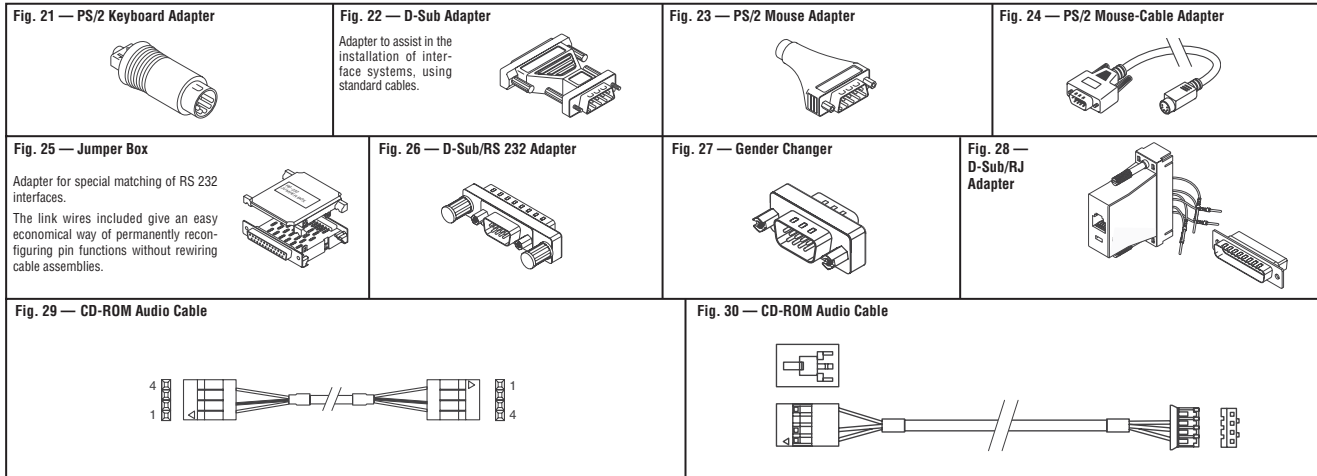

A

Fig.	Length Feet (Meters)	Lines	Description	Digi-Key Part No.	1	Price Each 10	25	Assmann Part No.
11	6.56 (2)	9	2x D-Sub 9-Pin Male to Female	AE1379-ND	4.49	3.95	3.54	AK131-2-R
	9.84 (3)			AE9871-ND	5.61	4.93	4.42	AK178-3-R
	6.56 (2)			AE9872-ND	5.56	4.89	4.38	AK152-2-R
	9.84 (3)			AE9873-ND	5.85	5.14	4.61	AK182-3-R
VGA Monitor Extension Cable - IBM PS/2 — RoHS Compliant								
12	6.56 (2)	—	2x HD D-Sub 15-Pin Male to Female	AE1380-ND	6.19	5.45	4.88	AK322-2-R
VGA Monitor Cable - IBM PS/2 — RoHS Compliant								
—	6.56 (2)	—	2x HD D-Sub 15 Pin Male to Male	AE10183-ND	6.06	5.33	4.78	AK532-2-R
Molded VGA to 5 x BNC, Monitor Cable — RoHS Compliant								
—	6.56 (2)	—	HD D-Sub 15-Pin Male to 5 x BNC Male	AE1381-ND	18.38	16.15	14.48	AK553-2-R
Molded Premium VGA Monitor Extension Cable — RoHS Compliant								
13	5.90 (1.8)	—	HD D-Sub 15-Pin Male to HD D-Sub 15-Pin Female	AE9874-ND	10.04	8.83	7.91	AK3220-1.8-R
IBM PC-XT/AT Keyboard Extension								
14	16.40 (5)	5	5-Pin Standard DIN Male to Female	AE10261-ND◆	9.32	8.19	7.35	AK307-5-R
Molded PS/2 Keyboard Extension — RoHS Compliant								
15	6.56 (2)	6	6-Pin MiniDIN Male to Female, Spiral	AE10177-ND	5.66	4.97	4.46	AK323-2-R
	16.40 (5)			AE10262-ND	10.23	8.99	8.06	AK528-5-R
16	6.56 (2)	6	MiniDIN 6-Pin Male to MiniDIN 6-Pin Female, Straight	AE9875-ND	3.00	2.64	2.36	AK323G-2-R
PS/2 Keyboard Cable - Straight — RoHS Compliant								
17	6.56 (2)	6	MiniDIN 6-Pin Male to MiniDIN 6-Pin Male, Molded	AE9876-ND	3.33	2.93	2.63	AK678-2-R
PC Modem (AT Adapter Cable) — RoHS Compliant								
18	.82 (.25)	9	D-Sub 9-Pin Female to D-Sub 25-Pin Male D-Sub 9-Pin Female to D-Sub 25-Pin Male	AE1382-ND	2.80	2.47	2.21	AK128-25-R
	6.56 (2)			AE9877-ND	4.41	3.88	3.48	AK125-2-R
Modem Cables — RoHS Compliant								
18	9.84 (3)	9	D-Sub 9-Pin Female to D-Sub 25-Pin Male D-Sub 9-Pin Female to D-Sub 25-Pin Female	AE9878-ND	5.92	5.21	4.67	AK149-3-R
				AE1383-ND	5.90	5.18	4.65	AK124-3-R
Null Modem, Cross-Cables — RoHS Compliant								
19	9.84 (3)	9	D-Sub 9-Pin Female to D-Sub 9-Pin Female D-Sub 9-Pin Male to D-Sub 9-Pin Female	AE9879-ND	6.06	5.33	4.78	AK143-3-R
				AE9880-ND	5.86	5.15	4.62	AK142-3-R
Null Modem, Serial Cables								
20	9.84 (3)	25	D-Sub 25-Pin Female to D-Sub 25-Pin Female D-Sub 25-Pin Female to D-Sub 25-Pin Female D-Sub 25-Pin Male to D-Sub 25-Pin Male D-Sub 25-Pin Female to D-Sub 25-Pin Female	AE1035-ND	3.19	2.80	2.52	AK144-3
				AE1384-ND◆	5.49	4.83	4.33	AK144-3-R
				AE1385-ND◆	7.67	6.75	6.05	AK250-3-R
				AE1386-ND◆	5.51	4.85	4.35	AK251-3-R
PS/2 Keyboard Adapters								
21	—	—	1 x MiniDIN, 6-Pin Female to 1 x DIN 5-Pin Male 1 x MiniDIN, 6-Pin Female to 1 x DIN 5-Pin Male 1 x MiniDIN, 6-Pin Male to DIN 5-Pin Female	AE1046-ND	2.85	2.51	2.25	AB961
				AE1387-ND◆	2.93	2.58	2.31	AB961-R
				AE1047-ND	2.21	1.94	1.74	AB440
D-Sub Adapters — RoHS Compliant								
22	—	—	9-Pin Male to 25-Pin Male 9-Pin Female to 25-Pin Male 9-Pin Male to 25-Pin Female	AE1389-ND	3.64	3.20	2.87	AB913-R
				AE9881-ND	3.26	2.87	2.58	AB914-R
				AE9882-ND	2.87	2.53	2.27	AB914-F-R
PS/2 Mouse Adapters								
23	—	—	1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Female 1 x MiniDIN, 6-Pin Female to 1 x D-Sub 25-Pin Female	AE1156-ND	1.49	1.31	1.18	AB406
				AE1056-ND	5.27	4.64	4.16	AB441
PS/2 Mouse-Cable Adapters								
24	.5 (.15)	—	1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Male 1 x MiniDIN, 6-Pin Male to 1 x D-Sub 9-Pin Female 1 x MiniDIN, 6-Pin Male to 1 x D-Sub 9-Pin Male 1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Female	AE1154-ND	1.49	1.31	1.18	AB401K
				AE1393-ND◆	2.32	2.05	1.84	AB450K-R
				AE1155-ND	1.49	1.31	1.18	AB405K
				AE1157-ND	1.49	1.31	1.18	AB406K
Jumper Box — RoHS Compliant								
25	—	—	1 x Male, 1 x Female, 25-Pin, Plastic 1 x Male, 1 x Female, 25-Pin, Metallized	AE10180-ND	9.66	8.49	7.61	AB972-R
				AE10182-ND	9.27	8.15	7.31	AB973-R

◆ RoHS Compliant

(Continued)

Free shipping on orders over £50! All prices are in British pound sterling and include duties.

uk.digikey.com — FREEPHONE: 0-800-587-0991 • 0-800-904-7786 — FREEFAX: 0-800-587-0992 • 0-800-904-7783