

ASSMANN Computer Cable Assemblies (Cont.)

A

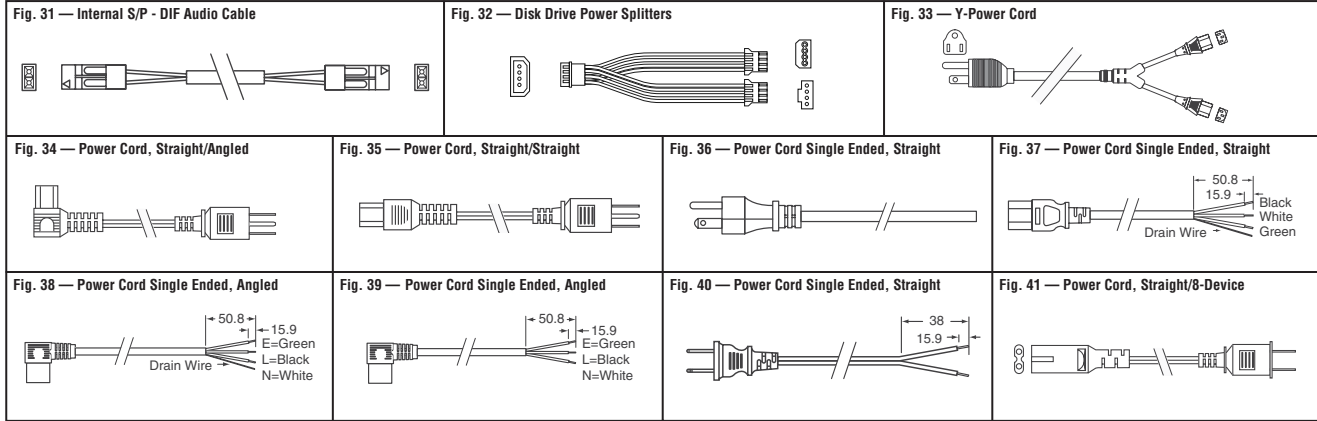


Fig.	Length Feet (Meters)	Lines	Description	Digi-Key Part No.	1	Price Each 10	25	Assmann Part No.
D-Sub/RS 232 Adapters — RoHS Compliant								
26	—	—	D-Sub 9-Pin Male to D-Sub 25-Pin Male	AE10291-ND	4.31	3.79	3.40	AB467-R
			D-Sub 9-Pin Male to D-Sub 25-Pin Female	AE10292-ND	3.77	3.32	2.97	AB468-R
			D-Sub 9-Pin Female to D-Sub 25-Pin Female	AE10293-ND	3.77	3.32	2.97	AB469-R
			D-Sub 9-Pin Female to D-Sub 25-Pin Male	AE10294-ND	3.50	3.08	2.76	AB470-R
Gender Changers — RoHS Compliant								
27	—	—	D-Sub 9 Position Male to Male	AE10295-ND	2.97	2.62	2.35	AB410-R
			D-Sub 9 Position Female to Female	AE10296-ND	2.97	2.62	2.35	AB411-R
			D-Sub 15 Position Male to Male	AE10297-ND	2.97	2.62	2.35	AB412-R
			D-Sub 15 Position Female to Female	AE10298-ND	3.09	2.72	2.44	AB413-R
			D-Sub 25 Position Male to Male	AE10299-ND	3.09	2.72	2.44	AB414-R
			D-Sub 25 Position Female to Female	AE10300-ND	3.24	2.85	2.55	AB415-R
			D-Sub HD 15 Position Male to Male	AE10301-ND	3.77	3.32	2.97	AB418-R
			D-Sub HD 15 Position Female to Female	AE10302-ND	3.77	3.32	2.97	AB420-R
D-Sub/RJ Adapters (Beige) — RoHS Compliant								
28	—	—	9 Position Male RJ12 Jack	AE10307-ND	3.91	3.44	3.08	AT-23064-R
			9 Position Female RJ12 Jack	AE10308-ND	3.91	3.44	3.08	AT-23065-R
			9 Position Male RJ45 Jack	AE10309-ND	3.91	3.44	3.08	AT-23066-R
			9 Position Female RJ45 Jack	AE10310-ND	3.91	3.44	3.08	AT-23067-R
			25 Position Male RJ12 Jack	AE10303-ND	4.17	3.67	3.29	AT-23052-R
			25 Position Female RJ12 Jack	AE10304-ND	4.17	3.67	3.29	AT-23053-R
			25 Position Male RJ45 Jack	AE10305-ND	4.17	3.67	3.29	AT-23054-R
			25 Position Female RJ45 Jack	AE10306-ND	4.17	3.67	3.29	AT-23055-R
Power Splitter Cables								
29	1.64 (0.5)	—	Audio CD-ROM 4 Position 3 Wire	AE1396-ND◆	1.34	1.18	1.06	AK2525-R
30	1.64 (0.5)	—	Audio CD-ROM 4 Position 3 Wire	AE1397-ND◆	1.34	1.18	1.06	AK2524-R
31	1.64 (0.5)	—	Internal Cable 2-Pin Housing/Housing	AE9884-ND◆	1.68	1.48	1.33	AK2526DVD-R
32	.66 (.2)	4	Power Cable for 2 - 5 1/4" Drives	AE9885-ND◆	1.85	1.63	1.46	AK319-2-R
			Power Cable for 2 - 3 1/2" Drives	AE1398-ND◆	2.13	1.88	1.68	AK520-2-R
			Power Cable for 3 1/2" and 5 1/4" Drives	AE1399-ND◆	2.13	1.88	1.69	AK521-2-R
Y-Power Cord — RoHS Compliant								
33	6.56 (2)	—	1 x Power Plug to 2 x Straight Connector, 10A, 125V	AE9886-ND	13.84	12.17	10.92	AK500/Y-U-R
Power Cords								
34	6.56 (2)	—	Power Plug, Straight to IEC Connector, Angled, 10A, 125V	AE9887-ND◆	6.42	5.65	5.06	AK500/U-1-R
35	6.56 (2)	—	Power Plug, Straight to IEC Connector, Straight, 10A, 125V	AE9888-ND◆	6.47	5.69	5.10	AK500/U-2-R
36	6.56 (2)	—	Cord SVT 18AWG 3 Cond Shielded	AE9889-ND◆	6.18	5.44	4.87	AK500-OE-5-2-R
	9.84 (3)		Cord SVT 18AWG 3 Cond Shielded	AE9890-ND◆	8.57	7.54	6.76	AK500-OE-5-3-R
	6.56 (2)		Cord SJT 18AWG 3 Cond Shielded	AE9891-ND◆	6.37	5.60	5.03	AK500-OE-6-2-R
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE9892-ND◆	8.96	7.88	7.06	AK500-OE-6-3-R
	6.56 (2)		Cord SVT 18AWG 3 Cond Shielded	AE9893-ND◆	6.06	5.33	4.78	AK500-OE-7-2-R
37	6.56 (2)	—	Cord SJT 18AWG 3 Cond Shielded	AE9895-ND◆	6.40	5.63	5.04	AK500-OE-9-2-R
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE1339-ND	4.55	4.00	3.59	AK500-OE-9-3
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE9896-ND◆	10.16	8.93	8.01	AK500-OE-9-3-R
38	6.56 (2)	—	Cord SJT 18AWG 3 Cond Shielded	AE1331-ND	3.30	2.91	2.61	AK500-RA-5-2
	6.56 (2)		Cord SJT 18AWG 3 Cond Shielded	AE9897-ND◆	6.35	5.58	5.01	AK500-RA-5-2-R
39	6.56 (2)	—	Cord SVT 18AWG 3 Cond	AE1333-ND	4.09	3.60	3.23	AK500-RA-6-2
	6.56 (2)		Cord SVT 18AWG 3 Cond	AE9899-ND◆	4.98	4.38	3.93	AK500-RA-6-2-R
	6.56 (2)		Cord SJT 18AWG 3 Cond	AE9900-ND◆	5.68	4.99	4.48	AK500-RA-7-2-R
	9.84 (3)		Cord SJT 18AWG 3 Cond	AE1335-ND	4.44	3.91	3.50	AK500-RA-7-3
40	6 (1.83)	—	Cord SPT-1 18AWG 2 Cond	AE9902-ND◆	4.02	3.54	3.18	AK500-OE-12-6F-R
	8.99 (2.74)		Cord SPT-1 18AWG 2 Cond	AE9903-ND◆	5.70	5.02	4.50	AK500-OE-12-9F-R
	6 (1.83)		Cord SPT-2 18AWG 2 Cond	AE9904-ND◆	4.17	3.67	3.29	AK500-OE-13-6F-R
	8 (2.44)		Cord SPT-2 18AWG 2 Cond	AE1348-ND	2.34	2.06	1.85	AK500-OE-13-8F
41	6.56 (2)	—	Power Plug, Straight to Figure 8 Device Connector, Straight	AE1123-ND	2.12	1.87	1.67	AK500/U-3
	6.56 (2)		Power Plug, Straight to Figure 8 Device Connector, Straight	AE9906-ND◆	5.08	4.47	4.01	AK500/U-3-R
Power Cord Extension								
42	6.56 (2)	—	IEC Plug, Straight to IEC Socket, Straight, 10A, 125V	AE9854-ND◆	8.00	7.04	6.31	AK500/U-4-R
	3.28 (1)		Cord SJT 18AWG 3 Cond Shielded	AE1336-ND	2.58	2.27	2.04	AK500-JC-5-1
	3.28 (1)		Cord SJT 18AWG 3 Cond Shielded	AE9908-ND◆	7.67	6.74	6.05	AK500-JC-5-1-R

◆ RoHS Compliant

(Continued)

Free shipping on orders over £50! All prices are in British pound sterling and include duties.

56 (UK091)

uk.digikey.com — FREEPHONE: 0-800-587-0991 • 0-800-904-7786 — FREEFAX: 0-800-587-0992 • 0-800-904-7783