 


ASSMANN SCSI, Serial ATA, USB, CAT5e and CAT6 Computer Cable Assemblies (Cont.)


Fig.	Length Meters	Lines	Description	Digi-Key Part No.	Price Each			Assmann Part No.
					1	10	25	
30	2.0	4	Cable USB B-B Male	AE1151-ND	3.59	3.16	2.84	AK673-2
	2.0			AE1457-ND	5.18	4.56	4.09	AK673-2-R
	1.0			AE1458-ND	3.43	3.02	2.70	AK673/2-1-R
	2.0			AE1459-ND	4.33	3.82	3.42	AK673/2-2-R
30	2.0	4	Cable USB 2.0, B-B Male	AE1460-ND	8.37	7.36	6.60	AK673/2-5-R
	1.5			AE9931-ND	4.27	3.76	3.37	AU-Y1002A-R
	2.0			AE9932-ND	4.37	3.85	3.45	AK672-2-R
	5.0			AE1461-ND	7.45	6.55	5.88	AK672-5-R
31	1.0	—	Cable USB 2.0, A-B Male	AE1462-ND	2.01	1.44	1.37	AK672/2-1-R
	2.0			AE1493-ND	2.87	2.05	1.95	AK672/2-2-R
	3.0			AE1463-ND	4.02	2.88	2.74	AK672/2-3-R
	5.0			AE9933-ND	6.06	5.33	4.78	AK672/2-5-R
32	2.0	4	Cable USB A-B Male, iMac Blue Cable USB A-B Male, iMac Purple Cable USB A-B Male, iMac Green Cable USB A-B Male, iMac Red	AE1361-ND	5.44	4.78	4.29	AK672MB-R
	2.0			AE1464-ND	5.44	4.78	4.29	AK672MG-R
	2.0			AE1465-ND	5.44	4.78	4.29	AK672ML-R
	2.0			AE1466-ND	5.44	4.78	4.29	AK672MS-R
32	1.8	4	USB A Male to USB A Female, Double Shield	AE9934-ND	4.94	4.34	3.89	AK669-18-R
	3.0			AE9935-ND	6.25	5.50	4.93	AK669-30-R
	5.0			AE1468-ND	9.60	8.45	7.57	AK669-50-R
33	2.0	4	USB B to Open End	AE1470-ND	3.91	3.44	3.09	AK673-OE-R
<b>USB Adapters — RoHS Compliant</b>								
34	—	—	USB 1.1 to PS/2 (2)	AE10287-ND	12.92	11.36	10.18	DA-70118
35	—	—	USB 1.1 to Serial Male/DB-9	AE10288-ND	17.95	16.32	14.69	DA-70145
	—	—	USB 2.0 to Serial Male/DB-9	AE10289-ND	22.44	20.41	18.37	DA-70146
36	—	—	USB 2.0 Repeater 5 Meters	AE10290-ND	20.19	18.36	16.52	DA-70130
<b>USB Adapters — Internal/External on Slot Bracket, Double Shielded — RoHS Compliant</b>								
37	0.25	—	2 x USB-A Female to 2 x 5-Pin, 2.54mm Socket Conn.	AE10179-ND	5.15	4.53	4.06	AK674-R
<b>USB Adapters — Molded</b>								
38	—	4	USB-A Female to USB-B Male	AE1159-ND	3.59	3.16	2.84	A-USB-2
			USB-A Male to USB-B Female	AE1472-ND	4.62	4.07	3.65	A-USB-3-R
			USB-A Female to USB-B Female	AE1318-ND	3.59	3.16	2.84	A-USB-1
			USB-A Female to USB-B Female	AE1473-ND	4.63	4.07	3.65	A-USB-1-R
39	1.83	—	Adapter USB Serial DB9/25 Male	AE1474-ND	4.63	4.07	3.65	A-USB-4-R
			Adapter USB Serial DB9/25 Male	AE1488-ND	23.68	21.86	20.33	DA-70119-R
<b>Modular Plugs</b>								
40	—	—	4P4C, Unshielded, for Flat Cable	AE1475-ND	.19	.17	.16	A-MO-4/4-SF-R
			6P4C, Unshielded, for Flat Cable	AE1476-ND	.15	.14	.13	A-MO-6/4-SF-R
			6P6C, Unshielded, for Flat Cable	AE1477-ND	.29	.26	.23	A-MO-6/6-SF-R
			8P8C, Unshielded, for Flat Cable	AE1478-ND	.38	.34	.31	A-MO-8/8-SF-R
			8P8C, Shielded, for Flat Cable, CAT5	AE1479-ND	.65	.58	.52	A-MO-8/8-SFS-R
			4P4C, Unshielded, for Round Cable	AE1195-ND	.12	.11	.10	A-MO-4/4-SR-R
			6P4C, Unshielded, for Round Cable	AE1481-ND	.19	.17	.16	A-MO-6/4-SR-R
			6P6C, Unshielded, for Round Cable	AE1482-ND	.29	.26	.23	A-MO-6/6-SR-R
40	—	—	8P8C, Unshielded, for Round Cable	AE1483-ND	.38	.34	.31	A-MO-8/8-SR-R
			8P8C, Shielded, for Round Cable, CAT5	AE1484-ND	.65	.58	.52	A-MO-8/8-SRS-R
<b>Keystone Jacks — RoHS Compliant</b>								
41	—	—	RJ45 Jack-Jack CAT5E	AE10093-ND	5.95	5.24	4.70	A-TA3534-R
			RJ45 Jack-Jack CAT6	AE10094-ND	6.80	5.98	5.37	A-TA3535-R

◆ RoHS Compliant


**Fig. 22 — USB 4P Female Right Angle Connector**




**Fig. 23 — USB 4P Female Dual Port Right Angle Thru-Hole Connector**




**Fig. 24 — USB Plugs and Hoods**

 


**Fig. 25 — Mini USB Cables with 4 Position Male**

 


**Fig. 26 — Mini USB Cables with 5 Position Male**




**Fig. 27 — Mini USB Cable with 5 Position Female to 5 Position Male**

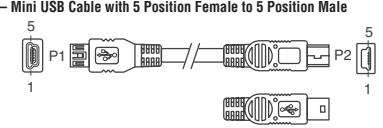


**Fig. 28 — USB Cable, A Male Open End**

 


**Fig. 29 — USB Cable, A-A Male**

 

**Fig. 30 — USB Cable, B-B Male**

 

**Fig. 31 — USB Cable, A-B Male**

 


A

Fig.	Length Meters	Description	Unshielded Version (UTP)				Shielded Version (FTP)					
			Digi-Key Part No.	Price Each			Assmann Part No.	Digi-Key Part No.	Price Each			Assmann Part No.
<b>PVC Cable Assembly CAT5(e), RJ45 — Molded</b>												
42	1.0	CAT 5e, Patch Cable, Gray	AE9936-ND	2.68	2.36	2.12	A-MCUP-80010-R	AE9961-ND	3.80	3.34	2.99	A-MCSP-80010-R
	2.0		AE9937-ND	4.08	3.59	3.22	A-MCUP-80020-R	AE9962-ND	4.53	3.99	3.57	A-MCSP-80020-R
	3.0		AE9938-ND	5.40	4.75	4.26	A-MCUP-80030-R	AE9963-ND	5.63	4.95	4.44	A-MCSP-80030-R
	5.0		AE9939-ND	7.88	6.93	6.22	A-MCUP-80050-R	AE9964-ND	7.81	6.87	6.16	A-MCSP-80050-R
	10.0		AE9940-ND	14.32	12.59	11.29	A-MCUP-80100-R	AE9965-ND	14.95	13.14	11.78	A-MCSP-80100-R
42	1.0	CAT 5e, Patch Cable, Red	—	—	—	—	—	AE1234-ND	2.06	1.82	1.63	A-MCSP-80010/R
	1.0		AE9941-ND	2.68	2.36	2.12	A-MCUP-80010/R-R	AE9966-ND	3.80	3.34	2.99	A-MCSP-80010/R-R
	2.0		—	—	—	—	—	AE1239-ND	2.90	2.55	2.29	A-MCSP-80020/R
	3.0		AE9942-ND	4.08	3.59	3.22	A-MCUP-80020/R-R	AE9967-ND	4.53	3.99	3.57	A-MCSP-80020/R-R
	5.0		AE1219-ND	2.66	2.34	2.10	A-MCUP-80030/R	AE1244-ND	3.72	3.27	2.93	A-MCSP-80030/R
42	3.0	CAT 5e, Patch Cable, Red	AE9943-ND	5.40	4.75	4.26	A-MCUP-80030/R-R	AE9968-ND	5.63	4.95	4.44	A-MCSP-80030/R-R
	5.0		AE1224-ND	3.88	3.42	3.06	A-MCUP-80050/R	AE1249-ND	5.18	4.55	4.08	A-MCSP-80050/R
	5.0		AE9944-ND	7.88	6.93	6.22	A-MCUP-80050/R-R	AE9969-ND	7.81	6.87	6.16	A-MCSP-80050/R-R
	10.0		AE1229-ND	7.00	6.15	5.52	A-MCUP-80100/R	AE1254-ND	9.23	8.11	7.27	A-MCSP-80100/R
	10.0		AE9945-ND	14.32	12.59	11.29	A-MCUP-80100/R-R	AE9970-ND	14.95	13.14	11.78	A-MCSP-80100/R-R
42	1.0	CAT 5e, Patch Cable, Blue	AE9946-ND	2.68	2.36	2.12	A-MCUP-80010/B-R	AE9971-ND	3.80	3.34	2.99	A-MCSP-80010/B-R
	2.0		AE9947-ND	4.08	3.59	3.22	A-MCUP-80020/B-R	AE9972-ND	4.53	3.99	3.57	A-MCSP-80020/B-R
	3.0		AE9948-ND	5.40	4.75	4.26	A-MCUP-80030/B-R	AE9973-ND	5.63	4.95	4.44	A-MCSP-80030/B-R
	5.0		AE1225-ND	3.88	3.42	3.06	A-MCUP-80050/B	AE1250-ND	5.18	4.55	4.08	A-MCSP-80050/B
	5.0		AE9949-ND	7.88	6.93	6.22	A-MCUP-80050/B-R	AE9974-ND	7.81	6.87	6.16	A-MCSP-80050/B-R
42	10.0	CAT 5e, Patch Cable, Blue	—	—	—	—	—	AE1255-ND	9.23	8.11	7.27	A-MCSP-80100/B
	10.0		AE9950-ND	14.32	12.59	11.29	A-MCUP-80100/B-R	AE9975-ND	14.95	13.14	11.78	A-MCSP-80100/B-R
	1.0		AE9951-ND	2.68	2.36	2.12	A-MCUP-80010/Y-R	AE9976-ND	3.80	3.34	2.99	A-MCSP-80010/Y-R
	2.0		AE9952-ND	4.08	3.59	3.22	A-MCUP-80020/Y-R	AE9977-ND	4.53	3.99	3.57	A-MCSP-80020/Y-R
	3.0		AE9953-ND	5.40	4.75	4.26	A-MCUP-80030/Y-R	AE9978-ND	5.63	4.95	4.44	A-MCSP-80030/Y-R
42	5.0	CAT 5e, Patch Cable, Yellow	—	—	—	—	—	AE1251-ND	5.18	4.55	4.08	A-MCSP-80050/Y
	5.0		AE9954-ND	7.88	6.93	6.22	A-MCUP-80050/Y-R	AE9979-ND	7.81	6.87	6.16	A-MCSP-80050/Y-R
	10.0		AE1231-ND	7.00	6.15	5.52	A-MCUP-80100/Y	AE1256-ND	9.23	8.11	7.27	A-MCSP-80100/Y
	10.0		AE9955-ND	14.32	12.59	11.29	A-MCUP-80100/Y-R	AE9980-ND	14.95	13.14	11.78	A-MCSP-80100/Y-R


◆ RoHS Compliant

(Continued)


**Fig. 32 — USB Extension Cable**

 


**Fig. 33 — USB Cable, B to Open End**




**Fig. 34 — USB to PS/2 Adapter**

 

**Fig. 35 — USB to Serial Adapter**



 **Fig. 36 — USB 2.0 Repeater Cable**



Free shipping on orders over £50! All prices are in British pound sterling and include duties.

uk.digikey.com — FREEPHONE: 0-800-587-0991 • 0-800-904-7786 — FREEFAX: 0-800-587-0992 • 0-800-904-7783