

Amphenol® Commercial Products

D-Sub Connectors (Cont.)



A

Fig.	No. of Pins	Type	Dim. A mm	Digi-Key Part No.	Price Each			Amphenol Part No.
					1	10	50	
Dust Covers								
—	9	Male	—	L17D4K63010-ND	.89	.70	.59	L17D4K63010
	9	Female	—	L17D4K63110-ND	.95	.74	.63	L17D4K63110
	15	Male	—	L17D4K63016-ND	.98	.76	.65	L17D4K63016
	15	Female	—	L17D4K63116-ND	.95	.74	.63	L17D4K63116
	25	Male	—	L17D4K63026-ND	1.03	.80	.68	L17D4K63026
Accessories								
—	Spring Latch			L17529-ND	3.70	3.06	2.56	L17529
	Screw Lock			L17D204182TX-ND	4.68	3.88	3.23	L17D204182TX
	Screw Lock			L17D20419EX-ND	4.98	4.13	3.44	L17D20419EX

No. of Pins	Material	Digi-Key Part No.	Price Each			Amphenol Part No.
			1	10	50	
Backshells						
9	Die Cast	17E-1657-09-ND	4.64	3.85	3.21	17E-1657-09
15	Die Cast	17E-1657-15-ND	4.56	3.86	3.34	17E-1657-15
25	Die Cast	17E-1657-25-ND	5.68	4.81	4.15	17E-1657-25
37	Die Cast	17E-1657-37-ND	6.33	5.78	4.96	17E-1657-37
9	Black Plastic	17E-1724-1-ND	2.12	1.76	1.47	17E-1724-1
9	Black Plastic	L171370-ND	2.11	1.75	1.46	L171370
9	Black Plastic	L17DPPK09JS-ND	2.27	1.88	1.57	L17DPPK09JS
15	Black Plastic	17E-1725-1-ND	2.19	1.82	1.52	17E-1725-1
25	Black Plastic	17E-1726-1-ND	2.31	1.92	1.60	17E-1726-1
37	Black Plastic	17E-1727-1-ND	2.75	2.28	1.90	17E-1727-1
50	Black Plastic	17E-1728-1-ND	2.83	2.35	1.96	17E-1728-1
50	Zinc Alloy, Zinc Plated	17E165750-ND	7.06	6.45	5.53	17E165750
9	Metallized Plastic	17E-1724-2-ND	3.01	2.50	2.08	17E-1724-2
15	Metallized Plastic	17E-1725-2-ND	3.32	2.75	2.29	17E-1725-2
25	Metallized Plastic	17E-1726-2-ND	3.68	3.05	2.54	17E-1726-2
37	Metallized Plastic	17E-1727-2-ND	5.20	4.41	3.81	17E-1727-2
50	Metallized Plastic	17E-1728-2-ND	5.55	4.70	4.06	17E-1728-2

AWG	Plating	Digi-Key Part No.	Pricing			Amphenol Part No.
			1	10	50	
Contacts for Female						
20-24	8µ" Gold	L17-RR-D1-F-01-100-ND	.06	.49	2.11	L17-RR-D1-F-01-100
20-24	20µ" Gold	L17-RR-D1-F-02-100-ND	.08	.73	3.29	L17-RR-D1-F-02-100
24-28	8µ" Gold	L17-RR-D2-F-01-100-ND	.06	.54	2.31	L17-RR-D2-F-01-100
24-28	20µ" Gold	L17-RR-D2-F-02-100-ND	.08	.73	3.29	L17-RR-D2-F-02-100
Contacts for Male						
20-24	8µ" Gold	L17-RR-D1-M-01-100-ND	.06	.49	2.11	L17-RR-D1-M-01-100
20-24	20µ" Gold	L17-RR-D1-M-02-100-ND	.08	.69	3.06	L17-RR-D1-M-02-100
24-28	8µ" Gold	L17-RR-D2-M-01-100-ND	.06	.53	2.27	L17-RR-D2-M-01-100
Crimp Tools						
Insert/Extraction for 17RR			L17D438SP-ND	25.07	—	L17D438SP
Crimper for 17RR 20-28AWG			L17D440SP-ND	329.30	—	L17D440SP

Description	Digi-Key Part No.	Pricing			Amphenol Part No.
		1	10	50	
Dustcovers and Boot					
Dustcover for MRJ Gray	MRJ-2586-10BP-ND	.85	6.54	27.72	MRJ-2586-10BP
Dustcover for MRJ Black	MRJ-2586-20BP-ND	1.00	7.77	32.92	MRJ-2586-20BP
Boot for MRJ Plug and Cable	MRJ-258E-11BP-ND	1.35	11.23	46.78	MRJ-258E-11BP
Dustcover for MUSB Type A Black	MUSB-2A111-024BP-ND	1.15	9.54	39.76	MUSB-2A111-024BP
Dustcover for MUSB Type A Gray	MUSB2A11104BP-ND	1.19	9.92	41.32	MUSB2A11104BP
Dustcover for MUSB Type B	MUSB2D11004BP-ND	.92	7.16	30.32	MUSB2D11004BP
Dustcover for Mini USB	MUSB2E151005BP-ND	1.00	7.77	32.92	MUSB2E151005BP
Dustcover for Mini USB Black	MUSB2E151015BP-ND	1.00	7.77	32.92	MUSB2E151015BP
Dust Cap Gray	FRJ2411-ND	.34	2.11	7.03	FRJ2411

Filtered D-Sub Connectors

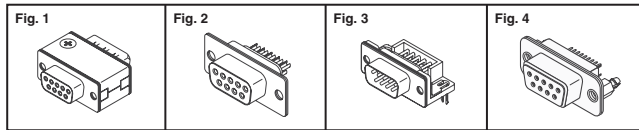


Fig.	Digi-Key Part No.	Price Each			Amphenol Part No.
		1	10	50	
1	FCE17-A15AD-250-ND	11.68	11.30	10.52	FCE17-A15AD-250
	FCE17-B25AD-250-ND	13.91	13.45	12.52	FCE17-B25AD-250
	FCE17-E09AD-250-ND	10.38	9.77	8.86	FCE17-E09AD-250
2	FCE17-A15PM-250-ND	7.43	6.88	6.17	FCE17-A15PM-250
	FCE17-A15PM-450-ND	8.57	7.93	7.11	FCE17-A15PM-450
	FCE17-A15SM-250-ND	7.53	6.97	6.25	FCE17-A15SM-250
	FCE17-B25PM-250-ND	9.00	8.48	7.68	FCE17-B25PM-250
	FCE17-B25PM-450-ND	9.97	9.38	8.51	FCE17-B25PM-450
	FCE17-B25SM-250-ND	9.13	8.60	7.79	FCE17-B25SM-250
	FCE17-B25SM-290-ND	9.13	8.60	7.79	FCE17-B25SM-290
	FCE17-B25SM-450-ND	10.10	9.51	8.62	FCE17-B25SM-450
	FCE17-E09PM-250-ND	6.09	5.56	4.77	FCE17-E09PM-250

Fig.	Digi-Key Part No.	Price Each			Amphenol Part No.
		1	10	50	
2	FCE17-E09PM-450-ND	7.39	6.76	5.79	FCE17-E09PM-450
	FCE17-E09SM-250-ND	6.20	5.67	4.86	FCE17-E09SM-250
	FCE17-E09SM-2E0-ND	5.91	5.40	4.63	FCE17-E09SM-2E0
	FCE17-E09SM-450-ND	7.51	6.86	5.88	FCE17-E09SM-450
	FCE17-A15PA-450-ND	8.09	7.49	6.72	FCE17-A15PA-450
3	FCE17-A15PB-440-ND	7.90	7.31	6.56	FCE17-A15PB-440
	FCE17-A15SA-450-ND	8.05	7.45	6.69	FCE17-A15SA-450
	FCE17-A15SB-440-ND	7.87	7.29	6.54	FCE17-A15SB-440
	FCE17E09PB440-ND	6.33	5.86	5.26	FCE17E09PB440
	FCE17-B25PA-450-ND	8.85	8.33	7.55	FCE17-B25PA-450
	FCE17-B25SA-450-ND	11.65	10.97	9.94	FCE17-B25SA-450
	FCE17-E09SB-440-ND	7.28	6.66	5.71	FCE17-E09SB-440
	FCE17-E09PA-450-ND	7.32	6.68	5.73	FCE17-E09PA-450
	FCE17E09SA450-ND	7.32	6.68	5.73	FCE17E09SA450
	FCE17-A15SE-450-ND	9.01	8.34	7.48	FCE17-A15SE-450
4	FCE17-B25SE-450-ND	10.01	9.43	8.55	FCE17-B25SE-450
	FCE17-E09SE-450-ND	7.28	6.74	6.04	FCE17-E09SE-450

MicroRibbon Solder Cup


 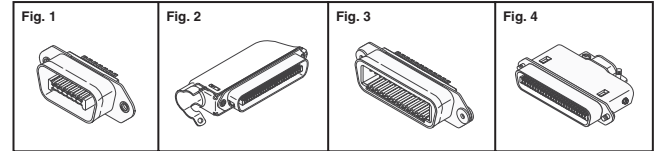


Fig.	Position	Digi-Key Part No.	Price Each			Amphenol Part No.
			1	10	50	
1	14	5710140-ND	4.71	3.90	3.25	5710140
2	50	571050014-ND	7.66	7.00	6.00	571050014
	50	57205007-ND	7.32	6.77	6.08	57205007
	50	157825003-ND	7.73	7.06	6.05	157825003
3	24	5720240-ND	5.73	4.85	4.19	5720240
4	36	5730360-ND	7.49	6.84	5.87	5730360
	50	5730500-ND	7.15	6.62	5.94	5730500
	50	57335001-ND	7.46	6.82	5.84	57335001

MicroPierce IDC



Position	Plating	Digi-Key Part No.	Price Each			Amphenol Part No.
			1	10	50	
10	—	8428001206030-ND	.70	.49	.38	8428001206030
10	30µ" Gold	8428121022134-ND	1.49	1.25	1.04	8428121022134
14	20µ" Gold	5730140-ND	5.86	5.36	4.60	5730140
14	—	8428001206031-ND	.63	.44	.34	8428001206031
14	30µ" Gold	8428121422134-ND	1.65	1.38	1.15	8428121422134
16	30µ" Gold	8428121622134-ND	1.73	1.45	1.21	8428121622134
20	—	8428001206033-ND	.70	.49	.38	8428001206033
20	30µ" Gold	8428122022134-ND	1.91	1.59	1.33	8428122022134
24	20µ" Gold	5730240-ND	6.73	6.15	5.27	5730240
26	—	8428001206034-ND	.73	.52	.40	8428001206034
26	30µ" Gold	8428122622134-ND	2.22	1.84	1.54	8428122622134
30	30µ" Gold	8428123022134-ND	2.15	1.79	1.49	8428123022134
30	30µ" Gold	8428123422134-ND	2.25	1.87	1.56	8428123422134
40	—	8428001206036-ND	.77	.54	.42	8428001206036
40	30µ" Gold	8428124022134-ND	2.61	2.17	1.81	8428124022134
50	20µ" Gold	15732500-ND	7.59	6.93	5.94	15732500
50	20µ" Gold	1573250010-ND	7.48	6.83	5.86	1573250010
50	20µ" Gold	157725003-ND	7.59	6.93	5.94	157725003
50	—	8428001206037-ND	1.27	1.06	.88	8428001206037
50	30µ" Gold	8428125022134-ND	3.04	2.52	2.10	8428125022134

Series 812/816 Protected Headers



Position	Digi-Key Part No.	Pricing			Amphenol Part No.
		1	10	50	
Key					
Key	8428001211002-ND	.58	3.62	12.06	8428001211002
Latches					
Short Latch	8428001607005-ND	.52	3.64	14.04	8428001607005
Long Latch	8428001607006-ND	.59	3.62	12.06	8428001607006
Headers					
20	8428162030035-ND	2.72	22.46	93.56	8428162030035
50	8428165030035-ND	4.99	41.25	171.87	8428165030035

Free shipping on orders over £50! All prices are in British pound sterling and include duties.