



"1206" (3216) SMD High Temperature Fuses 0437 and 0469 Series (Cont.)

Table with columns: Amp Rate, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (3,000)

"1206" (3216) SMD Nano2® Inrush Withstand Fuses 0458 Series

Specifications: • Maximum Voltage Rating: 63V • Operating Temperature: -55°C - 125°C • Materials: Body: Ceramic; Cap: Gold Plated Brass • Interrupting Rating: 50A @ 63VDC

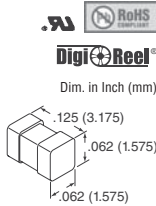


Table with columns: Amp Rate, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (1,500)

"1206" (3216) SlimLine™ SMD Thin-Film Fuses 0466 and 0468 Series

Features: • Complies with electronic industry environmental standards for lead reduction • Product is compatible with lead-free solders and higher temperature profiles • Element covering material is resistant to industry standard cleaning operations

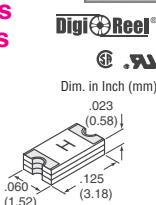


Table with columns: Amp Rate, Marking Code, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (5,000)

Table with columns: Amp Rate, Marking Code, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (5,000)

Table with columns: Amp Rate, Marking Code, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (3,000)

• 466-KIT-ND Digi-Key® 466 Series Fuse Very Fast Acting Slimline™ Lead Free 10 each of parts indicated, plus a plastic storage box 78.75

"1206" (3216) SMD High Current Fuses 0501 Series

Specifications: • Voltage Rating: 24V • Operating Temperature: -55°C - 150°C • Materials: Body: Advanced Ceramic; Terminations: Gold/Nickel/Tin • Element Cover Coating: Lead-Free Glass • Interrupting Rating: 150A @ 24VDC


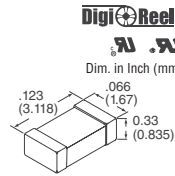


Table with columns: Amp Rate, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (3,000)

SMD Nano2® Fuse with Omni-Blok® Fuse Block 0154(T) Series

 The Omni-Blok® Fuseholder permits quick and easy replacement of Nano2® surface mount fuses. The fuse block and pre-installed fuse combination can be placed on the PC board in one efficient manufacturing operation.



Specifications: • Voltage Rating: 125V • Ambient Temperature: -55°C - 125°C • Molded Parts: Thermoplastic (UL94V-0) • Packaging: 16mm wide Tape and Reel per EIA Standard 481

Note: Installed fuses have silver plated end caps, installed to accommodate solder reflow process. Use 451 Series Fast Acting Fuse with tin/lead alloy plated end caps for replacement purposes of the 154 Series product. Use 452 Series Slo-Blo® Fuse with tin/lead alloy plated end caps for replacement purposes of the 154xxxT Series.


Table with columns: Amp Rate, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (1,500)

Table with columns: Amp Rate, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (1,500)

• 154-KIT-ND Digi-Key® 154 Series Fuseblock with Fuse Fast Acting and Slo-Blo® Surface Mount Nano2® 5 each of parts indicated, plus a plastic storage box 103.15

SMD Nano2® Fuses 0451, 0452, 0453 and 0454 Series

 Nano2® Surface Mount Fuses incorporate proven Picofuse performance and dependability in a flat top design which permits efficient pick and place assembly.



Specifications:

• Voltage Rating: 125V; (65V for part numbers F2592, F2593, F3142 and F3341) • Operating Temperature Range: -55°C - 125°C • Materials: Body: Ceramic; Terminations: (451/452 series) Gold-plated caps (453/454 series) Silver-plated caps

Note: See data sheet for detailed Amperage Safety Approvals.

Table with columns: Amp Rate, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (1,000)

Table with columns: Amp Rate, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (1,000)

Table with columns: Amp Rate, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (1,000)

Table with columns: Amp Rate, Digi-Key Part No., Cut Tape Price Each (1, 10, 100), Digi-Key Part No., Tape & Reel Pricing (1,000)

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

Free shipping on orders over £50! All prices are in British pound sterling and include duties.

2156 (UK2011-EN) www.digikey.co.uk — FREEPHONE: 0-800-587-0991 • 0-800-904-7786 — FREEFAX: 0-800-587-0992 • 0-800-904-7783