




Expertise Applied | Answers Delivered

SMD Nano²⁰ Fuses with Clip Assembly — 0157(T) Series



Specifications:

- Operating Temperature: -55°C ~ 125°C
- Construction Materials: Body: Ceramic Cap: 157 Series: (0.125A) Gold Plated Brass, (0.250A - 10A) Silver Plated Brass Cap: 157T Series: (0.375A - 5A) Silver Plated Brass
- Clip Plating: Matte Tin • Interrupting Rating: (0.125A - 8A) 50A @ 125VAC/VDC, 300A @ 32VDC (10A) 35A @ 125VAC, 50A @ 125VDC, 300A @ 32VDC

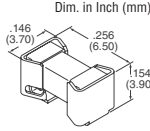


Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each 1 10	Digi-Key Part No.	T&R Pricing 1,500
0157 Series — Very Fast Acting					
0.125	125	F2958CT-ND	2.31 2.13	F2958TR-ND	894.32/M
0.250	125	F2959CT-ND	2.20 2.03	F2959TR-ND	851.12/M
0.500	125	F2960CT-ND	2.20 2.03	F2960TR-ND	851.12/M
1.00	125	F2962CT-ND	1.87 1.72	F2962TR-ND	722.49/M
1.50	125	F2963CT-ND	1.87 1.72	F2963TR-ND	722.49/M
2.00	125	F2964CT-ND	1.87 1.72	F2964TR-ND	722.49/M
2.50	125	F2965CT-ND	1.87 1.72	F2965TR-ND	722.49/M
3.00	125	F2966CT-ND	1.87 1.72	F2966TR-ND	722.49/M
3.50	125	F2967CT-ND	1.87 1.72	F2967TR-ND	722.49/M
4.00	125	F2968CT-ND	1.87 1.72	F2968TR-ND	722.49/M
5.00	125	F2969CT-ND	1.87 1.72	F2969TR-ND	722.49/M
6.30	125	F2970CT-ND	1.87 1.72	F2970TR-ND	722.49/M
7.00	125	F2971CT-ND	1.87 1.72	F2971TR-ND	722.49/M
8.00	125	F2972CT-ND	1.87 1.72	F2972TR-ND	722.49/M
10.00	125	F2973CT-ND	2.00 1.84	F2973TR-ND	772.74/M
0157T Series — Slo-Blo®					
0.375	125	F2974CT-ND	2.74 2.53	F2974TR-ND	1062.13/M
0.500	125	F2975CT-ND	2.74 2.53	F2975TR-ND	1062.13/M
1.00	125	F2977CT-ND	2.42 2.23	F2977TR-ND	934.52/M
1.50	125	F2978CT-ND	2.42 2.23	F2978TR-ND	934.52/M
2.00	125	F2979CT-ND	2.42 2.23	F2979TR-ND	934.52/M
2.50	125	F2980CT-ND	2.42 2.23	F2980TR-ND	934.52/M
3.00	125	F2981CT-ND	2.42 2.23	F2981TR-ND	934.52/M
3.50	125	F2982CT-ND	2.42 2.23	F2982TR-ND	934.52/M
4.00	125	F2983CT-ND	2.42 2.23	F2983TR-ND	934.52/M
5.00	125	F2984CT-ND	2.42 2.23	F2984TR-ND	934.52/M

SMD Nano²⁰ 250V Fuses with Clip Assembly — 0160 Series




- Operating Temperature: -55°C ~ 125°C
- Materials: Body: Ceramic, Cap: Silver Plated Brass
- Interrupting Rating: 50A @ 250VAC

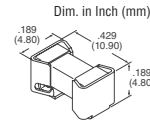

Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each 1 10	Digi-Key Part No.	T&R Pricing 1,000
0160 Series — Slo-Blo®					
0.500	250	F3558CT-ND	2.62 2.42	F3558TR-ND	1013.89
0.750	250	F3559CT-ND	2.62 2.42	F3559TR-ND	1013.89
1.00	250	F3560CT-ND	2.62 2.42	F3560TR-ND	1013.89
1.50	250	F3561CT-ND	2.62 2.42	F3561TR-ND	1013.89
2.00	250	F3562CT-ND	2.62 2.42	F3562TR-ND	1013.89
2.50	250	F3563CT-ND	2.62 2.42	F3563TR-ND	1013.89
3.00	250	F3564CT-ND	2.62 2.42	F3564TR-ND	1013.89
3.50	250	F3565CT-ND	2.62 2.42	F3565TR-ND	1013.89
4.00	250	F3566CT-ND	2.62 2.42	F3566TR-ND	1013.89
5.00	250	F3567CT-ND	2.62 2.42	F3567TR-ND	1013.89

 SMD Nano²⁰ 250V Fuses 0443 Series




- Operating Temperature: -55°C ~ 125°C
- Construction Materials: Body: Ceramic, Cap: Silver Plated Brass
- Interrupting Rating: 50A @ 250VAC

Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each 1 10	Digi-Key Part No.	T&R Pricing 1,500
0443 Series — Slo-Blo®					
.500	250	F2904CT-ND	1.12 1.04	F2904TR-ND	435.10/M
.750	250	F2905CT-ND	1.12 1.04	F2905TR-ND	435.10/M

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each 1 10	Digi-Key Part No.	T&R Pricing 1,500
1.00	250	F2906CT-ND	1.12 1.04	F2906TR-ND	435.10/M
1.50	250	F2907CT-ND	1.12 1.04	F2907TR-ND	435.10/M
2.00	250	F2908CT-ND	1.12 1.04	F2908TR-ND	435.10/M
2.50	250	F2909CT-ND	1.12 1.04	F2909TR-ND	435.10/M
3.00	250	F2910CT-ND	1.12 1.04	F2910TR-ND	435.10/M
3.50	250	F2911CT-ND	1.12 1.04	F2911TR-ND	435.10/M
4.00	250	F2912CT-ND	1.12 1.04	F2912TR-ND	435.10/M
5.00	250	F2913CT-ND	1.09 1.01	F2913TR-ND	422.04/M

SMD Nano²⁰ High Current Fuses 0456 Series

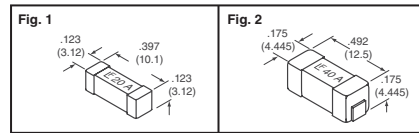

- Operating Temperature: -55°C ~ 125°C with proper derating
- Materials: Body: Ceramic, Cap: Silver Plated Brass
- Interrupting Rating: (20A - 30A) 100A @ 125VAC; (40A) 600A @ 60VDC

Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each 1 10	Digi-Key Part No.	T&R Pricing 2,500
Fig. 1 — 0456 Series					
20	125	F3344CT-ND	3.66 3.37	F3344TR-ND	1335.82/M
30	125	F3345CT-ND	3.37 3.11	F3345TR-ND	1233.29/M


Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each 1 10	Digi-Key Part No.	T&R Pricing 1,500
Fig. 2 — 0456 Series					
40	60	F3364CT-ND	4.18 3.85	F3364TR-ND	1614.80/M

Axial PICO^{II} Pico Fuses 0251 Series



Specifications:

- Operating Temperature: -55°C ~ 125°C
- Construction Materials: Body: UL94V-0 epoxy coating, green
- Materials: Pure tin coated copper wire leads
- Interrupting Ratings: 300VDC, 50A VAC

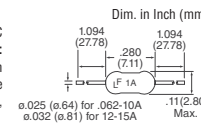

Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Price Each 1 10 100
0251 Series — Very Fast Acting (Bulk)			
.062	125	F2307-ND	.82 .77 .58
.125	125	F2308-ND	.52 .49 .37
.250	125	F2309-ND	.52 .49 .37
.375	125	F2310-ND	.52 .49 .37
.500	125	F2311-ND	.44 .41 .31
.630	125	F2312-ND	.44 .41 .31
.750	125	F2353-ND	.44 .41 .31
1.00	125	F2313-ND	.44 .41 .31
1.25	125	F2323-ND	.44 .41 .31
1.50	125	F2319-ND	.44 .41 .31
2.00	125	F2314-ND	.44 .41 .31
2.50	125	F2321-ND	.44 .41 .31
3.00	125	F2315-ND	.44 .41 .31
3.50	125	F2322-ND	.44 .41 .31
4.00	125	F2316-ND	.44 .41 .31
5.00	125	F2317-ND	.44 .41 .31
7.00	125	F2318-ND	.44 .41 .31
10.00	125	F2320-ND	.44 .41 .31
12.00	32	F2351-ND	.59 .55 .41
15.00	32	F2352-ND	.59 .55 .41

Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each 1 10	Digi-Key Part No.	T&R Pricing 1,000
0251 Series — Very Fast Acting					
.250	125	F3165CT-ND	62 .58	F3165TR-ND	242.17
.375	125	F3166CT-ND	62 .58	F3166TR-ND	242.17
.500	125	F3167CT-ND	52 .48	F3167TR-ND	200.97
.750	125	F3168CT-ND	52 .48	F3168TR-ND	200.97
1.00	125	F3169CT-ND	52 .48	F3169TR-ND	200.97
1.50	125	F3170CT-ND	52 .48	F3170TR-ND	200.97
2.00	125	F3171CT-ND	52 .48	F3171TR-ND	200.97
3.00	125	F3172CT-ND	52 .48	F3172TR-ND	200.97
4.00	125	F3173CT-ND	52 .48	F3173TR-ND	200.97
5.00	125	F3174CT-ND	52 .48	F3174TR-ND	200.97


Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each 1 10	Digi-Key Part No.	T&R Pricing 1,000
7.00	125	F3175CT-ND	.52 .48	F3175TR-ND	200.97
10.00	125	F3176CT-ND	.52 .48	F3176TR-ND	200.97
15.00	32	F3177CT-ND	.71 .65	F3177TR-ND	272.31

• 251L-473L-KIT-ND Digi-Key® 251 Series Fuse Very Fast Acting and 473 Series Fuse Slo-Blo® Axial Pico II™ 5 each of parts indicated, plastic storage box not included..... 72.82

Axial PICO^{II} Pico Fuses 0473L Series



 - Operating Temperature: -55°C ~ 125°C
- Construction Materials: Body: UL94V0 epoxy coating, Gold; Leads: Solder coated Copper wire



Note: See data sheet for detailed Amperage Safety Approvals.


Amp Rating	Voltage Rating	Digi-Key Part No.	Cut Tape Price Each 1 10	Digi-Key Part No.	T&R Pricing 1,000
0473L Series — Slo-Blo®					
.375	125	F2338CT-ND	1.66 1.52	F2338TR-ND	639.08
.500	125	F2339CT-ND	1.66 1.52	F2339TR-ND	639.08
.750	125	F2340CT-ND	1.66 1.52	F2340TR-ND	639.08
1.00	125	F2341CT-ND	1.66 1.52	F2341TR-ND	639.08
1.50	125	F2347CT-ND	1.66 1.52	F2347TR-ND	639.08
2.00	125	F2342CT-ND	1.66 1.52	F2342TR-ND	639.08
2.50	125	F2348CT-ND	1.66 1.52	F2348TR-ND	639.08
3.00	125	F2343CT-ND	1.66 1.52	F2343TR-ND	639.08
3.50	125	F2349CT-ND	1.66 1.52	F2349TR-ND	639.08
4.00	125	F2344CT-ND	1.66 1.52	F2344TR-ND	639.08
5.00	125	F2345CT-ND	1.66 1.52	F2345TR-ND	639.08
7.00	125	F2346CT-ND	1.66 1.52	F2346TR-ND	639.08

• 251L-473L-KIT-ND Digi-Key® 251 Series Fuse Very Fast Acting and 473 Series Fuse Slo-Blo® Axial Pico II™ 5 each of parts indicated, plastic storage box not included..... 72.82

Axial PICO^{II} 250V Pico Fuses 0263L Series



 - Operating Temperature: -55°C ~ 125°C
- Materials: Encapsulated epoxy-coated Body; Pure tin coated copper leads; Green in color
- Interrupting Rating: 50A @ 250VAC




Note: See data sheet for detailed Amperage Safety Approvals.

Amp Rating	Voltage Rating	Digi-Key Part No.	Price Each 1 10 100
0263L Series — Very Fast Acting			
.062	250	F2324-ND	1.84 1.70 1.28
.125	250	F2325-ND	1.46 1.36 1.02
.250	250	F2326-ND	1.46 1.36 1.02
.375	250	F2327-ND	1.46 1.36 1.02
.500	250	F2328-ND	1.46 1.36 1.02
.750	250	F2329-ND	1.21 1.12 .84
1.00	250	F2330-ND	1.21 1.12 .84
1.50	250	F2335-ND	1.21 1.12 .84
2.00	250	F2331-ND	1.21 1.12 .84
2.50	250	F2336-ND	1.21 1.12 .84
3.00	250	F2332-ND	1.21 1.12 .84
3.50	250	F2337-ND	1.21 1.12 .84
4.00	250	F2333-ND	1.21 1.12 .84
5.00	250	F2334-ND	1.21 1.12 .84

Axial PICO^{II} CCC Approved Fuses 0316 Series



 - Operating Temperature: -55°C ~ 125°C
- Materials: Body: Ceramic; Leads: Tin Coated Copper
- Encapsulated: Epoxy-Coated body
- Interrupting Rating: 50A @ 125VAC, 50A @ 125VDC



Note: See data sheet for detailed Am