

Fig.	Length Feet (Meters)	Lines	Description	Digi-Key Part No.	1	Price Each 10	25	Assmann Part No.
11	6.56 (2)	9	2x D-Sub 9-Pin Male to Female	AE1379-ND	4.49	3.95	3.54	AK131-2-R
	9.84 (3)			AE9871-ND	5.61	4.93	4.42	AK178-3-R
	6.56 (2)			AE9872-ND	5.56	4.89	4.38	AK152-2-R
	9.84 (3)			AE9873-ND	5.85	5.14	4.61	AK182-3-R
VGA Monitor Extension Cable - IBM PS/2 — RoHS Compliant								
12	6.56 (2)	—	2x HD D-Sub 15-Pin Male to Female	AE1380-ND	6.19	5.45	4.88	AK322-2-R
VGA Monitor Cable - IBM PS/2 — RoHS Compliant								
—	6.56 (2)	—	2x HD D-Sub 15 Pin Male to Male	AE10183-ND	6.06	5.33	4.78	AK532-2-R
Molded VGA to 5 x BNC, Monitor Cable — RoHS Compliant								
—	6.56 (2)	—	HD D-Sub 15-Pin Male to 5 x BNC Male	AE1381-ND	18.38	16.15	14.48	AK553-2-R
Molded Premium VGA Monitor Extension Cable — RoHS Compliant								
13	5.90 (1.8)	—	HD D-Sub 15-Pin Male to HD D-Sub 15-Pin Female	AE9874-ND	10.04	8.83	7.91	AK3220-1.8-R
IBM PC-XT/AT Keyboard Extension								
14	16.40 (5)	5	5-Pin Standard DIN Male to Female	AE10261-ND◆	9.32	8.19	7.35	AK307-5-R
Molded PS/2 Keyboard Extension — RoHS Compliant								
15	6.56 (2)	6	6-Pin MiniDIN Male to Female, Spiral	AE10177-ND	5.66	4.97	4.46	AK323-2-R
	16.40 (5)			AE10262-ND	10.23	8.99	8.06	AK528-5-R
16	6.56 (2)	6	MiniDIN 6-Pin Male to MiniDIN 6-Pin Female, Straight	AE9875-ND	3.00	2.64	2.36	AK323G-2-R
PS/2 Keyboard Cable - Straight — RoHS Compliant								
17	6.56 (2)	6	MiniDIN 6-Pin Male to MiniDIN 6-Pin Male, Molded	AE9876-ND	3.33	2.93	2.63	AK678-2-R
PC Modem (AT Adapter Cable) — RoHS Compliant								
18	.82 (.25)	9	D-Sub 9-Pin Female to D-Sub 25-Pin Male D-Sub 9-Pin Female to D-Sub 25-Pin Male	AE9879-ND	2.80	2.47	2.21	AK128-25-R
	6.56 (2)			AE9877-ND	4.41	3.88	3.48	AK125-2-R
Modem Cables — RoHS Compliant								
18	9.84 (3)	9	D-Sub 9-Pin Female to D-Sub 25-Pin Male D-Sub 9-Pin Female to D-Sub 25-Pin Female	AE9878-ND	5.92	5.21	4.67	AK149-3-R
				AE1383-ND	5.90	5.18	4.65	AK124-3-R
Null Modem, Cross-Cables — RoHS Compliant								
19	9.84 (3)	9	D-Sub 9-Pin Female to D-Sub 9-Pin Female D-Sub 9-Pin Male to D-Sub 9-Pin Female	AE9879-ND	6.06	5.33	4.78	AK143-3-R
				AE9880-ND	5.86	5.15	4.62	AK142-3-R
Null Modem, Serial Cables								
20	9.84 (3)	25	D-Sub 25-Pin Female to D-Sub 25-Pin Female D-Sub 25-Pin Female to D-Sub 25-Pin Female D-Sub 25-Pin Male to D-Sub 25-Pin Male D-Sub 25-Pin Female to D-Sub 25-Pin Female	AE1035-ND	3.19	2.80	2.52	AK144-3
				AE1384-ND◆	5.49	4.83	4.33	AK144-3-R
				AE1385-ND◆	7.67	6.75	6.05	AK250-3-R
				AE1386-ND◆	5.51	4.85	4.35	AK251-3-R
PS/2 Keyboard Adapters								
21	—	—	1 x MiniDIN, 6-Pin Female to 1 x DIN 5-Pin Male 1 x MiniDIN, 6-Pin Female to 1 x DIN 5-Pin Male 1 x MiniDIN, 6-Pin Male to DIN 5-Pin Female	AE1046-ND	2.85	2.51	2.25	AB961
				AE1387-ND◆	2.93	2.58	2.31	AB961-R
				AE1047-ND	2.21	1.94	1.74	AB440
D-Sub Adapters — RoHS Compliant								
22	—	—	9-Pin Male to 25-Pin Male 9-Pin Female to 25-Pin Male 9-Pin Male to 25-Pin Female	AE1389-ND	3.64	3.20	2.87	AB913-R
				AE9881-ND	3.26	2.87	2.58	AB914-R
				AE9882-ND	2.87	2.53	2.27	AB914-F-R
PS/2 Mouse Adapters								
23	—	—	1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Female 1 x MiniDIN, 6-Pin Female to 1 x D-Sub 25-Pin Female	AE1156-ND	1.49	1.31	1.18	AB406
				AE1056-ND	5.27	4.64	4.16	AB441
PS/2 Mouse-Cable Adapters								
24	.5 (.15)	—	1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Male 1 x MiniDIN, 6-Pin Male to 1 x D-Sub 9-Pin Female 1 x MiniDIN, 6-Pin Male to 1 x D-Sub 9-Pin Male 1 x MiniDIN, 6-Pin Female to 1 x D-Sub 9-Pin Female	AE1154-ND	1.49	1.31	1.18	AB401K
				AE1393-ND◆	2.32	2.05	1.84	AB450K-R
				AE1155-ND	1.49	1.31	1.18	AB405K
				AE1157-ND	1.49	1.31	1.18	AB406K
Jumper Box — RoHS Compliant								
25	—	—	1 x Male, 1 x Female, 25-Pin, Plastic 1 x Male, 1 x Female, 25-Pin, Metallized	AE10180-ND	9.66	8.49	7.61	AB972-R
				AE10182-ND	9.27	8.15	7.31	AB973-R

◆ RoHS Compliant

(Continued)

Free shipping on orders over £50! All prices are in British pound sterling and include duties.

uk.digikey.com — FREEPHONE: 0-800-587-0991 • 0-800-904-7786 — FREEFAX: 0-800-587-0992 • 0-800-904-7783

A

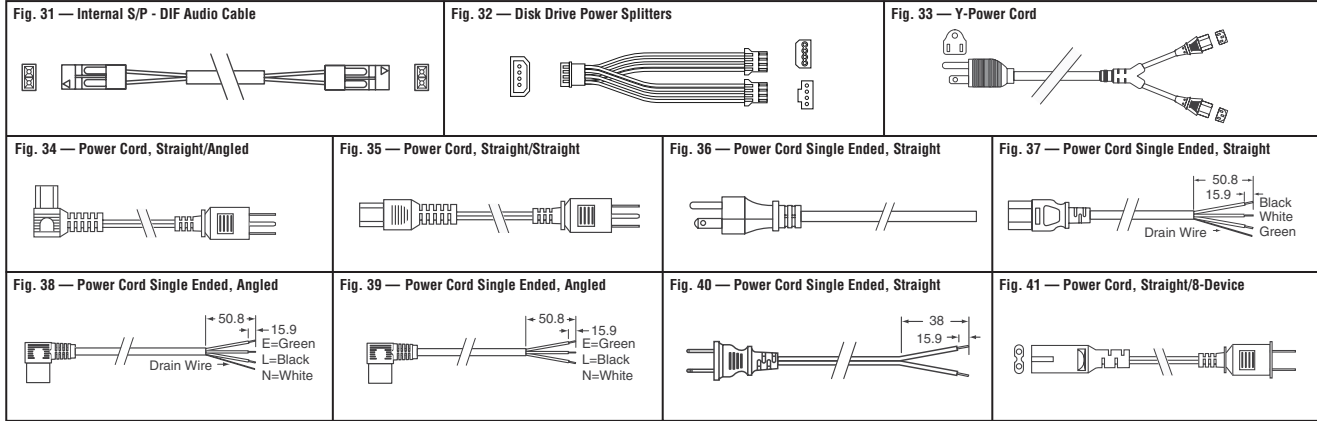


Fig.	Length Feet (Meters)	Lines	Description	Digi-Key Part No.	1	Price Each 10	25	Assmann Part No.
D-Sub/RS 232 Adapters — RoHS Compliant								
26	—	—	D-Sub 9-Pin Male to D-Sub 25-Pin Male	AE10291-ND	4.31	3.79	3.40	AB467-R
			D-Sub 9-Pin Male to D-Sub 25-Pin Female	AE10292-ND	3.77	3.32	2.97	AB468-R
			D-Sub 9-Pin Female to D-Sub 25-Pin Female	AE10293-ND	3.77	3.32	2.97	AB469-R
			D-Sub 9-Pin Female to D-Sub 25-Pin Male	AE10294-ND	3.50	3.08	2.76	AB470-R
Gender Changers — RoHS Compliant								
27	—	—	D-Sub 9 Position Male to Male	AE10295-ND	2.97	2.62	2.35	AB410-R
			D-Sub 9 Position Female to Female	AE10296-ND	2.97	2.62	2.35	AB411-R
			D-Sub 15 Position Male to Male	AE10297-ND	2.97	2.62	2.35	AB412-R
			D-Sub 15 Position Female to Female	AE10298-ND	3.09	2.72	2.44	AB413-R
			D-Sub 25 Position Male to Male	AE10299-ND	3.09	2.72	2.44	AB414-R
			D-Sub 25 Position Female to Female	AE10300-ND	3.24	2.85	2.55	AB415-R
			D-Sub HD 15 Position Male to Male	AE10301-ND	3.77	3.32	2.97	AB418-R
			D-Sub HD 15 Position Female to Female	AE10302-ND	3.77	3.32	2.97	AB420-R
D-Sub/RJ Adapters (Beige) — RoHS Compliant								
28	—	—	9 Position Male RJ12 Jack	AE10307-ND	3.91	3.44	3.08	AT-23064-R
			9 Position Female RJ12 Jack	AE10308-ND	3.91	3.44	3.08	AT-23065-R
			9 Position Male RJ45 Jack	AE10309-ND	3.91	3.44	3.08	AT-23066-R
			9 Position Female RJ45 Jack	AE10310-ND	3.91	3.44	3.08	AT-23067-R
			25 Position Male RJ12 Jack	AE10303-ND	4.17	3.67	3.29	AT-23052-R
			25 Position Female RJ12 Jack	AE10304-ND	4.17	3.67	3.29	AT-23053-R
			25 Position Male RJ45 Jack	AE10305-ND	4.17	3.67	3.29	AT-23054-R
			25 Position Female RJ45 Jack	AE10306-ND	4.17	3.67	3.29	AT-23055-R
Power Splitter Cables								
29	1.64 (0.5)	—	Audio CD-ROM 4 Position 3 Wire	AE1396-ND	1.34	1.18	1.06	AK2525-R
30	1.64 (0.5)	—	Audio CD-ROM 4 Position 3 Wire	AE1397-ND	1.34	1.18	1.06	AK2524-R
31	1.64 (0.5)	—	Internal Cable 2-Pin Housing/Housing	AE9884-ND	1.68	1.48	1.33	AK2526DVD-R
32	.66 (.2)	4	Power Cable for 2 - 5 1/4" Drives	AE9885-ND	1.85	1.63	1.46	AK319-2-R
			Power Cable for 2 - 3 1/2" Drives	AE1398-ND	2.13	1.88	1.68	AK520-2-R
			Power Cable for 3 1/2" and 5 1/4" Drives	AE1399-ND	2.13	1.88	1.69	AK521-2-R
Y-Power Cord — RoHS Compliant								
33	6.56 (2)	—	1 x Power Plug to 2 x Straight Connector, 10A, 125V	AE9886-ND	13.84	12.17	10.92	AK500/Y-U-R
Power Cords								
34	6.56 (2)	—	Power Plug, Straight to IEC Connector, Angled, 10A, 125V	AE9887-ND	6.42	5.65	5.06	AK500/U-1-R
35	6.56 (2)	—	Power Plug, Straight to IEC Connector, Straight, 10A, 125V	AE9888-ND	6.47	5.69	5.10	AK500/U-2-R
36	6.56 (2)	—	Cord SVT 18AWG 3 Cond Shielded	AE9889-ND	6.18	5.44	4.87	AK500-OE-5-2-R
	9.84 (3)		Cord SVT 18AWG 3 Cond Shielded	AE9890-ND	8.57	7.54	6.76	AK500-OE-5-3-R
	6.56 (2)		Cord SJT 18AWG 3 Cond Shielded	AE9891-ND	6.37	5.60	5.03	AK500-OE-6-2-R
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE9892-ND	8.96	7.88	7.06	AK500-OE-6-3-R
	6.56 (2)		Cord SVT 18AWG 3 Cond Shielded	AE9893-ND	6.06	5.33	4.78	AK500-OE-7-2-R
37	6.56 (2)	—	Cord SJT 18AWG 3 Cond Shielded	AE9895-ND	6.40	5.63	5.04	AK500-OE-9-2-R
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE1339-ND	4.55	4.00	3.59	AK500-OE-9-3
	9.84 (3)		Cord SJT 18AWG 3 Cond Shielded	AE9896-ND	10.16	8.93	8.01	AK500-OE-9-3-R
38	6.56 (2)	—	Cord SJT 18AWG 3 Cond Shielded	AE1331-ND	3.30	2.91	2.61	AK500-RA-5-2
	6.56 (2)		Cord SJT 18AWG 3 Cond Shielded	AE9897-ND	6.35	5.58	5.01	AK500-RA-5-2-R
39	6.56 (2)	—	Cord SVT 18AWG 3 Cond	AE1333-ND	4.09	3.60	3.23	AK500-RA-6-2
	6.56 (2)		Cord SVT 18AWG 3 Cond	AE9899-ND	4.98	4.38	3.93	AK500-RA-6-2-R
	6.56 (2)		Cord SJT 18AWG 3 Cond	AE9900-ND	5.68	4.99	4.48	AK500-RA-7-2-R
	9.84 (3)		Cord SJT 18AWG 3 Cond	AE1335-ND	4.44	3.91	3.50	AK500-RA-7-3
40	6 (1.83)	—	Cord SPT-1 18AWG 2 Cond	AE9902-ND	4.02	3.54	3.18	AK500-OE-12-6F-R
	8.99 (2.74)		Cord SPT-1 18AWG 2 Cond	AE9903-ND	5.70	5.02	4.50	AK500-OE-12-9F-R
	6 (1.83)		Cord SPT-2 18AWG 2 Cond	AE9904-ND	4.17	3.67	3.29	AK500-OE-13-6F-R
	8 (2.44)		Cord SPT-2 18AWG 2 Cond	AE1348-ND	2.34	2.06	1.85	AK500-OE-13-8F
41	6.56 (2)	—	Power Plug, Straight to Figure 8 Device Connector, Straight	AE1123-ND	2.12	1.87	1.67	AK500/U-3
	6.56 (2)		Power Plug, Straight to Figure 8 Device Connector, Straight	AE9906-ND	5.08	4.47	4.01	AK500/U-3-R
Power Cord Extension								
42	6.56 (2)	—	IEC Plug, Straight to IEC Socket, Straight, 10A, 125V	AE9854-ND	8.00	7.04	6.31	AK500/U-4-R
	3.28 (1)		Cord SJT 18AWG 3 Cond Shielded	AE1336-ND	2.58	2.27	2.04	AK500-JC-5-1
	3.28 (1)		Cord SJT 18AWG 3 Cond Shielded	AE9908-ND	7.67	6.74	6.05	AK500-JC-5-1-R

◆ RoHS Compliant

(Continued)

Free shipping on orders over £50! All prices are in British pound sterling and include duties.