


HP = Half Pitch

A

Fig.	Length Meters	Lines	Description	Digi-Key Part No.	Price Each 1 10 25	Assmann Part No.
FAST SCSI 2 to SCSI 2 Cable, Shielded, UL 2919 — RoHS Compliant						
1	0.90 2.0	50	HP D-sub 50, HP D-sub, Male Clip to HP D-sub 50, HP D-sub, Male, Clip	AE1428-ND AE1429-ND	19.92 17.51 15.70 21.54 19.59 17.63	AK579/F-1-R AK579/F-2-R
SCSI-2 Series, Round Cable						
2	0.91	50	HP D-sub 50 Male to Centronic 50 Male, A Cable	AE1069-ND	12.05 10.59 9.50	AK-Y1202
SCSI-3 Series, Round Cable						
3	0.91	68	HP D-sub 68 Male X 2, A Cable	AE1430-ND	20.55 18.68 16.81	AK-Y1301-R
4	0.91	50	HP D-sub 68 Male to Centronic 50 Male, A Cable	AE1071-ND	13.75 12.09 10.84	AK-Y1302
SCSI-3 Series, Flat Cable						
5	0.45	68	.635mm HP D-sub 68 Male X 2, P Cable	AE1489-ND	12.68 11.15 10.00	AK-Y2301-R
6	1.6	68	.635mm HP D-sub 68 Female X 2 to .635mm HP D-sub 68 Male X 8	AE1079-ND	30.62 28.26 26.29	AK-Y2310
Hard Drive Cable for 2 x IDE / AT Bus Hard Drives — RoHS Compliant						
7	0.5	40	(3) 40 Pin Socket Connectors	AE10263-ND	3.45 3.04 2.72	AK5430-5-R
Ultra ATA Flat Cable — RoHS Compliant						
8	0.46	40	Ultra ATA HDD 100Mbps	AE10184-ND	4.02 3.54 3.18	AK-ATA-100-R
Serial ATA Cables — RoHS Compliant						
9	0.3 0.5 0.75 1.0	7	Serial ATA Cable	AE10077-ND AE10079-ND AE10081-ND AE10083-ND	2.57 2.27 2.03 2.49 2.19 1.97 3.00 2.64 2.36 3.02 2.66 2.38	AK-SATA-030-R AK-SATA-050-R AK-SATA-075-R AK-SATA-100-R
10	0.3 0.5 0.75	7	Serial ATA Cable Right Angle	AE10078-ND AE10080-ND AE10082-ND	2.57 2.27 2.03 2.49 2.19 1.97 3.00 2.64 2.36	AK-SATA-030DL-R AK-SATA-050DL-R AK-SATA-075DL-R
11	0.5 0.75 1.0	7	Serial ATA Cable 4-Pos. Power Connector	AE10084-ND AE10085-ND AE10086-ND	4.79 4.22 3.78 5.10 4.49 4.03 5.35 4.71 4.22	AK-SATA-SP-050-R AK-SATA-SP-075-R AK-SATA-SP-100-R
12	0.15	4	Power Supply Cable 15-Pos. - 4-Pos.	AE10087-ND	2.16 1.90 1.70	AK-SATA-PC-015-R
HDMI / DVI Cables and Adapters — RoHS Compliant						
13	2.0 3.0 5.0	—	HDMI-A Male to HDMI-A Male Cable HDMI-A Male to HDMI-A Male Cable HDMI-A Male to HDMI-A Male Cable	AE10256-ND AE10257-ND AE10246-ND	16.27 14.30 12.82 18.55 16.87 15.18 21.97 20.28 18.86	AK627-2-R AK627-3-R AK627-5-R
14	2.0 3.0 5.0	—	HDMI-A Male to DVI-D Cable HDMI-A Male to DVI-D Cable HDMI-A Male to DVI-D Cable	AE10258-ND AE10259-ND AE10260-ND	17.66 15.52 13.92 17.47 15.89 14.30 22.11 20.40 18.98	AK639-2-R AK639-3-R AK639-5-R
—	—	—	HDMI-A Male to DVI-D 24+1, Female Adapter HDMI-A Male to DVI-D 24+1, Male Adapter HDMI-A Female to DVI-D 24+1, Female Adapter HDMI-A Female to DVI-D 24+1, Male Adapter HDMI-A Female to HDMI-A, Female Adapter HDMI-A Male to HDMI-A, Female Adapter HDMI-A Male to HDMI-A, Male Adapter	AE10249-ND AE10250-ND AE10254-ND AE10255-ND AE10251-ND AE10252-ND AE10253-ND	11.96 10.51 9.42 11.96 10.51 9.42 13.16 11.57 10.38 11.96 10.51 9.42 11.96 10.51 9.42 13.16 11.57 10.38 11.96 10.51 9.42	AB556-R AB557-R AB566-R AB567-R AB566-R AB561-R AB562-R
IEEE 1394 Cable Double Shielded						
15	1.8 3.0 5.0	6	6-Pin Male to 6-Pin Male	AE1432-ND AE1433-ND AE1434-ND	10.96 9.63 8.64 13.56 11.92 10.69 16.73 15.44 14.37	AK-1394-18-R AK-1394-30-R AK-1394-50-R
16	1.8 3.0 5.0	4	6-Pin Male to 4-Pin Male	AE1435-ND AE1436-ND AE1437-ND	10.13 8.91 7.99 10.88 9.90 8.91 15.28 14.10 13.12	AK-1394-184-R AK-1394-304-R AK-1394-504-R
17	1.8 1.8 5.0	4	4-Pin Male to 4-Pin Male	AE1127-ND AE1438-ND AE1133-ND	16.97 15.43 13.89 8.67 7.88 7.09 21.08 19.45 18.10	AK-1394-1844-R AK-1394-1844-R AK-1394-5044
IEEE 1394 and USB Connectors — RoHS Compliant						
18	—	—	IEEE 1394 Recept Horizontal SMT	AE9920-ND	2.06 1.82 1.63	A-IE-S-SMT-R
19	—	—	IEEE 1394 Recept Horizontal PCB	AE9921-ND	1.97 1.74 1.56	A-IE-S-DIP-R
20	—	—	IEEE 1394 Recept Vertical PCB	AE9922-ND	1.97 1.74 1.56	A-IE-E-DIP-R
21	—	4	USB 4P Recept Thru-hole, Type A USB 4P Recept SMT, Type A	AE9923-ND AE9924-ND	.62 .55 .50 .73 .64 .58	AU-Y1005-R AU-Y1006-R
22	—	4	USB 4P Recept Thru-hole, Type B	AE9925-ND	.79 .70 .63	AU-Y1007-R
23	—	4	USB 4P Recept Dual Port, Type A	AE9926-ND	1.10 .98 .88	AU-Y1008-R
USB Plugs and Hoods — RoHS Compliant						
24	—	—	USB A-Male, Solder Version Hood for USB A Male Hood for USB B Male USB B-Male, Solder Version	AE10091-ND AE10090-ND AE1441-ND AE10178-ND	.33 .29 .26 .30 .27 .24 .30 .27 .24 .33 .29 .26	A-USBPA-R A-USBPA-HOOD-R A-USBPB-HOOD-R A-USBPB-R
USB Cables						
25	1.0 2.0 5.0	4	Cable Mini USB 4-Pin Male	AE1442-ND AE1443-ND AE1283-ND	3.34 2.94 2.64 4.09 3.60 3.23 3.17 2.78 2.50	AK670M-1-R AK670M-2-R AK670M-5
25	1.0 2.0 3.0 5.0	4	Cable Mini USB 2.0, 4-Pin Male	AE1444-ND AE1445-ND AE1446-ND AE1447-ND	3.76 3.31 2.97 4.53 3.98 3.57 5.57 4.90 4.39 7.83 6.89 6.18	AK670M/2-1-R AK670M/2-2-R AK670M/2-3-R AK670M/2-5-R
26	1.0 2.0 3.0 5.0	4	Cable Mini USB 5-Pin Male	AE1448-ND AE9927-ND AE9928-ND AE1449-ND	4.33 3.82 3.42 4.70 4.13 3.71 4.79 4.22 3.78 6.80 5.98 5.37	AK672M-1-R AK672M-2-R AK672M-3-R AK672M-5-R
26	1.0 2.0 3.0 5.0	4	Cable Mini USB 2.0, 5-Pin Male	AE1450-ND AE9929-ND AE1451-ND AE1452-ND	2.49 1.78 1.69 3.59 2.57 2.44 4.35 3.11 2.96 6.32 5.55 4.98	AK672M/2-1-R AK672M/2-2-R AK672M/2-3-R AK672M/2-5-R
27	1.0 2.0	4	Cable Mini USB, 5-Pin Female to 5-Pin Male	AE10311-ND AE10312-ND	3.98 3.50 3.14 5.87 5.16 4.63	AK669M-1-R AK669M-2-R
28	2.0 2.0 5.0	4	Cable USB A Male, Open End Cable USB A-Male Male	AE9855-ND AE9930-ND AE1453-ND	2.93 2.10 1.99 4.60 4.05 3.63 8.36 7.35 6.59	AK670-OE-R AK670/2-R AK670-5-R
29	1.0 3.0 5.0	4	Cable USB 2.0, A-A Male	AE1454-ND AE1455-ND AE1456-ND	3.43 3.02 2.70 5.87 5.16 4.63 8.46 7.44 6.67	AK670/2-1-R AK670/2-3-R AK670/2-5-R

◆ RoHS Compliant

(Continued)

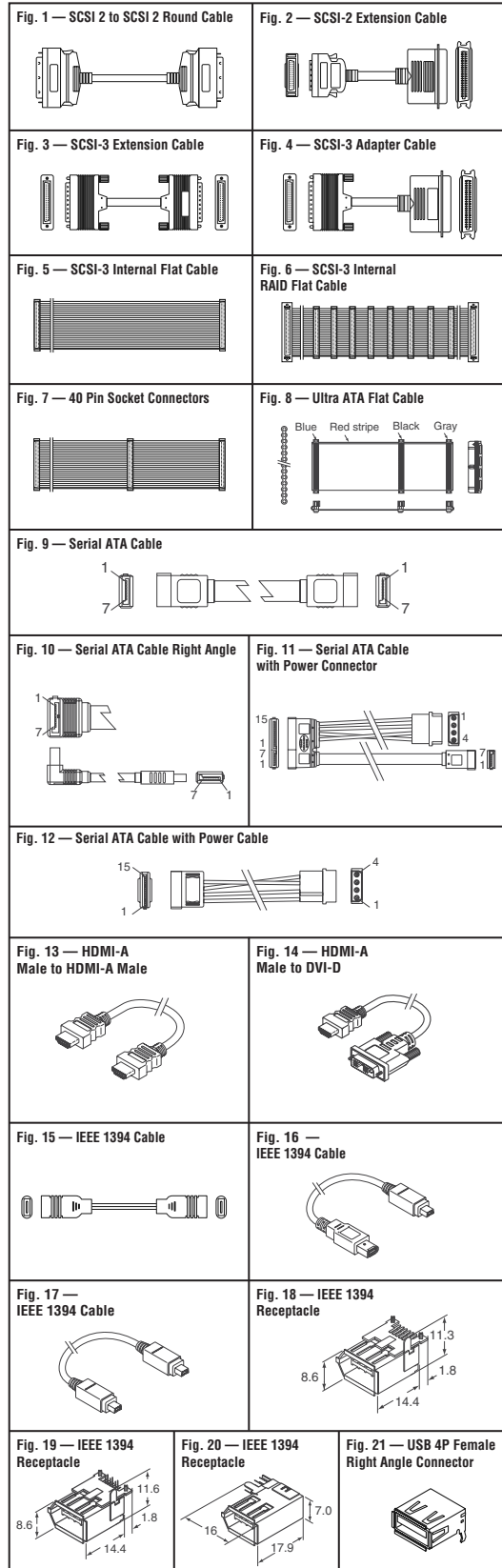

Free shipping on orders over £50! All prices are in British pound sterling and include duties.

58 (UK091)

uk.digikey.com — FREEPHONE: 0-800-587-0991 • 0-800-904-7786 — FREEFAX: 0-800-587-0992 • 0-800-904-7783