



BergStik™ .100" (2.54mm) Headers (Cont.)



Fig.	No. of Positions	Plating	Dimensions - Inches (mm)		Digi-Key Part No.	Pricing		FCI Part No.				
			A	B								
3	16	100µ" Tin	0.230 (5.84)	0.120 (3.05)	609-3398-ND	3.79	63.03	67997-416HLF				
	20				609-3399-ND	.70	8.97	67997-420HLF				
	24				609-3245-ND	.71	9.30	67997-424HLF				
	26				609-3246-ND	.76	9.85	67997-426HLF				
	32				609-3247-ND	.86	12.12	67997-432HLF				
	32				609-2221-ND	.89	12.12	67997-472HLF				
	4				30µ" Gold	0.230 (5.84)	0.150 (3.81)	609-3361-ND	.90	12.66	68602-104HLF	
8	609-3362-ND	.30	3.62	68602-108HLF								
12	609-3363-ND	.36	4.28	68602-112HLF								
16	609-3364-ND	.45	5.61	68602-116HLF								
20	609-3365-ND	.76	9.97	68602-120HLF								
24	609-3366-ND	.87	11.96	68602-124HLF								
26	609-3367-ND	.87	12.31	68602-126HLF								
32	609-3368-ND	.97	13.14	68602-132HLF								
3	4	15µ" Gold	0.230 (5.84)	0.150 (3.81)				609-3369-ND	.23	2.55	68602-204HLF	
	6							609-3370-ND	.30	3.62	68602-206HLF	
	8							609-3371-ND	.36	4.31	68602-208HLF	
	10				609-3372-ND	.44	5.36	68602-210HLF				
	12				609-3373-ND	.52	6.32	68602-212HLF				
	16				609-3374-ND	.67	8.39	68602-216HLF				
	20				609-3375-ND	.75	10.26	68602-220HLF				
24	609-3376-ND	.84	11.59	68602-224HLF								
26	609-3377-ND	.98	13.18	68602-226HLF								
32	609-3378-ND	1.05	14.75	68602-232HLF								
4	4	100µ" Tin	0.230 (5.84)	0.150 (3.81)	609-3379-ND	.23	2.55	68602-404HLF				
	8				609-3380-ND	.38	4.67	68602-408HLF				
	12				609-3381-ND	.52	6.32	68602-412HLF				
	16				609-3382-ND	.53	6.62	68602-416HLF				
	20				609-3383-ND	.75	10.26	68602-420HLF				
	24				609-3384-ND	.84	11.59	68602-424HLF				
	26				609-3385-ND	.76	9.86	68602-426HLF				
	32				609-3386-ND	.86	12.13	68602-432HLF				
	Right Angle Dual Row											
	4				4	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3333-ND	.22	2.49	68021-104HLF
6		609-3334-ND	.30	3.54	68021-106HLF							
8		609-3335-ND	.55	7.01	68021-108HLF							
10		609-3409-ND	1.12	15.09	68021-110HLF							
12		609-3336-ND	1.12	15.09	68021-112HLF							

Fig.	No. of Positions	Plating	Dimensions - Inches (mm)		Digi-Key Part No.	Pricing		FCI Part No.				
			A	B								
3	16	30µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3337-ND	.57	7.26	68021-116HLF				
	20				609-3338-ND	.71	9.39	68021-120HLF				
	24				609-3339-ND	.85	11.71	68021-124HLF				
	26				609-3340-ND	.81	11.19	68021-126HLF				
	32				609-3341-ND	.90	12.71	68021-132HLF				
	72				609-2228-ND	2.55	39.26	68021-172HLF				
	4				4	15µ" Gold	0.230 (5.84)	0.120 (3.05)	609-3342-ND	.22	2.51	68021-204HLF
6		609-3343-ND	.30	3.51	68021-206HLF							
8		609-3344-ND	.35	4.13	68021-208HLF							
10		609-3410-ND	.36	4.17	68021-210HLF							
12		609-3345-ND	.81	11.07	68021-212HLF							
16		609-3346-ND	.64	8.16	68021-216HLF							
20		609-3347-ND	.71	9.39	68021-220HLF							
24		609-3348-ND	.85	11.71	68021-224HLF							
26		609-3349-ND	.72	9.55	68021-226HLF							
32		609-3350-ND	1.07	14.90	68021-232HLF							
72		609-2229-ND	2.11	32.26	68021-272HLF							
5	4	30µ" Gold	0.230 (5.84)	—	609-3351-ND	.22	2.51	68021-404HLF				
	6				609-3352-ND	.30	3.51	68021-406HLF				
	8				609-3353-ND	.45	5.63	68021-408HLF				
	10				609-3354-ND	.24	2.78	68021-410HLF				
	12				609-3355-ND	.63	8.11	68021-412HLF				
	16				609-3356-ND	.76	10.35	68021-416HLF				
	20				609-3357-ND	.91	12.34	68021-420HLF				
	24				609-3358-ND	1.06	14.82	68021-424HLF				
5	4	15µ" Gold	0.230 (5.84)	—	609-3359-ND	1.13	15.28	68021-426HLF				
	6				609-3360-ND	1.07	14.90	68021-432HLF				
	8				609-2230-ND	2.53	37.29	68021-472HLF				
	Straight Dual Row SMT											
	40				30µ" Gold	0.230 (5.84)	—	609-2231-ND	.94	14.59	95157-140LF	
	40				15µ" Gold	0.230 (5.84)	—	609-2232-ND	.95	14.76	95157-240LF	
	40				Tin	0.230 (5.84)	—	609-3124-ND	.74	11.43	95157-440LF	

Fig.	Housing Color	Plating	Dimensions - Inches (mm)			Digi-Key Part No.	Pricing		FCI Part No.
			A	B	C				
Shunts									
6	White	30µ" Gold	0.236 (6.0)	0.199 (5.05)	0.098 (2.49)	609-2997-ND	.15	1.68	63429-202LF
	Blue	Tin	0.385 (9.78)	0.205 (5.21)	0.100 (2.54)	609-2215-ND	.24	2.81	65474-002LF
		30µ" Gold				609-2216-ND	.38	4.54	65474-010LF
		40µ" Gold				609-2835-ND	.44	5.47	65474-001LF
	Black	15µ" Gold	0.200 (5.08)	0.198 (5.03)	0.098 (2.49)	609-3121-ND	.15	1.66	68786-102LF
		30µ" Gold				609-2217-ND	.20	2.17	68786-202LF
		Tin				609-2218-ND	.20	2.26	68786-302LF
	Black	15µ" Gold	0.360 (9.15)	0.198 (5.03)	0.098 (2.49)	609-2462-ND	.21	2.32	71363-102LF
		30µ" Gold				609-2463-ND	.23	2.54	71363-202LF

.100" (2.54mm) PCB Mounted Receptacles

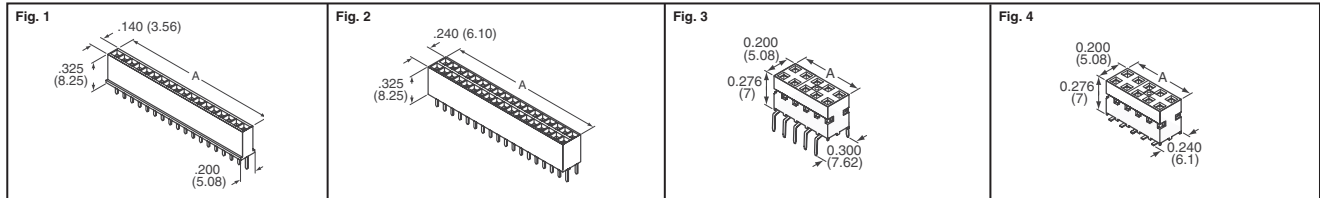


Fig.	No. of Positions	Dimension A Inch (mm)	Digi-Key Part No.	Price Each		FCI Part No.	
			1	25	100		
Vertical Single Row							
1	3	0.30 (7.62)	609-2233-ND	1.31	.67	.57	66951-003LF
	4	0.40 (10.16)	609-2234-ND	1.78	.91	.77	66951-004LF
	5	0.50 (12.70)	609-2235-ND	1.66	.95	.82	66951-005LF
	6	0.60 (15.24)	609-2236-ND	1.80	1.01	.87	66951-006LF
	7	0.70 (17.78)	609-2237-ND	1.69	.93	.79	66951-007LF
	8	0.80 (20.32)	609-2238-ND	1.85	1.03	.90	66951-008LF
	9	0.90 (22.86)	609-2239-ND	3.68	2.18	1.94	66951-009LF
	10	1.00 (25.40)	609-2240-ND	1.55	.92	.80	66951-010LF
	12	1.20 (30.48)	609-2242-ND	2.97	1.76	1.56	66951-012LF
	13	1.30 (33.02)	609-2243-ND	2.32	1.39	1.22	66951-013LF
	14	1.40 (35.56)	609-2244-ND	2.53	1.52	1.33	66951-014LF
	15	1.50 (38.10)	609-2245-ND	5.99	3.56	3.19	66951-015LF
	16	1.60 (40.64)	609-2246-ND	3.03	1.87	1.67	66951-016LF
	17	1.70 (43.18)	609-2247-ND	3.92	2.41	2.09	66951-017LF
	18	1.80 (45.72)	609-2248-ND	2.89	1.79	1.57	66951-018LF
	20	2.00 (50.80)	609-2250-ND	3.70	2.28	2.01	66951-020LF
	26	2.60 (66.04)	609-2256-ND	2.63	1.63	1.48	66951-026LF
	32	3.20 (81.28)	609-2262-ND	4.80	3.33	2.94	66951-032LF
35	3.50 (88.90)	609-2265-ND	6.93	4.61	4.14	66951-035LF	
36	3.60 (91.44)	609-2266-ND	6.00	3.83	3.50	66951-036LF	
Vertical Dual Row							
2	6	0.30 (7.62)	609-2267-ND	1.27	.71	.62	66953-003LF
	8	0.40 (10.16)	609-2268-ND	3.53	1.96	1.68	66953-004LF
	10	0.50 (12.70)	609-2269-ND	2.12	1.18	1.04	66953-005LF
	12	0.60 (15.24)	609-2270-ND	3.14	1.85	1.60	66953-006LF
	14	0.70 (17.78)	609-2271-ND	2.70	1.60	1.42	66953-007LF
	16	0.80 (20.32)	609-2272-ND	1.91	1.15	1.00	66953-008LF
	18	0.90 (22.86)	609-2273-ND	2.11	1.26	1.13	66953-009LF
	20	1.00 (25.40)	609-2274-ND	2.72	1.67	1.45	66953-010LF
	24	1.20 (30.48)	609-2276-ND	3.70	2.29	2.02	66953-012LF
	26	1.30 (33.02)	609-2277-ND	3.77	2.35	2.12	66953-013LF
	28	1.40 (35.56)	609-2278-ND	3.35	2.08	1.88	66953-014LF
	30	1.50 (38.10)	609-2279-ND	3.53	2.20	1.99	66953-015LF
	32	1.60 (40.64)	609-2280-ND	3.56	2.23	2.04	66953-016LF
	34	1.70 (43.18)	609-2281-ND	4.63	2.88	2.61	66953-017LF
	40	2.00 (50.80)	609-2284-ND	5.11	3.26	2.98	66953-020LF
	50	2.50 (63.50)	609-2289-ND	4.72	3.14	2.82	66953-025LF

Fig.	No. of Positions	Dimension A Inch (mm)	Digi-Key Part No.	Price Each		FCI Part No.	
			1	25	100		
2	60	3.00 (76.20)	609-2294-ND	4.27	2.84	2.55	66953-030LF
	64	3.20 (81.28)	609-2296-ND	9.05	6.16	5.54	66953-032LF
Vertical Dual Row - Dual Entry							
3	10	0.497 (12.62)	609-2998-ND	1.36	.81	.70	71991-305LF
	12	0.597 (15.16)	609-3035-ND	1.56	.93	.82	71991-306LF
	14	0.697 (17.70)	609-3036-ND	1.77	1.07	.93	71991-307LF
	16	0.797 (20.24)	609-3037-ND	1.96	1.17	1.05	71991-308LF
	18	0.897 (22.78)	609-2999-ND	2.11	1.29	1.12	71991-309LF
	20	0.997 (25.32)	609-3000-ND	2.29	1.42	1.25	71991-310LF
	22	1.097 (27.86)	609-3001-ND	2.45	1.52	1.34	71991-311LF
	24	1.197 (30.4)	609-3002-ND	2.58	1.61	1.46	71991-312LF
	26	1.297 (32.94)	609-3003-ND	2.80	1.74	1.58	71991-313LF
	28	1.397 (35.48)	609-3004-ND	3.01	1.88	1.70	71991-314LF
	30	1.497 (38.02)	609-3005-ND	3.11	2.01	1.79	71991-315LF
	32	1.597 (40.56)	609-3006-ND	3.33	2.08	1.90	71991-316LF
	34	1.697 (43.1)	609-3007-ND	3.54	2.21	2.02	71991-317LF
	36	1.797 (45.64)	609-3008-ND	3.33	2.08	1.91	71991-318LF
	38						