

A

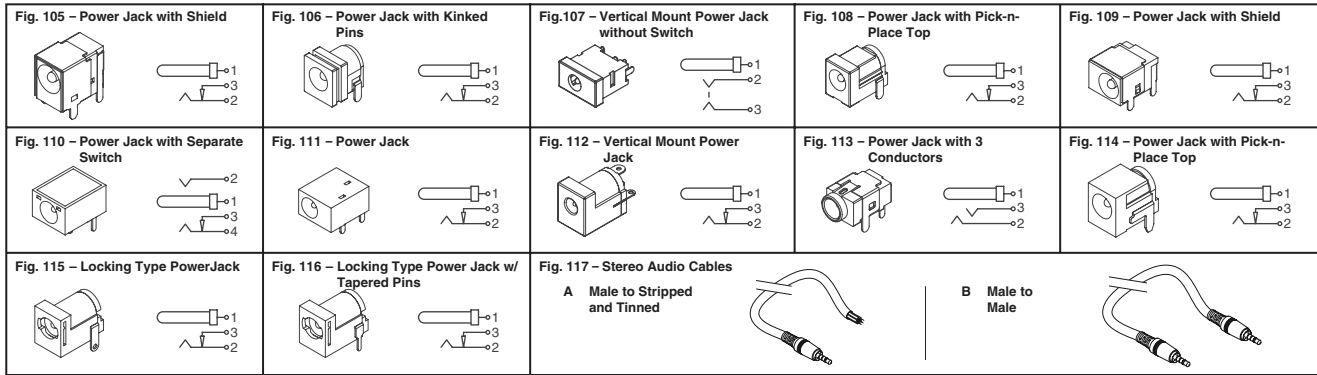


Fig.	Mates With	Dia. (mm)	Digi-Key Part No.	Price Each			CUI Inc. Part No.
				1	10	100	
105	PP3-002A	2.0	CP-047A-ND◆	.47	.41	.32	PJ-047A
	PP3-002B	2.5	CP-047B-ND◆	.47	.41	.32	PJ-047B
	PP3-002A	2.0	CP-047AH-ND◆	.50	.44	.34	PJ-047AH
	PP3-002B	2.5	CP-047BH-ND◆	.50	.44	.34	PJ-047BH
106	CA-2224 Cable Assy.	3.0	CP-048H-ND◆	.52	.45	.35	PJ-048H
107	PP-014	1.65	CP-049-ND◆	.44	.38	.30	PJ-049
108	PP3-002A	2.0	CP-050A-ND◆	.41	.36	.28	PJ-050A
	PP3-002B	2.5	CP-050B-ND◆	.41	.36	.28	PJ-050B
	PP3-002A	2.0	CP-050AH-ND◆	.44	.39	.30	PJ-050AH
	PP3-002B	2.5	CP-050BH-ND◆	.44	.39	.30	PJ-050BH
109	PP3-002A	2.0	CP-051A-ND◆	.47	.41	.32	PJ-051A
	PP3-002B	2.5	CP-051B-ND◆	.47	.41	.32	PJ-051B
	PP3-002A	2.0	CP-051AH-ND◆	.50	.44	.34	PJ-051AH
	PP3-002B	2.5	CP-051BH-ND◆	.50	.44	.34	PJ-051BH
110	PP3-002C	1.0	CP-052C-ND◆	.45	.39	.30	PJ-052C
	PP3-002D	1.3	CP-052D-ND◆	.45	.39	.30	PJ-052D
111	PP3-002C	1.0	CP-053C-ND◆	.48	.42	.32	PJ-053C
	PP3-002D	1.3	CP-053D-ND◆	.48	.42	.32	PJ-053D
	PP3-002C	1.0	CP-053CH-ND◆	.52	.45	.35	PJ-053CH
	PP3-002D	1.3	CP-053DH-ND◆	.52	.45	.35	PJ-053DH
	PP-013	1.65	CP-054-ND◆	.52	.46	.35	PJ-054

Fig.	Mates With	Dia. (mm)	Digi-Key Part No.	Price Each			CUI Inc. Part No.
				1	10	100	
112	PP3-002C	1.0	CP-055C-ND◆	.32	.28	.22	PJ-055C
	PP3-002D	1.3	CP-055D-ND◆	.32	.28	.22	PJ-055D
	PP3-002A	2.0	CP-044A-ND◆	.30	.27	.21	PJ-044A
	PP3-002B	2.5	CP-044B-ND◆	.30	.27	.21	PJ-044B
113	PP3-002A	2.0	CP-044AH-ND◆	.34	.30	.23	PJ-044AH
	PP3-002B	2.5	CP-044BH-ND◆	.34	.30	.23	PJ-044BH
114	PP-019	1.0	CP-056-ND◆	.49	.43	.33	PJ-056
115	PP3-002A	2.0	CP-057A-ND◆	.47	.41	.32	PJ-057A
	PP3-002B	2.5	CP-057B-ND◆	.47	.41	.32	PJ-057B
	PP3-002A	2.0	CP-057AH-ND◆	.51	.44	.34	PJ-057AH
	PP3-002B	2.5	CP-057BH-ND◆	.51	.44	.34	PJ-057BH
116	CA-2222 Cable Assy.	2.0	CP-058A-ND◆	.38	.33	.26	PJ-058A
	CA-2223 Cable Assy.	2.5	CP-058B-ND◆	.38	.33	.26	PJ-058B
	CA-2222 Cable Assy.	2.0	CP-058AH-ND◆	.44	.38	.29	PJ-058AH
117	CA-2223 Cable Assy.	2.5	CP-058BH-ND◆	.44	.38	.29	PJ-058BH
	CA-2222 Cable Assy.	2.0	CP-059A-ND◆	.38	.33	.26	PJ-059A
	CA-2223 Cable Assy.	2.5	CP-059B-ND◆	.39	.34	.26	PJ-059B
	CA-2222 Cable Assy.	2.0	CP-059AH-ND◆	.44	.38	.29	PJ-059AH
118	CA-2223 Cable Assy.	2.5	CP-059BH-ND◆	.44	.38	.29	PJ-059BH



Fig.	Diameter (mm)	Length Meters	Digi-Key Part No.	Price Each			CUI Inc. Part No.	Mating Jacks
				1	10	100		
<b>Cable Assembly 4 Conductor</b>								
117A	2.5	1.83	CP-254CS-ND	3.88	3.36	2.59	CA-254CS	SJ-4252X-SMT
	2.5		CP-254S-ND◆	3.77	3.27	2.52	CA-254S	SJ-4251X-SMT, SJ-4243X-SMT
	3.5		CP-354S-ND◆	4.42	3.84	2.95	CA-354S	SJ-4351X, SJ-43502PM
117B	2.5	1.83	CP-254CS-M/M-ND	4.56	3.95	3.04	CA-254CS-M/M	SJ-4252X-SMT
	2.5		CP-254S-M/M-ND◆	4.42	3.84	2.95	CA-254S-M/M	SJ-4251X-SMT, SJ-4243X-SMT, SJ-4251X
	3.5		CP-354S-M/M-ND◆	4.84	4.19	3.23	CA-354S-M/M	SJ-4351X, SJ-43502PM
<b>Cable Assembly 6 Conductor</b>								
117A	3.5	1.83	CP-356CS-ND	6.19	5.37	4.13	CA-356CS	SJ-63516
117B			CP-356CS-M/M-ND◆	9.13	7.92	6.09	CA-356CS-M/M	SJ-63516

\* Threaded with nut † Non-threaded ◆ Shielded version ◆ RoHS Compliant

## Single Ended Power Cables



Fig.	Dimensions (mm)			Wire Awg	Digi-Key Part No.	Price Each			CUI Inc. Part No.
	A	B	C			1	10	100	
1	0.7	2.35	9.5	24	CP-2192-ND	1.44	1.25	.96	CA-2192
	0.9	3.2	9.0	24	CP-2221-ND	2.81	2.44	1.88	CA-2221
	1.35	3.5	9.5	24	CP-2193-ND	1.31	1.14	.88	CA-2193
	1.7	4.0	10.0	24	CP-2194-ND	1.35	1.17	.91	CA-2194
	1.7	4.75	9.5	24	CP-2195-ND	1.35	1.17	.91	CA-2195
	2.1	5.5	12.0	18	CP-2187-ND	2.11	1.84	1.41	CA-2187
	2.1	5.5	12.0	18	CP-2222-ND*	2.90	2.52	1.94	CA-2222
	2.1	5.5	12.0	18	CP-2185-ND	1.26	1.10	.85	CA-2185
	2.5	5.5	12.0	18	CP-2186-ND	2.11	1.84	1.41	CA-2186
	2.5	5.5	12.0	18	CP-2223-ND*	2.90	2.52	1.94	CA-2223
2	2.5	5.5	12.0	24	CP-2184-ND	1.26	1.10	.85	CA-2184
	3.0	6.5	12.0	18	CP-2224-ND	2.77	2.40	1.85	CA-2224
	0.7	2.35	11.0	24	CP-2196-ND	1.39	1.21	.93	CA-2196
	1.35	3.5	10.0	24	CP-2197-ND	1.31	1.14	.88	CA-2197
	1.7	4.0	9.5	24	CP-2198-ND	1.35	1.17	.91	CA-2198
	1.7	4.75	9.5	24	CP-2199-ND	1.35	1.17	.91	CA-2199
	2.1	5.5	12.0	24	CP-2189-ND	1.26	1.10	.85	CA-2189
	2.1	5.5	10.0	18	CP-2191-ND	2.11	1.84	1.41	CA-2191
	2.5	5.5	12.0	24	CP-2188-ND	1.26	1.10	.85	CA-2188
	2.5	5.5	10.0	18	CP-2200-ND	2.11	1.84	1.41	CA-2200

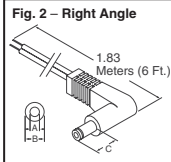
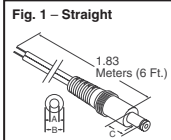


\* Twist Lock

## Single Ended Audio Cables



Fig.	Dim. (mm)		Wire Awg	Digi-Key Part No.	Price Each			CUI Inc. Part No.
	A	B			1	10	100	
<b>Mono Plug - Straight</b>								
1	2.5	11.5	24	CP-2201-ND	1.89	1.65	1.27	CA-2201
	3.5	13	24	CP-2205-ND	1.92	1.67	1.28	CA-2205
<b>Stereo Plug - Straight</b>								
1	2.5	11	24	CP-2203-ND	1.92	1.67	1.28	CA-2203
	3.5	13	24	CP-2207-ND	1.96	1.70	1.31	CA-2207
<b>Mono Plug - Right Angle</b>								
2	2.5	11.5	24	CP-2202-ND	1.89	1.65	1.27	CA-2202
	3.5	14.5	24	CP-2206-ND	1.92	1.67	1.28	CA-2206
<b>Stereo Plug - Right Angle</b>								
2	2.5	11	24	CP-2204-ND	1.92	1.67	1.28	CA-2204
	3.5	14	24	CP-2208-ND	1.96	1.70	1.31	CA-2208

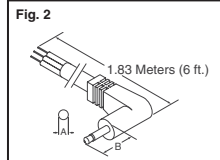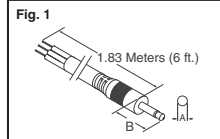

## DC Extension Cables

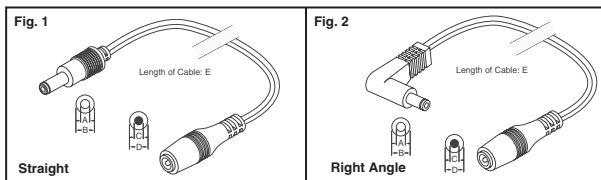


Fig.	Diameter (mm)				Length (E) Meters	Digi-Key Part No.	Price Each			CUI Inc. Part No.
	A	B	C	D			1	10	100	
1	1.35	3.50	1.35	3.50	.915	CP-2217-ND	1.94	1.68	1.30	CA-2217
	2.10	5.50	2.10	5.50	.915	CP-2216-ND	2.22	1.93	1.49	CA-2216
	2.50	5.50	2.50	5.50	.915	CP-2215-ND	2.22	1.93	1.49	CA-2215
	1.35	3.50	1.35	3.50	1.830	CP-2211-ND	2.11	1.84	1.41	CA-2211
	2.10	5.50	2.10	5.50	1.830	CP-2210-ND	2.79	2.42	1.86	CA-2210
	2.50	5.50	2.50	5.50	1.830	CP-2209-ND	2.79	2.42	1.86	CA-2209
2	1.35	3.50	1.35	3.50	.915	CP-2220-ND	1.94	1.68	1.30	CA-2220
	2.10	5.50	2.10	5.50	.915	CP-2219-ND	2.22	1.93	1.49	CA-2219
	2.50	5.50	2.50	5.50	.915	CP-2218-ND	2.22	1.93	1.49	CA-2218
	1.35	3.50	1.35	5.50	1.830	CP-2214-ND	2.11	1.84	1.41	CA-2214
	2.10	5.50	2.10	5.50	1.830	CP-2213-ND	2.79	2.42	1.86	CA-2213
	2.50	5.50	2.50	5.50	1.830	CP-2212-ND	2.79	2.42	1.86	CA-2212

Digi-Reel® Most SMT cutdown parts are available on a Digi-Reel®. For Digi-Reel part number, change 1-ND to 6-ND or CT-ND to DKR-ND. See Digi-Key® Services on page 2 for additional information.

Free shipping on orders over £50! All prices are in British pound sterling and include duties.  
 442 (UK091) uk.digikey.com — FREEPHONE: 0-800-587-0991 • 0-800-904-7786 — FREEFAX: 0-800-587-0992 • 0-800-904-7783