



压接导线 Mini-PV™ 插座体座和接头



A

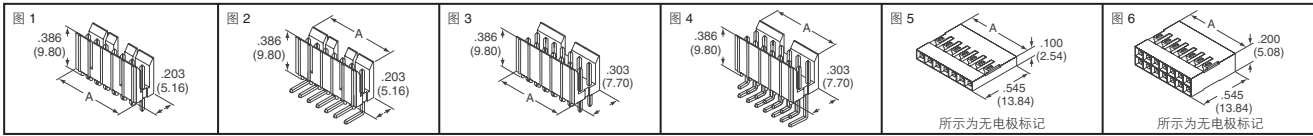


图	位置数量	尺寸 A 英寸 (mm)	Digi-Key 零件编号	1	价格 25	100	FCI 零件编号	
垂直单排接头								
1	3	0.30 (7.62)	609-2410-ND	1.20	14.44	48.12	69167-103HLF	
	4	0.40 (10.16)	609-2411-ND	1.28	16.06	54.46	69167-104HLF	
	5	0.50 (12.70)	609-2412-ND	1.24	16.46	55.61	69167-105HLF	
	6	0.60 (15.24)	609-2413-ND	1.29	17.79	59.85	69167-106HLF	
	7	0.70 (17.78)	609-2414-ND	1.52	20.51	70.31	69167-107HLF	
	8	0.80 (20.32)	609-2415-ND	1.63	21.95	75.24	69167-108HLF	
	9	0.90 (22.86)	609-2416-ND	1.69	23.31	79.92	69167-109HLF	
	10	1.00 (25.40)	609-2417-ND	1.93	26.12	91.42	69167-110HLF	
	11	1.10 (27.94)	609-2418-ND	2.15	30.65	107.28	69167-111HLF	
	12	1.20 (30.48)	609-2419-ND	1.77	24.62	86.15	69167-112HLF	
	14	1.40 (35.56)	609-2421-ND	1.91	27.34	94.60	69167-114HLF	
	15	1.50 (38.10)	609-2422-ND	2.34	32.45	112.28	69167-115HLF	
	垂直双排接头							
	2	3	0.30 (7.62)	609-2449-ND	.88	10.55	35.16	78208-103HLF
		4	0.40 (10.16)	609-2450-ND	1.11	14.15	47.99	78208-104HLF
5		0.50 (12.70)	609-2451-ND	1.29	16.92	58.44	78208-105HLF	
6		0.60 (15.24)	609-2452-ND	1.41	19.34	65.05	78208-106HLF	
7		0.70 (17.78)	609-2453-ND	1.60	21.54	73.85	78208-107HLF	
8		0.80 (20.32)	609-2454-ND	1.78	24.61	84.39	78208-108HLF	
9		0.90 (22.86)	609-2455-ND	3.57	48.26	168.89	78208-109HLF	
10		1.00 (25.40)	609-2456-ND	2.11	29.30	102.53	78208-110HLF	
12		1.20 (30.48)	609-2458-ND	1.82	24.62	85.17	78208-112HLF	
15		1.50 (38.10)	609-2461-ND	2.43	34.82	123.57	78208-115HLF	
垂直双排接头								
3		6	0.30 (7.62)	609-2423-ND	1.36	18.68	62.84	69168-106HLF
		8	0.40 (10.16)	609-2424-ND	1.78	24.61	84.38	69168-108HLF
		10	0.50 (12.70)	609-2425-ND	2.08	28.09	98.32	69168-110HLF
		12	0.60 (15.24)	609-2426-ND	1.85	25.85	88.61	69168-112HLF
	14	0.70 (17.78)	609-2427-ND	2.07	28.71	100.49	69168-114HLF	
	16	0.80 (20.32)	609-2428-ND	2.30	32.81	113.52	69168-116HLF	
	18	0.90 (22.86)	609-2429-ND	2.51	36.92	127.73	69168-118HLF	
	20	1.00 (25.40)	609-2430-ND	2.71	39.98	141.89	69168-120HLF	
	22	1.10 (27.94)	609-2431-ND	2.79	41.89	146.08	69168-122HLF	
	24	1.20 (30.48)	609-2432-ND	3.20	47.97	167.30	69168-124HLF	
	26	1.30 (33.02)	609-2433-ND	3.25	48.25	172.67	69168-126HLF	
	28	1.40 (35.56)	609-2434-ND	3.56	54.55	189.49	69168-128HLF	
	30	1.50 (38.10)	609-2435-ND	3.81	58.44	203.00	69168-130HLF	
	垂直双排接头							
	4	6	0.30 (7.62)	609-2436-ND	1.48	20.31	68.32	78207-106HLF
8		0.40 (10.16)	609-2437-ND	1.77	24.72	84.76	78207-108HLF	
10		0.50 (12.70)	609-2438-ND	1.35	18.51	62.25	78207-110HLF	
12		0.60 (15.24)	609-2439-ND	1.91	25.85	90.46	78207-112HLF	
14		0.70 (17.78)	609-2440-ND	2.07	28.71	100.49	78207-114HLF	
16		0.80 (20.32)	609-2441-ND	2.41	34.44	119.16	78207-116HLF	
20		1.00 (25.40)	609-2443-ND	2.71	39.98	141.89	78207-120HLF	
24		1.20 (30.48)	609-2445-ND	3.15	46.75	167.33	78207-124HLF	
26		1.30 (33.02)	609-2446-ND	6.57	100.65	360.23	78207-126HLF	
30		1.50 (38.10)	609-2448-ND	3.81	56.91	200.56	78207-130HLF	
单排插座，无中央电极标记								
5		1	0.10 (2.54)	609-2342-ND	.81	10.18	32.56	65039-036LF
		2	0.20 (5.08)	609-2341-ND	.95	11.39	37.98	65039-035LF
		3	0.30 (7.62)	609-2340-ND	1.03	13.02	42.32	65039-034LF
		4	0.40 (10.16)	609-2339-ND	1.28	16.46	54.95	65039-033LF
	5	0.50 (12.70)	609-2338-ND	1.22	15.26	51.55	65039-032LF	
	6	0.60 (15.24)	609-2337-ND	1.32	17.53	59.20	65039-031LF	
	7	0.70 (17.78)	609-2336-ND	1.33	17.56	59.30	65039-030LF	
	8	0.80 (20.32)	609-2335-ND	1.36	18.65	62.73	65039-029LF	
	9	0.90 (22.86)	609-2334-ND	1.47	20.15	67.77	65039-028LF	
	10	1.00 (25.40)	609-2333-ND	1.53	21.64	70.81	65039-027LF	
	11	1.10 (27.94)	609-2332-ND	1.59	23.68	73.24	65039-026LF	
	12	1.20 (30.48)	609-2331-ND	1.65	25.11	79.22	65039-025LF	
	13	1.30 (33.02)	609-2330-ND	1.71	27.07	80.75	65039-024LF	
	14	1.40 (35.56)	609-2329-ND	1.86	25.13	87.94	65039-023LF	
	15	1.50 (38.10)	609-2328-ND	2.15	29.85	104.46	65039-022LF	
	16	1.60 (40.64)	609-2327-ND	2.30	31.88	111.58	65039-021LF	
	17	1.70 (43.18)	609-2326-ND	2.34	32.55	113.93	65039-020LF	
	18	1.80 (45.72)	609-2325-ND	2.33	33.25	115.03	65039-019LF	
	20	2.00 (50.80)	609-2323-ND	2.51	36.98	127.95	65039-017LF	
	21	2.10 (53.34)	609-2322-ND	2.63	38.82	137.78	65039-016LF	
	22	2.20 (55.88)	609-2321-ND	2.38	34.10	121.01	65039-015LF	
	25	2.50 (63.50)	609-2318-ND	2.98	44.68	155.82	65039-012LF	
	32	3.20 (81.28)	609-2311-ND	3.40	52.09	180.94	65039-005LF	
	36	3.60 (91.44)	609-2307-ND	3.42	52.36	181.90	65039-001LF	
	带中央电极标记的单排插座							
	5	3	0.30 (7.62)	609-2395-ND	1.11	14.16	47.84	78211-003LF
		4	0.40 (10.16)	609-2396-ND	1.29	17.70	59.53	78211-004LF
		5	0.50 (12.70)	609-2397-ND	1.53	20.55	70.45	78211-005LF
		6	0.60 (15.24)	609-2398-ND	1.71	23.06	80.71	78211-006LF
		7	0.70 (17.78)	609-2399-ND	1.81	24.48	85.68	78211-007LF
		8	0.80 (20.32)	609-2400-ND	1.63	22.49	77.09	78211-008LF
		9	0.90 (22.86)	609-2401-ND	2.20	32.28	111.69	78211-009LF
		10	1.00 (25.40)	609-2402-ND	1.59	22.03	75.53	78211-010LF
		12	1.20 (30.48)	609-2404-ND	2.10	30.06	103.99	78211-012LF
		14	1.40 (35.56)	609-2406-ND	3.11	47.70	170.71	78211-014LF
		无中央电极标记的双排插座						
6		4	0.20 (5.08)	609-2377-ND	1.37	17.90	61.85	65043-035LF
		6	0.30 (7.62)	609-2376-ND	1.32	17.53	59.20	65043-034LF
		8	0.40 (10.16)	609-2375-ND	1.52	20.86	70.17	65043-033LF
	10	0.50 (12.70)	609-2374-ND	1.96	26.46	92.59	65043-032LF	
	12	0.60 (15.24)	609-2373-ND	.56	8.27	26.71	65043-031LF	
	14	0.70 (17.78)	609-2372-ND	2.54	37.31	129.08	65043-030LF	
	16	0.80 (20.32)	609-2371-ND	2.34	32.56	113.94	65043-029LF	
	18	0.90 (22.86)	609-2370-ND	2.81	40.35	143.17	65043-028LF	
	20	1.00 (25.40)	609-2369-ND	2.99	44.87	156.49	65043-027LF	
	22	1.10 (27.94)	609-2368-ND	3.31	49.58	172.91	65043-026LF	

图	位置数量	尺寸 A 英寸 (mm)	Digi-Key 零件编号	1	价格 25	100	FCI 零件编号
6	24	1.20 (30.48)	609-2367-ND	3.38	50.23	179.78	65043-025LF
	26	1.30 (33.02)	609-2366-ND	3.45	52.85	189.14	65043-024LF
	28	1.40 (35.56)	609-2365-ND	3.62	55.42	198.34	65043-023LF
	30	1.50 (38.10)	609-2364-ND	3.91	59.93	208.16	65043-022LF
	32	1.60 (40.64)	609-2363-ND	3.40	52.09	180.94	65043-021LF
	34	1.70 (43.18)	609-2362-ND	3.42	52.41	182.04	65043-020LF
	36	1.80 (45.72)	609-2361-ND	3.51	53.76	186.75	65043-019LF
	40	2.00 (50.80)	609-2359-ND	3.86	59.51	209.73	65043-017LF
	44	2.20 (55.88)	609-2357-ND	4.07	62.72	221.06	65043-015LF
	46	2.30 (58.24)	609-2356-ND	3.65	56.24	198.19	65043-014LF
	48	2.40 (60.96)	609-2355-ND	4.18	64.83	234.82	65043-013LF
	50	2.50 (63.50)	609-2354-ND	4.11	63.32	223.15	65043-012LF
	54	2.70 (68.58)	609-2352-ND	4.70	72.94	264.19	65043-010LF
	58	2.90 (73.66)	609-2350-ND	4.33	67.19	243.36	65043-008LF
	64	3.20 (81.28)	609-2347-ND	5.12	82.35	292.82	65043-005LF
72	3.60 (91.44)	609-2343-ND	4.99	77.41	280.41	65043-001LF	
带中央电极标记的双排插座							
6	4	0.20 (5.08)	609-2379-ND	1.88	26.35	90.34	69176-004LF
	6	0.30 (7.62)	609-2380-ND	2.01	27.13	94.94	69176-006LF
	8	0.40 (10.16)	609-2381-ND	2.30	31.88	111.58	69176-008LF
	10	0.50 (12.70)	609-2382-ND	2.47	35.27	122.03	69176-010LF
	12	0.60 (15.24)	609-2383-ND	2.72	39.01	138.45	69176-012LF
	14	0.70 (17.78)	609-2384-ND	2.95	43.65	154.90	69176-014LF
	16	0.80 (20.32)	609-2385-ND	3.09	46.30	161.45	69176-016LF
	18	0.90 (22.86)	609-2386-ND	3.26	48.94	170.65	69176-018LF
	20	1.00 (25.40)	609-2387-ND	3.45	52.84	189.13	69176-020LF
	22	1.10 (27.94)	609-2388-ND	3.70	56.70	196.94	69176-022LF
	24	1.20 (30.48)	609-2389-ND	3.87	59.28	205.92	69176-024LF
	26	1.30 (33.02)	609-2390-ND	4.04	61.86	214.90	69176-026LF
	28	1.40 (35.56)	609-2391-ND	4.23	65.25	229.96	69176-028LF
	30	1.50 (38.10)	609-2392-ND	4.40	67.77	238.83	69176-030LF
	6	0.300 (7.62)	609-3547-ND	1.96	27.26	95.41	65846-015LF
8	0.400 (10.16)	609-3548-ND	2.01	27.97	97.90	65846-016LF	
10	0.500 (12.70)	609-3532-ND	2.23	32.86	113.68	65846-010LF	
12	0.600 (15.24)	609-3533-ND	2.42	34.76	123.35	65846-017LF	
14	0.700 (17.78)	609-3534-ND	2.64	39.59	138.02	65846-007LF	
16	0.800 (20.32)	609-3535-ND	2.91	43.64	152.17	65846-011LF	
18	0.900 (22.86)	609-3536-ND	2.86	42.99	149.57	65846-008LF	
20	1.000 (25.40)	609-3537-ND	3.09	45.84	164.05	65846-006LF	
24	1.200 (30.48)	609-3538-ND	3.56	54.48	189.24	65846-001LF	
26	1.300 (33.02)	609-3539-ND	3.94	60.72	213.99	65846-019LF	
30	1.500 (38.10)	609-3540-ND	3.90	60.15	212.00	65846-002LF	
34	1.700 (43.18)	609-3541-ND	4.34	67.33	243.90	65846-022LF	
38	1.900 (48.26)	609-3542-ND	4.66	72.38	262.17	65846-003LF	
40	2.000 (50.80)	609-35					